

# MULTIOUTLET USB CHARGING

Plugmold® Multioutlet Systems are now available with multiple USB charging options that provide power and USB charging options for any application.

Choose from models with a single USB charging module and power receptacles, one with alternating USB charging modules and power receptacles, or an all USB charging module version.

Included tamper-resistant receptacles provide safety for multi-user facilities, residential living spaces and kitchens. Designed to easily mount on wall surfaces, the low-profile design is aesthetically pleasing and available in 3', 5' and 6' lengths in a variety of colors and finishes. Alternating USB/PWR available in 5' lengths only.


## FEATURES & BENEFITS

- **USB Charging** - Dual-port charging modules share 2.4 amps of charging capacity and can charge multiple phones, tablets or other mobile devices at the same time.
- **Tamper-resistant receptacles** - Prevents the insertion of foreign objects into receptacles reducing the risk of shocks or electrocution. Meets 2014 NEC section 406 requirements.
- **Multiple colors and finishes** - Choose from black or ivory ScuffCoat, white or gray painted enamel, or durable stainless steel finishes.
- **Compact design.** Low-profile design installs in tight locations while offering multiple power and USB charging connections. Receptacle spacing accommodates bulky AC adapters.

Plugmold with USB Module		
Part Number	Length	Finish
AL20GB306TRUSB	36" [914mm]	Anodized Aluminum
AL20GB506TRUSB	60" [1.5m]	Anodized Aluminum
BK20GB306TRUSB	36" [914mm]	Black Painted
BK20GB506TRUSB	60" [1.5m]	Black Painted
BK20GB606TRUSB	72" [1.8m]	Black Painted
G20GB306TRUSB	36" [914mm]	Gray Painted
G20GB506TRUSB	60" [1.5m]	Gray Painted
G20GB606TRUSB	72" [1.8m]	Gray Painted
S20GB306TRUSB	36" [914mm]	Stainless Steel
S20GB506TRUSB	60" [1.5m]	Stainless Steel
S20GB606TRUSB	72" [1.8m]	Stainless Steel
V20GB306TRUSB	36" [914mm]	Ivory Painted
V20GB506TRUSB	60" [1.5m]	Ivory Painted
V20GB606TRUSB	72" [1.8m]	Ivory Painted
WH20GB306TRUSB	36" [914mm]	White Painted
WH20GB506TRUSB	60" [1.5m]	White Painted
WH20GB606TRUSB	72" [1.8m]	White Painted

All USB Plugmold			
Part Number	Length	Finish	# of Modules
AL20USB312	36" [914mm]	Anodized Aluminum	3
AL20USB512	60" [1.5m]	Anodized Aluminum	5
BK20USB312	36" [914mm]	Painted Black	3
BK20USB512	60" [1.5m]	Painted Black	5
G20USB312	36" [914mm]	Painted Gray	3
G20USB512	60" [1.5m]	Painted Gray	5
S20USB312	36" [914mm]	Stainless Steel	3
S20USB512	60" [1.5m]	Stainless Steel	5
V20USB312	36" [914mm]	Painted Ivory	3
V20USB512	60" [1.5m]	Painted Ivory	5
WH20USB312	36" [914mm]	Painted White	3
WH20USB512	60" [1.5m]	Painted White	5

Alternating USB-Power Receptacle Plugmold			
Part Number	Length	Finish	# of Modules
AL20GB509TRUSBA	60" [1.5m]	Anodized Aluminum	3 Outlets & 3 USB Modules
BK20GB509TRUSBA	60" [1.5m]	Black Painted	3 Outlets & 3 USB Modules
G20GB509TRUSBA	60" [1.5m]	Gray Painted	3 Outlets & 3 USB Modules
S20GB509TRUSBA	60" [1.5m]	Stainless Steel	3 Outlets & 3 USB Modules
V20GB509TRUSBA	60" [1.5m]	Ivory Painted	3 Outlets & 3 USB Modules
WH20GB509TRUSBA	60" [1.5m]	White Painted	3 Outlets & 3 USB Modules

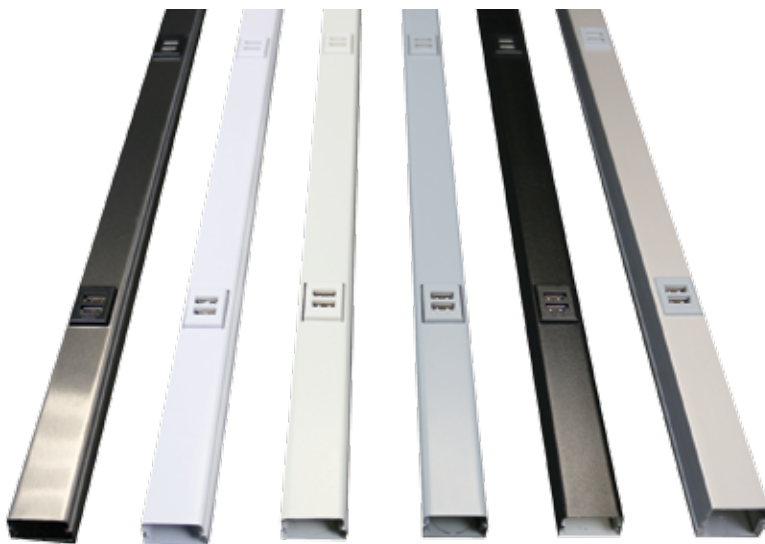

©2014 Legrand All Rights Reserved ED1700R5 1214

designed to be better.™



**Electrical Wiring Systems**

60 Woodlawn Street  
West Hartford, CT 06110  
1.877.BY.LEGRAND (295.3472)  
www.legrand.us

570 Applewood Crescent  
Vaughan, Ontario L4K 4B4  
905.738.9195  
www.legrand.ca

FOLLOW US

