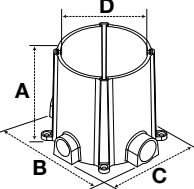


## Flush Round Single or Multi-Service Non-Metallic Floor Boxes, for Use In Concrete Floors

### Dimensions Inches (mm)

|                                                                                  |                                                                                                        |
|----------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------|
|  | <br><b>PFB1</b>       |
| Min. Depth of Pour                                                               | 3.00" (76.2)                                                                                           |
| Capacity                                                                         | 100 cubic inches prior to cutting level to floor (19.5 cubic inches per inch of depth).                |
| Dimensions – A                                                                   | 6.00" (152.4)                                                                                          |
| Dimensions – B                                                                   | 7.08" (179.8)                                                                                          |
| Dimensions – C                                                                   | 6.69" (169.9)                                                                                          |
| Dimensions – D                                                                   | 5.38" (136.5)                                                                                          |
| Hubs                                                                             | (2) 1.0" and (2) ¾" conduit hubs                                                                       |
| Concrete Cover Included                                                          | ✓                                                                                                      |
| Closure/Reducer Plugs                                                            | (2) 1" plugs close off 1" hubs or reduce 1" to ¾"<br>(2) ¾" plugs close off ¾" hubs or reduce ¾" to ½" |

Note: UL File Number E92074, CSA File Number LR18416.

| Description                                                                                                                                                                                                                 | Catalog Number                                                                                         |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------|
| <b>Adapter</b><br>Required for all applications.                                                                                                                                                                            | <br><b>PFBA1A</b>   |
| <b>Low Voltage Divider</b><br>Required for use with catalog number <b>PFB1</b> when used in multi-service applications. Accepts Hubbell standard duplex receptacles or 15A Twist-Lock® duplex receptacles (HBL4700 series). | <br><b>PFBT1A</b>   |
| <b>"Y" Adapter</b><br>¾ in. "Y" adapter to feed parallel runs of ¾ in. conduit.                                                                                                                                             | <br><b>PFBYA1</b>   |
| Pre-pour PVC stand increases <b>PFB1</b> box height 2.5 in. to 4.0 in. within the concrete pour.                                                                                                                            | <br><b>PFBSTAND</b> |

### Flush Round Covers and Flanges

#### Multi-Service Cover and Flange Assemblies

Includes floor box cover with duplex flaps, (2) ½ in. dia. low voltage feed through holes and matching carpet flange. 6.25 in. Diameter

**SF39253A**



Brass

**PFBCBRA**



Brown  
Non-Metallic

**PFBCBLA**



Black  
Non-Metallic

**PFBCGYA**



Gray  
Non-Metallic

**PFBCIA**



Ivory  
Non-Metallic

### Single Service Covers

Brass  
Aluminum  
3.88 in. Dia.

**S3925**  
**SA3925**



Duplex  
Flap

**S3725**  
**SA3725**



Duplex  
Screw

**S2525**  
**SA2525**



2½" x ¾"  
Combination

**S2725**  
**SA2725**



2½" x 1"  
Combination

**S2925**  
**SA2925**



2½" Single  
Receptacle

**S3525**  
—



2½" Single  
Receptacle

**S3325**  
—



2½" Single  
Receptacle  
(Terrazzo Floor)

### Metal Carpet Flange

Use with single service covers for carpet applications. 6.25 in. Diameter

**S3082**



Brass

**SA3082**



Brushed Aluminum

### Adapter Ring

Use with single service covers for tile applications.

**S5016**



Brass

**SA5016**



Aluminum

### Furniture Feed Plate

Unpainted plate with 1 in. threaded opening.

**PFBP1**



Steel

### One Piece Brass Cover and Carpet Flange

Brass  
Aluminum  
6.25 in. Dia.

**SF3925**  
**SFA3925**



Duplex  
Flap

**SF2525**  
—



2½" x ¾"  
Combination

**SF2725**  
—



2½" x 1"  
Combination

**SF2925**  
—



2½" Single  
Receptacle

Note: Adapter ring S5016 is required for mounting SF series covers onto PFBA1A.

Dimensions in Inches (mm)