

KNIPEX-CoBolt Compact Bolt Cutters



Now even more
versatile and
comfortable



New variants:

- ▶ 20° angled head for almost flush cutting
- ▶ very slim dual component handles
- ▶ integrated opening spring with comfortable locking device

NEW

KNIPEX Quality – Made in Germany

KNIPEX-CoBolt Compact Bolt Cutters



71 22 200

Easy cutting of bolts, nails and rivets up to 5.2 mm diameter



20° angled head for flush cutting

The new CoBolt version with angled head and newly designed joint construction now also allows almost flush cutting. The handles, which now run at an angle to the cutting blades, also offer ample space for gripping.

Very slim dual component handles

The dual component handles are now slimmer in total. In particular the slimmer collar makes it easier to handle the CoBolt. The contact surface at the end of the handle is wider than before, allowing a better distribution of pressure, which makes work more pleasant.


Integrated opening spring with comfortable locking device

The opening spring always presses the pliers into the hand gently; the effort needed to hold the pliers is considerably reduced. For secure transport the pliers can be locked with a spring clip.

- ▶ with precision cutting edges for soft, hard and piano wire
- ▶ cuts material like bolts, nails, rivets, etc. up to 5.2 mm diameter
- ▶ exceptional cutting performance with minimum effort because of highly effective lever action design
- ▶ cutting edges additionally induction hardened, cutting edge hardness approx. 64 HRC
- ▶ forged
- ▶ high performance Chrome Vanadium steel, oil-hardened and tempered

Cut with model 71 21 200:
nearly flush surface

Cut with model 71 01 200:
protruding residue

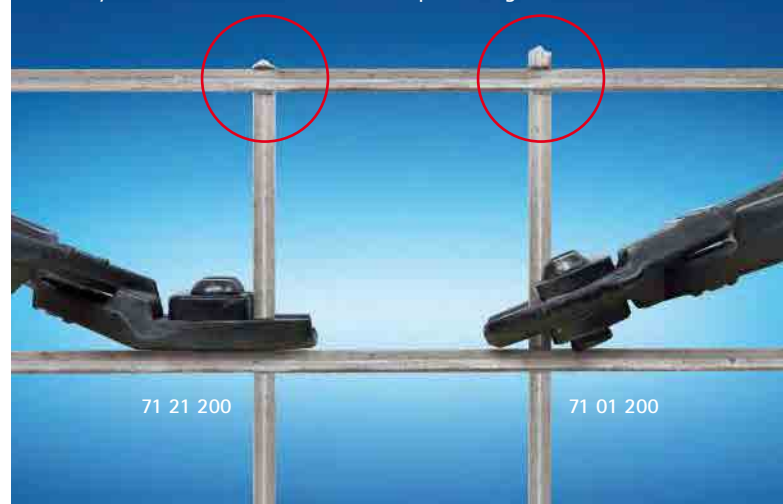

71 21 200

71 01 200



71 31 200



The KNIPEX Compact Bolt Cutter is a "clever muscle man". The ingeniously designed lever action mechanism guarantees an extremely favourable lever ratio with low friction. The cutting performance is 20 times higher than the handforce applied.

Requires > 60% less effort

Cutting a piano wire of 2.0 mm diameter with the KNIPEX-CoBolt requires handforce of only ~ 190 N (19 kp) instead of ~ 500 N (50 kp) with a High Leverage Diagonal Cutter of the same length.



Secure locking with the user-friendly spring clip



The recess in the blade allows easier cutting of thicker wires, e. g. hanging rods for false ceilings



71 31 200
71 32 200
71 41 200

The recess near the joint keeps thicker wires to be cut in a secure position, ensuring optimum application of cutting performance

KNIPEX-CoBolt Compact Bolt Cutters

	Article-No.	EAN 4003773-	Finish	Style						
					6.0	5.2	4.0	3.6	mm	g
 ▶▶	71 01 200	033165	head atramentized, handles plastic coated	0					200	320
 ▶▶	71 02 200	047056	head atramentized, with slim, two-colour dual component handles	0					200	355
 MM ▶▶	71 12 200	066859	head atramentized, with slim, two-colour dual component handles	1					200	390
 ≈ 60 mm ∠20° ◀▶	71 21 200	066866	head atramentized, handles plastic coated	2					200	320
 ≈ 60 mm ∠20° MM ◀▶	71 22 200	066873	head atramentized, with slim, two-colour dual component handles	2					200	360
 ▶▶	71 31 200	042327	head atramentized, handles plastic coated	3					200	315
 MM ▶▶	71 32 200	066880	head atramentized, with slim, two-colour dual component handles	3					200	370
 ≈ 60 mm ∠20° ◀▶	71 41 200	066897	head atramentized, handles plastic coated	4					200	320

▶▶ Centre cutter

◀▶ Cutting edges with bevel

MM with opening spring

Your distributor



KNIPEX-Werk
C. Gustav Putsch KG

Oberkamper Strasse 13
42349 Wuppertal (Germany)

Tel.: +49 (0) 202 – 47 94-0
Fax: +49 (0) 202 – 47 74 94

info@knipex.de
www.knipex.de