




ACO 230




FCO 230




**Dimensions**

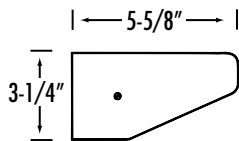


FCO 2 Lamp

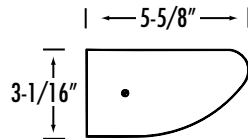


ACO 2 Lamp

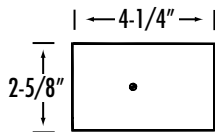

FCO 1 Lamp

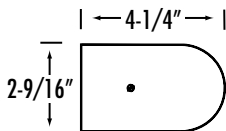

PCO 1 Lamp

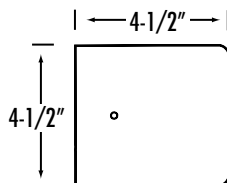

WBT 2 Lamp

ACO, FCO (2 Lamp), PCO and WBT lengths are 18-1/4", 24-1/4", 36-1/4" and 48-1/4". FCO 1 lamp lengths are 18-3/8", 24-3/8" and 48-3/8".

- Choice of chrome or white ends.
- Wraparound, translucent, milk white acrylic diffuser.
- Fully enclosed unit for easy cleaning.
- Grounded convenience outlet and push switch included. (120V only)
- Flush, wall mount.
- U.L. listed damp location.

**Wall Brackets Ordering Information**

Series	# Lamps	Lamp Type	Ends
ACO	1	15 = 15W 18" T8	Leave blank for chrome
FCO	2	17 = 17W 12" T8	WE = White ends
PCO*		20 = 20W 24" T12	
WBT		25 = 25W 36" T8	
		30 = 30W 36" T12	
		32 = 32W 48" T8	
		40 = 34/40W 48" T12	

\*PCO fixtures are available with 1-lamp only

Ballast	Voltage	Options
B11 = Electronic T8	UNV = 120-277V*	Push Switch and Outlet (Standard)
B22 = LPF T8/T12 120V	120 = 120V	CO = Convenience Outlet only
		SW = Switch only
		LA = Less switch and outlet

\*UNV only available when unit is less outlet and switch