

Junction Boxes

Size (in.)	Part Number	Part Number	A sq.	B sq.	C (inches)	D	H	T
◇ 4 x 4 x 2	JB442	078242	4.375	4.000	2.020	2.200	4	0.187
◇◇ 4 x 4 x 4	JB444	078243	4.375	4.000	4.000	4.187	4	0.187
◇◇◇ 4 x 4 x 6	JB446	078244	4.000	3.675	6.000	6.225	4	0.225
◇◇◇ 5 x 5 x 2	JB552	078245	5.000	4.680	2.000	2.000	4	0.155
◇◇ 6 x 6 x 4	JB664	078246	6.375	6.000	4.000	4.187	4	0.187
◇◇ 6 x 6 x 6	JB666	078247	6.375	6.000	6.000	6.187	4	0.187
◇◇ 8 x 8 x 4	JB884	078248	8.812	8.000	4.000	4.187	4	0.187
◇◇ 8 x 8 x 7	JB887	078249	8.812	8.000	7.000	7.175	4	0.250
◇◇ 12 x 12 x 4	JB12124	078250	12.687	12.000	4.000	4.250	8	0.250
◇◇ 12 x 12 x 6	JB12126	078251	12.687	12.000	6.000	6.250	8	0.250
◇◇◇ 12 x 12 x 8	JB12128	078252	12.580	12.085	8.025	8.250	8	0.225

◇NEMA 1, 2, 3, 3R, 4, 4X, 5, 6P


◇◇NEMA 1, 2, 4, 4X, 5 6, 6P

◇◇◇NEMA 1, 2, 3, 4, 4X, 6P, 12 & 13

Note: Boxes include cover, gasket and screws.

External mounting feet are supplied with all sizes except JB444 and JB446.

Fabricated Junction Boxes are available upon request. Contact your Kraloy Customer Service Representative for more information.

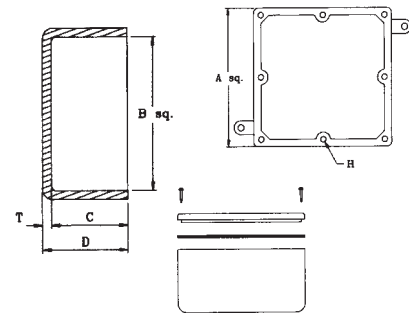

Junction Box Adapters

Size (in.)	Part Number	Product Code	ID (in.)	OD (in.)	L (in.)	OL (in.)
1/2	JBA05	078276	0.605	1.125	0.812	1.000
3/4	JBA07	078277	0.807	1.375	0.937	1.125
1	JBA10	078278	1.060	1.625	1.120	1.325
1-1/4	JBA12	078279	1.355	1.975	1.125	1.325
1-1/2	JBA15	078280	1.560	2.330	1.100	1.370
2	JBA20	078281	2.030	2.890	1.315	1.650
2-1/2	JBA25	078282	2.450	3.375	1.843	2.156
3	JBA30	078283	3.030	4.000	2.093	2.406
3-1/2	JBA35	078284	3.150	3.500	2.125	2.525
4	JBA40	078285	4.016	5.000	2.375	2.687

