


CONNECTORS

Compression H-Tap & Service Entrance Connectors

Compression Connectors

- Hinged polyethylene cover
- Installs easily, quickly and is less expensive than taping
- Positive snap-locks fasten securely
- Drain ports prevent accumulation of corrosion-causing moisture
- Ultra-violet stabilized

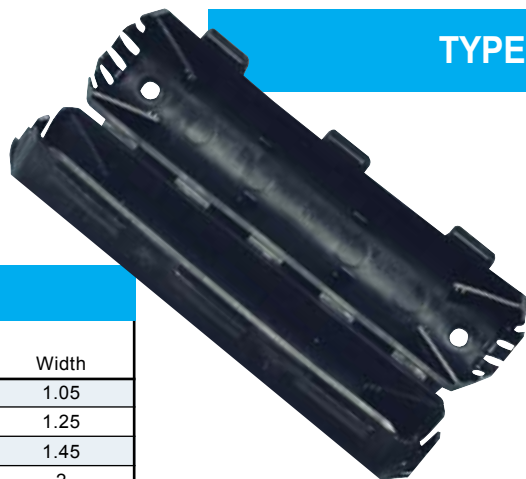

TYPE C

TYPE C – COMPRESSION CONNECTOR COVERS


Cat. No.	Capacity*	Dimension		
		Height	Length	Width
C2BB	All 5/8" O.D., sleeves 2" long or less	1.1	4	1.05
C5BB	All "O" Die taps, 13/4" long or less	1.6	3.75	1.25
C7	All "D" Die taps, 2 1/2" long or less	1.8	5	1.45
C9	All "N" and "D" die taps, up to 2" long	2.75	4.25	2
C9L	All "N" and "D" die taps, up to 5" long	2.75	7.25	2

*Before compression.

TYPE CS & CSC – SERVICE ENTRANCE SLEEVES 5/8 DIE


Cat. No.		End "A"					End "B"				
		Conductor Range		Diameter (in.)		Color Code	Conductor Range		Diameter (in.)		Color Code
Bare Sleeve	Sleeve With Cover	ASCR	AWG	max.	min.		ASCR	AWG	max.	min.	
CS61 ⁺	CSC61	—	8 str. 6 sol.	.162	.146	Green	—	8 str. 6 sol.	.162	.146	Green
CS62 ⁺	CSC62	6%	6 str. 4 sol.	.204	.184	Blue	1	10 str. 8 sol.	.128	.116	Brown
CS63 ⁺	CSC63	6%	6 str. 4 sol.			Blue	—	8 str. 6 sol.	.162	.146	Green
CS64 ⁺	CSC64	6%	6 str. 4 sol.	.258	.232	Blue	6%	6 str. 4 sol.	.204	.184	Blue
CS65 ⁺	CSC65	4% 7/16	3-4 str. 2 sol.			Orange	—	10 str. 8 sol.	.128	.116	Brown
CS66 ⁺	CSC66	4% 7/16	3-4 str. 2 sol.			Orange	—	8 str. 6 sol.	.162	.146	Green
CS67 ⁺	CSC67	4% 7/16	3-4 str. 2 sol.			Orange	6%	6 str. 4 sol.	.204	.184	Blue
CS68 ⁺	CSC68	4% 7/16	3-4 str. 2 sol.	.328	.292	Orange	4% 7/16	3-4 str. 2 sol.	.258	.232	Orange
CS69 ⁺	CSC69	2% 7/16	1-2 str.			Red	—	10 str. 8 sol.	.128	.116	Brown
CS70 ⁺	CSC70	2% 7/16	1-2 str.			Red	—	8 str. 6 sol.	.162	.146	Green
CS71 ⁺	CSC71	2% 7/16	1-2 str.	.398	.368	Red	6%	6 str. 4 sol.	.204	.184	Blue
CS72 ⁺	CSC72	2% 7/16	1-2 str.			Red	4% 7/16	3-4 str. 2 sol.	.258	.232	Orange
CS73 ⁺	CSC73	2% 7/16	1-2 str.			Red	2% 7/16	1-2 str.	.328	.292	Red
CS74 ⁺	CSC74	1/0	1/0 str.	.414	.414	Yellow	—	8 str. 6 sol.	.162	.146	Green
CS75 ⁺	CSC75	1/0	1/0 str.			Yellow	6%	6 str. 4 sol.	.204	.184	Blue
CS76 ⁺	CSC76	1/0	1/0 str.			Yellow	4% 7/16	3-4 str. 2 sol.	.258	.232	Orange
CS77 ⁺	CSC77	1/0	1/0 str.			Yellow	2% 7/16	1-2 str.	.328	.292	Red
CS78 ⁺	CSC78	1/0	1/0 str.	Yellow	1/0	1/0 str.	.398	.368	Yellow		
CS84 ⁺	CSC84	—	2/0 str.	Grey	1/0	1/0 str.	.398	.368	Yellow		
CS85 ⁺	CSC85	—	2/0 str.	Grey	—	2/0 str.	.414	.414	Grey		

*RUS Listed.

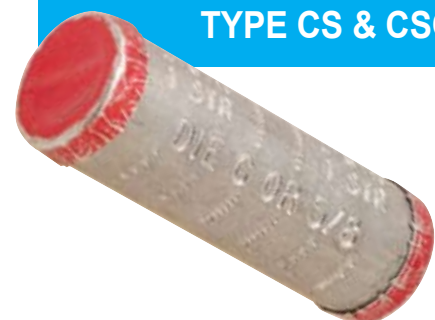

TYPE CS & CSC

- For combinations of aluminum-aluminum and aluminum-copper conductors
- Pass the requirements of ANSI C119.4
- Sleeves are made of highly conductive aluminum
- Quick identification with color-coded foil caps
- Install with standard compression dies

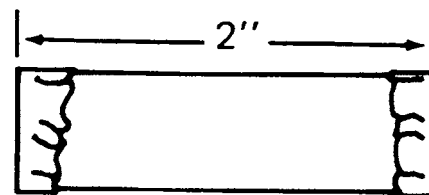

INSTALLATION INFORMATION

Cat. No.	Installation Dies	
	Mech.	Hyd.
All	5/8 (OD58 Tool) Peach, BG, G, TU	U-BG B58CS, 52