



Motion Controlled Wallpacks

NEW! Energy-Saving Perimeter Wallpacks – NRG®300B • WGC/WGH Series

Hubbell Outdoor Lighting introduces three versatile energy-saving compact fluorescent motion controlled wallpacks. The NRG®300B series is perfect for on/off security/welcome lighting applications such as: schools, apartment complexes or single family homes. The WGC/WGH series provides perimeter security for commercial buildings, storage facilities and warehouses with normal operation at 50% output. The motion sensor triggers the second lamp for full brightness only when needed. These rugged fixtures feature sensors with 180° detection range with adjustable time-on and sensitivity settings.

THREE DESIGN STYLES



NRG-304B-MS

NRG-304B-MS

- Die-cast back housing for rigid mounting and heat dissipation
- One piece polycarbonate front is vandal resistant; Philips and Torx hardware included
- 42w CFL 3500K lamp controlled by motion sensor; On only when needed
- Motion sensors are PIR type with 180° detection range and adjustable time-on/sensitivity settings
- Listed to UL1598 for use in wet locations
- Lamps included; 4-Pin CFL



WGC-84F-MS42

WGC-84F-MS42

- Durable die-cast housing and door are light weight for installation ease
- Tempered, stippled glass lens protects lamp and softens lamp image
- Full Cutoff output with no uplight, neighbor friendly, IDA approved
- 2x42w 3500K CFL with one lamp controlled by sensor; provides 50% energy savings
- Motion sensors are PIR type with 180° detection range and adjustable time-on/sensitivity settings
- Listed to UL1598 for use in wet locations
- Lamps included; 4-Pin CFL



WGH-84F-MS42

WGH-84F-MS42

- Durable die-cast housing and door are light weight for installation ease
- Borosilicate prismatic glass lens spreads lamp lumens uniformly
- Non-cutoff distribution fills the area with light, illuminating vertical surfaces for safety
- 2x42w 3500K CFL with one lamp controlled by sensor; provides 50% energy savings
- Motion sensors are PIR type with 180° detection range and adjustable time-on/sensitivity settings
- Listed to UL1598 for use in wet locations
- Lamps included; 4-Pin CFL



ORDERING INFORMATION ON REVERSE SIDE




Polycarbonate NRG300B – Entry/Perimeter Wallpack

ORDERING INFORMATION

CATALOG NUMBER	WATTAGE	VOLTAGE	COLOR	WEIGHT LBS. (KG)
MOTION CONTROLLED ELECTRONIC FLUORESCENT				
NRG-304B-MS^{1,2}	42w CFL	120V	Bronze	5 (2.3)

- 1 CFL lamps are 4-Pin, 3500K
- 2 Motion sensor has 180° detection range, adjustable time-on and sensitivity settings

NRG-304B-MS

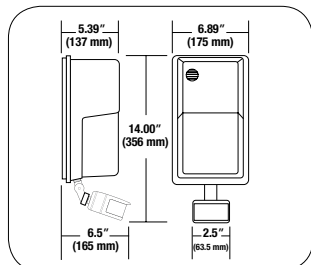


Full Cutoff 2-lamp Wallpack – 50% Energy Saver!

ORDERING INFORMATION

CATALOG NUMBER	WATTAGE/SOURCE	VOLTAGE	FINISH	WEIGHT LBS. (KG)
MOTION CONTROLLED ELECTRONIC FLUORESCENT				
WGC-84F-MS42^{1,2}	2x42w CFL	120V	Bronze	12 (5.8)

- 1 CFL lamps are 4-Pin, 3500K
- 2 Unit has individual ballasts, can easily be field-wired for motion control of both lamps if desired

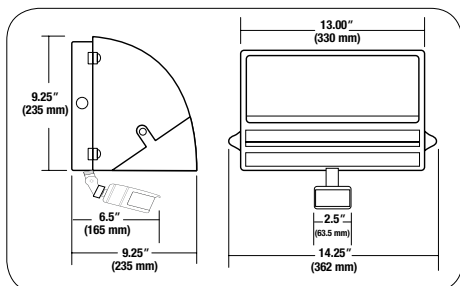

Glass Refractor 2-lamp Wallpack – 50% Energy Saver!

ORDERING INFORMATION

CATALOG NUMBER	WATTAGE/SOURCE	VOLTAGE	FINISH	WEIGHT LBS. (KG)
MOTION CONTROLLED ELECTRONIC FLUORESCENT				
WGH-84F-MS42^{1,2}	2x42w CFL	120V	Bronze	11 (5.0)

- 1 CFL lamps are 4-Pin, 3500K
- 2 Unit has individual ballasts, can easily be wired for motion control of both lamps if desired

