



Stainless Steel Rutgers with 72"  
Reversible Walnut/Sable Blades

Model . . . **RU72SS5**  
Blade . . . **Included**  
Light. . . . **Not Shown**

# Rutgers


FEATURES

- Heavy-Duty, 3 Speed Reversible Motor
- 6" Downrod (Included)
- Limited Lifetime Warranty
- Custom Rutgers Blades (Included)
- Light Kit Adaptable (Optional)
- Universal Control Adaptable (Optional)

SPECS

Blade Sweep Option. . . . .	68" & 72"
Number of Blades . . . . .	5
Blade Pitch . . . . .	13°
Motor Size (MM). . . . .	.212 x 35
AMPS (HI Speed). . . . .	<1
Watts (HI Speed) . . . . .	.99
Shipping Wt. (lbs.) . . . . .	.36.60
CU. FT. in Carton . . . . .	.3.63
Airflow* (Cubic Feet Per Minute) . . . . .	5,840
Airflow Efficiency* (CFM Per Watt) . . . . .	59

CEILING DROP DIMENSIONS

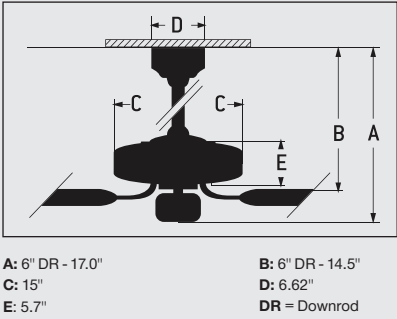

"Compare: 49" to 60" ceiling fans have airflow efficiencies ranging from approximately 51 to 176 cubic feet per minute per watt at high speed."



POPULAR COMBINATIONS

Rutgers | TRADITIONAL STYLE



**A** Oiled Bronze Gilded Rutgers with 72" Reversible Walnut/Cherry Blades

Model-Finish     **RU72OBG5**  
Blade-Finish     **Included**  
Light-Finish     **Not Shown**

**B** Aged Bronze Textured Rutgers with 72" Reversible Light Cherry/Cherry Blades

Model-Finish     **RU72AG5**  
Blade-Finish     **Included**  
Light-Finish     **Not Shown**

AVAILABLE FINISHES

- AG** Aged Bronze Textured
- OBG** Oiled Bronze Gilded
- SS** Stainless Steel

BLADE OPTIONS

**Blades Included - Model Specific**  
Type 4 Blades (Optional)  
(see pages 233-234 )

LIGHT KIT OPTIONS

**Bowl Light Kits**  
(see pages 242-246)




**Complete Light Kits**  
(see pages 246-248)



**Customize Your Own**  
(see pages 249-252)



REMOTES



**Universal Remote Control System**  
(Optional)  
**UC-2000-2**