

NORTH PARK



P4004-09



Rediscover handsome hardware styles with modern and classic looks. Twin arching arms and square etched glass shades in an updated mission style.

FINISHES

- Brushed Nickel - 09
- Venetian Bronze - 74

ALSO AVAILABLE IN

Bath & Vanity
Close-to-Ceiling
Fan light kit

PAIR WITH

Cascadia



P3597-09



P4001-09



P3906-09



P4002-09



P5135-09



P4003-09



P4053-09



P2733-09

SEMI-FLUSH CONVERTIBLE

P3597-09 Brushed Nickel
Hanging and ceiling mount hardware included.
12-3/4" sq., 13-5/8" ht.
Overall ht. w/chain 89"; wire 15'.
Two medium base lamps, each 100w max.

TWO-LIGHT INVERTED PENDANT

P3906-09 Brushed Nickel
16" sq., 24-1/8" ht.
Overall ht. w/chain 100"; wire 15'.
Two medium base lamps, each 100w max.

FOUR-LIGHT CHANDELIER

P4001-09 Brushed Nickel
21" W., 19-5/8" ht.
Overall ht. w/chain 95"; wire 15'.
Four medium base lamps, each 100w max.

FOUR-LIGHT CHANDELIER

P4002-09 Brushed Nickel
21" W., 22-3/4" ht.
Overall ht. w/chain 98"; wire 15'.
Four medium base lamps, each 100w max.

SIX-LIGHT LINEAR CHANDELIER

P4003-09 Brushed Nickel
27-1/4" L., 14-1/4" W., 21-3/4" ht.
Overall ht. w/chain 97"; wire 15'.
Six medium base lamps, each 100w max.

EIGHT-LIGHT CHANDELIER

P4004-09 Brushed Nickel
27-1/4" W., 24-5/8" ht.
Overall ht. w/chain 100"; wire 15'.
Eight medium base lamps, each 100w max.

TWELVE-LIGHT CHANDELIER

P4053-09 Brushed Nickel
Two-tier.
27-1/4" W., 30-1/8" ht.
Overall ht. w/chain 154"; wire 15'.
Twelve medium base lamps, each 100w max.

MINI-PENDANT

P5135-09 Brushed Nickel
5-1/2" dia., 7-1/8" ht.
Overall ht. ww/stem 64-1/8"; wire 10'.
One medium base lamp, 100w max.

WALL BRACKET

P2733-09 Brushed Nickel
5-1/2" W., 10-1/8" ht. Extends 7-1/8".
One medium base lamp, 100w max.



Shown: P4004-20 chandelier
(Image: Toll Brothers)



P4002-74



P4001-74



P3597-74



P4004-74



P3906-74



P4053-74



P4003-74



P5135-74



P2733-74

NORTH PARK

SEMI-FLUSH CONVERTIBLE

P3597-74 Venetian Bronze
Hanging and ceiling mount hardware included.
12-3/4" sq., 13-5/8" ht.
Overall ht. w/chain 89"; wire 15'.
Two medium base lamps, each 100w max.

TWO-LIGHT INVERTED PENDANT

P3906-74 Venetian Bronze
16" sq., 24-1/8" ht.
Overall ht. w/chain 100"; wire 15'.
Two medium base lamps, each 100w max.

FOUR-LIGHT CHANDELIER

P4001-74 Venetian Bronze
21" W., 19-5/8" ht.
Overall ht. w/chain 95"; wire 15'.
Four medium base lamps, each 100w max.

FOUR-LIGHT CHANDELIER

P4002-74 Venetian Bronze
21" W., 22-3/4" ht.
Overall ht. w/chain 98"; wire 15'.
Four medium base lamps, each 100w max.

SIX-LIGHT LINEAR CHANDELIER

P4003-74 Venetian Bronze
27-1/4" L., 14-1/4" W., 21-3/4" ht.
Overall ht. w/chain 97"; wire 15'.
Six medium base lamps, each 100w max.

EIGHT-LIGHT CHANDELIER

P4004-74 Venetian Bronze
27-1/4" W., 24-5/8" ht.
Overall ht. w/chain 100"; wire 15'.
Eight medium base lamps, each 100w max.

TWELVE-LIGHT CHANDELIER

P4053-74 Venetian Bronze
Two-tier.
27-1/4" W., 30-1/8" ht.
Overall ht. w/chain 154"; wire 10'.
Twelve medium base lamps, each 100w max.

MINI-PENDANT

P5135-74 Venetian Bronze
5-1/2" dia., 7-1/8" ht.
Overall ht. w/stem 64-1/8"; wire 15'.
One medium base lamp, 100w max.

WALL BRACKET

P2733-74 Venetian Bronze
5-1/2" W., 10-1/8" ht. Extends 7-1/8".
One medium base lamp, 100w max.

NORTH PARK



Clean linear forms offer a modern interpretation of two blended styles – Craftsman and Mission. Square etched glass shades give nod to a classic feel.

FINISHES

- Brushed Nickel - 09
- Venetian Bronze - 74

ALSO AVAILABLE IN

Fixture Collections
Close-to-Ceiling

ONE-LIGHT BATH

P2733-09 Brushed Nickel
P2733-74 Venetian Bronze
5-1/2" W., 10-1/8" ht. Extends 7-1/8".
One medium base lamp,
100w max.

TWO-LIGHT BATH

P2738-09 Brushed Nickel
P2738-74 Venetian Bronze
14-1/4" W., 9" ht. Extends 7-1/8".
Two medium base lamps,
each 100w max.

THREE-LIGHT BATH


P2743-09 Brushed Nickel
P2743-74 Venetian Bronze
23" W., 9" ht. Extends 7-1/8".
Three medium base lamps,
each 100w max.

FOUR-LIGHT BATH

P2745-09 Brushed Nickel
P2745-74 Venetian Bronze
32-1/8" W., 9" ht. Extends 7-1/8".
Four medium base lamps,
each 100w max.



P2733-09

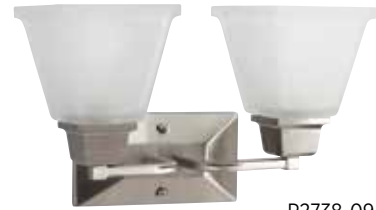

P2738-09



P2743-09



P2745-09



P2733-74



P2738-74



P2743-74



P2745-74

NORTH PARK

Clean linear forms with square etched glass shades.



P3597-09



P3597-74

SEMI-FLUSH CONVERTIBLE

P3597-09 Brushed Nickel

P3597-74 Venetian Bronze

Hanging and ceiling mount hardware included.

12-3/4" sq., 13-5/8" ht.

Overall ht. w/chain 89"; wire 15'.

Two medium base lamps, each 100w max.



P3852-09



P3852-74

TWO-LIGHT FLUSH MOUNT

P3852-09 Brushed Nickel

P3852-74 Venetian Bronze

15" sq., 7-1/8" ht.

Two medium base lamps, each 100w max.



P3854-09



P3854-74

ONE-LIGHT FLUSH MOUNT

P3854-09 Brushed Nickel

P3854-74 Venetian Bronze

12-1/2" sq., 6-1/8" ht.

One medium base lamp, 100w max.

NORTH PARK



P2531-20 shown with Cherry blades

52" 4-blade ceiling fan with reversible Natural Cherry/Cherry blades and a Brushed Nickel finish or reversible Cherry/Classic Walnut blades and an Antique Bronze finish. The North Park ceiling fan offers great performance and value. This contemporary styled fan features a powerful, 3-speed motor that can be reversed to provide year-round comfort. The North Park fan will also accept a universal light kit.

FEATURES

- 30-year limited warranty
- 45° Canopy
- SureConnect System
- Compatible with universal light kits
- Three speed pull-chain switch
- Add a P2630-30 wall control or P2614-01 hand-held remote control

SIZE

52" dia., 15-3/4" ht.
CTC 11" ht.
80" lead wires

FINISHES

- ● Brushed Nickel - 09
- ● Antique Bronze - 20

P2531-09

Brushed Nickel shown
with Natural Cherry blades



Natural Cherry



Cherry



P2531-20

shown with
P2654-01WB light kit*
Antique Bronze shown
with Cherry blades



Classic Walnut



Cherry




ENERGY INFORMATION AT HIGH SPEED

AIRFLOW:	4,248 cubic feet per minute
ELECTRICITY USE:	57 watts (excludes lights)
AIRFLOW EFFICIENCY:	76 cubic feet per minute per watt

* Light kit sold separately.

PROGRESSLIGHTING.COM

 CTC INSTALLATION



Fan



Dry

Indoor only

NORTH PARK

Universal-style with quick-connect wiring.

P2654-01WB

with etched glass.

Included Finials:

-09 Brushed Nickel

-20 Antique Bronze

12-1/2" sq., 6-1/4" ht.

Two medium base 10w, 3000K,

LED lamps included.

800 lumens/lamp, 90 CRI.

Indoor use only. (dimmable)



Dry
Indoor only



P2654-01WB
*Shown with
-09 finial*



P2654-01WB
*Shown with
-20 finial*