


 
Bronze

For color photos of finishes see inside front cover.

STANDARD SHAPE

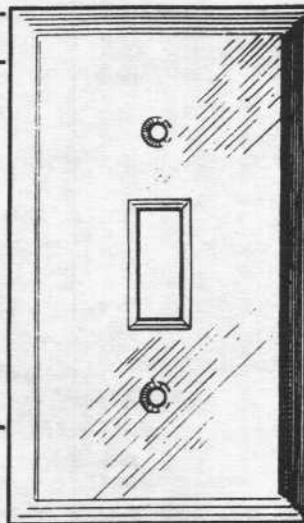

See page A84 for ordering Custom Plates not found in this listing.

	BRONZODIC LACQUER ON TYPE 302 STAINLESS (.035")	BANK BRONZE (.040") ANTIQUED & RELIEVED US #10B (4ABR)	SATIN BRONZE (.040") SATIN FINISH US #10 (4SBR)	STATUARY BRONZE (.040") DARK ANTIQUED & RELIEVED US#20 (4DBR)
 1 Toggle Switch (1T)	61071	65071	66071	69071
 2 Toggle Switches (2T)	61072	65072	66072	69072
 3 Toggle Switches (3T)	61073	65073	66073	69073
 4 Toggle Switches (4T)	61074	65074	66074	69074
 5 Toggle Switches (5T)	61075	65075	66075	69075
 6 Toggle Switches (6T)	61076	65076	66076	69076
 7 Toggle Switches (7T)	61077	65077	66077	69077
 8 Toggle Switches (8T)	61078	65078	66078	69078
 9 Toggle Switches (9T)	61079	65079	66079	69079
 10 Toggle Switches (10T)	61080	65080	66080	69080
 1 Duplex Receptacle (10DR)	61101	65101	66101	69101
 2 Duplex Receptacles (20DR)	61102	65102	66102	69102

Bronze

		BRONZODIC	BANK BRONZE	SATIN BRONZE	STATUARY BRONZE
	3 Duplex Receptacles (30DR)	61103	65103	66103	69103
	4 Duplex Receptacles (40DR)	61104	65104	66104	69104
	5 Duplex Receptacles (50DR)	61105	65105	66105	69105
	6 Duplex Receptacles (60DR)	61106	65106	66106	69106
	1 Single Recept. (1.405") (10R)	61091	65091	66091	69091
	2 Single Recepts. (1.405") (20R)	61092	65092	66092	69092
	3 Single Recepts. (1.405") (30R)	61093	65093	66093	69093
	1 Blank with Mounting Strap (Device Mntg. 2.375") (1BDE)	61121	65121	66121	69121
	2 Blanks with Mounting Straps (Device Mntg. 2.375") (2BDE)	61122	65122	66122	69122
	3 Blanks with Mounting Straps (Device Mntg. 2.375") (3BDE)	61123	65123	66123	69123
	1 Blank (Box Mntg. 3.281") (1B)	61151	65151	66151	69151
	2 Blanks (Box Mntg. 3.281") (2B)	61152	65152	66152	69152
	3 Blanks (Box Mntg. 3.281") (3B)	61153	65153	66153	69153
	4 Blanks (Box Mntg. 3.281") (4B)	61154	65154	66154	69154
	5 Blanks (Box Mntg. 3.281") (5B)	61155	65155	66155	69155
	6 Blanks (Box Mntg. 3.281") (6B)	61156	65156	66156	69156
	7 Blanks (Box Mntg. 3.281") (7B)	61157	65157	66157	69157
	8 Blanks (Box Mntg. 3.281") (8B)	61158	65158	66158	69158

Bronze

		BRON- ZODIC	BANK BRONZE	SATIN BRONZE	STATUARY BRONZE
	9 Blanks (Box Mntg. 3.281") (9B)	61159	65159	66159	69159
	10 Blanks (Box Mntg. 3.281") (10B)	61160	65160	66160	69160
	Block Duplex/GFI Recept. (SRM)	61401	65401	66401	69401
	2 Block Duplex/GFI Recepts. (2SRM)	61402	65402	66402	69402
	3 Block Duplex/GFI Recepts. (3SRM)	61403	65403	66403	69403
	4 Block Duplex/GFI Recepts. (4SRM)	61404	65404	66404	69404
	5 Block Duplex/GFI Recepts. (5SRM)	61405	65405	66405	69405
	6 Block Duplex/GFI Recepts. (6SRM)	61406	65406	66406	69406
	7 Block Duplex/GFI Recepts. (7SRM)	61407	65407	66407	69407
	8 Block Duplex/GFI Recepts. (8SRM)	61408	65408	66408	69408
	9 Block Duplex/GFI Recepts. (9SRM)	61409	65409	66409	69409
	10 Block Duplex/GFI Recepts. (10SRM)	61410	65410	66410	69410
	One 5/8" ID Phone (Box Mntg. 3.281") (01)*	61201	65201	66201	69201
	Two 5/8" ID Phones (Box Mntg. 3.281") (02)*	61202	65202	66202	69202
	One 5/8" ID Phone with Metal Bushing (Box Mntg. 3.281") (61)*	61591	65591	66591	69591
	One Phone .5" with .375 ID Grommet and Mounting Strap (Device Mntg. 2.375")*	61181	65181	66181	69181
	One Phone 1.405" with 1" ID Plastic Bushing (Box Mntg. 3.281") (71)*	61581	65581	66581	69581

	BRONZODIC	BANK BRONZE	SATIN BRONZE	STATUARY BRONZE
 One 20A TL Recept. 1.620" ID Hole (3R)	61111	65111	66111	69111
 Two 20A TL Recepts. 1.620" ID Hole Must Use 3 Gang Plate (23R)	61113	65113	66113	69113
 One 30A 3 & 4 Wire TL Recept. 1.730" ID Hole (3330R)	61229	65229	66229	69229
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole(3D)	61221	65221	66221	69221
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole 2 Gang Plate (23D)	61222	65222	66222	69222
 30/50A 3 Wire Range/Dryer Recept. 2.125" ID Hole(N23D)	61227	65227	66227	69227
 30/50/60A 3 & 4 Wire Recepts. 2.480" ID Hole(5R)	61223	65223	66223	69223
 30/50/60A 4 Wire for Leviton 278 & 279 Recepts. 2.625" ID Hole (L5R)	61225	65225	66225	69225
 30/50/60A 4 Wire Offset Recepts. 2.275" ID Hole(N5RR)	61226	65226	66226	69226
 30/50/60A 4 Wire Recepts. 2.255" ID Hole(P5R)	61228	65228	66228	69228
 Louver, Horizontal (Device Mntg. 2.375") (LH)	61630	65630	66630	69630
 Louver, Vertical (Device Mntg. 2.375") (LV)	61631	65631	66631	69631
 2 Louvers (Device Mntg. 2.375") (2LV)	61632	65632	66632	69632
 Interchangeable 1 Hole Horizontal (71A)	61011X	65011X	66011X	69011X
 Interchangeable 1 Hole Per Gang, Horizontal (72A)	61012X	65012X	66012X	69012X
 Interchangeable 2 Holes (71B)	61021X	65021X	66021X	69021X
 Interchangeable 2 Holes Per Gang (72B)	61022X	65022X	66022X	69022X
 Interchangeable 2 Holes Per Gang (73B)	61023X	65023X	66023X	69023X

Bronze

	BRONZODIC	BANK BRONZE	SATIN BRONZE	STATUARY BRONZE
 Interchangeable 3 Holes (71C)	61031X	65031X	66031X	69031X
 Interchangeable 3 Holes Per Gang (72C)	61032X	65032X	66032X	69032X
 Interchangeable 1 Hole Vertical (71G)	61041X	65041X	66041X	69041X
 Interchangeable 1 Hole Horizontal, 2 Holes (71A-71B)	61052X	65052X	66052X	69052X
 Toggle Switch, Duplex Recept. (1T-10DR)	61532	65532	66532	69532
 Toggle Switch, Interchangeable 2 Holes (1T-71B)	61062X	65062X	66062X	69062X
 Toggle Switch, Interchangeable 3 Holes (1T-71C)	61132X	65132X	66132X	69132X
 Toggle Switch, Single Recept. (1.405" ID Hole) (1T-10R)	61512	65512	66512	69512
 Toggle Switch, 5/8" ID Phone (Box Mntg. 3.281") (1T-01)	61472	65472	66472	69472
 Toggle Switch, Blank (Box Mntg. 3.281") (1T-1B)	61522	65522	66522	69522
 Toggle Switch, Block Duplex/GFI Recept. (1T-SRM)	61432	65432	66432	69432
 Duplex Recept., Blank (Box Mntg. 3.281") (10DR-1B)	61542	65542	66542	69542
 Duplex Recept., 5/8" ID Phone (Box Mntg. 3.281") (10DR-01)	61582	65582	66582	69582
 Duplex Recept., Single Recept. (1.405" ID Hole) (10DR-10R)	61572	65572	66572	69572
 Duplex Recept., Block Duplex/GFI Recept. (10DR-SRM)	61672	65672	66672	69672
 Duplex Recept., Interchangeable 2 Holes (10DR-71B)	61142X	65142X	66142X	69142X
 Duplex Recept., Interchangeable 3 Holes (10DR-71C)	61172X	65172X	66172X	69172X
 Duplex Recept., 20A TL Recept. (1.620" ID Hole) (10DR-3R)	61390	65390	66390	69390

	BRONZODIC	BANK BRONZE	SATIN BRONZE	STATUARY BRONZE
	61180	65180	66180	69180
	61552	65552	66552	69552
	61422	65422	66422	69422
	61772	65772	66772	69772
	61773	65773	66773	69773
	61774	65774	66774	69774
	61775	65775	66775	69775
	61543	65543	66543	69543
	61533	65533	66533	69533
	61443	65443	66443	69443
	61453	65453	66453	69453
	61133	65133	66133	69133
	61553	65553	66553	69553
	61503	65503	66503	69503
	61423	65423	66423	69423
	61193	65193	66193	69193

Bronze

		BRONZODIC	BANK BRONZE	SATIN BRONZE	STATUARY BRONZE
	Blank (Box Mntg. 3.281"), 2 Duplex Recepts. (1B-20DR)	61163	65163	66163	69163
	Single Recept. (1.405" ID Hole), 2 Duplex Recepts. (10R-20DR)	61593	65593	66593	69593
	Toggle Switch, Blank (Box Mntg. 3.281"), Duplex Recept. (1T-1B-10DR)	61233	65233	66233	69233
	3 Toggle Switches, Duplex Recept. (3T-10DR)	61554	65554	66554	69554
	3 Toggle Switches, Block Recept. (3T-SRM)	61454	65454	66454	69454
	3 Toggle Switches, Blank (Box Mntg. 3.281") (3T-1B)	61544	65544	66544	69544
	2 Toggle Switches, 2 Duplex Recepts. (2T-20DR)	61564	65564	66564	69564
	2 Toggle Switches, 2 Blanks (Box Mntg. 3.281") (2T-2B)	61574	65574	66574	69574
	Toggle Switch, 3 Duplex Recepts. (1T-30DR)	61584	65584	66584	69584
	2 Duplex Recepts., 2 Blanks (Box Mntg. 3.281") (20DR-2B)	61164	65164	66164	69164
	4 Toggle Switches, Duplex Recept. (4T-10DR)	61565	65565	66565	69565
	4 Toggle Switches, 1 Block Recept. (4T-SRM)	61465	65465	66465	69465
	3 Toggle Switches, 2 Duplex Recepts. (3T-20DR)	61575	65575	66575	69575
	5 Toggle Switches, Duplex Recept. (5T-10DR)	61576	65576	66576	69576