

Top-Bite Saddle Type Connectors

90° with Insulated Throat

Features

- With insulated throat
- Male hub threads - NPSM
- One piece malleable construction affording extra strength
- Dual gripping saddle clamps
- Saddle clamps ride up and down on screw for ease of installation
- Tri combo head screw

Applications


- To connect Flex, AC, and MC cables to a box or enclosure

Standard Material

- Malleable iron
- Steel locknuts
- Steel clamps

Standard Finish

- Zinc plated

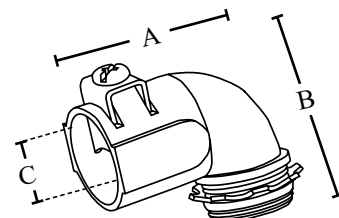

Catalog Number	UPC	Size	KO	Unit Carton	Ship Case	Weight/Case	Opening Min.	Cable Max.	A	Inches B	C
490TBS	85186	3/8"	1/2"	50	300	54	.437	.656	1.75	2.06	1
491TBS	85187	1/2"	1/2"	25	150	43	.750	.937	2.13	2.26	1.25
492TBS	85188	3/4"	3/4"	20	120	43	.906	1.13	2.50	2.50	1.38
493TBS	85189	1"	1"	5	60	34	1.25	1.47	2.81	2.88	1.69