

**Application**

- Adjustable bar hanger allows box to be placed between ceiling joists or wall studs quickly and easily

**Product Features**

 
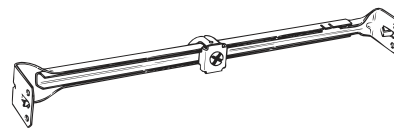
- Both RACO® 920 and 922 bar fixture hangers allow box to be located anywhere along length of bar
- RACO® 920 includes 3/8" trade size stud to accommodate fixture stem
- 922 Clip installs in 1/2" knockout located in bottom (back) of box
- RACO® box must be ordered separately

**Box Installation**

- Bar hangers attach to octagon or square boxes through center 1/2" knockouts
- Remove the knockout
- Remove the screw and fixture stud (or clip) from bar hanger
- Place the stud inside the box and replace the screw
- When box is located accurately between the joists, tighten the screw securely

**Compliance**

-  – File E195978

**920, 8920****922****ORDERING INFORMATION - DIMENSIONS**

ADJUSTABLE BAR HANGERS					
CATALOG NUMBER	DESCRIPTION	STD. PKG.	UPC BAR CODE	MAX. RECOMMENDED SUPPORT LOADS	
				CEILING FAN (DYNAMIC) LBS.	FIXTURE (STATIC) LBS.
<b>920</b>	3/8" Stud, adj. 14-1/4" to 22-1/2"	50	—	No	10*
<b>8920</b>	3/8" Stud, adj. 14-1/4" to 22-1/2"	50		No	10*
<b>922</b>	Clip, adj. 14-1/4" to 22-1/2"	50	—	No	10*

\*UL Rated at 50 lbs.

**RACO®**