



PROJECT	TYPE
CATALOG NUMBER	

### HOUSING CONSTRUCTION

- 1 piece low profile (1-3/8" height)
- Die-formed 18 ga. cold rolled steel housing
- Die cast end caps
- Mounting holes with pre-affixed screws
- Multiple vents for cool operation
- Powder coat paint / or stainless steel finish

### ELECTRICAL

- 120V G9 Xenon • Hi-low-off switch
- Wire mold knock-outs on end caps
- Dimmable with standard dimmer

### OPTICS

- 2900K
- Tempered frosted prismatic diffuser

### CERTIFICATION


- UL

### WARRANTY

- 5 year warranty

### PRODUCT DESCRIPTION

A 120V undercabinet lighting fixture with 35W xenon lamps that deliver excellent color rendition and maximum light output along with long lamp life. The unique housing and reflector unit features an Open Wide™ hinged system that enables hands-free re-lamping and maintenance. LumenTask is rapidly becoming the preferential undercabinet lighting system for residential lighting applications.

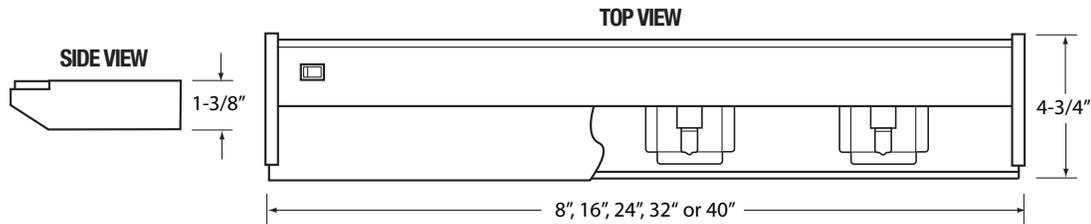

### FIXTURE ORDERING INFORMATION

Catalog No.	Length	Wattage*	Lamp	CRI	Kelvin Temp.*	Finish
X8-120-WH	8"	35W	120V G9 Xenon	95+	2900K	White
X8-120-BZ	8"	35W	120V G9 Xenon	95+	2900K	Bronze
X8-120-SS	8"	35W	120V G9 Xenon	95+	2900K	Stainless Steel
X16-120-WH	16"	2 X 35W	120V G9 Xenon	95+	2900K	White
X16-120-BZ	16"	2 X 35W	120V G9 Xenon	95+	2900K	Bronze
X16-120-SS	16"	2 X 35W	120V G9 Xenon	95+	2900K	Stainless Steel
X24-120-WH	24"	3 X 35W	120V G9 Xenon	95+	2900K	White
X24-120-BZ	24"	3 X 35W	120V G9 Xenon	95+	2900K	Bronze
X24-120-SS	24"	3 X 35W	120V G9 Xenon	95+	2900K	Stainless Steel
X32-120-WH	32"	4 X 35W	120V G9 Xenon	95+	2900K	White
X32-120-BZ	32"	4 X 35W	120V G9 Xenon	95+	2900K	Bronze
X32-120-SS	32"	4 X 35W	120V G9 Xenon	95+	2900K	Stainless Steel
X40-120-WH	40"	5 X 35W	120V G9 Xenon	95+	2900K	White
X40-120-BZ	40"	5 X 35W	120V G9 Xenon	95+	2900K	Bronze
X40-120-SS	40"	5 X 35W	120V G9 Xenon	95+	2900K	Stainless Steel

### ACCESSORY ORDERING INFORMATION

Cat. No.	Description
EZ-1	EZ Connector (connects 2 fixtures)
EZ-3	3" interconnect modular cable
EZ-6	6" interconnect modular cable
EZ-12	12" interconnect modular cable
EZ-18	18" interconnect modular cable
JB-1	Junction box - 4 knock-outs 4"L x 2"W x 1-5/8"H
CP-6	6' modular cord and plug for wall outlet
GL8	8" replacement lens for 8" fixtures
GL16	16" replacement lens for 16" fixtures
GL24	24" replacement lens for 24" fixtures
GL32	32" replacement lens for 32" fixtures
G9-120VCL	120V 35W Xenon replacement lamp

NOTE: All EZ connectors are 3-wire.

### PHOTOMETRICS

- Please see our website at [gmlighting.net](http://gmlighting.net).

**OPEN WIDE FEATURE:** Accessing the interior of LumenTask without dismantling is easy. Our Open Wide design keeps the fixture open and your hands free to wire. By simply pressing the wire compartment holding tab, the wiring compartment cover swings down and out, and stays in position until you're ready to snap it back.

in its closed position, and slide the lens back in place.