

Components

RT-[E] Mount kit



Middle Clamp kit




End Clamp kit




Available for 31,32,33,35,38,40,46 and 50 mm PV frame thickness

Dimensions in (mm)




Installation

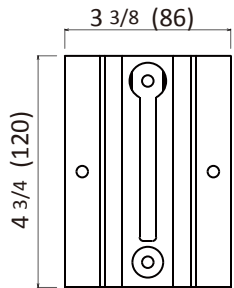

End Clamp

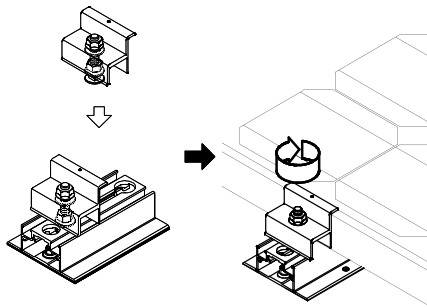


Middle Clamp

 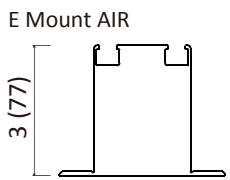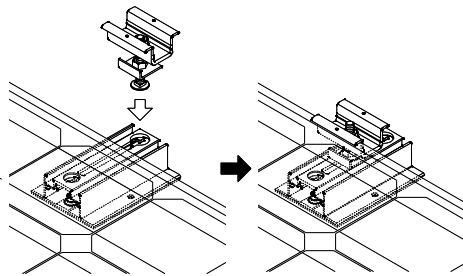

Material Description

RT- [E] Mount / E Mount AIR	Anodized aluminum
Clamps	
Microinverter bracket	
Cable holder bracket	Stainless steel
Hardware	
Flexible Flashing	
Cable clamp	PBT

20 Year Limited Warranty
PAT US8647009

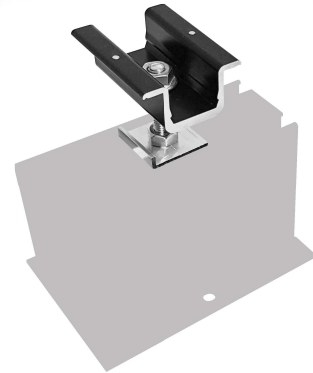

20 Year Limited Warranty
Preassembled hardware
Fewer parts



Roof Tech Inc.

www.roof-tech.us info@roof-tech.us
333 H Street, Suite 5000, Chula Vista, CA 91910
619.551.7029

* OSB 7/16" minimum, please download and review the engineering report.

GEN II

Product Brochure

RT- [E] Mount is the only rail-less PV mounting system with integrated flexible flashing certified by the ICC.

UL441 testing



ASTM2140 testing



UV testing (7500 hrs.)



ICC ESR-3575
evaluation report



***We are proud of our product and history.
You will be satisfied with our high quality
product and customer support.***

New England



More News &
installation



Gulf Coast

E Mount series Options

E Mount AIR with
“Microinverter Bracket” and
“Cable holder Bracket”



RT-[E] Mount with
“L -foot option”



E Mount AIR with “Skirt: Eaves
Cover”

