




SensaSwitch™ + SensaDimmer™

SensaSwitches include passive infrared (PIR) sensor technology, automatically turning lights on or off when you enter or leave a room. The design features an innovative micro-movement that allows you to also manually turn on lights with a soft touch of the finger. SensaSwitches are available in three models:

- Auto-ON/Auto-OFF: Automatically turns lights on when you enter a room and off when you leave. (Occupancy Sensor)
- Manual-ON/Auto-OFF: Allows you to turn lights on when you enter a room and automatically turns them off when you leave. (Vacancy Sensor)
- Manual-ON/Timed-OFF: Allows you to turn lights on when you enter a room and select a time for lights to turn off (options include 10, 20, 30, and 60 minutes). (Timer)

SensaSwitches are perfect for kitchens, bathrooms, garages, and pantries. The SensaDimmer turns lights on when you enter a room and off when you leave, but can be adjusted to become Manual-ON/Auto-OFF if desired. The chart to the right provides an overview of the sensor coverage area.

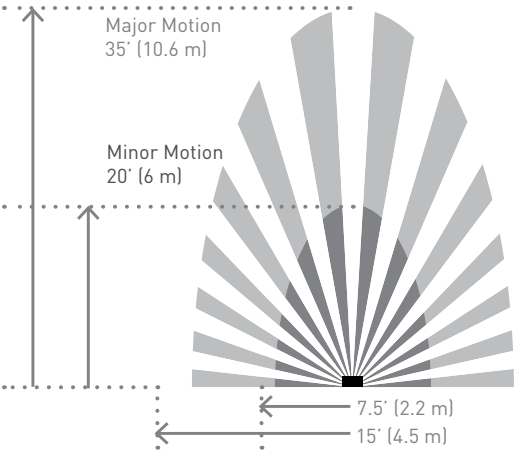

SensaSwitch™ + SensaDimmer™ Coverage Area

The Occupancy Sensor, Vacancy Sensor, and SensaDimmer each have a maximum coverage range of 180 degrees and a coverage area of 600 sq. ft. The sensor must have a clear and unobstructed view of the coverage area. Objects blocking the sensor’s lens may prevent detection thereby causing the light to turn off even though someone is in the area. Windows, glass doors, and other transparent barriers will obstruct the sensor’s view and prevent detection.

| NAME                                                                                                                    | SPECIFICATIONS                                                                                                                                                                                                                                                                                          | RATING                       | COMPATIBLE LOADS                                                                                                                                                                                                | TIME DELAY             | COMPLIANCE                                                                                           | FINISH OPTIONS     | PART NUMBER              |
|-------------------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------------|------------------------------------------------------------------------------------------------------|--------------------|--------------------------|
| <br>SensaSwitch, Auto-ON/Auto-OFF     | Single-Pole/3-Way<br><br>4-Way<br><br>Occupancy Sensor<br>(Must be paired with another SensaSwitch or SensaDimmer)                    | 600W, 120VAC, 60 Hz, 1/6 Hp  | All Loads                                                                                                                                                                                                       | 5 minutes – 30 minutes |                   | White<br>Magnesium | ASOS32W4<br>ASOS32M4     |
| <br>SensaSwitch, Manual-ON/Auto-OFF  | Single-Pole/3-Way<br><br>4-Way<br><br>Vacancy Sensor<br>(Must be paired with another SensaSwitch or SensaDimmer)                  | 600W, 120VAC, 60 Hz, 1/6 Hp  | All Loads                                                                                                                                                                                                       | 5 minutes – 30 minutes | <br>CA Title 24 | White<br>Magnesium | ASVS12W4<br>ASVS12M4     |
| <br>SensaSwitch, Manual-ON/Timed-OFF | Single-Pole/3-Way<br><br>4-Way<br><br>Timer<br>(Must be paired with another SensaSwitch or SensaDimmer)                           | 600W, 120VAC, 60 Hz, 1/6 Hp  | All Loads                                                                                                                                                                                                       |                        |                 | White<br>Magnesium | ASTM2W2<br>ASTM2M2       |
| <br>SensaDimmer, Auto-ON/Auto-OFF    | Single-Pole/3-Way<br><br>4-Way<br><br>Dimming Occupancy Sensor 3-Wire<br>(Must be paired with another SensaSwitch or SensaDimmer) | 25W - 700W<br><br>25W - 450W | Incandescent, <br>Halogen<br><br>CFL/LED  | 5 minutes – 30 minutes |                 | White<br>Magnesium | ADSM703HW2<br>ADSM703HM2 |

Wave™

The Wave switch features innovative technology combined with sleek, contemporary design. Simply wave your hand in front of the switch to turn lights on and off.

With its touch-free motion, the Wave is ideal for countertop areas in kitchens and bathrooms. It has a preset sensor distance of approximately 4". However, this can be easily adjusted to sense movement from 1" to 6" in front of switch. See pages 74 & 78 for switch installation instructions.



| NAME                                                                                                 | SPECIFICATIONS                                                                                             | RATING               | COMPATIBLE LOADS | COMPLIANCE                                                                            | FINISH OPTIONS     | PART NUMBER              |
|------------------------------------------------------------------------------------------------------|------------------------------------------------------------------------------------------------------------|----------------------|------------------|---------------------------------------------------------------------------------------|--------------------|--------------------------|
| <br>Wave Switch | Single-Pole/3-Way<br> | 15A, 120 VAC, 1/2 Hp | All Loads        |  | White<br>Magnesium | ASWV1532W2<br>ASWV1532M2 |

Wireless Lighting Remote Control

This unique remote allows you to control your wireless switches and dimmers from anywhere in the home as well as create lighting scenes.

The remote is easy to program and is compatible with adorné multi-location wireless lighting controls. It allows up to four lighting scenes, as well as one-touch dimming or brightening of your lights.

| NAME                                                                                                                      | PART NUMBER |
|---------------------------------------------------------------------------------------------------------------------------|-------------|
| <br>Wireless Lighting Remote Control | ADMHRM4     |



Touch™

The Touch design features a stunning translucent face and operates just like an iPhone® - simply touch your finger on the circle to turn lights on and off, or use the arrows on the right to dim them (Touch dimmer only).

The white Touch interface is created using a unique translucent material. In multi-gang installations, we recommend pairing white Touch switches and dimmers for optimal consistency.

See pages 74 & 78 for switch and dimmer installation instructions.

| NAME                                                                                                                         | SPECIFICATIONS                                                                                                                                                                                                                                                                                                              | RATING                                                | COMPATIBLE LOADS                                                                                                                                                                                                                                                                                                                                                                        | COMPLIANCE                                                                                                                                                                         | FINISH OPTIONS                               | PART NUMBER                                                                                    |
|------------------------------------------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------|------------------------------------------------------------------------------------------------|
|  Touch Switch                               | Single-Pole/3-Way<br>                                                                                                                                                                                                                      | 15A,<br>120 VAC,<br>1/2 Hp                            | All Loads                                                                                                                                                                                                                                                                                                                                                                               |                                                                                                 | White<br>Magnesium                           | ASTH1532W2<br>ASTH1532M2                                                                       |
|  Touch Switch,<br>Whole-House Wireless     | Wireless Master, Whole-House<br><br><br>Wireless Remote, Whole-House<br>                                                                                 |                                                       | All Loads                                                                                                                                                                                                                                                                                                                                                                               |                                                                                                 | White<br>Magnesium                           | ASTH155RMW1<br>ASTH155RMM1<br><br>ASTHRRW1<br>ASTHRRM1                                         |
|  Touch Dimmer,<br>Multi-Location Wireless | Wireless Master, Multi-Location<br><br><b>Tru-Universal</b><br>3-Wire<br><br>Wireless Remote, Multi-Location<br>                                      | 6W -<br>700W<br><br>6W -<br>450W                      | Incandescent, Halogen, Forward-Phase ELV, MLV, Fluorescent<br><br>CFL, LED, Reverse-Phase ELV<br>                                                                                                                 |                                                                                               | White<br>Magnesium                           | ADTH700MMTUW2<br>ADTH700MMTUM2<br><br>ADTHMRUW2<br>ADTHMRUM2                                   |
|  Touch Dimmer,<br>Whole-House Wireless    | Wireless Master, Whole-House<br><br><b>Tru-Universal</b><br>3-Wire<br><br>Wireless Master, Whole-House 2-Wire<br><br>Wireless Remote, Whole-House<br> | 6W -<br>700W<br><br>6W -<br>450W<br><br>60W -<br>600W | Incandescent, Halogen, Forward-Phase ELV, MLV, Fluorescent<br><br>CFL, LED, Reverse-Phase ELV<br><br>Incandescent, Halogen<br> | <br><br> | White<br>Magnesium<br><br>White<br>Magnesium | ADTH700RMTUW1<br>ADTH700RMTUM1<br><br>ADTH600RMHW1<br>ADTH600RMHM1<br><br>ADTHRRW1<br>ADTHRRM1 |

iPhone® is a registered trademark of Apple, Inc.

Dimensions

| NAME                                    | PART NUMBER                                                                            | DIMENSIONS (H x W x D)                                                          |
|-----------------------------------------|----------------------------------------------------------------------------------------|---------------------------------------------------------------------------------|
| Paddle Switch, 2-Module                 | ASPD1531W4<br>ASPD1532M4<br>ASPD2032W4<br>ASPD2032M4<br>ASPD2042W4<br>ASPD2042M4       | 1.77" x 1.77" x 1.5"<br><br>1.77" x 1.77" x 1.59"<br><br>1.77" x 1.77" x 1.72"  |
| Paddle Dimmer                           | ADPD703HW4<br>ADPD703HM4<br>ADPD1103HW4<br>ADPD1103HM2<br>ADPD453LW2<br>ADPD453LM2     | 4.20" x 1.77" x 1.62"<br><br>4.20" x 2.51" x 1.62"<br><br>4.20" x 1.77" x 1.62" |
| Paddle Switch, 1-Module                 | ASPD1531W4<br>ASPD1531M4                                                               | 1.77" x 0.89" x 1.5"                                                            |
| Paddle Fan Speed Control                | AAFN4S16AW4<br>AAFN4S16AM4                                                             | 2.66" x 1.77" x 1.85"                                                           |
| Whisper Switch                          | ASWR1532W4<br>ASWR1532M4                                                               | 1.77" X 1.77" x 1.63"                                                           |
| Whisper Dimmer                          | ADWR703HW4<br>ADWR703HM4<br>ADWR1103HW4<br>ADWR1103HM4                                 | 4.20" x 1.77" x 1.77"<br><br>4.20" x 2.51" x 1.77"                              |
| Whisper Dimmer, Multi-Location Wireless | ADWR700MMUW2<br>ADWR700MMUM2<br>ADWR700MMHW2<br>ADWR700MMHM2<br>ADWRMRUW2<br>ADWRMRUM2 | 4.20" x 1.77" x 1.79"<br><br>4.20" x 1.77" x 1.79"<br><br>4.20" x 1.77" x 1.79" |
| sofTap Switch                           | ASTP1532W4<br>ASTP1532M4                                                               | 2.66" x 1.77" x 1.63"                                                           |
| sofTap Dimmer                           | ADTP703HW2<br>ADTP703HM2<br>ADTP1103HW4<br>ADTP1103HM4<br>ADTP703UW2<br>ADTP703UM2     | 4.20" x 1.77" x 1.79"<br><br>4.20" x 2.51" x 1.79"<br><br>4.20" x 1.77" x 1.79" |
| sofTap Switch, Multi-Location Wireless  | ASTPRF2W2<br>ASTPRF2M2<br>ASTPRFR2W2<br>ASTPRFR2M2                                     | 2.66" x 1.77" x 1.63"<br><br>2.66" x 1.77" x 1.63"                              |
| sofTap Switch, Whole-House Wireless     | ASTP155RMW1<br>ASTP155RMM1<br>ASTPRRW1<br>ASTPRRM1                                     | 2.66" x 1.77" x 1.63"<br><br>2.66" x 1.77" x 1.63"                              |
| sofTap Dimmer, Multi-Location Wireless  | ADTP700MMUW2<br>ADTP700MMUM2<br>ADTP700MMHW2<br>ADTP700MMHM2<br>ADTPMRUW2<br>ADTPMRUM2 | 4.20" x 1.77" x 1.79"<br><br>4.20" x 1.77" x 1.79"<br><br>4.20" x 1.77" x 1.79" |
| sofTap Dimmer, Whole-House Wireless     | ADTP700RMHW1<br>ADTP700RMHM1<br>ADTP700RMUW1<br>ADTP700RMUM1<br>ADTPRRW1<br>ADTPRRM1   | 4.20" x 1.77" x 1.79"<br><br>4.20" x 1.77" x 1.79"<br><br>4.20" x 1.77" x 1.79" |

| NAME                                   | PART NUMBER                                                                          | DIMENSIONS (H x W x D)                             |
|----------------------------------------|--------------------------------------------------------------------------------------|----------------------------------------------------|
| Push Switch                            | ASPU1532W4<br>ASPU1532M4                                                             | 1.77" X 1.77" x 1.82"                              |
| SensaSwitch, Auto-ON/<br>Auto-OFF      | ASOS32W4<br>ASOS32M4                                                                 | 2.66" x 1.77" x 1.85"                              |
| SensaSwitch, Manual-<br>ON/Auto-OFF    | ASVS12W4<br>ASVS12M4                                                                 | 2.66" x 1.77" x 1.85"                              |
| SensaSwitch, Manual-<br>ON/Timed-OFF   | ASTM2W2<br>ASTM2M2                                                                   | 2.66" x 1.77" x 1.85"                              |
| SensaDimmer, Auto-<br>ON/Auto-OFF      | ADSM703HW2<br>ADSM703HM2                                                             | 4.20" x 1.77" x 1.85"                              |
| Wave Switch                            | ASWV1532W2<br>ASWV1532M2                                                             | 2.66" x 1.77" x 1.71"                              |
| Touch Switch                           | ASTH1532W2<br>ASTH1532M2                                                             | 2.66" x 1.77" x 1.63"                              |
| Touch Switch, Whole-House Wireless     | ASTH155RMW1<br>ASTH155RMM1<br>ASTHRRW1<br>ASTHRRM1                                   | 2.66" x 1.77" x 1.63"<br><br>2.66" x 1.77" x 1.63" |
| Touch Dimmer, Multi-Location Wireless  | ADTH700MMUW2<br>ADTH700MMUM2<br>ADTHMRUW2<br>ADTHMRUM2                               | 4.20" x 1.77" x 1.79"<br><br>4.20" x 1.77" x 1.79" |
| Touch Dimmer, Whole-House Wireless     | ADTH700RMHW1<br>ADTH700RMHM1<br>ADTH700RMUW1<br>ADTH700RMUM1<br>ADTHRRW1<br>ADTHRRM1 | 4.20" x 1.77" x 1.79"<br><br>4.20" x 1.77" x 1.79" |
| Blank, 1-Module                        | AABK1W4<br>AABK1M4                                                                   | 1.77" X 0.89" x 0.96"                              |
| Tamper-Resistant Outlet, 2-Module      | ARTR152W4<br>ARTR152M4<br>ARTR202W4<br>ARTR202M4                                     | 2.12" x 1.77" x 1.73"<br><br>2.12" x 1.77" x 1.73" |
| Tamper Resistant Out-<br>let, 3-Module | ARTR153W4<br>ARTR153M4                                                               | 3" x 1.77" x 1.48"                                 |
| Tamper-Resistant GFCI, 2-Module        | AGFTR152W4<br>AGFTR152M4<br>AGFTR202W4<br>AGFTR202M4                                 | 2.66" x 1.77" x 1.82"<br><br>2.66" x 1.77" x 1.82" |
| Tamper-Resistant GFCI, 3-Module        | AGFTR153W4<br>AGFTR153M4                                                             | 3.00" x 1.76" x 1.82"                              |
| Energy-Saving ON/OFF Outlet            | ARPS152W4<br>ARPS152M4                                                               | 2.66" x 1.77" x 1.73"                              |
| Wireless Outlet                        | ARPS15RF2W4<br>ARPS15RF2M4                                                           | 2.66" x 1.76" x 1.82"                              |
| USB Outlet, 1-Module                   | ARUSBW4<br>ARUSBM4                                                                   | 1.77" X 0.89" x 1.81"                              |