

Digital Programmable Wall Heater



- ▶ 5/2 DAY PROGRAMMABLE THERMOSTAT
- ▶ LED TOUCH SCREEN OPERATION WITH ADJUSTABLE SOUND
- ▶ AUTOMATIC ADJUSTABLE WATTAGE OUTPUT
- ▶ FAN ONLY MODE
- ▶ CONVENIENT REMOTE CONTROL INCLUDED
- ▶ 5 YEAR ELEMENT WARRANTY
- ▶ APPLICATIONS INCLUDE:
 - DENS
 - BASEMENTS
 - BATHROOMS
 - BEDROOMS
 - OFFICES
 - AND MUCH MORE



OPTIONAL GRILLE COLORS



White

Gray




The Choice of Professionals

SELECTION CHART

CATALOG NUMBER	UPC	VOLTS	WATTS	AMPS	BTU/HR	WIRE SIZE
FSSWH2004	6 85360 15312 4	240	1.0 - 8.3	250 - 2000	853 - 6826	14 AWG
FSSWH1502	6 85360 15311 7	120	1.6 - 12.5	200 - 1500	682 - 5120	12 AWG
SURFACE MOUNTING FRAMES						
SMHTSSNW	6 85360 15631 6	Northern White Surface Mounting Frame - 14-5/8"W X 20-1/4"H X 3-3/4"D				
SMHTSSBL	6 85360 15630 9	Black Surface Mounting Frame - 14-5/8"W X 20-1/4"H X 3-3/4"D				

NOTE: Add W (White) suffix to catalog number for White grille. Example: FSSWH2004W


THERMOSTAT DISPLAY

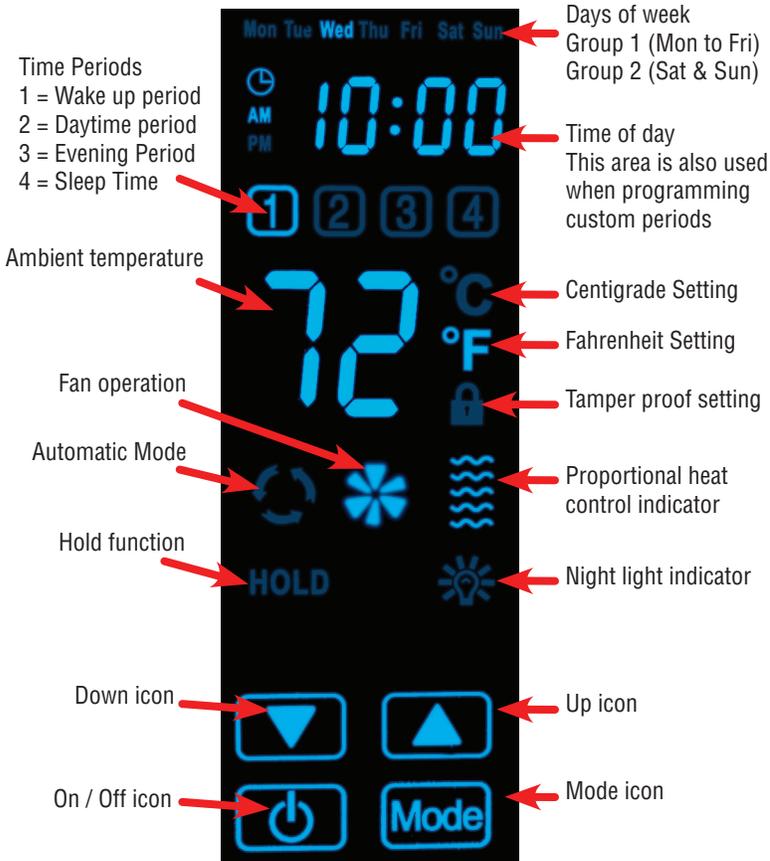

FEATURES

- ▶ Heater automatically adjusts wattage output and blower speed resulting in whisper quiet operation for optimum comfort.
- ▶ Heating element is heavy duty non-glowing steel fins brazed to steel sheathed tubular elements in a grid pattern that covers the entire discharge area.
- ▶ Built-in fan delay operates when unit is turned off after heating to prolong element life.
- ▶ 5/2 day electronic programmable built-in thermostat adaptable to fit any life-style while providing energy savings and precise temperature performance.
- ▶ Easy to use LED touch screen operation.
- ▶ Convenient remote control included.
- ▶ Contemporary, clean design with night light feature complements any decor.
- ▶ Designed for easy installation. Heater is mounted prior to wiring. Both hands are free to make field connections in roomy compartment.
- ▶ This heater is designed for installation in 2 x 4 frame or larger wall sections using the wall box provided.
- ▶ The heater may be wired with standard building wire (60°C). Refer to specification chart for correct supply voltage and wire size.

DIMENSIONS

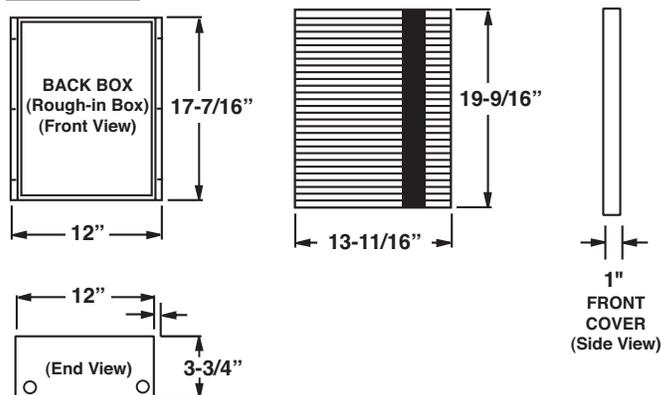

MOUNTING LIMITATIONS

Do not install heater closer than 12" to the floor, 12" to an adjacent wall, 36" to the ceiling.

Do not install heater behind towel rack or door, upside down or sideways, in the floor, ceiling, or in closets.

HEATER REMOTE

An easy to use remote control is included to provide convenient heat and power adjustment from up to 12 feet away. Heater must be in direct line of sight to operate correctly. Unit can be controlled with or without remote control.

