




Pass & Seymour

Decorator Devices Heavy-Duty Receptacles Tamper-Resistant 15 & 20A, 125V

TR26262, TR26362

Sturdy tamper-resistant receptacles in Decorator-style.

Sleek, ergonomic Decorator-style matches other Decorator devices while giving the same performance and ease of installation as our standard tamper-resistant devices. The thermoplastic dual mechanical shutter system helps prevent children from sticking objects into the receptacle. They feature screw-pressure-plate back wiring and a back wire clamp on the ground terminal.

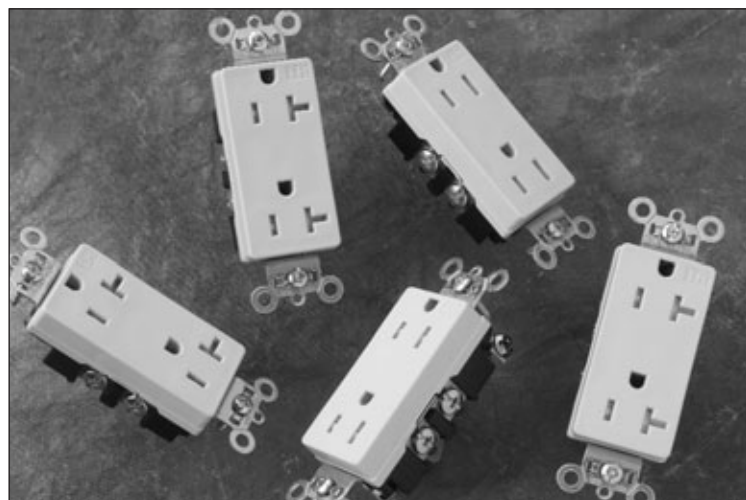

Features & Benefits

Auto-ground clip assures positive ground.

Dual mechanical shutter system to help prevent insertion of foreign objects.

One-piece brass triple-wipe power contacts for reliable plug retention.

Two drive screws anchor strap to back body and face where abrupt removal torque is strongest.

Patented external screw-pressure-plate back wire clamp on ground terminal for faster, easier installation.

Easily accessed break-off, line-contact connecting tab for fast, easy split-circuit wiring.

External screw-pressure-plate back wire clamps with #10 brass terminal screws for visual assurance of a good connection.

One-piece plated steel mounting strap with integral ground for superior long-term performance.

TR26362-I

Field Uses/Vertical Markets

■ Health Care

■ Education

■ Institutional


■ Multiple Dwelling

SF907R1 — Updated September 2006 — For latest specs visit www.legrand.us/passandseymour

Decorator Devices Heavy-Duty Receptacles Tamper-Resistant 15 & 20A, 125V

Ordering Information

Catalog Number	Rating A. V.	Color	NEMA Config. No.
Duplex Receptacles Back & Side Wire			
TR26262-I	15 125	Ivory	5-15R
TR26262-W	15 125	White	5-15R
TR26262	15 125	Brown	5-15R
TR26262-GRY	15 125	Gray	5-15R
TR26262-BK	15 125	Black	5-15R
TR26262-RED	15 125	Red	5-15R
TR26262-LA	15 125	Light Almond	5-15R
TR26362-I	20 125	Ivory	5-20R
TR26362-W	20 125	White	5-20R
TR26362	20 125	Brown	5-20R
TR26362-GRY	20 125	Gray	5-20R
TR26362-BK	20 125	Black	5-20R
TR26362-RED	20 125	Red	5-20R
TR26362-LA	20 125	Light Almond	5-20R

 

For more information on these and other P&S products refer to our Catalog or visit our web site.

Decorator Devices Heavy-Duty Receptacles Tamper-Resistant 15 & 20A, 125V

legrand®
Pass & Seymour

Technical Specifications

3rd Party Compliance

UL Listed, File Number E140596, Standard UL498.
Federal Specification WC596.
CSA Certified, File Number LR16063, Standard CSA-C22.2 No. 42.
Conforms to NEMA WD-1 and WD-6.

Performance

Electrical


Dielectric Voltage	Withstands 2000V minimum
Maximum Working Voltage	250V
Current Interrupting	Certified for current interrupting at full-rated current
Temperature Rise	Maximum 30°C temperature rise at full-rated current after 50 cycles of overload at 150% of rated current with direct current

Mechanical

Terminal Identification	Terminal Identification in accordance with UL498 (Brass, White, Green)
Terminal Accommodation	#14 AWG – #10 AWG copper conductor only
Product Identification	Ratings are a permanent part of the device

Environmental

Flammability	UL94 V2
Operating Temperature	Maximum continuous +60°C, minimum -40°C without impact

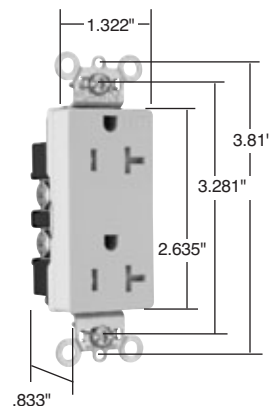

**Dimensions for
15 & 20 Amp**


Materials

Face	Nylon	Terminal Screws	#10 Tri-Drive Brass (Neutral = Nickel-Plated Steel)
Back Body	Nylon	Ground Screw	#10 Hex Tri-Drive Brass
Line Contacts	.036 688 Brass	Assembly Drive Screw	Zinc-Plated Steel
Mounting Strap	Plated Steel	Auto-Ground Clip	Steel
Ground Contacts	Strap with Integral Ground	Mounting Screws	Tri-Drive Steel
Pressure Plate	.031 260 Brass		
Tamper Shutter	Thermoplastic		

Warranty


1 Year

Complimentary Devices & Accessories

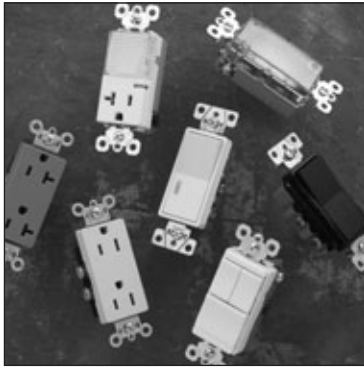


DECORATOR DEVICES

- Construction Grade Switches
- Specification Grade Combo Switches
- Construction Grade Receptacles
- Commercial Grade Receptacles
- Specification Grade Hallway Lights

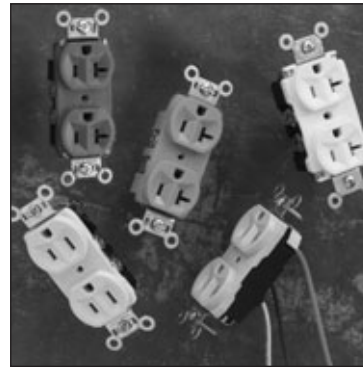


STRAIGHT BLADE RECEPTACLES

- Extra Heavy-Duty
- Heavy-Duty
- Hard Use
- Construction Grade
- Construction Grade Leaded
- Commercial Grade

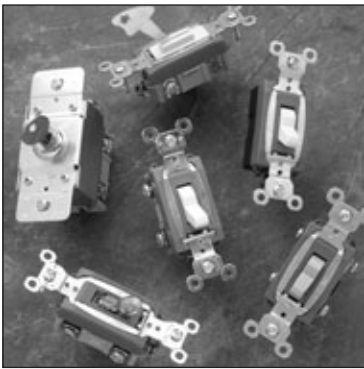

SWITCHES

- Extra Heavy-Duty
- Extra Heavy-Duty Lighted
- Extra Heavy-Duty Security
- Extra Heavy-Duty Locking
- Hard Use
- Commercial Grade

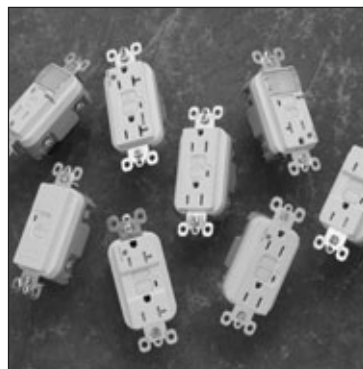

GFCIs

- Specification Grade
- Dead Front



WALL PLATES

- TradeMaster® Thermoplastic Nylon
- Screwless Polycarbonate
- Stainless Steel
- Brass
- Aluminum
- Dustproof Stainless Steel Covers

Also available...

- | | | | |
|----------------------------------|--------------------------------------|-------------------------------|-------------------------------|
| ■ Light Almond Devices | ■ Ground Continuity Monitoring (GCM) | ■ Turnlok® Locking Devices | ■ IEC 309 Industrial Products |
| ■ Hospital Grade Devices | ■ Straight Blade Plugs & Connectors | ■ Weatherproof Boxes & Covers | ■ Flexcor® Wire Mesh Grips |
| ■ PlugTail™ Devices | | | ■ Configurable Solutions |
| ■ TVSS & Isolated Ground Devices | | | |



Legrand/Pass & Seymour
P.O. Box 4822
Syracuse, NY 13221-4822
800-223-4185

North America Headquarters
60 Woodlawn Street
West Hartford, CT 06110
Phone: 1.877.BY.LEGRAND (295.3472)
Fax: 1.860.232.2062
www.legrand.us

Legrand Canada
570 Applewood Crescent
Vaughan, ON, L4K 4B4
Phone: 905.738.9195
Fax: 905.738.9721
www.legrand.ca