

Submersible Pedestal Connectors

ISPB, ISPC SERIES



FEATURES

- Manufactured from high strength 6061-T6 aluminum alloy, providing premium electrical and mechanical performance.
- Radial tipped set-screws reduce conductor strand damage, and the range taking design allows for many sizes and types of conductors — all in one connector.
- Encapsulated in rubber with a nominal thickness of 125 mils. and high dielectric strength.
- ISPC connectors (clear) allow for an easier installation.
- Abrasion and chemical resistant, UV resistant.
- Will not support combustion.

RATINGS

Meets or exceeds ANSI C119.4 Class A specifications

TEMPERATURE RATING/VOLTAGE:

AL9CU. Cold temperature rated to -45 °C, rated 600V, 90 °C.

WIRE TYPE:


For use with copper and/or aluminum cables.

INSTALLATION INSTRUCTIONS:

See page 214 for detailed installation information.

All dimensional data is listed in inches.

CAT. NO.	NO. OF PORTS
ISPB350-3	3
ISPB350-4	4
ISPB350-6	6
ISPC350-3	3
ISPC350-4	4
ISPC350-6	6
ISPB600-3	3
ISPB600-4	4
ISPB600-6	6

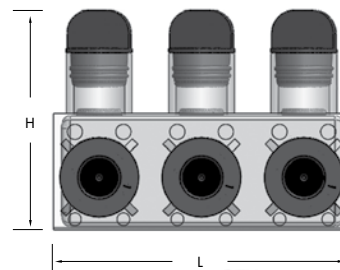



COLOR	WIRE RANGE	LENGTH (L)	WIDTH (W)	HEIGHT (H)	TORQUE VALUE (IN./LBS.)	HEX SIZE	STD. CTN. QTY.
Black	350 MCM-12 AWG	3.610	4.190	3.060	360	5/16	1
Black	350 MCM-12 AWG	4.800	4.190	3.060	360	5/16	1
Black	350 MCM-12 AWG	7.180	4.190	3.060	360	5/16	1
Clear	350 MCM-12 AWG	3.610	4.190	3.060	360	5/16	1
Clear	350 MCM-12 AWG	4.800	4.190	3.060	360	5/16	1
Clear	350 MCM-12 AWG	7.180	4.190	3.060	360	5/16	1
Black	600 MCM-12 AWG	4.870	5.460	3.130	550	5/16	1
Black	600 MCM-12 AWG	6.560	5.460	3.130	550	5/16	1
Black	600 MCM-12 AWG	9.940	5.460	3.130	550	5/16	1

