


T&B Conduit Fittings

Liquidtight Flexible Metal Conduit Fittings




External Grounding Strap

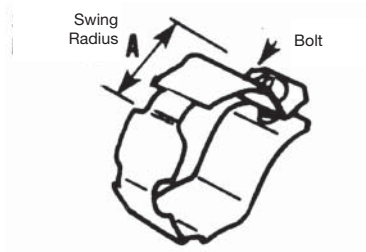

For retrofit applications. Includes strap, nut and bolt.

Cat. No.	Conduit Size	A Swing Radius	B Bolt Size
GR1W	3/8"	1	10-24
GR2W	1/2"	1-1/16	10-24
GR3W	3/4"	1-3/8	1/4-20
GR4W	1"	1-1/2	1/4-20
GR5W	1-1/4"	1-7/8	5/16-18

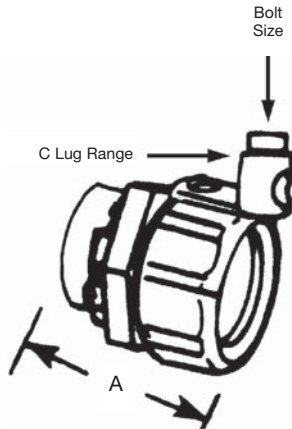

Liquidtight to Rigid External Ground Adaptor



Cat. No.	Conduit Size	A Overall Length	B Bolt Size	C Lug Range
5271GR*	3/8"	1-15/32	10-24	14-8
5272GR	1/2"	1-3/8	10-24	14-8
5273GR	3/4"	1-21/32	1/4-20	14-4
5274GR	1"	1-7/8	1/4-20	14-4
5275GR	1-1/4"	2-1/4	5/16-18	8-1/0
5276GR	1-1/4"	2-29/32	3/8-16	3/8-16

* 3/8" conduit fittings have 1/4" trade size hub.

For Dura-Plate™ finish add prefix 040- to Cat. No. Consult Customer Service for details.

Revolver® Grounding Device



Cat. No.	Conduit Size
38GR-TB	3/8"
12GR-TB	1/2"
34GR-TB	3/4"
1GR-TB	1"

The grounding device is a combination of a set screw and a grounding lug that can be used to retrofit any existing liquidtight fitting to an externally grounded version.