


# Conduit Body Covers

## Zinc Plated Steel with Screws

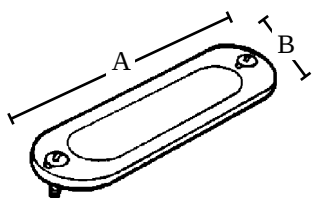

### Features

- Domed design allows for additional wiring space
- Includes screws

### Applications

- Designed for use with Topaz Conduit Bodies; interchangeable with all major brands

### Standard Material


- Steel

### Standard Finish

- Zinc plated

| Catalog Number | UPC   | Size                 | Unit Carton | Ship Case | Weight/Case | A      | B     |
|----------------|-------|----------------------|-------------|-----------|-------------|--------|-------|
| <b>571S</b>    | 15520 | <b>1/2"</b>          | 25          | 250       | 15          | 3.875  | 1.310 |
| <b>572S</b>    | 15530 | <b>3/4"</b>          | 25          | 250       | 20          | 4.625  | 1.520 |
| <b>573S</b>    | 15540 | <b>1"</b>            | 10          | 100       | 8           | 5.315  | 1.710 |
| <b>574S</b>    | 15550 | <b>1-1/4"-1-1/2"</b> | ---         | 25        | 4           | 7.240  | 2.510 |
| <b>576S</b>    | 15560 | <b>2"</b>            | ---         | 25        | 7           | 9.484  | 3.110 |
| <b>577S</b>    | 15570 | <b>2-1/2"-3"</b>     | ---         | 10        | 7           | 12.187 | 4.440 |
| <b>579S</b>    | 15580 | <b>3-1/2"-4"</b>     | ---         | 5         | 9           | 14.937 | 5.500 |

## Malleable Iron

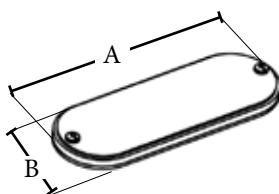

### Features

- Heavy duty malleable iron
- Includes screws

### Applications

- Designed for use with Topaz Conduit Bodies; interchangeable with all major brands

### Standard Material

- Malleable iron

### Standard Finish

- Zinc plated

| Catalog Number | UPC   | Size                 | Unit Carton | Ship Case | Weight/Case | A      | B     |
|----------------|-------|----------------------|-------------|-----------|-------------|--------|-------|
| <b>571M</b>    | 86402 | <b>1/2"</b>          | 25          | 250       | 23          | 3.875  | 1.310 |
| <b>572M</b>    | 86403 | <b>3/4"</b>          | 25          | 250       | 31          | 4.625  | 1.520 |
| <b>573M</b>    | 86404 | <b>1"</b>            | 10          | 100       | 41          | 5.315  | 1.710 |
| <b>574M</b>    | 86405 | <b>1-1/4"-1-1/2"</b> | ---         | 25        | 91          | 7.240  | 2.510 |
| <b>576M</b>    | 86406 | <b>2"</b>            | ---         | 25        | 208         | 9.484  | 3.110 |
| <b>577M</b>    | 86407 | <b>2-1/2"-3"</b>     | ---         | 10        | 358         | 12.187 | 4.440 |
| <b>579M</b>    | 86408 | <b>3-1/2"-4"</b>     | ---         | 5         | 56          | 14.937 | 5.500 |