

## COVERS ONLY WIREWAY

## COVERS ONLY S.C. BOXES

| Cat No.   | Price  | Cat No.     | List Price |
|-----------|--------|-------------|------------|
| CO221     | \$4.00 | CO 6x6      | \$5.00     |
| CO222     | 8.00   | CO 8x8      | 6.00       |
| CO223     | 11.00  | CO 8x6      | 5.50       |
| CO224     | 12.00  | CO 10x10    | 7.00       |
| CO225     | 15.00  | CO 12x12    | 8.00       |
| L2-90     | 11.00  | CO 16x16    | 19.00      |
| L2-45     | 11.00  | CO 18x12    | 22.00      |
| T2        | 15.00  | CO 18X15    | 23.00      |
| CO441     | 5.00   | CO 18X18    | 23.00      |
| CO442     | 9.00   | CO 24X12    | 25.00      |
| CO443     | 11.00  | CO 24X18    | 48.00      |
| CO444     | 13.00  | CO 24x24    | 54.00      |
| CO445     | 15.00  | CO 30x18    | 72.00      |
| L4-90     | 14.00  | CO 30x24    | 79.00      |
| L4-45     | 14.00  | CO 30x30    | 84.00      |
| T4        | 18.00  | CO 36x24    | 92.00      |
| CO661     | 7.00   | CO 36x30    | 102.00     |
| CO662     | 13.00  | CO 36x36    | 110.00     |
| CO663     | 16.00  | CO 48x36    | 145.00     |
| CO664     | 22.00  | CO 48x48    | 186.00     |
| CO665     | 24.00  | CO N-205    | 30.00      |
| L6-90     | 18.00  | CO N-215    | 62.00      |
| L6-45     | 18.00  | CO N-484    | 109.00     |
| T6        | 26.00  | CO RTN-205  | 36.00      |
| CO881     | 12.00  | CO RTN-215  | 110.00     |
| CO882     | 23.00  | CO RTN-484  | 200.00     |
| CO883     | 29.00  | CO WP 6x6   | 14.00      |
| CO884     | 35.00  | CO WP 8x8   | 20.00      |
| CO885     | 42.00  | CO WP 10x10 | 25.00      |
| L8-90     | 34.00  | CO WP 12x12 | 32.00      |
| L8-45     | 34.00  | CO WP 18x18 | 44.00      |
| T8        | 36.00  | CO WP 24x24 | 80.00      |
| CO1010-1  | 16.00  | CO WP 36x36 | 110.00     |
| CO1010-2  | 26.00  |             |            |
| CO1010-3  | 42.00  |             |            |
| CO1010-4  | 48.00  |             |            |
| CO1010-5  | 55.00  |             |            |
| L10-90    | 45.00  |             |            |
| L10-45    | 45.00  |             |            |
| T10       | 54.00  |             |            |
| CO1212-1  | 18.00  |             |            |
| CO1212-2  | 37.00  |             |            |
| CO1212-3  | 50.00  |             |            |
| CO1212-4  | 60.00  |             |            |
| CO1212-4  | 75.00  |             |            |
| CO 1212-5 | 42.00  |             |            |
| L12-90    | 52.00  |             |            |
| L12-45    | 52.00  |             |            |



## GANG BOXES 1 5/8" deep

(1/2" & 3/4" knockouts)



| CAT NO.  | Length  | Cubic Inch Capacity | Knockouts Sides | Knockouts Ends | Knockouts Bottom | List Price |
|----------|---------|---------------------|-----------------|----------------|------------------|------------|
| 2G 1-5/8 | 7       | 46.0                | 8               | 4              | 4 2              | \$6.58     |
| 3G 1-5/8 | 8 7/8   | 58.5                | 10              | 4              | 6 4              | 8.34       |
| 4G 1-5/8 | 10 5/8  | 71.0                | 12              | 4              | 6 4              | 11.62      |
| 5G 1-5/8 | 12 1/2  | 84.0                | 14              | 4              | 6 4              | 18.72      |
| 6G 1-5/8 | 14 1/4  | 95.0                | 16              | 4              | 6 4              | 32.90      |
| 7G 1-5/8 | 16 1/16 | 108.5               | 18              | 4              | 6 4              | 55.20      |
| 8G 1-5/8 | 17 7/8  | 122.0               | 20              | 4              | 6 4              | 60.96      |
| 9G 1-5/8 | 19 3/4  | 133.5               | 22              | 4              | 6 4              | 82.80      |

## GANG BOXES 2 1/2" deep




AVAILABLE IN BOTH 1/2-3/4 AND 3/4-1 KO CONFIGURATIONS

| CAT NO.  | Length  | Cubic Inch Capacity | Knockouts Sides | Knockouts Ends | Knockouts Bottom | List Price |
|----------|---------|---------------------|-----------------|----------------|------------------|------------|
| 2G 2-1/2 | 7       | 71.0                | 8               | 4              | 4 2              | \$8.86     |
| 3G 2-1/2 | 8 7/8   | 90.5                | 10              | 4              | 6 4              | 11.38      |
| 4G 2-1/2 | 10 5/8  | 111.8               | 12              | 4              | 6 4              | 18.98      |
| 5G 2-1/2 | 12 1/2  | 128.7               | 14              | 4              | 6 4              | 32.20      |
| 6G 2-1/2 | 14 1/4  | 148.2               | 16              | 4              | 6 4              | 56.36      |
| 7G 2-1/2 | 16 1/16 | 169.5               | 18              | 4              | 6 4              | 73.60      |
| 8G 2-1/2 | 17 7/8  | 188.8               | 20              | 4              | 6 4              | 92.00      |
| 9G 2-1/2 | 19 3/4  | 208.8               | 22              | 4              | 6 4              | 109.26     |


## RAISED COVERS

### 1/2" RAISED COVERS

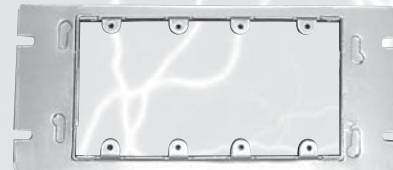

| Part#  | # of Gangs | Cubic Inch | Description         | Length Capacity | List Price |
|--------|------------|------------|---------------------|-----------------|------------|
| 2G-1/2 | 2          | 8.1        | Fits 2 Gang Box     | 7               | \$4.60     |
| 3G-1/2 | 3          | 11.7       | Fits 3 & 2 Gang Box | 8 13/16         | 5.76       |
| 4G-1/2 | 4          | 14.9       | Fits 4 & 3 Gang Box | 10 5/8          | 6.44       |
| 5G-1/2 | 5          | 17.5       | Fits 5 & 4 Gang Box | 12 7/16         | 8.86       |
| 6G-1/2 | 6          | 20.4       | Fits 6 & 5 Gang Box | 14 1/4          | 18.72      |
| 7G-1/2 | 7          | 24.1       | Fits 7 & 6 Gang Box | 16 1/16         | 35.42      |
| 8G-1/2 | 8          | 26.9       | Fits 8 & 7 Gang Box | 17 7/8          | 43.64      |
| 9G-1/2 | 9          | 31.8       | Fits 9 & 8 Gang Box | 19 11/16        | 50.60      |

### 3/4" RAISED COVERS

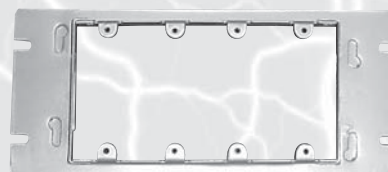

| Part#  | # of Gangs | Cubic Inch | Description         | Length Capacity | List Price |
|--------|------------|------------|---------------------|-----------------|------------|
| 2G-3/4 | 2          | 11.2       | Fits 2 Gang Box     | 7               | \$4.02     |
| 3G-3/4 | 3          | 17.1       | Fits 3 & 2 Gang Box | 8 13/16         | 4.72       |
| 4G-3/4 | 4          | 21.6       | Fits 4 & 3 Gang Box | 10 5/8          | 6.32       |
| 5G-3/4 | 5          | 26.2       | Fits 5 & 4 Gang Box | 12 7/16         | 8.86       |
| 6G-3/4 | 6          | 30.5       | Fits 6 & 5 Gang Box | 14 1/4          | 13.80      |
| 7G-3/4 | 7          | 36.1       | Fits 7 & 6 Gang Box | 16 1/16         | 24.16      |
| 8G-3/4 | 8          | 41.3       | Fits 8 & 7 Gang Box | 17 7/8          | 33.36      |
| 9G-3/4 | 9          | 46.3       | Fits 9 & 8 Gang Box | 19 11/16        | 42.56      |



## GANG BOX COLLARS (1/2" & 3/4" knockouts)



### GANG BOX COLLARS 1 5/8" deep


| Part #    | Length  | Cubic Inch Capacity | Knockouts Sides | Knockouts Ends | List Price |
|-----------|---------|---------------------|-----------------|----------------|------------|
| COLL158-2 | 7       | 46.0                | 8               | 4              | \$13.48    |
| COLL158-3 | 8 7/8   | 58.5                | 10              | 4              | 15.94      |
| COLL158-4 | 10 5/8  | 71.0                | 12              | 4              | 16.34      |
| COLL158-5 | 12 1/2  | 84.0                | 14              | 4              | 21.58      |
| COLL158-6 | 14 1/4  | 95.0                | 16              | 4              | 37.28      |
| COLL158-7 | 16 1/16 | 108.5               | 18              | 4              | 58.92      |
| COLL158-8 | 17 7/8  | 122.0               | 20              | 4              | 67.46      |
| COLL158-9 | 19 3/4  | 133.5               | 22              | 4              | 80.96      |

### GANG BOX COLLARS 2 1/2" deep

| Part #    | Length  | Cubic Inch Capacity | Knockouts Sides | Knockouts Ends | List Price |
|-----------|---------|---------------------|-----------------|----------------|------------|
| COLL212-2 | 7       | 71.0                | 8               | 4              | \$15.94    |
| COLL212-3 | 8 7/8   | 90.5                | 10              | 4              | 20.24      |
| COLL212-4 | 10 5/8  | 111.82              | 12              | 4              | 22.72      |
| COLL212-5 | 12 1/2  | 128.7               | 14              | 4              | 30.54      |
| COLL212-6 | 14 1/4  | 148.2               | 16              | 4              | 53.98      |
| COLL212-7 | 16 1/16 | 169.5               | 18              | 4              | 69.60      |
| COLL212-8 | 17 7/8  | 188.8               | 20              | 4              | 83.80      |
| COLL212-9 | 19 3/4  | 208.8               | 22              | 4              | 98.08      |

## FLAT BLANK COVERS

| Part#   | # of Gangs | Description     | Length   | List Price |
|---------|------------|-----------------|----------|------------|
| COVFL-2 | 2          | Fits 2 Gang Box | 7        | \$1.38     |
| COVFL-3 | 3          | Fits 3 Gang Box | 8 13/16  | 2.08       |
| COVFL-4 | 4          | Fits 4 Gang Box | 10 5/8   | 2.82       |
| COVFL-5 | 5          | Fits 5 Gang Box | 12 7/16  | 4.14       |
| COVFL-6 | 6          | Fits 6 Gang Box | 14 1/4   | 8.06       |
| COVFL-7 | 7          | Fits 7 Gang Box | 16 1/16  | 14.96      |
| COVFL-8 | 8          | Fits 8 Gang Box | 17 7/8   | 18.40      |
| COVFL-9 | 9          | Fits 9 Gang Box | 19 11/16 | 20.70      |

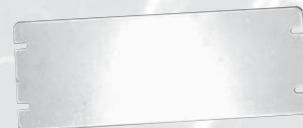

## TOGGLE SWITCH COVERS

| Part#   | # of Gangs | Description     | Length   | List Price |
|---------|------------|-----------------|----------|------------|
| COVTS-2 | 2          | Fits 2 Gang Box | 7        | \$3.16     |
| COVTS-3 | 3          | Fits 3 Gang Box | 8 13/16  | 4.28       |
| COVTS-4 | 4          | Fits 4 Gang Box | 10 5/8   | 5.82       |
| COVTS-5 | 5          | Fits 5 Gang Box | 12 7/16  | 7.60       |
| COVTS-6 | 6          | Fits 6 Gang Box | 14 1/4   | 8.46       |
| COVTS-7 | 7          | Fits 7 Gang Box | 16 1/16  | 18.98      |
| COVTS-8 | 8          | Fits 8 Gang Box | 17 7/8   | 22.78      |
| COVTS-9 | 9          | Fits 9 Gang Box | 19 11/16 | 27.84      |



## GANG BOX PARTITIONS

| Part#      | Description                                        | List Price |
|------------|----------------------------------------------------|------------|
| PART158-SQ | Fits 1 5/8" Deep Gang Box<br>No Rise on Cover-Flat | \$2.50     |
| PART158-12 | Fits 1 5/8" Deep Gang Box<br>w/ 1/2" Cover Rise    | 4.25       |
| PART158-34 | Fits 1 5/8" Deep Gang Box<br>w/ 3/4" Cover Rise    | 4.25       |
| PART212-SQ | Fits 2 1/2" Deep Gang Box<br>No Rise on Cover-Flat | 3.00       |
| PART212-12 | Fits 2 1/2" Deep Gang Box<br>w/ 1/2" Cover Rise    | 4.90       |
| PART212-34 | Fits 2 1/2" Deep Gang Box<br>w/ 3/4" Cover Rise    | 5.60       |