



TYPE GAR (CONTINUED)

FENCE POST GROUNDING CONNECTOR

Catalog Number	Conductor			H	J	W
	Tube I.P.S.	Rod	Cable			
GAR204C	3	3 - 3-1/2	8 Sol. - 4 Str.	5-5/8	3/8	4-3/4
GAR2026			4 Sol. - 2/0 Str.			
GAR2029			2/0 Sol. - 250			
GAR2034			300-500	6-3/8	1/2	5-1/4
GAR214C	3-1/2	3-1/2 - 4	8 Sol. - 4 Str.	6-1/4	3/8	5-3/8
GAR2126			4 Sol. - 2/0 Str.			
GAR2129			2/0 Sol. - 250			
GAR2134			300-500	6-3/4	1/2	5-3/4
GAR224C	4	4 - 4-1/2	8 Sol. - 4 Str.	6-3/8	3/8	5-7/8
GAR2226			4 Sol. - 2/0 Str.			
GAR2229			2/0 Sol. - 250			
GAR2234			300-500	6-7/8	1/2	6-1/4
GAR244C	5	-	8 Sol. - 4 Str.	7-3/4	3/8	6-7/8
GAR2426			4 Sol. - 2/0 Str.			
GAR2429			2/0 Sol. - 250		1/2	7-1/4
GAR2434			300-500	8-5/8		
GAR8629	6	-	2/0 Sol. - 250	8-13/16	1/2	8-3/8

Contact BURNDY for additional pipe and wire size combinations not shown.



1

TYPE GAR



FENCE POST GROUNDING CONNECTOR

FOR PARALLEL OR 90°
COPPER CABLE
CONNECTION


TO ROD OR PIPE WITH
THE SAME CONNECTOR

High copper alloy ground connector for joining a range of cable, parallel or at right angles to rod or tube. Especially good for fence posts. High copper alloy cast body with DURUM U-bolts, nuts and lockwashers, permit entire connection to be buried in ground or concrete without danger of corrosion.

- One-wrench installation.
- UL 467 listed.
- Acceptable for direct burial.

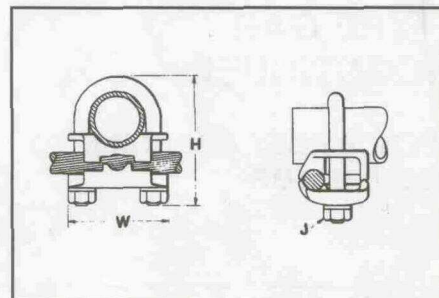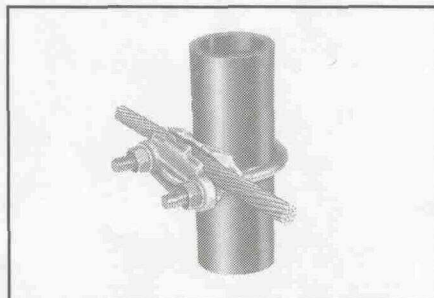

2

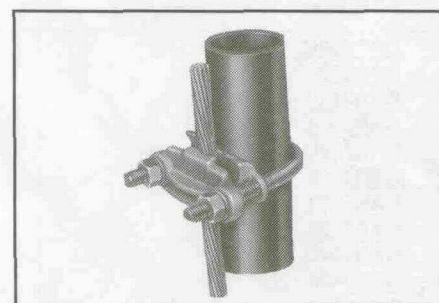

D-27

Catalog Number	Conductor			H	J	W
	Tube I.P.S.	Rod	Cable			
GAR114C	1/4	1/2	8 Sol. - 4 Str.	2-1/2	3/8	1-7/8
GAR1126			4 Sol. - 2/0 Str.			
GAR1129			2/0 Sol. - 250			
GAR644C	3/8	5/8 - 3/4	8 Sol. - 4 Str.	2-7/8		2-1/8
GAR6426			4 Sol. - 2/0 Str.			
GAR6429			2/0 Sol. - 250			
GAR6434	1/2 - 3/4	7/8 - 1	300-500	3-1/2	1/2	2-1/2
GAR144C			8 Sol. - 4 Str.	2-3/4	3/8	2-3/8
GAR1426			4 Sol. - 2/0 Str.	3		
GAR1429			2/0 Sol. - 250			
GAR1434			300-500	3-3/4	1/2	2-3/4
GAR154C	1	1-1/8 - 1-1/4	8 Sol. - 4 Str.	2-7/8	3/8	2-5/8
GAR1526			4 Sol. - 2/0 Str.	3-3/8		
GAR1529			2/0 Sol. - 250	4-1/2		
GAR1534			300-500			
GAR164C	1-1/4	1-3/8 - 1-1/2	8 Sol. - 4 Str.	3-1/2	3/8	3
GAR1626			4 Sol. - 2/0 Str.			
GAR1629			2/0 Sol. - 250			
GAR1634			300-500			
GAR174C	1-1/2	1-5/8 - 1-7/8	8 Sol. - 4 Str.	4	3/8	3-1/4
GAR1726			4 Sol. - 2/0 Str.			
GAR1729			2/0 Sol. - 250			
GAR1734			300-500			
GAR184C	2	2 - 2-3/8	8 Sol. - 4 Str.	4-1/4	3/8	3-3/4
GAR1826			4 Sol. - 2/0 Str.			
GAR1829			2/0 Sol. - 250			
GAR1834			300-500			
GAR194C	2-1/2	2-1/2 - -7/8	8 Sol. - 4 Str.	5	3/8	4-1/4
GAR1926			4 Sol. - 2/0 Str.			
GAR1929			2/0 Sol. - 250			
GAR1934			300-500			