



Shown: 300018OBB Oil Brushed Bronze™ Finish with Walnut Blades

56" Hatteras Bay™



300018BAB
Burnished Antique Finish
Poplar Burl Blades



300018BSS
Brushed Stainless Steel Finish
Dark Oak Blades



300018DBK
Distressed Black Finish
Walnut Blades

BLADE SPECS

Fan Finish Blade Finish & Part Number
(Side 1) (Reversible)

BAB Burnished Antique Brass	Elm Burl FB300018 BAB	Poplar Burl FB300018 BAB
BSS Brushed Stainless Steel	Medium Oak FB300018 BSS	Dark Oak FB300018 BSS
DBK Distressed Black	Cherry FB300018 DBK	Walnut FB300018 DBK
OB Oil Brushed Bronze™	Cherry FB300018 OB	Walnut FB300018 OB

INCLUDED FEATURES

Blades (5) Included

- 14° Pitch
- 56" Sweep
- Reversible
- Wood

Downrods 12" Downrod with 1" (O.D.)

Downlight Integrated. Uses (4) E-12
40-W Krypton/T3 Lamps

Downlight Glass Fresnel Lens
(Etched White Inside)

Optional Downlight N/A

Uplight N/A

Uplight Glass N/A

Low Ceiling Adaptable Yes, Flush Mount
Included. Note: Decor trim must be
removed for flush mount application.

Control 3-Speed CoolTouch™ -
Full Function

FAN FEATURES

Mounting Slope – Pitch 22° or 4/12

Lead Wire 78"

cUL Listed Indoor

Hanging Weight 33.00 lbs.

Warranty Limited Lifetime

MOTOR FEATURES

Motor Size/Type 188mm x 25mm, AC

Amps 0.66 on High

RPM 149 on High

Energy Star N/A

INCLUDED CONTROLS

**3-SPEED
COOLTOUCH™
FULL FUNCTION**

- 3 Forward Speeds
& Reverse
- Lights On/Off with
Full Range Dimming
- Motor Off



OPTIONAL CONTROLS



370038MULTR

WALL TRANSMITTER - FULL FUNCTION

See pages 306-308 for more information.

COORDINATING LIGHTING

To see the complete Hatteras Bay™
Collection visit kichler.com.




HANGING MEASUREMENTS

WITH 12" DOWNROD

Fixture Drop (from ceiling)	Blade Drop (from ceiling)	Housing (width)	Ceiling Canopy (width)
A: 22.50"	B: 18.50"	C: 15.25"	D: 6.63"

FLUSH MOUNT

Fixture Drop (from ceiling)	Blade Drop (from ceiling)	Housing (width)	Ceiling Canopy (width)
A: 11.25"	B: 7.25"	C: 15.25"	D: 6.63"

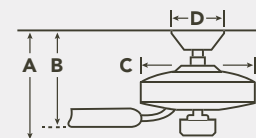

AIR PERFORMANCE

AIRFLOW	POWER USAGE	AIRFLOW EFFICIENCY
5515	80	69
Cubic Ft. Per Minute on High	Watts on High (Excludes Lights)	Cubic Ft. Per Minute Per Watt



Shown: 310117WZC Weathered Zinc Finish with Dark Walnut Blades

60" Hatteras Bay™ Patio



310117DBK
Distressed Black Finish
Cherry Blades



310117TZP
Tannery Bronze™ Finish
Walnut Blades



310117WCP
Weathered Copper™ Finish
Medium Walnut Blades

BLADE SPECS

Fan Finish Blade Finish & Part Number
(Side 1) (Reversible)

DBK Distressed Black	Cherry FB310117 DBK	Walnut FB310117 DBK
TZP Tannery Bronze™	Cherry FB310117 TZP	Walnut FB310117 TZP
WCP Weathered Copper™	Medium Walnut FB310117 WCP	Dark Walnut FB310117 WCP
WZC Weathered Zinc	Medium Walnut FB310117 WZC	Dark Walnut FB310117 WZC

INCLUDED FEATURES

Blades (5) Included

- 12° Pitch
- 60" Sweep
- Reversible
- ABS

Downrods 6" Downrod with 1" (O.D.)

Downlight Integrated. Uses (4) E-12
40-W B-10.5 Lamps

Downlight Glass Fresnel Lens

Optional Downlight N/A

Uplight N/A

Uplight Glass N/A

Low Ceiling Adaptable Yes, Flush Mount
Canopy Included.

Control Wall Control System -
Full Function

FAN FEATURES

Mounting Slope – Pitch 22° or 4/12

Lead Wire 78"

cUL Listed Damp

Hanging Weight 32.36 lbs.

Warranty Limited Lifetime

MOTOR FEATURES

Motor Size/Type 188mm x 25mm, AC

Amps 0.57 on High

RPM 150 on High

Energy Star N/A

INCLUDED CONTROLS

**WALL CONTROL SYSTEM – FULL FUNCTION**

- 3 Forward Speeds & Reverse
- Lights On/Off with Full Range Dimming
- Motor Off
- Receiver Included
- White Faceplate Included

OPTIONAL CONTROLS



337009WHTR

COOLTOUCH™ TRANSMITTER – FULL FUNCTION

See pages 306-308 for more information.

COORDINATING LIGHTING

To see the complete Hatteras Bay™
Collection visit kichler.com.

**Wall
Lantern**
49064OZ




**Wall
Lantern**
49067OZ



HANGING MEASUREMENTS

WITH 6" DOWNROD

Fixture Drop (from ceiling)	Blade Drop (from ceiling)	Housing (width)	Ceiling Canopy (width)
A: 17.52"	B: 12.90"	C: 15.36"	D: 6.63"

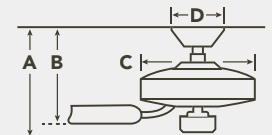

AIR PERFORMANCE

AIRFLOW	POWER USAGE	AIRFLOW EFFICIENCY
6665 Cubic Ft. Per Minute on High	69 Watts on High (Excludes Lights)	97 Cubic Ft. Per Minute Per Watt





Shown: 310101WCP Weathered Copper Finish with Medium Walnut Blades

44" Hatteras Bay™ Patio



310101GST
Galvanized Steel Finish
Walnut Blades



310101TZP
Tannery Bronze™ Finish
Cherry Blades

BLADE SPECS

Fan Finish Blade Finish & Part Number
(Side 1) (Reversible)



INCLUDED FEATURES

Blades (5) Included

- 14° Pitch
- 44" Sweep
- Reversible
- ABS

Downrods 12" Downrod with 1" (O.D.)

Downlight Integrated. Uses (4) E-12 40-W Krypton/T3 Lamps

Downlight Glass Fresnel Lens

Optional Downlight N/A

Uplight N/A

Uplight Glass N/A

Low Ceiling Adaptable Yes, Flush Mount Canopy Included. Note: Must remove downrod decor.

Control 3-Speed CoolTouch™ - Full Function

FAN FEATURES

Mounting Slope – Pitch 22° or 4/12

Lead Wire 78"

cUL Listed Damp

Hanging Weight 24.50 lbs.

Warranty Limited Lifetime

MOTOR FEATURES

Motor Size/Type 153mm x 17mm, AC

Amps 0.45 on High

RPM 213 on High

Energy Star N/A

INCLUDED CONTROLS

3-SPEED COOLTOUCH™ FULL FUNCTION

- 3 Forward Speeds & Reverse
- Lights On/Off with Full Range Dimming
- Motor Off



OPTIONAL CONTROLS



370038MULTR

WALL TRANSMITTER - FULL FUNCTION

See pages 306-308 for more information. Note: Receiver is WET rated. Transmitter for indoor use.

COORDINATING LIGHTING

To see the complete Hatteras Bay™ Patio Collection visit kichler.com.

Wall Lantern
49064OZ



Wall Lantern
49067OZ




HANGING MEASUREMENTS

WITH 12" DOWNROD

Fixture Drop (from ceiling)	Blade Drop (from ceiling)	Housing (width)	Ceiling Canopy (width)
A: 22.50"	B: 18.50"	C: 14.00"	D: 6.63"

FLUSH MOUNT

Fixture Drop (from ceiling)	Blade Drop (from ceiling)	Housing (width)	Ceiling Canopy (width)
A: 11.25"	B: 7.25"	C: 14.00"	D: 6.63"

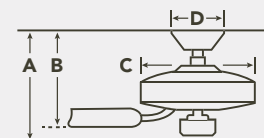

AIR PERFORMANCE

AIRFLOW	POWER USAGE	AIRFLOW EFFICIENCY
4299	54	80
Cubic Ft. Per Minute on High	Watts on High (Excludes Lights)	Cubic Ft. Per Minute Per Watt

