

Rigid Conduit/IMC Fittings

Insulated Bushings — Iron/Zinc Plated




CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
BI-901	1/2	1 1/32	1/2	1,000
BI-902	3/4	1 1/4	1/2	1,000
BI-903	1	1 5/16	5/8	500
BI-904	1 1/4	1 15/16	19/32	200
BI-905	1 1/2	2 3/64	5/8	100

UL File No. E-23018.



CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
BI-906	2	2 5/64	5/8	50
BI-907	2 1/2	3 3/32	9/16	30
BI-908	3	3 7/32	9/16	25
BI-909	3 1/2	4 1/16	7/8	25
BI-910	4	4 31/32	2 3/32	25

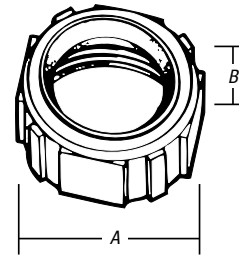

Insulated Grounding Bushings — Malleable Iron/Zinc Plated




CAT. NO.	TRADE SIZE (IN.)	GROUNDING LUG WIRE CAPACITY	DIMENSIONS (IN.)		STD. CTN.
			A	B	
BG-801	1/2	—	1 1/32	1/2	500
BG-802	3/4	#14-#4 CU	1 1/4	1/2	500
BG-803	1	or	1 5/16	5/8	250
BG-804	1 1/4	#12-#4 AL	1 15/16	19/32	150
BG-805	1 1/2	—	2 3/64	5/8	150

UL File No. E-3060.

1/2"-2" Iron, 2 1/2"-4" Die-Cast Zinc.



CAT. NO.	TRADE SIZE (IN.)	GROUNDING LUG WIRE CAPACITY	DIMENSIONS (IN.)		STD. CTN.
			A	B	
BG-806	2	—	2 5/64	5/8	100
BG-807	2 1/2	#14-1/0 CU	3 3/16	9/16	60
BG-808	3	or #12-1/0 AL	3 3/8	9/16	30
BG-809	3 1/2	#6-250 kcmil	4 1/16	7/8	30
BG-810	4	CU or AL	4 7/32	2 3/32	30

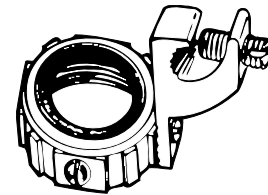

Grounding Bushings Malleable Iron/Zinc Plated — Insulated with Aluminum Lug

- For copper or aluminum bare ground wire
- 105° C thermoplastic liners
- Heavy reinforced ribs



CAT. NO.	TRADE SIZE (IN.)	GROUNDING LUG WIRE SIZE		STD. CTN.
		MIN.	MAX.	
BG801A	1/2	14 AWG	6 AWG	500
BG-802A	3/4	14 AWG	6 AWG	500
BG-803A	1	14 AWG	6 AWG	250
BG-804A	1 1/4	14 AWG	2 AWG	200
BG-805A	1 1/2	14 AWG	2 AWG	100
BG-806A	2	14 AWG	2 AWG	100

UL File No. E-3060.



CAT. NO.	TRADE SIZE (IN.)	GROUNDING LUG WIRE SIZE		STD. CTN.
		MIN.	MAX.	
BG-807A	2 1/2	14 AWG	2/0 AWG	50
BG-808A	3	14 AWG	2/0 AWG	50
BG-809A	3 1/2	14 AWG	2/0 AWG	10
BG-810A	4	14 AWG	2/0 AWG	10
BG-810B	4	6 AWG	250 kcmil	10

Reducing Bushings

- RB-121 thru RB-165 — Steel
- RB-175 thru RB-187 — Malleable iron (concrete tight), zinc plated



CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
RB-121	3/4-1/2	5/8	1/2	100
RB-131	1-1/2	5/8	1 1/8	50
RB-132	1-3/4	5/8	1 1/2	50
RB-141	1 1/4-1/2	1 1/16	1 7/16	50
RB-142	1 1/4-3/4	1 1/16	1 7/16	50
RB-143	1 1/4-1	1 1/16	1 7/16	50
RB-151	1 1/2-1/2	2 3/32	1 11/16	50
RB-152	1 1/2-3/4	2 3/32	1 11/16	50
RB-153	1 1/2-1	2 3/32	1 11/16	50
RB-154	1 1/2-1 1/4	2 3/32	1 11/16	50

UL File No. E-23018.



CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)		STD. CTN.
		A	B	
RB-161	2-1/2	2 7/32	2 3/32	25
RB-162	2-3/4	2 7/32	2 3/32	25
RB-163	2-1	2 7/32	2 3/32	25
RB-164	2-1 1/4	2 7/32	2 3/32	25
RB-165	2-1 1/2	2 7/32	2 3/32	25
RB-175	2 1/2-1 1/2	7/8	2 13/16	25
RB-176	2 1/2-2	7/8	2 13/16	25
RB-186	3-2	2 9/32	2 1/16	25
RB-187	3-2 1/2	2 9/32	2 1/16	25

