

Support Grips


Service Drop

Single Eye, Tin-Coated Bronze




IMPORTANT!

It is important that you read all breaking strength, safety and technical data relating to this product on pages T-43 through T-48.

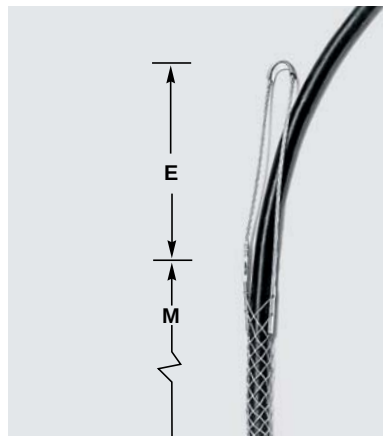

Light Duty, Single Eye, Closed Mesh

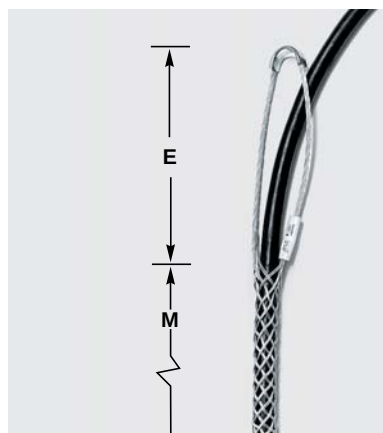

Heavy Duty, Single Eye, Closed Mesh

Light Duty, Single Eye, Closed Mesh Single Weave

For permanent support when cable end is available to be installed.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs. (N)	E Inches (cm)	M Inches (cm)	Catalog Numbers
.23"-.31" (.58-.79)	290 (1,290)	3" (7.62)	3 ³ / ₄ " (9.52)	02216001
.29"-.37" (.74-.94)	290 (1,290)	5" (12.70)	4 ¹ / ₄ " (10.79)	02216002
.35"-.44" (.89-1.12)	500 (2,224)	5 ¹ / ₂ " (13.97)	4 ³ / ₄ " (12.06)	02216003
.41"-.50" (1.04-1.27)	500 (2,224)	5 ¹ / ₂ " (13.97)	5" (12.70)	02216004
.46"-.56" (1.17-1.42)	660 (2,936)	6" (15.24)	5 ¹ / ₄ " (13.33)	02216005
.52"-.62" (1.32-1.57)	790 (3,514)	7" (17.78)	6 ¹ / ₄ " (15.87)	02216006
.58"-.68" (1.47-1.73)	790 (3,514)	7" (17.78)	6 ¹ / ₂ " (16.51)	02216007
.64"-.75" (1.63-1.90)	790 (3,514)	7" (17.78)	6 ³ / ₄ " (17.14)	02216008
.70"-.81" (1.78-2.06)	790 (3,514)	7" (17.78)	7 ¹ / ₄ " (18.41)	02216009
.75"-.87" (1.90-2.21)	1,020 (4,537)	8" (20.32)	8" (20.32)	02216010
.81"-.94" (2.06-2.39)	1,020 (4,537)	8" (20.32)	8 ¹ / ₄ " (20.95)	02216011
.87"-.1.00" (2.21-2.54)	1,020 (4,537)	8" (20.32)	8 ³ / ₄ " (22.22)	02216012
.94"-.1.06" (2.39-2.69)	1,020 (4,537)	9" (22.86)	9" (22.86)	02216013
1.00"-.1.18" (2.54-3.00)	1,020 (4,537)	9" (22.86)	9 ¹ / ₂ " (24.13)	02216014
1.06"-.1.25" (2.69-3.17)	1,020 (4,537)	9" (22.86)	9 ¹ / ₂ " (24.13)	02216015

Heavy Duty, Single Eye, Closed Mesh Multi-Weave

For permanent support when cable end is available to be installed.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs. (N)	E Inches (cm)	M Inches (cm)	Catalog Numbers
.23"-.31" (.58-.79)	500 (2,224)	5" (12.70)	4 ¹ / ₂ " (11.43)	02217001
.29"-.37" (.74-.94)	500 (2,224)	5" (12.70)	5 ¹ / ₂ " (13.97)	02217002
.35"-.44" (.89-1.12)	870 (3,870)	6" (15.24)	6 ¹ / ₂ " (16.51)	02217003
.41"-.50" (1.04-1.27)	870 (3,870)	6" (15.24)	7 ¹ / ₂ " (19.05)	02217004
.46"-.56" (1.17-1.42)	1,050 (4,670)	6" (15.24)	8" (20.32)	02217005
.52"-.62" (1.32-1.57)	1,050 (4,670)	7" (17.78)	8 ¹ / ₂ " (21.59)	02217006
.58"-.68" (1.47-1.73)	1,050 (4,670)	7" (17.78)	9 ¹ / ₂ " (24.13)	02217007
.64"-.75" (1.63-1.90)	1,390 (6,183)	7" (17.78)	9 ¹ / ₂ " (24.13)	02217008
.70"-.81" (1.78-2.06)	1,390 (6,183)	8" (20.32)	10 ¹ / ₂ " (26.67)	02217009
.75"-.87" (1.90-2.21)	1,390 (6,183)	8" (20.32)	10 ¹ / ₂ " (26.67)	02217010
.81"-.94" (2.06-2.39)	1,390 (6,183)	8" (20.32)	10 ¹ / ₂ " (26.67)	02217011
.87"-.1.00" (2.21-2.54)	1,790 (7,962)	8" (20.32)	11 ¹ / ₂ " (29.21)	02217012
.94"-.1.06" (2.39-2.69)	1,790 (7,962)	9" (22.86)	12 ¹ / ₂ " (31.75)	02217013
1.00"-.1.18" (2.54-3.00)	1,790 (7,962)	9" (22.86)	13 ¹ / ₂ " (34.29)	02217014
1.06"-.1.25" (2.69-3.17)	1,790 (7,962)	9" (22.86)	14 ¹ / ₂ " (36.83)	02217015

E-Eye length

M-Mesh length at nominal diameter

