



# LED Omni-Directional GU Based A-Lamps

**LED Omni GU Based A-Lamps** 25,000 Hours average rated life, 120Volts

### Applications:

Ideal for dimmable A-lamp applications with GU sockets.

- + General Lighting
- + Sconces
- + Table Lamps
- + Floor Lamps
- + Ceiling Fixtures




### Features and Benefits

- Smooth, uniform dimming from 100% to 5%
- Energy Efficient: Up to 80% less energy than standard incandescent
- Exceeds all industry performance requirements for non-standard lamps
- Long life: 25,000 hours
- Very Durable: Solid state lighting technology significantly reduces lighting service & maintenance due to robust lighting design
- Excellent Color consistency and high color rendering (CRI)



10W Omni-Directional A-Lamp

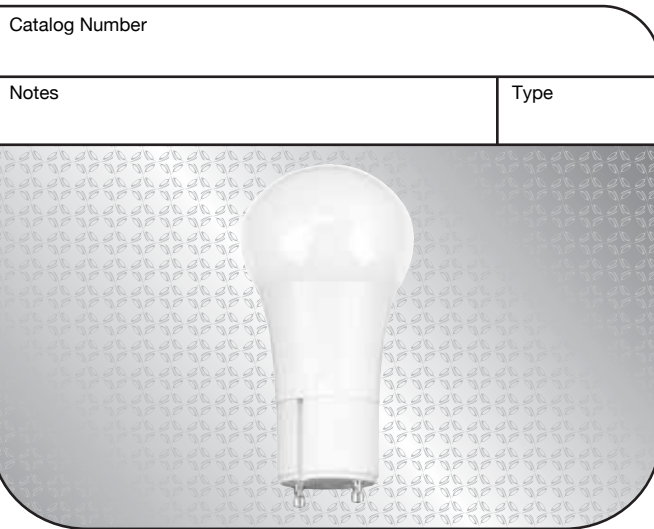

### Specifications

Input Line Voltage:	120 VAC
Input Power	10W
Input Line Frequency	50/60HZ
Lamp Life (Rated)	25,000 hrs
Minimum Starting Temp	-20°C
Maximum Operating Temp	40°C

### Warranties and Certifications:



**5 YEAR WARRANTY**  
based on 12 hours use per day

For the most up-to-date specs, please visit [www.tcp.com](http://www.tcp.com)

Item #	Description	Voltage	Wattage	Replacement	Lumens	LPW	M.O.L. (inches)	Diameter (inches)	CCT	CRI	STK/MTO	Case Quantity	Enclosed/Recessed Luminaire
<b>Dimmable Omni GU Based 10W A19</b>													
LED10A19GUDOD27K	Dim Omni 10W GU Base A19 - 2700K	120	10	60	800	80.0	4.6	2.6	2700K	80	STK	12	Y
LED10A19GUDOD30K	Dim Omni 10W GU Base A19 - 3000K	120	10	60	825	82.5	4.6	2.6	3000K	80	STK	12	Y
LED10A19GUDOD41K	Dim Omni 10W GU Base A19 - 4100K	120	10	60	850	85.0	4.6	2.6	4100K	80	STK	12	Y

