



Pole Mount




 
2-3/8" Slipfitter



Trunion



Trunion Mounting Spacing

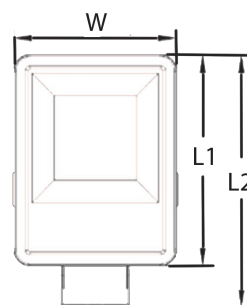

Area & Flood Lighting

- Cree COB LEDs
- Meanwell Driver
- Integral Cooling Fin Releases Heat Efficiently to Maintain the Life of LEDs & LED Driver
- Corrosion Resistant Die Cast Aluminum Housing
- Tempered Glass Lens
- Superior Architectural Bronze Powder Coat Finish
- Stainless Steel Hardware
- Photo control can be installed remotely
- 50,000+ Hour Life Expectancy
- Voltage: 120/208/240/277VAC
- Color Temperature: 5000K
- CRI: 81
- Light Pattern: Type II 120° Beam Angle
- Operating Temperature: -40°F To 131°F
- IP65 (NEMA 4X) Rated Dust & Water Tight
- cULus Listed for Wet Locations
- DLC Listed
- 5 Year Warranty

Cat. No.	#of LEDs	Mounting	Watts	Delivered Lumens	Replaces Metal Halide	Dimensions (Inches)					Weight (Lbs)	Case Qty	
						L1	L2	W	D	E			
71380	4	Trunion	120	10,321	400W	15	17-1/2	11-3/4	4-1/4	2	18	1	
71381	4	2-3/8" Slipfitter	120	10,321	400W	15	22-5/16	11-3/4	4-1/4	-	18	1	
71386	4	Pole Mount	120	10,321	400W	15	20	11-3/4	4-1/4	-	18	1	
71382	6	Trunion	160	14,830	600W	18-7/8	22-29/32	15	4-7-16	2	29	1	
71383	6	2-3/8" Slipfitter	160	14,830	600W	18-7/8	26-1/8	15	4-7-16	-	29	1	
71387	6	Pole Mount	160	14,830	600W	18-7/8	24-1/4	15	4-7-16	-	29	1	
71384	6	Trunion	200	17,911	750W	18-7/8	22-29/32	15	4-7-16	2	29	1	
71385	6	2-3/8" Slipfitter	200	17,911	750W	18-7/8	26-1/8	15	4-7-16	-	29	1	
71388	6	Pole Mount	200	17,911	750W	18-7/8	24-1/4	15	4-7-16	-	29	1	