



Industrial Grade Retractable Power Cord Reels

FEATURES

NEMA 4 rated for indoor/outdoor environments, including wet locations

- 30-Amp/600-Volt rated slip ring
- Heavy-duty formed steel mounting base: mount to ceiling, floor, or wall
- All steel construction
- Yellow powder-coat finish, or
- **NEW!** White powder-coat finish
- Adjustable ball stop included
- Positive lock ratchet included
- 6' Feeder cord included
- Made in USA



OPTIONS

- 2 - 4 Conductors
- 12 - 16 AWG
- SJOW, SOOW, SEOW (black or white cable)
- 25', 35' and 50' standard cord length, custom cord lengths available upon request

ACCESSORIES*:

RTB Series Cord Reels are de-rated to NEMA 2 when accessories are added. GFCI inline with feeder cord.



- Options include: outlet boxes, plugs, connectors, or work lights
- Optional Swivel Base for 360° continuous rotation
- Optional Pivot Base rotates up to 345°

APPLICATIONS


Construction	Maintenance/Service
Manufacturing	Vehicle Charging Stations
Retail	Education/Hospitality
Utilities	Medical/Laboratories

* See accessories

Specifications

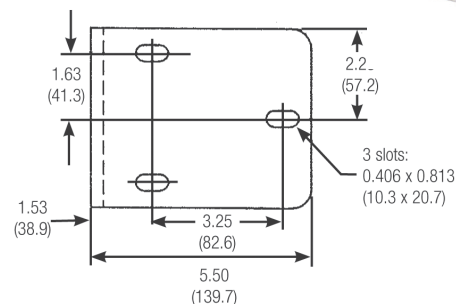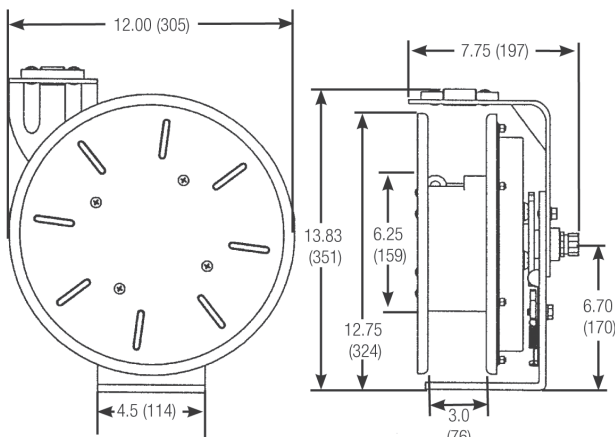

Weight based on cable type and length

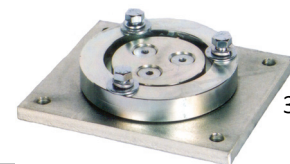

345° Pivot Base



360° Continuous Swivel Base



RTB Yellow Powder-Coated Retractable Cord Reel Series

KH Industries offers the following selection of **yellow-powder coated retractable power cord reels** that will meet most lift/drag applications and environmental needs. Additional models are available including stretch or retrieve cord reels, as well as made-to-order cord reels, and specialty application cord reels; contact us for details.

Configuration (payout end)	Cord Length	Gauge/ Conductor	Cord Type	Volts	Max Amps	Slip ring rating	NEMA Plug (Feeder end)	KH Model #
All Models Below Feature Yellow Powder-Coated Cable Reel with Black Cable								
Blunt End	25'	16/3	SO	600	10	600V/30A	Blunt End	RTBA3L-WW-B16F
Blunt End	35'	16/3	SO	600	10	600V/30A	Blunt End	RTBA3L-WW-B16H
Blunt End	50'	16/3	SO	600	10	600V/30A	Blunt End	RTBA3L-WW-B16K
Yellow Outlet Box 15A Duplex/Duplex	25'	16/3	SJ	125	10	600V/30A	5-15P	RTBA3L-WDD515-J16F
Yellow Outlet Box 15A Duplex/Duplex	35'	16/3	SJ	125	10	600V/30A	5-15P	RTBA3L-WDD515-J16H
Yellow Outlet Box 15A Duplex/Duplex	50'	16/3	SJ	125	10	600V/30A	5-15P	RTBA3L-WDD515-J16K
Yellow Outlet Box 15A Duplex/Duplex	50'	14/3	SJ	125	15	600V/30A	5-15P	RTBA3L-WDD515-J14K
Blunt End	50'	14/3	SJ	300	15	600V/30A	Blunt End	RTBA3L-WW-J14K
Blunt End	25'	14/3	SO	600	15	600V/30A	Blunt End	RTBB3L-WW-B14F
Blunt End	25'	12/3	SJ	125	20	600V/30A	5-20P	RTBB3L-WW-J12F
Blunt End	50'	12/3	SJ	125	20	600V/30A	5-20P	RTBB3L-WW-J12K
Yellow Outlet Box 20A Duplex/Blank	25'	12/3	SJ	125	20	600V/30A	5-20P GFCI	RTBB3L-WGB520-J12F
Yellow Outlet Box 20A Duplex/Blank	50'	12/3	SJ	125	20	600V/30A	5-20P GFCI	RTBB3L-WGB520-J12K
Yellow Outlet Box 20A Duplex/Duplex	25'	12/3	SJ	125	20	600V/30A	5-20P	RTBB3L-WDD520-J12F
Yellow Outlet Box 20A Duplex/Duplex	50'	12/3	SJ	125	20	600V/30A	5-20P	RTBB3L-WDD520-J12K
Blunt End	25'	12/3	SO	600	20	600V/30A	Blunt End	RTBB3L-WW-B12F
Blunt End	25'	12/4	SO	600	16	600V/30A	Blunt End	RTBB4L-WW-B12F
Accessories								
Pivot Base, 345°								RTBF-PVB
Swivel Base, 360° continuous		3C				600V/30A		RTBF-SWB3

Additional configurations are available, including custom cord lengths, black outlet boxes, cover plates, plugs, and connectors. RTB Series can accommodate: 2 - 4 Conductors; 12 - 16 AWG Cord Gauges ; SJOW (white or black color), SOOW (black only), SEOW (white only) cord types.

KH ReelTuff™ Cord Reels are available from KH Industries.
For more information, including custom configuration:
Call: 716-312-0088 or Visit: www.KHindustries.com



RTB White Powder-Coated Retractable Cord Reel Series

KH Industries offers the following selection of **white powder-coated retractable power cord reels** that will meet most lift/drag applications and environmental needs. Additional models are available including stretch or retrieve cord reels, as well as made-to-order cord reels, and specialty application cord reels; contact us for details.

Configuration (payout end)	Cord Length	Gauge/ Conductor	Cord Type/Color	Volts	Max Amps	Slip ring rating	NEMA Plug (Feeder end)	KH Model #
All Models Below Feature White Powder-Coated Cable Reel with White Cable								
Blunt End	25'	12/3	SEOW White	600	20	600V/30A	Blunt End	RTBB3LW-WW-H12F
Blunt End	25'	12/3	SJOW White	300	20	600V/30A	Blunt End	RTBB3LW-WW-P12F
Black Outlet Box 15A Duplex/Duplex	25'	12/3	SJOW White	125	15	600V/30A	5-15P	RTBB3LW-1DD515-P12F
Black Outlet Box 20A Duplex/Duplex	25'	12/3	SEOW White	125	20	600V/30A	5-20P	RTBB3LW-1DD520-H12F
Black Outlet Box 20A Duplex/Duplex	25'	12/3	SJOW White	125	20	600V/30A	5-20P	RTBB3LW-1DD520-P12F
Black Outlet Box 20A GFCI/Duplex	25'	12/3	SEOW White	125	20	600V/30A	5-20P	RTBB3LW-1GD520-H12F
Black Outlet Box 20A GFCI/Blank	25'	12/3	SJOW White	125	20	600V/30A	5-20P	RTBB3LW-1GB520-P12F
5-20R	25'	12/3	SEOW White	125	20	600V/30A	5-20P	RTBB3LW-C520-H12F
5-20R	25'	12/3	SJOW White	125	20	600V/30A	5-20P	RTBB3LW-C520-P12F
Blunt End	35'	12/3	SJOW White	300	20	600V/30A	Blunt end	RTBB3LW-WW-P12H
Black Outlet Box 20A GFCI/Duplex	30'	12/3	SEOW White	125	20	600V/30A	5-20P	RTBB3LW-1GD520-H12G
Black Outlet Box 20A Duplex/Duplex	35'	12/3	SJOW White	125	20	600V/30A	5-20P	RTBB3LW-1DD520-P12H
Black Outlet Box 20A GFCI/Blank	35'	12/3	SJOW White	125	20	600V/30A	5-20P	RTBB3LW-1GB520-P12H
Blunt End	50'	12/3	SJOW White	300	20	600V/30A	Blunt End	RTBB3LW-WW-P12K
5-20R	50'	12/3	SJOW White	125	20	600V/30A	5-20P	RTBB3LW-C520-P12K
Accessories								
Pivot Base, 345°								RTBF-PVB
Swivel Base, 360° continuous		3C				600V/30A		RTBF-SWB3
Additional configurations are available, including custom cord lengths, yellow outlet boxes, cover plates, plugs, or connectors. RTB Series can accommodate: 2 - 4 Conductors; 12 - 16 AWG Cord Gauges ; SJOW (white or black color), SOOW (black only), SEOW (white only) cord types.								

KH ReelTuff™ Cord Reels are available from KH Industries.
For more information, including custom configuration:
Call: 716-312-0088 or Visit: www.KHindustries.com

