
 


The sleek low profile design of the Straight Edge™ makes it ideal for under cabinet, cove and niche applications where space is at a premium. High output LEDs project very little heat and no UV or Infrared radiation; perfect for upscale retail applications involving color sensitive or perishable items.

- Available in 5 lengths
- Multiple connectors and cables available to facilitate custom layouts
- Four mounting options provided for different surfaces
- Each section includes (2) flat mounting clips, (2) 45° angle mounting clips and (1) "I" connector
- Adjustable angle mounting clips (sold separately), allow fixture to be easily aimed while securely mounted for optimal task lighting performance and flexibility
- 120° beam spread
- May be dimmed to 1% with electronic low voltage (ELV) dimmer
- Extruded aluminum with Lexan spread lens
- 50,000 hour rated life
- 5 year WAC Lighting product warranty

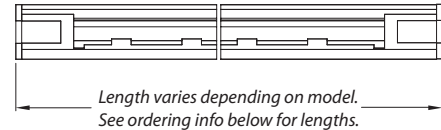

Adjustable angle mounting clip (SL-C3-WT)



Order Number and Fixture Performance

Color Temp: **2700K** CRI: **85** Efficacy: **47Lm/W**

Description	Model #	Length	Lumens	Watts
8 inch	LS-LED08-W-WT	7¼"	121	2.6
14 inch	LS-LED14-W-WT	13¾"	233	4.8
20 inch	LS-LED20-W-WT	19¼"	340	7.2
26 inch	LS-LED26-W-WT	25¼"	455	9.6
32 inch	LS-LED32-W-WT	31¼"	564	11.9

Example: **LS-LED08-W-WT**

Color Temp: **4500K** CRI: **82** Efficacy: **50Lm/W**

Description	Model #	Length	Lumens	Watts
8 inch	LS-LED08-C-WT	7¼"	130	2.6
14 inch	LS-LED14-C-WT	13¾"	245	4.8
20 inch	LS-LED20-C-WT	19¼"	352	7.2
26 inch	LS-LED26-C-WT	25¼"	484	9.6
32 inch	LS-LED32-C-WT	31¼"	617	11.9

Example: **LS-LED08-C-WT**

Power Supplies

Plug-in

EN-2460-P-AR-S	120V, 24VAC/60W – May be dimmed
EN-24100-P-AR-S	120V, 24VAC/96W – May be dimmed

Remote (Hard-Wired)

EN-2460-RB2-S	120V, 24VAC/60W – May be dimmed
EN-24100-RB2-S	120V, 24VAC/96W – May be dimmed
EN-24100-277-R	277V, 24VAC/96W – May not be dimmed

Power Supply Accessories

TB-S	Wiring box with switch
MTB	Multiple terminal block
SL-EXT-144	12' extension cable
SL-WC-1	Wire Clip

Connection Accessories

SL-IC	Joiner cables
SL-I	"I" connector
SL-IF	Custom cable extenders
SL-X	4 way "X" connector
SL-Y	3 way "Y" connector
TB-S	Wiring box with switch

Mounting Accessories

SL-C1	Flat Mounting Clip
SL-C2	45° Angle Mounting Clip
SL-C3	Adjustable Angle Mounting Clip
MAG-TAPE-36	Magnetic Tape