

# LED "CORN COB" Work Light

## Low, Medium & High Bay LED Work Light

Bergen's new LED work light offers High lumen, omni directional lamps perfect for industrial, commercial & residential job site applications. LED Corn Cob lamps are high lumen and energy efficient replacements for Metal Halide (MH) and High Pressure Sodium (HPS) lamps.

### Overall Features

- Replaces HID, CFL, and Incandescent
- 6ft Power Cord, NEMA 5-15 120v
- 1ft. Daisy-Chain Option
- Locking Connector
- 60w or 100w
- 300° Illumination
- Fully Assembled
- Snap-Lock Hook & Wire Guard

Bergen's NEW fixture design with female Daisy-chain outlet comes assembled right out of the box. This new daisy-chain feature saves the electrician time and money when installing multiple fixtures. The function of the daisy-chain allows up to fourteen 100w units to be connected together on a single 15A circuit compared only three of the 400w Metal Halide units. The daisy-chain locking feature can also be used to connect a drop cord for power tools.

Fixture can be used with E39 CFL or LED




BLITE-100LED



Locking Connector

Now with daisy-chain outlet

new

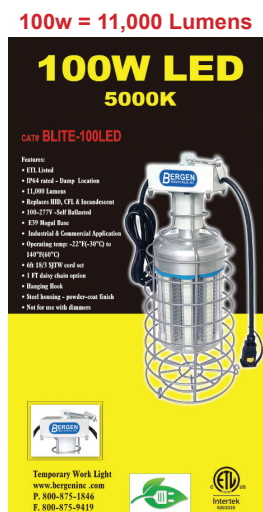

new

Full Color Packaging, Compact Design. Great For Counter Display Area!

Cat#	Description	Replaces	Watts	Base	Volts	CCT	Life/Hours
BLITE-60LED	LED Work Light, Hook / Lamp / Cord Plug & Cage Included	250w HID	60	Mogul	120-277	5000K	40,000
BLITE-100LED	LED Work Light, Hook / Lamp / Cord Plug & Cage Included	400w HID	100	Mogul	120-277	5000K	40,000



Bergen Industries, Inc. | P. 800.875.1846 | F. 800.875.9419 | [www.bergeninc.com](http://www.bergeninc.com)