

CABLE TIES AND ACCESSORIES

AIR HANDLING CABLE TIES

PLENUM RATED



- Ideal Application: Air Handling Spaces, above drop ceilings and below raised flooring
- Meets UL 1565 low smoke generation, low heat release, and mechanical strength test
- UL Listed suitable for use in Air Handling Spaces in accordance with the Section 300.22 (C) and (D) of the National Electrical Code and Rules 12-010 (3), (4), and (5) and 12-020 of the Canadian Electrical Code, Part 1
- Strong and Pure manufactured from filtered nylon 6/6 reducing particle contamination
- Mounting Hole Style secures and positions wire bundles, cables, etc. to surfaces with one mechanical fastener
- Low Profile Style reduces head height increases safety, eliminates snags, cuts, and abrasions to cables, surrounding products, and users

STOCK NO.	UPC NO.	DESCRIPTION	LENGTH IN.	TIE TENSILE LBS.	PKG. QTY.	SUGGESTED TRADE LIST PRICE PER
CTAH7S	22672	Standard	7	50	100	16.63/c
CTAH11S	22682	Standard	11	50	100	35.38/c
CTAH14S	22693	Standard	14	50	100	46.30/c
CTAH7MH	22671	Mounting Hole	7	50	100	28.40/c
CTAH7LP	22670	Low Profile	7	50	100	38.28/c

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

AMERICA'S SOURCE FOR PREMIER AND INNOVATIVE FASTENERS & ANCHORS

ONLY METALLICS!



A Modern Up to Date Roll Threading Machine at our Affiliate, Avanti Screw.


MADE IN USA




Metallics and Avanti Screw, Inc., prime American manufacturers of fastener products, have always worked to present the latest in fastener technology to our distributors and their contractors/users.

Hex Washer Head fasteners have historically only offered three drives-the hex, phillips and the slot. In 1999, we introduced "The QuaDrive" square, hex, slotted and Phillips, in fourteen of the most popular sizes of sheet metal screws.


The QuaDrive


Square Drive


+


Hex


+


Slotted

+


Phillips

=


QuaDrive

America's Newest Drive - Designed, Developed and Manufactured by Metallics/Avanti Screw

These sheet metal screws are being manufactured to fill the need of the growing demand in the North American markets.

Please note: We recommend driving these sheet metal screws with a hex driving tool. The slotted, Phillips, hex and square drives make it convenient for disassembly.








CABLE TIES AND ACCESSORIES

NYLON CABLE TIES

WHITE NYLON AND BLACK UV STABILIZED

ALL CABLE TIES PACKAGED IN PLASTIC BAGS



STOCK NO.	UPC NO.	MIN. TENSILE STRENGTH	MAX. BUNDLE DIAMETER	OVERALL LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE
WHITE NYLON BENT TIP CABLE TIE - 100 PACK							
CT1	22600	18 LBS	3/4	4	.07	100	2.75/c
CT2	22605	18 LBS	1 3/8	6	.09	100	4.88/c
CT3	22610	40 LBS	1 1/4	5	.16	100	4.80/c
CT6	22615	50 LBS	2	7	.27	100	6.28/c
CT4	22620	50 LBS	2 3/4	11	.39	100	12.70/c
CT5	22625	50 LBS	4 1/2	14	.49	100	14.95/c
WHITE NYLON 1000 AND 500 PACK							
CT1B	22601	18 LBS	3/4	4	.62	1000	24.85/m
CT2B	22606	18 LBS	1 3/8	6	.89	1000	44.00/m
CT3B	22611	40 LBS	1 1/4	5	1.53	1000	43.30/m
CT6B	22616	50 LBS	2	7	3.00	1000	56.40/m
CT4B	22621	50 LBS	2 3/4	11	1.97	500	57.25/ea. pkg.
CT5B	22626	50 LBS	4 1/2	14	2.59	500	67.15/ea. pkg.
BLACK WEATHER-RESISTANT UV-STABILIZED CABLE TIE 100 PACK							
CT1UV	22645	18 LBS	3/4	4	.07	100	2.98/c
CT6UV	22650	50 LBS	2	7	.30	100	6.68/c
CT4UV	22655	50 LBS	2 3/4	11	.39	100	13.35/c
CT5UV	22660	50 LBS	4 1/2	14	.50	100	15.73/c
*CT21UV	22659	50 LBS	6	21	.75	100	121.32/c NEW
BLACK UV 1000 AND 500 PACK							
CT1UVB	22646	18 LBS	3/4	4	.62	1000	26.85/m
CT3UVB	22612	50 LBS	1 1/4	5	3.00	1000	50.00/m NEW
CT6UVB	22651	50 LBS	2	7	2.76	1000	60.10/m
CT4UVB	22656	50 LBS	2 3/4	11	2.02	500	60.10/ea. pkg.
CT5UVB	22661	50 LBS	4 1/2	14	2.41	500	70.65/ea. pkg.
WHITE NYLON - 100 PACK MOUNTING TAB CABLE TIE							
MCT10	22700	30 LBS	3/4	5	.19	100	12.63/c
MCT12	22710	50 LBS	2	7	.34	100	14.68/c
MCT13	22715	50 LBS	3	11	.43	100	23.10/c
MCT14	22720	120 LBS	4	14	.56	100	33.38/c
BLACK NYLON - 100 PACK MOUNTING TAB CABLE TIE							
MCT15BLK	22764	120 LBS	4	15 5/16	1.33	100	37.48/c NEW
HEAVY DUTY - 50 PACK WHITE NYLON ADJUSTABLE CLAMPS							
HCT19	22800	120 LBS	4 1/4	14	.65	50	16.48/ea. pkg.
HCT21	22810	175 LBS	5 7/8	24	.95	50	33.50/ea. pkg.
HCT22	22815	175 LBS	9 3/4	33	2.05	50	39.70/ea. pkg.
HEAVY DUTY - 50 PACK BLACK UV							
HCT22UV	22816	175 LBS	9 3/4	33	.85	25	30.23/ea. pkg. NEW
HORIZONTAL I.D. TIE							
*CT1HID	22602	18 LBS	3/4	4	.55	100	15.10/c NEW

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

*DENOTES A PRODUCT NOT MADE IN THE USA



Metallics

**[CONTRACTOR
APPROVED]**

NEW!
2014-2015

Save **TIME**
and **MONEY**
with these
Cable Tie
Kits!

Cable Tie Kits

NOW AVAILABLE!

Packaged in an EZ Hang Reusable, Visual Plastic Box



Standard Cable Tie Kit

PART #	UPC #	LENGTH (IN.)	TIE TENSILE (LBS.)	QTY / PKG	SUG. TRADE LIST / PKG
CTKS1 Natural	23030	11	50	100	\$ 27.25
		7	50	100	
		4	18	200	
CTKS1UV Black	23031	11	50	100	\$ 27.38
		7	50	100	
		4	18	200	



Tension Tool Cable Tie Kit

PART #	UPC #	LENGTH (IN.)	TIE TENSILE (LBS.)	QTY / PKG	SUG. TRADE LIST / PKG
CTKTT1* Natural	23035	11	50	100	\$ 49.75
		7	50	100	
		4	18	200	
CTKTT1UV* Black	23036	11	50	100	\$ 50.15
		7	50	100	
		4	18	200	

*Includes one (1) Tension Tool per kit



3/4 Mounting Pad Cable Tie Kit

PART #	UPC #	LENGTH (IN.)	TIE TENSILE (LBS.)	QTY / PKG	SUG. TRADE LIST / PKG
CTKMP1° Natural	23040	11	50	100	\$ 35.00
		7	50	100	
CTKMP1UV° Black	23041	11	50	100	\$ 35.62
		7	50	100	

°Includes one hundred (100) 3/4" adhesive Mounting Pads per kit

"Growth Through Innovation"

Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • Fax 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • Fax 800-269-6278
Email saleswest@metallicsonline.com

CABLE TIES AND ACCESSORIES



ASSORTED CABLE TIES IN A BAG

A handy assortment of popular sizes
in one convenient package so
you're ready for any job!



PACKAGED IN PLASTIC BAGS

FOUR POPULAR SIZES IN EACH BAG

BENT TIP TIES

AVAILABLE IN WHITE NYLON OR BLACK UV STABILIZED

STOCK NO.	UPC NO.	DESCRIPTION OF CONTENTS	STD. PKG.	WT. PER BAG	SUGGESTED TRADE LIST PRICE PER
WHITE NYLON					
CTA1	22825	Bag of 100 Cable Ties includes: 25 CT1 4" White Nylon Ties 25 CT6 7" White Nylon Ties 25 CT4 11" White Nylon Ties 25 CT5 14" White Nylon Ties	1 Bag	.31	11.70/ea
BLACK UV STABILIZED					
CTUA1	22826	Bag of 100 Cable Ties includes: 25 CT1UV 4" Black Weather Resistant Ties 25 CT6UV 7" Black Weather Resistant Ties 25 CT4UV 11" Black Weather Resistant Ties 25 CT5UV 14" Black Weather Resistant Ties	1 Bag	.32	12.90/c

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



VELCRO® CABLE TIES

PACKAGED IN PLASTIC BAGS



FEATURES

- Eliminates the potential for damage to fiber optics or cables caused by overcinching or accidental cutting.
- Easy to install and adjust without installation tools.
- Reusable

APPLICATIONS

- Wire and cable assemblies
- Fiber optic installations
- Network installations
- Electrical/electronics products

Maximum loop tensile strength:
Roll - 50 lbs Loop ties - 40 lbs

STOCK NO.	UPC NO.	DESCRIPTION OF CONTENTS	STD. PKG.	WT. PER BAG	SUGGESTED TRADE LIST PRICE PER
VR12	22801	Velcro® Roll - 1/2" x 15'	.08	One Roll	14.68/ea
VR34	22802	Velcro® Roll - 3/4" x 15'	.13	One Roll	18.15/ea
VT8	22803	Velcro® Loop Tie - 1" tab 1/2" width x 8"	.05	10 Loop Ties	15.20/ea
VT12	22804	Velcro® Loop Tie - 1" tab 1/2" width x 12"	.07	10 Loop Ties	20.95/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

VELCRO® IS A REGISTERED TRADEMARK

CABLE TIES AND ACCESSORIES



CABLE TIE TOOL

FEATURES A SHORT SQUEEZE STROKE

The cut-off feature ensures a consistently flush, burr-free edge

Polycarbonate Construction

STOCK NO.	UPC NO.	SIZE	WT. EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
RT2	23215	Accepts Cable Tie series CT-1 through MCT14	.78	1	72.93/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



CABLE CLAMPS

WHITE & BLACK NYLON PLASTIC

Clamps are designed with bevelled inside edges to prevent damage to cables from chafing, Molded to shape and size.



STOCK NO.	UPC NO.	WIRE SIZE	MOUNTING SCREW DIA.	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
WHITE						
NCC116	23102	1/16	3/16	.03	100	9.75/c NEW
NCC0	23100	1/8	3/16	.09	100	7.23/c
NCC1	23103	3/16	3/16	.09	100	9.83/c NEW
NCC3	23107	5/16	5/16	.09	100	16.15/c NEW
NCC2	23105	1/4	3/16	.11	100	10.15/c
NCC4	23110	3/8	3/16	.24	100	12.38/c
NCC6	23115	1/2	3/16	.28	100	14.00/c
NCC7	23117	5/8	3/16	.35	100	14.28/c NEW
BLACK						
NCC4BLK	23132	3/8	3/16	.16	100	12.83/c NEW
NCC6BLK	23137	1/2	3/16	.25	100	14.78/c NEW

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



CABLE CLAMPS

STEEL ZINC PLATED



STOCK NO.	UPC NO.	WIRE SIZE	MOUNTING SCREW DIA.	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SCC316	21546	3/16	3/16	.56	100	16.95/c
SCC14	21541	1/4	3/16	.61	100	17.35/c
SCC38	21543	3/8	3/16	.79	100	19.18/c
SCC12	21540	1/2	3/16	.46	50	10.50/ea. pkg.
SCC58	21544	5/8	3/16	.65	50	12.23/ea. pkg.
SCC34	21542	3/4	1/4	.37	25	6.60/ea. pkg.
SCC78	21545	7/8	1/4	.41	25	7.03/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

Helpful Hints From Metallics:
Did You forget to ask?

GOT FASTENERS?

CABLE TIES AND ACCESSORIES

NEOPRENE WRAPPED STEEL CABLE CLAMPS



Light to medium duty steel cable clamp with neoprene cushion for electrical insulation and vibration absorption

- Steel clamps are electroplated for corrosion resistance
- Silver with black neoprene
- Mounts to steel, wood or concrete
- Reusable

STOCK NO.	UPC NO.	MAX WIRE DIAMETER	MOUNTING SCREW DIA.	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SPN316	51165	3/16	3/16	.19	25	29.35/ea. pkg.
SPN14	51170	1/4	3/16	.23	25	21.25/ea. pkg.
SPN38	51175	3/8	3/16	.21	20	23.50/ea. pkg.
SPN12	51180	1/2	3/16	.33	20	23.35/ea. pkg.
SPN58	51185	5/8	3/16	.32	20	23.50/ea. pkg.
SPN34	51190	3/4	1/4	.43	20	23.50/ea. pkg.
SPN78	51195	7/8	1/4	.24	10	29.33/ea. pkg.
SPN1	51200	1	1/4	.29	10	29.33/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

4-WAY CABLE TIE MOUNTING CLIP

NYLON MOUNT WITH ACRYLIC ADHESIVE



Clean or wipe surface before mounting.
See Page 291

STOCK NO.	UPC NO.	SIZE	SCREW DIA.	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
WHITE						
MP25	23005	3/4 sq.	#6	.18	100	26.05/c
MP20	23000	1 sq.	#8	.30	100	31.40/c
BLACK UV						
MP25UV	23020	3/4 sq.	#6	.18	100	28.65/c
MP20UV	23015	1 sq.	#8	.33	100	34.53/c

Jar packaging available

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



SCREW MOUNT FLAT CABLE TIE HOLDER



NYLON 6/6


Cable Tie Not Included

- Mounts with #6 or #8 Pan or Flat Head screw
- Accepts cable ties up to 3/16" width in any length

STOCK NO.	UPC NO.	MAX CABLE TIE WIDTH	MOUNTING SCREW	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
FTHS01	51070	3/16	#6 or #8	.03	25	11.75/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

CABLE TIES AND ACCESSORIES

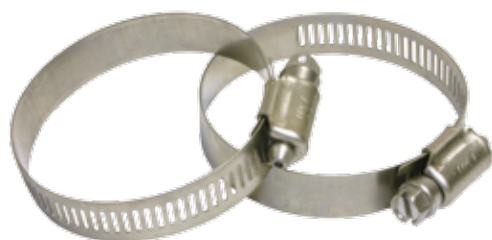

HOSE CLAMPS

STOCK NO.	UPC NO.	DESCRIPTION	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
HMC6SS	23406	7/16"-7/8" ss hose clamp	10	\$28.73
HMC24SS	23424	1-1/16"-2" ss hose clamp	10	\$29.63
HMC32SS	23432	1-9/16"-2-1/2" ss hose clamp	10	\$30.15
HMC36SS	23436	1-13/16"-2-3/4" ss hose clamp	10	\$31.38
HMC40SS	23440	2-1/16"-3" ss hose clamp	10	\$35.93
HMC88SS	23488	5-1/16"-6" ss hose clamp	10	\$71.55
HMC104SS	23534	6-1/16"-7" ss hose clamp	10	\$74.60
MHC6	22906	7/16"-7/8" hose clamp	10	\$23.20
MHC24	22924	1-1/16"-2" hose clamp	10	\$24.00
MHC28	22928	1-5/16"-2-1/2" hose clamp	10	\$24.45
MHC32	22932	1-9/16"-2-1/2" hose clamp	10	\$24.45
MHC36	22936	1-13/16"-2-3/4" hose clamp	10	\$25.25
MHC48	22948	2-9/16"-3-1/2" hose clamp	10	\$34.60
MHC52	22952	2-13/16"-3-3/4" hose clamp	10	\$36.75
MHC60	22960	3-5/16"-4-1/4" hose clamp	10	\$38.05
MHC64	22964	3-9/16"-4-1/2" hose clamp	10	\$38.40

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

MANUFACTURING CAPABILITIES

Diameter range #2 thru 5/16" / 1.5mm thru 8mm • Length range 1/8" thru 3" / 3.5mm thru 75mm
Materials: Steel, Brass, Stainless, Aluminum, Bronze.

NEED SCREWS...

Let Us Make Them For You!



A METALLICS AFFILIATE

P.O. Box 1600 • 231 Cross Street
Bristol, CT 06011-1600
Tel: 800-984-8945 • Fax: 800-984-8946

CAPABILITIES LIST

PLANT SIZE: 100,000 SQUARE FEET

LOCATION: Bristol, Connecticut

EQUIPMENT: 27 Hi-Speed Cold Headers
8 Burr-Free Screw Slotters
3 Shank Slotters
2 Pointers
14 High Speed Thread Rollers

MADE IN USA



ADDITIONAL PLANT INFO: Modern shipping facility utilizing digital scale counting machines. In-house packaging facilities - boxing, sorting, baggings. All material boxed, palletized & labeled with your needs in mind for domestic or export shipping.

SECONDARY WORK: All plating & heat treating is done on the outside and certified for your guarantee.

INFORMATION SYSTEMS: Our facility has new and upgraded Technology to meet your customers specific requirements.

CABLE TIES AND ACCESSORIES


MASONRY MOUNT FLAT CABLE TIE HOLDER

BLACK UV STABILIZED NYLON 6/6



- Tap into 1/4" pre-drilled hole
- Affix wire and cable permanently
- Accepts cable ties up to 3/16" wide and any length

Cable Tie Not Included

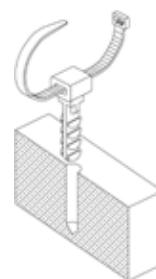

STOCK NO.	UPC NO.	PRE-DRILLED HOLE SIZE	MAX CABLE TIE WIDTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
FTHM14	51060	1/4	3/16	.07	25	8.35/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

RIVET MOUNT FLAT CABLE TIE HOLDER


YELLOW NYLON 6/6

Accepts a variety of cable tie lengths.

- Punch into pre-drilled hole (.196")
- Has built-in rivet
- One piece construction



Cable Tie Not Included

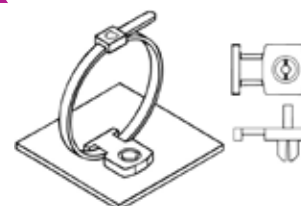


STOCK NO.	UPC NO.	RIVET HOLE DIAMETER	MAX CABLE TIE WIDTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
FTHR01	51065	.196	3/16	.07	50	7.70/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

C STYLE CABLE CLAMP

GRAY PVC

- Great for routing all types of wire
- Adhesive backing mounts quickly and easily
- Clean or wipe surface before mounting with a solvent cleaner/degreaser

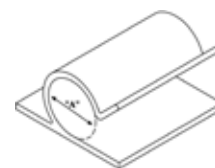

STOCK NO.	UPC NO.	MAX CABLE CAPACITY "A"	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
KKC14	51040	1/4	.06	20	17.78/ea. pkg.
KKC38	51045	3/8	.07	20	19.83/ea. pkg.
KKC12	51050	1/2	.13	10	11.03/ea. pkg.
KKC34	51055	3/4	.15	10	15.78/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

America's Source For Premier And Innovative Fasteners

CABLE TIES AND ACCESSORIES

MADE IN USA




U STYLE CABLE CLAMP

GRAY PVC

- Great for routing all types of wire
- Adhesive backing mounts quickly and easily
- Clean or wipe surface with a solvent cleaner/degreaser before mounting.

See Page 291

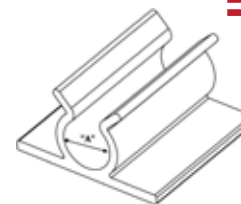

STOCK NO.	UPC NO.	MAX CABLE CAPACITY "A"	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
KKU14	51020	1/4	.08	20	17.83/ea. pkg.
KKU38	51025	3/8	.07	20	19.88/ea. pkg.
KKU12	51030	1/2	.13	10	11.03/ea. pkg.
KKU34	51035	3/4	.08	10	15.63/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

ADJUSTABLE C STYLE CABLE CLAMP

NYLON 6/6

PACKAGED IN POLY BAGS

Holds cables from 5/16" to 1" in diameter

- Handles dozens of routing jobs
- Locks securely and can be easily re-opened for routing changes
- Adhesive backing for easy, quick installation
- Clean or wipe surface with a solvent cleaner/degreaser before mounting

See Page 291



STOCK NO.	UPC NO.	BUNDLE RANGE DIAMETER "B"	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
AKK516	51000	5/16 - 13/32	.05	10	9.68/ea. pkg.
AKK1532	51005	15/32 - 9/16	.07	10	12.08/ea. pkg.
AKK3764	51010	37/64 - 3/4	.11	10	16.68/ea. pkg.
AKK78	51015	7/8 - 1	.24	10	18.85/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST


TIE-ON-BASE WIRE ROUTING CLIP

NYLON 6/6

Cable tie and mounting clip all in one!

- Adhesive base has slot to guide strap under locking mechanism
- Release tab allows for load to be removed, replaced or changed when necessary
- Tensile strength 40 lbs.
- One size fits a variety of applications
- Clean or wipe surface with a solvent before mounting.

See Page 291

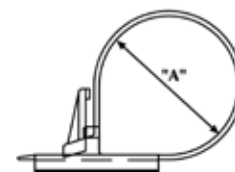


Cable Tie Not Included

STOCK NO.	UPC NO.	MAX CABLE CAPACITY "A"	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
TOB1	51125	1-1/8	.06	10	7.40/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

CABLE TIES AND ACCESSORIES

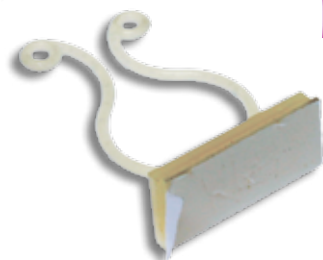

Cable Tie Not Included



KURLY STYLE CABLE WRAP WITH ADHESIVE BASE

NYLON 6/6

For easy cable routing in a variety of applications.

- Adhesive backing for quick and easy installation.
- Wires can be routed and re-routed after installation.
- Clean or wipe surface with a solvent cleaner/degreaser before mounting.




See Page 291

STOCK NO.	UPC NO.	MAX CABLE CAPACITY "A"	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
KLB38	51075	$\frac{3}{8}$.02	10	5.45/ea. pkg.
KLB12	51080	$\frac{1}{2}$.03	10	6.05/ea. pkg.
KLB78	51085	$\frac{7}{8}$.04	10	6.35/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST




Cable Tie Not Included

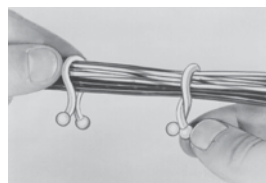

TWIST STYLE CABLE WRAP

NYLON 6/6

Simply twist to secure wire bundles. Reusable.

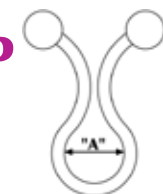

STOCK NO.	UPC NO.	MAX CABLE CAPACITY "A"	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
TL516	51090	$\frac{5}{16}$.01	25	2.70/ea. pkg.
TL38	51095	$\frac{3}{8}$.02	25	2.93/ea. pkg.
TL12	51105	$\frac{1}{2}$.02	25	3.18/ea. pkg.
TL78	51110	$\frac{7}{8}$.03	25	3.83/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



VINYL HOLE GROMMET

BLACK FLEXIBLE VINYL


Installs instantly. Simply snap into hole in panel box, etc., to protect cable.



STOCK NO.	UPC NO.	INSIDE DIA./ OUTSIDE DIA.	HOLE SIZE	PANEL THICKNESS	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
HG14	51130	$\frac{1}{4} \times \frac{9}{16}$.37	$\frac{3}{32}$.02	10	2.60/ea. pkg.
HG38	51135	$\frac{3}{8} \times \frac{43}{64}$.49	$\frac{1}{16}$.02	10	4.30/ea. pkg.
HG12	51140	$\frac{1}{2} \times \frac{55}{64}$.69	$\frac{1}{16}$.04	10	5.18/ea. pkg.
HG58	51145	$\frac{5}{8} \times \frac{55}{64}$.75	$\frac{1}{16}$.02	10	5.73/ea. pkg.
HG4764	51150	$\frac{47}{64} \times \frac{115}{64}$.99	$\frac{1}{16}$.09	10	10.30/ea. pkg.
HG5564	51155	$\frac{55}{64} \times \frac{13}{16}$	1.00	$\frac{1}{16}$.06	10	13.05/ea. pkg.
HG3132	51160	$\frac{31}{32} \times 1\frac{1}{2}$	1.25	$\frac{1}{16}$.13	10	15.80/ea. pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

 CABLE TIES AND ACCESSORIES



WIRE HARNESS WRAP

BLACK POLYETHYLENE/U.V. STABILIZED



- Wraps around cables to bundle and provide protection.
- Flexible enough to bend around corners, retains elasticity.
- Free assembly tool included with every 100' roll.

STOCK NO.	UPC NO.	DIAMETER "A"	CABLE BUNDLE RANGE	WT. PER ROLL	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
HW14	51115	1/4	3/16-1"	1.25	100 ft. roll	80.30/ea
HW12	51120	1/2	3/4-4"	3.38	100 ft. roll	168.05/ea

WHITE WIRE HARNESS WRAP AVAILABLE BY SPECIAL ORDER

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

MANUFACTURING CAPABILITIES

Diameter range #2 thru 5/16" / 1.5mm thru 8mm • Length range 1/8" thru 3" / 3.5mm thru 75mm
Materials: Steel, Brass, Stainless, Aluminum, Bronze.

NEED SCREWS...
Let Us Make Them For You!



A METALLICS AFFILIATE

P.O. Box 1600 • 231 Cross Street
Bristol, CT 06011-1600
Tel: 800-984-8945 • Fax: 800-984-8946

CAPABILITIES LIST

PLANT SIZE: 100,000 SQUARE FEET

LOCATION: Bristol, Connecticut

EQUIPMENT: 27 Hi-Speed Cold Headers
8 Burr-Free Screw Slotters
3 Shank Slotters
2 Pointers
14 High Speed Thread Rollers



ADDITIONAL PLANT INFO: Modern shipping facility utilizing digital scale counting machines. In-house packaging facilities - boxing, sorting, baggings. All material boxed, palletized & labeled with your needs in mind for domestic or export shipping.

SECONDARY WORK: All plating & heat treating is done on the outside and certified for your guarantee.

INFORMATION SYSTEMS: Our facility has new and upgraded Technology to meet your customers specific requirements.