

ILT CanopyLight-11K and 13K

LED Canopy Light Retrofit Kits



CanopyLight-11K™ & 13K™ Features:

- ◆ Two Models: CanopyLight-13K (13,000 Lumens) & CanopyLight-11K (11,000 Lumens)
- ◆ DLC Listed for Rebate Eligibility - ILT DLC Qualified Products List (QPL)
- ◆ CanopyLight-11K Meets Rebate Qualifications For Replacing 320W Fixtures (Less Than 1/3 Power Consumption!)
- ◆ Retrofit Gas Station Fuel Pump Under-Canopy Light Fixtures - "Scottsdale" to "Dakota" (2' x 2' Drop Boxes)*
- ◆ Fast Installation & No Leaks - Existing Canopy Roof Seals Not Disturbed
- ◆ Significantly Reduced Energy Consumption – 105W or 135W vs. Up To 400W Metal Halide
- ◆ Focused Light – Lights Gas Pumps & Fueling Areas
- ◆ Completely Eliminates Existing Inefficient Light Fixture Lens
- ◆ 5 Year Warranty on Fixtures and Power Supplies
- ◆ Power Supply - Highly Efficient (up to 91%) and Reliable (5 Year Warranty)



The ILT new improved CanopyLight-11K and 13K LED Retrofit Kits are designed to replace existing metal halide light fixtures in gasoline pump canopies easily and cost-effectively.


The LED-based retrofit kits use the existing light fixture roof mounting system - existing canopy seals are not disrupted eliminating potential roof leaks common with other canopy light retrofit procedures. And because install time is only 15 minutes, **CanopyLight-11K and 13K have one of the lowest installed costs on the market!**



ILT INNOVATIONS



Years of Innovation
in Light Technology
1965-2015

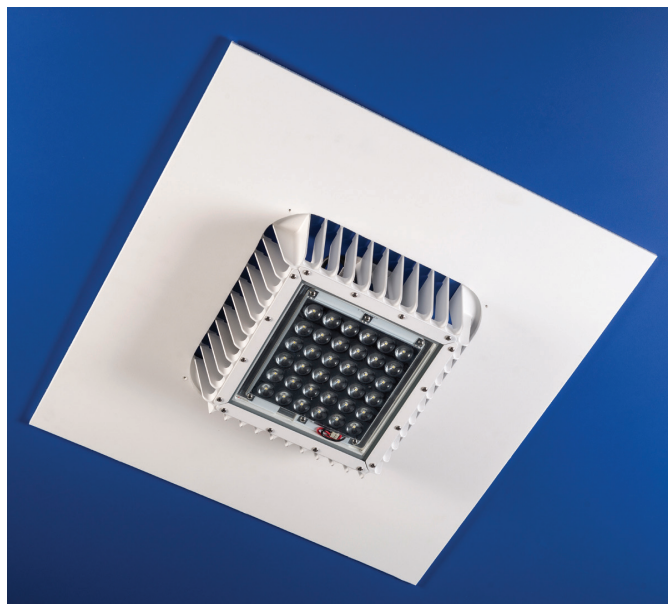

CanopyLight Fixture in Adapter Plate

CanopyLight Part Numbers

Fixture Being Replaced	ILT CanopyLight Fixture (Either 11K or 13K)	Adapter Plate (Part Number)
LSI Scottsdale* - Drop Lens	ILTCPY-W50C-11K or 13K	Not Needed
LSI Dakota* - Drop Lens	ILTCPY-W50C-11K or 13K	FLANGE-KIT215P
LSI Dakota* - Flushmount	ILTCPY-W50C-11K or 13K	FLANGE-KIT215A
LSI Richmond* - Flushmount	ILTCPY-W50C-8K***	Not Needed
Whiteway Riviera**	ILTCPY-W50C-11K or 13K	FLANGE-KIT215P
Whiteway Vision**	ILTCPY-W50C-11K or 13K	FLANGE-KIT215A
Whiteway Civic**	ILTCPY-W50C-8K***	Not Needed
2X2 Drop Box - Drop Lens	ILTCPY-W50C-11K or 13K	FLANGE-KIT215P
2X2 Drop Box - Flushmount	ILTCPY-W50C-11K or 13K	FLANGE-KIT215A

*** Fixture Contains Two (2) 4K Light Modules

CanopyLight-11K & 13K Specifications:

Optical Specs	CanopyLight-11K	CanopyLight-13K
LED Spec & Quantity	36X3W (White) LEDs	36X3W (White) LEDs
LED Color Temp	5000K	5000K
Luminaire Efficiency	> 108.5 Lumens/W	> 95.5 Lumens/W
LED Efficiency	135 Lumens/W	135Lumens/W
Initial Delivered Lumen Tj = 25°C	11,300 Lumens with Improved Light Distribution	13,000 Lumens with Improved Light Distribution
Illuminance Distribution at 10 ft	54.3 FC (Single Unit)	64.1 FC (Single Unit)
Color Rendering Index	Ra > 70	Ra > 70
Beam Angle	110°	110°
Electrical Specs	CanopyLight-11K	CanopyLight-13K
Input Voltage & Frequency	AC 100-277V, 50-60Hz	AC 100-277V, 50-60Hz
Power Factor	> 0.95 @ 277 VAC	> 0.88 @ 277 VAC
Input Current	< 0.88A (120V)	< 1.15A (120V)
Total Power Consumption	< 105W	< 135W
Power Supply Efficiency	> 90%	> 91%
Other Specs	CanopyLight-11K	CanopyLight-13K
Operating Temp. & Humidity	-30 to 50°C / 10-90% RH	-30 to 50°C / 10-90% RH
Storage Temp.	-40~85°C	-40~85°C
Dimensions	Minimum: L 12.76" X W 12.76" X D 3.6" Adapter Plate: L 21.5" X W 21.5" D 0.25"	Minimum: L 12.76" X W 12.76" X D 3.6" Adapter Plate: L 21.5" X W 21.5" D 0.25"
Net Weight	9.2 lbs.	9.2 lbs.
IP Rating	IP65	IP65
Lifespan	> 50,000 Hrs. (L70 Predicted Life of more than 200,000 Hrs.)	> 50,000 Hrs. (L70 Predicted Life of more than 200,000 Hrs.)
Warranty	5 Years	5 Years



* Scottsdale, Richmond & Dakota are Registered Trademarks of LSI Industries.

** Whiteway Riviera, Vision & Civic are Trademarks of Hubbell Lighting, Inc.



InternationalLight
TECHNOLOGIES

ISO 9001 / ISO/IEC 17025

10 Technology Drive, Peabody, MA 01960

978-818-6180 978-818-6181 fax

www.intl-lighttech.com

International Light Technologies