

Job Name: _____ Type: _____ Voltage: _____ Cat #: _____



IP65

Rated for enclosed fixtures

360° beam

TECHNICAL SPECIFICATIONS:

- :: Input voltage: 120-277V AC
- :: CCT: 3000K and 5000K
- :: CRI: 84 CRI
- :: Lamp base: E26 medium base
Mogul base adaptors optional
- :: Chip: Samsung LED chips with Rubycon driver
- :: Beam angle: 360°
- :: LED quantity: 56 x (18W) / 108 x (36W)
- :: Operating temp: -20°C~+65°C

APPLICATIONS:


- :: Ideal for retrofitting existing HID highbay, shoebox, flood light, or wall pack fixtures
- :: Can be used in enclosed luminaires



CL-18W




CL-36W

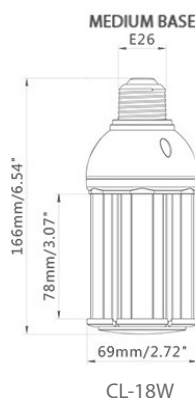

Long Lifespan of 10years



 
Rated for 1M switches




Safety Protection Circuit



 No Mercury
No UV Light



Big Saving(87%)
on Electricity Costs

 

Usable in Enclosed Luminaires



Omni Wide Angle
360°

CORN LAMP (18W & 36W)

CATALOG NO.	WATTAGE	LUMENS	VOLTAGE	DIMENSION	WEIGHT	COLOR TEMP
CL-18W-30K	18W	1710	120-277V AC	6-1/2" (H) x 2-3/4" (Dia)	3/4 lbs.	3000K
CL-18W-50K	18W	1800	120-277V AC	6-1/2" (H) x 2-3/4" (Dia)	3/4 lbs.	5000K
CL-36W-30K	36W	3620	120-277V AC	9-1/4" (H) x 3-3/4" (Dia)	1-1/2 lbs.	3000K
CL-36W-50K	36W	3800	120-277V AC	9-1/4" (H) x 3-3/4" (Dia)	1-1/2 lbs.	5000K
E26 ENLARGER			Enlarges E26 bulb to be used in E39 socket			



Job Name: _____ Type: _____ Voltage: _____ Cat #: _____



IP65

Rated for
enclosed
fixtures360°
beam

TECHNICAL SPECIFICATIONS:

- :: Input voltage: 120-277V AC
- :: CCT: 3000K and 5000K
- :: CRI: 84 CRI
- :: Lamp base: E26 medium base for CL-54W, E39 mogul base for CL-120W
- Mogul base adaptors optional
- :: Chip: Samsung LED chips with Rubycon driver
- :: Beam angle: 360°
- :: LED quantity: 56 x (18W) / 108 x (36W)
- :: Operating temp: -20°C~+65°C

APPLICATIONS:


- :: Ideal for retrofitting existing HID highbay, shoebox, flood light, or wall pack fixtures
- :: Can be used in enclosed luminaires



CL-54W



CL-120W

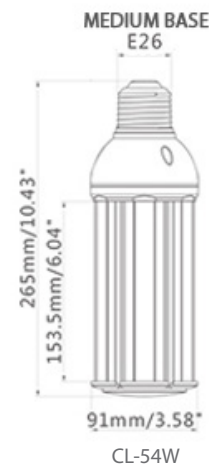

CL-54W



 
CL-120W

Samsung
LM561B

Rubycon

E26
(E39 adaptor
optional)

Long Lifespan of 10years

Rated for 1M
switches

Safety Protection Circuit

No Mercury
No UVLightBig Saving (87%)
on Electricity CostsUsable in Enclosed
LuminairesOmni Wide Angle
360°

CORN LAMP (54W & 120W)

CATALOG NO.	WATTAGE	LUMENS	VOLTAGE	DIMENSION	WEIGHT	COLOR TEMP
CL-54W-30K	54W	5440	120-277V AC	10-1/2" (H) x 3-3/4" (Dia)	2 lbs.	3000K
CL-54W-50K	54W	5700	120-277V AC	10-1/2" (H) x 3-3/4" (Dia)	2 lbs.	5000K
CL-120W-30K	120W	12000	120-277V AC	12" (H) x 5-3/4" (Dia)	3-1/2 lbs.	3000K
CL-120W-50K	120W	12600	120-277V AC	12" (H) x 5-3/4" (Dia)	3-1/2 lbs.	5000K
E39 REDUCER			Reduces E39 bulb to be used in E26 socket			

L24



Corn Lamps

