

CLEAR



FROSTED

T8-2FT-10W-32K-C / T8-2FT-10W-41K-C / T8-2FT-10W-50K-C
T8-4FT-18W-32K-C / T8-4FT-18W-41K-C / T8-4FT-18W-50K-C / T8-4FT-18W-50K-F
T8-4FT-22W-32K-C / T8-4FT-22W-41K-C / T8-4FT-22W-50K-C / T8-4FT-22W-50K-F
T8-6FT-31W-50K-C / T8-8FT-40W-50K-C

T-8 LED Tube Lamps

Ideal for offices, retail stores, showrooms and residential applications. Especially suited for areas where accessing the fixture is challenging. Rated for use in open fixtures only. Not for use in enclosed fixtures

ELECTRICAL SPECIFICATIONS:

- Voltage: 120–277V AC input

LIGHTING SPECIFICATIONS:

- Beam spread: 120°
- Base: fits standard T-8 or T-12 sockets (G-13)
- Color temperature: daylight (DL = 5000K), natural white (NW 4100K), warm white (WW = 3200K)
- CRI: 80
- Rated life: 50,000 hours
- Ambient operating temperature: -10°C to 30°C
- Not dimmable (dimmable version available by special order)

WARRANTY:

- Five-year warranty

SPECIAL FEATURES:

- T-8 LED lamp operates on line voltage with existing electronic ballast or without a ballast; one socket wired to line voltage
- Heat sink: 6063 extruded aluminum with heat dissipation ribs for superior thermal management
- Requires no ballast. Existing ballast must be bypassed and sockets wired directly to line voltage
- Special order: available in 3', 6', 8' lengths or with frosted lens, or with dimmable driver

CERTIFICATIONS:

- UL-listed / DLC-rated



T8-2FT-10W-32K-C / T8-2FT-10W-41K-C / T8-2FT-10W-50K-C

T8-4FT-18W-32K-C / T8-4FT-18W-41K-C / T8-4FT-18W-50K-C / T8-4FT-18W-50K-F

T8-4FT-22W-32K-C / T8-4FT-22W-41K-C / T8-4FT-22W-50K-C / T8-4FT-22W-50K-F

T8-6FT-31W-50K-C / T8-8FT-40W-50K-C


T-8 LED Tube Lamps



MODEL NO.	CHIP	WATT	LUMENS	COLOR TEMP	LENS
T8-2FT-10W-32K-C	60 SMD2835	10W	1100	WW 3200K	Clear
T8-2FT-10W-41K-C	60 SMD2835	10W	1150	NW 4100K	Clear
T8-2FT-10W-50K-C	60 SMD2835	10W	1200	DL 5000K	Clear
T8-4FT-18W-32K-C	110 SMD2835	18W	1800	WW 3200K	Clear
T8-4FT-18W-41K-C	110 SMD2835	18W	1900	NW 4100K	Clear
T8-4FT-18W-50K-C	110 SMD2835	18W	2050	DL 5000K	Clear
T8-4FT-18W-50K-F	110 SMD2835	18W	1950	DL 5000K	Frosted
T8-4FT-22W-32K-C	132 SMD2835	22W	2100	WW 3200K	Clear
T8-4FT-22W-41K-C	132 SMD2835	22W	2300	NW 4100K	Clear
T8-4FT-22W-50K-C	132 SMD2835	22W	2420	DL 5000K	Clear
T8-4FT-22W-50K-F	132 SMD2835	22W	2300	DL 5000K	Frosted
T8-6FT-31W-50K-C	144 SMD2835	31W	3100	DL 5000K	Clear
T8-8FT-40W-50K-C	210 SMD2835	40W	4800	DL 5000K	Clear

Installation Instructions

Powered from one end
(Retrofit Application)

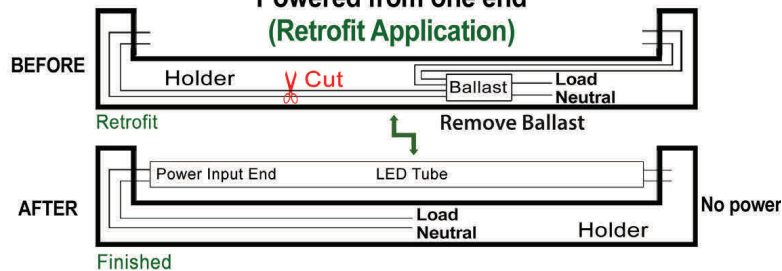


T8-2FT-10W-32K-C / T8-2FT-10W-41K-C / T8-2FT-10W-50K-C
T8-4FT-18W-32K-C / T8-4FT-18W-41K-C / T8-4FT-18W-50K-C / T8-4FT-18W-50K-F
T8-4FT-22W-32K-C / T8-4FT-22W-41K-C / T8-4FT-22W-50K-C / T8-4FT-22W-50K-F
T8-6FT-31W-50K-C / T8-8FT-40W-50K-C

T-8 LED Tube Lamps


Chromaticity Diagram— Sphere Spectroradiometer Method




LM79 T8-4FT-18W-50K-C

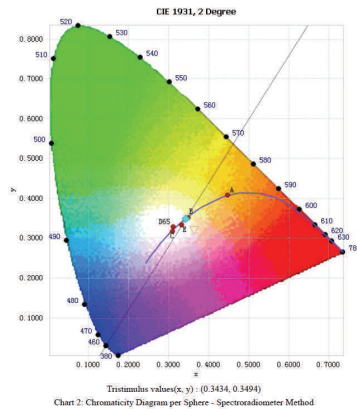


LM79 T8-4FT-22W-50K-F

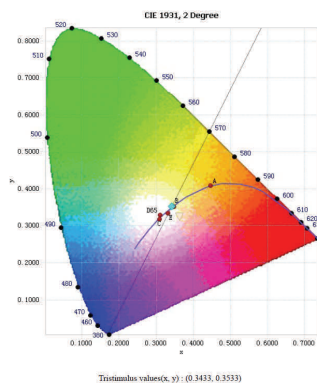

LM79 T8-4FT-22W-41K-F

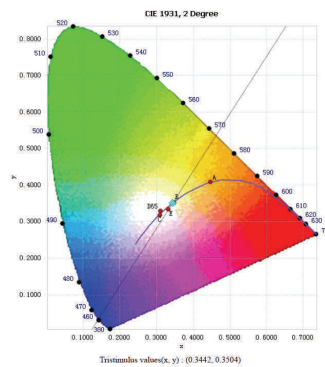

LM79 T8-4FT-18W-41K-C

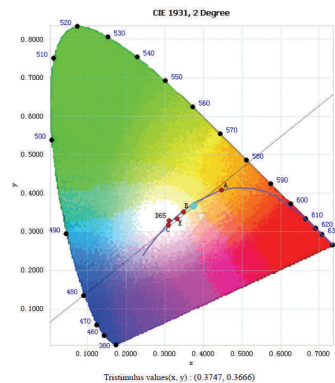

LM79 T8-4FT-18W-41K-F

