

Features

- Direct replacement T5HO LED tube
- Environmentally friendly with no mercury
- High lumen efficiency & high CRI
- Replaces existing fluorescent T5 lamp without removing electronic ballast
- Compatible with programmable start T5HO electronic ballasts
- LED 50,000 hours life
- Five years limited warranty
- UL listed




Specifications*

Model	T5LED-28W
Ballast Input Voltage	120-277V, 347V (ballast dependent)
LED Tube Wattage	26W
System Wattage	28W (ballast dependent)
Lumen (nom)	2800 lm (ballast dependent)
Color Temp	3000K / 4000K / 5000K
CRI	80+
Power Factor	> 0.9
THD	< 20% (ballast dependent)

*Specs based on data when tested with Sunpark T5HO PS ballast

Dimensions

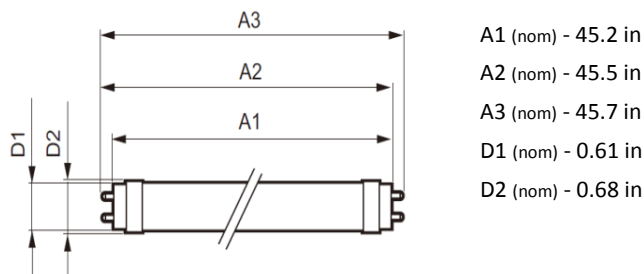

Installation

Warning: LED tubes can only be used with fixtures installed with programmable start T5HO electronic ballasts

Please ensure T5 sockets are in good condition prior to installing LED T5 lamps

1. Switch off power to the light fixture
2. Remove existing fluorescent lamp
3. Install & rotate LED T5 replacement lamp