

## SPECIFICATION & FEATURES

## 1-GANG BLANK AND DEVICE OVERS

### FEATURES & DIMENSION:

- 1-Gang Blank and Device Covers
- Zinc Die Cast (Except 1-BC, 1-BC-G, & 1CA-SW)
- Gasket included
- Device mounted
- Meets NEC Article 406.9 (A) for damp and wet locations
- Width: 2-3/4"
- Height: 4-1/2"

### CERTIFICATION:




File E227970



Listed



Wet Location

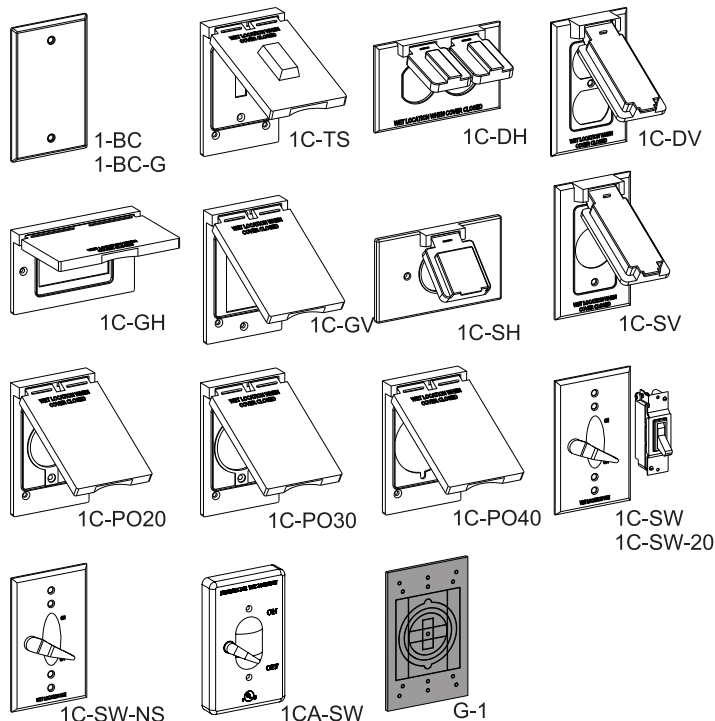

### CONFIGURATION DATA:

| Part No. |                  |          | Description                                              | Std.Pkg. |
|----------|------------------|----------|----------------------------------------------------------|----------|
| Gray     | Bronze           | White    |                                                          |          |
| 1-BC     | -                | -        | Aluminum Blank (Unpainted)                               | 50       |
| 1-BC-G   | 1-BC-BR          | 1-BC-W   | Heavy-Duty Galvanized Steel Blank                        | 50       |
| 1C-TS    | 1C-TS-BR         | 1C-TS-W  | Toggle Switch                                            | 25       |
| 1C-DH    | 1C-DH-BR         | 1C-DH-W  | Duplex/Combo. Device - Horizontal                        | 25       |
| 1C-DV    | 1C-DV-BR         | 1C-DV-W  | Duplex/Combo. Device - Vertical                          | 25       |
| 1C-GH    | 1C-GH-BR         | 1C-GH-W  | GFCI - Horizontal                                        | 25       |
| 1C-GV    | 1C-GV-BR         | 1C-GV-W  | GFCI - Vertical                                          | 25       |
| 1C-SH    | -                | -        | Single recept. or Switch Horizontal - 1.406" Diameter    | 25       |
| 1C-SV    | 1C-SV-BR         | 1C-SV-W  | Single recept. or Switch Vertical - 1.406" Diameter      | 25       |
| 1C-PO20  | -                | -        | 20A Power Outlet - 1.594" Diameter                       | 25       |
| 1C-PO30  | -                | -        | 30A Power Outlet - 1.750" Diameter                       | 25       |
| 1C-PO40  | -                | -        | 40-50A Power Outlet - 2.281" Diameter                    | 25       |
| 1C-SW    | 1C-SW-BR         | 1C-SW-W  | Lever + 15A Single-Pole Switch                           | 25       |
| 1C-SW-20 | -                | -        | Lever + 20A Single-Pole Switch                           | 25       |
| 1C-SW-NS | -                | -        | Lever Cover without Switch                               | 25       |
| 1CA-SW   | 1CA-SW-BR        | 1CA-SW-W | Aluminum Lever, compatible with Standard Toggle Switches | 25       |
| -        | G-1 (Black only) | -        | Universal 1-Gang Foam Gasket                             | 50       |

