



DesignLights Consortium™
Qualified Luminaires:
LWPQF1X58U5K*

FEATURES

Die Cast Aluminum Housing & Hinged Front Frame, ½" Coin Plugs with O-rings for Conduit & Photocell, Textured Architectural Bronze Powdercoat Finish Over a Chromate Conversion Coating.

Molded Prismatic Borosilicate Glass Lens.

Cast-in Template for Mounting Directly Over a 4" Recessed Outlet Box, or Use ½" Surface Conduit.

Custom Colors Available Upon Request.

LumaFit LED:

Delivered Lumens: 7,820 (4K); 8,146 (5K)

CRI: 85; CCT: 4000K, 5000K

Rated Life: 50,000 Hours; 5-Year Warranty

Aluminum Boards

Wattage: Array: 57.8w, System: 67.3w

Driver: Electronic Driver, 120-277V, 50/60Hz or 347/480V, 50/60Hz; Dimmable Driver

Listing & Ratings: CSA: Listed for Wet Locations. IP65
Operating Temperatures: -40°C to +40°C

Options: Surge Protection; PC1 120V Button Photocell;
PC2 240V Button Photocell; Battery Backup

Accessories Sold Separately.

LM-79 Reports Available on Select Models.




DuraLED Large Wallpack



LWP

DIMENSIONS

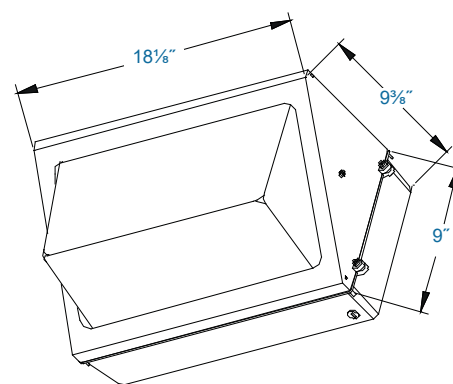

LWP

ORDER INFORMATION

DuraLED Large Wallpack

Catalog #	Description	
Complete Units		
Ordering Information		
Example: LWPQF1X58U5KZSP		
LWP	Model:	LWP
Q	LED Mfr:	Q=QSSI
F	Optics:	F=Medium Beam Spread
1X	Number of Arrays:	1X=One
58	Wattage:	58=58w
U	Ballast:	U=120-277V, H=347/480V
5K	CCT:	4K=4000K, 5K=5000K
Z	Color:	Z=Bronze
-	Mounting:	N/A
SP	Options:	SF=Single Fuse, DF=Double Fuse, SP=Surge Protection, PC1=120V Button Photocell, PC2=240V Button Photocell

APPLICATIONS

Warehouse Facilities
Shipping and Receiving Areas
Cold Storage Facilities
Industrial Plants
Commercial Buildings

LED


ACCESSORIES

OPTIONS:

Wireguard: **LWPWG**
 Full Cutoff: **LWPFC**
 Side Cutoff: **LWPSCS**
 Vandal Shield: **LWPVS**
 Glass Lens: **LWPGL**
 Provides 90 Minutes of Backup Power:
3EBL1202774500
 120V Button Photocell: **PC1**
 240V Button Photocell: **PC1**



Wireguard
(LWPWG)

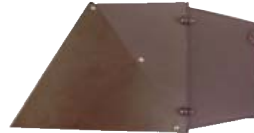


Full Cutoff
(LWPFC)



Side Cutoff
(LWPSCS)



Vandal Shield
(LWPVS)

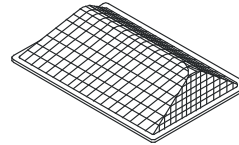

Glass Lens
(LWPGL)




Battery Backup
(3EBL1202774500)



Button Photocell
(PC1, PC2)

PHOTOMETRICS

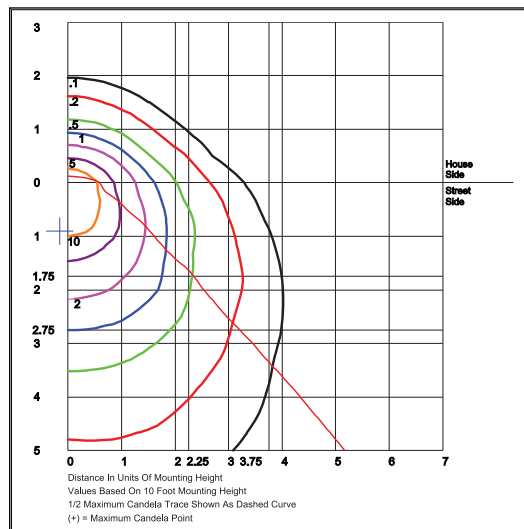

LWPQF1X58U5K

Specifications subject to change without notice.



DuraLED Large Wallpack

LED lighting facts[®] DURAGUARD
A Program of the U.S. DOE

Light Output (Lumens)	6804
Watts	68.06
Lumens per Watt (Efficacy)	99.97

Color Accuracy	83
Color Rendering Index (CRI)	

Light Color
Correlated Color Temperature (CCT)

5270 (Daylight)

Warm White	Bright White	Daylight
2700K	3000K	4500K
		6500K

All results are according to IESNA LM-79-2008: Approved Method for the Electrical and Photometric Testing of Solid-State Lighting. The U.S. Department of Energy (DOE) verifies product test data and results.

Visit www.lightingfacts.com for the Label Reference Guide.

 
Registration Number: -QNSKC4 (7/13/2015)
Model Number: LWPQF1X5BU5K*
Type: Luminaire - Area/Roadway

LM-79 Report Available.
DesignLights Consortium™ Qualified Luminaire.

LED



DuraLED Large Wallpack



Specifications subject to change without notice.