



BREAKER CROSS REFERENCE CHART




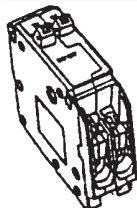


EATON | Cutler-Hammer

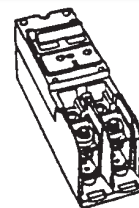

BREAKER CROSS REFERENCE REPLACEMENT FOR THESE BRANDS

Locke#	Part#	Type	ITE	GTE	GS	CROUSE-HINDS	BRYANT	AMERICAN SWITCH
P1675	A120	1/2" SP 20A	X	X	X	X	X	X
P0152	B02020	TWIN 1" SP 20A	X	X	X	X	X	X
P0153	B03020	TWIN 1" SP20-30A	X	X	X	X	X	X
P0175	BR2020	TWIN 1" SP20-20A	X	X	X	X	X	X
P1677	A230	1" 2P 30A	X	X	X	X	X	X
P1678	A240	1" 2P 40A	X	X	X	X	X	X
P1679	A250	1" 2P 50A	X	X	X	X	X	X
P0149	BR115	1" SP 15A	X	X	X	X	X	X
P0150	BR120	1" SP 20A	X	X	X	X	X	X
P0151	BR130	1" SP 30A	X	X	X	X	X	X
P0171	BR140	1" SP 40A	X	X	X	X	X	X
P0172	BR150	1" SP 50A	X	X	X	X	X	X
P0154	BR220	2" 2P 20A	X	X	X	X	X	X
P0155	BR230	2" 2P 30A	X	X	X	X	X	X
P0156	BR240	2" 2P 40A	X	X	X	X	X	X
P0157	BR250	2" 2P 50A	X	X	X	X	X	X
P0158	BR260	2" 2P 60A	X	X	X	X	X	X
P0159	BR270	2" 2P 70A	X	X	X	X	X	X
P0160	BR2BO	2" 2P BOA	X	X	X	X	X	X
P0161	BR290	2" 2P 90A	X	X	X	X	X	X
P0162	BR2100	2" 2P 100A	X	X	X	X	X	X
P0163	BR2125	2" 2P 125A	X	X	X	X	X	X
P0921	BR320	3" 3P 20A	X	X	X	X	X	X
P0922	BR330	3" 3P 30A	X	X	X	X	X	X
P0923	BR340	3" 3P 40A	X	X	X	X	X	X
P0924	BR350	3" 3P 50A	X	X	X	X	X	X
P0925	BR360	3" 3P 60A	X	X	X	X	X	X
P0926	BR3100	3" 3P 100A	X	X	X	X	X	X
P0170	GFCB120	1" SP 20A GFI	X	X	X	X	X	
P0174	GFCB130	1" SP 30A GFI	X	X	X	X	X	
P0188	GFCB220	2" 2P 20A GFI	X	X	X	X	X	
P0189	GFCB230	2" 2P 30A GFI	X	X	X	X	X	
P0190	BJ2200	2P 200 MCB					X	
P0191	BJ2225	2P 225 MCB					X	
P2765	BQC220220	Two 2P 20A/20A					X	
P2766	BQC220230	Two 2P 20A/30A					X	
P2767	BQC220240	Two 2P 20A/40A					X	
P2768	BQC220250	Two 2P 20A/50A					X	
P2769	BQC230230	Two 2P 30A/30A					X	
P2770	BQC230240	Two 2P 30A/40A					X	
P2771	BQC230250	Two 2P 30A/50A					X	

  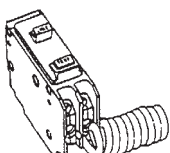 

P / ELECTRIC

CORdS, AdApTERS, GFCI, STRIPs ANd SuRGE pROTECTORS

LEVITON®

AUTOMATIC RESET GFCI CORD SETS AND EXTENSION CORD



- Comply with NEC Code article #305-6A mandating GFCI protection for temporary wiring at construction sites & other areas where permanently wired GFCIs are not available.
- Conforms with OSHA regulation CFR 1926.404b (i) (ii) for construction sites.
- 14/3 SJTW-A high-visibility yellow cable
- Ground fault and open neutral protection.
- Water-resistant enclosure. Sealed by ultrasonic welding, surpasses 4 hour UL submergence test.
- Complies with UL Standard 943.

Locke#

T3111 66591-6C 6' 15A GFCI Cord Set



T3112 66891-3 3' 20A GFCI Cord Set



AMERICAN
INSULATED WIRE CORP.

OUTDOOR/INDOOR EXTENSION CORDS



300 VOLT, UL Listed
All weather, Extra Flexible,
Oil Resistant, -40 Degrees C

Locke#	Vendor#	Description	Length	Color	Power
T2470	2271	16/3 SJTW-A	25'	Orange	13A 125V 1625W
T2471	2273	16/3 SJTW-A	50'	Orange	13A 125V 1625W
T2472	2275	16/3 SJTW-A	100'	Orange	10A 125V 1250W
T2473	2275	14/3 SJTW-A	25'	Orange	15A 125V 1875W
T2474	2281	14/3 SJTW-A	50'	Orange	15A 125V 1875W
T2475	2283	14/3 SJTW-A	100'	Orange	13A 125V 1625W
T0291	2285	12/3 SJTW-A	50'	Orange	15A 125V 1875W
T0280	2294	12/3 SJTW-A	100'	Orange	15A 125V 1875W

LEVITON®

3 OUTLET PLUG-IN ADAPTER



Locke#

P4599 697-1 3 Outlet Plug-In Adapter

LEVITON®

PLUG ADAPTER



Locke#

P4600 274 Plug adapter

LEVITON®

PLUG-IN MULTIPLE OUTLET SURGE SUPPRESSOR



Locke#

P4149 3500PT 6 Outlet Box with Phone & Surge Suppressor

LEVITON®

MULTIPLE OUTLET STRIP SURGE SUPPRESSOR



Locke#

P4147 S1000-OPS 6 Outlet Strip with Surge Suppressor

EATON

Powering Business Worldwide

POWER STRIPS NO SURGE PROTECTION



6 Grounded Outlets and a built-in circuit breaker. UL/cUL Listed.


Locke#

P8591 PSXVAL6AC4 4' Cord

P8590 PSXVAL6AC8 8' Cord

ERICSON
safety electrical specialties

GFCI CORD SET

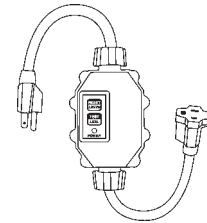


Locke#

T2482 1080-14-2S Molded-On Plug & Connector GFCI Cord Set

ERICSON
safety electrical specialties

TRI-TAP GFCI

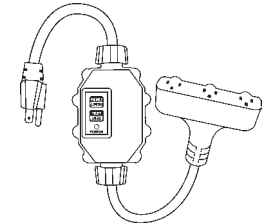

Locke#

T2483 1080-12-2TT 3 Outlet PVC Molded Connector & Plug

GFCI QUAD



Locke#

T2484 30334052 15A 125V GFCI Protected Quad Outlet

P / ELECTRIC



Powering Business Worldwide

AC POWER/PHONE SURGE PROTECTOR



6' Cord. \$75,000 connected equipment Warranty. 330 V Clamping Voltage, EMI/RFI Noise Filter up to 40dB, 125 Vac, 15A, 60Hz, 1875W, UL/cUL Listed.

- 1080 Joules
- 72 kA Max Peak Current
- 7 Outlets with Sliding Safety Covers

Locke#

P8584 SMAX7T AC & Phone Surge



Powering Business Worldwide

AC POWER/COAX SURGE PROTECTOR



6' Cord. \$75,000 connected equipment Warranty. 330 V Clamping Voltage, EMI/RFI Noise Filter up to 40dB, 125 Vac, 15A, 60Hz, 1875W, UL/cUL Listed.

- 1080 Joules
- 72 kA Max Peak Current
- 7 Outlets with Sliding Safety Covers

Locke#

P8583 SMAX7C AC & Coax Surge



Powering Business Worldwide

AC POWER/PHONE/COAX SURGE PROTECTOR



6' Cord. \$75,000 connected equipment Warranty. 330 V Clamping Voltage, EMI/RFI Noise Filter up to 40dB, 125 Vac, 15A, 60Hz, 1875W, UL/cUL Listed.

- 2160 Joules
- 144 kA Max Peak Current
- 8 Outlets with Sliding Safety Covers

Locke#

P8582 SMAX8TC AC Power/Phone/Coax Surge



Powering Business Worldwide

AC POWER/PHONE/COAX CABLE/NETWORK SURGE PROTECTOR



Cord Length of 6' and offer a *\$150,000 Warranty. Ratings include: 330 V Clamping Voltage, EMI/RFI Noise Filter up to **58dB, 125 Vac, 15A, 60Hz, 1875W, UL/cUL Listed.

- 4320 Joules
- 288 kA Max Peak Current
- Protects AC Power/Phone/ Coax Cable/ Network
- 12 Outlets (4 fixed, 8 rotating for extra plug-in space)

Locke#

P8580 SULT12TC AC Power/Phone/Coax Cable/Network Surge Protector



Powering Business Worldwide

AC POWER/COAX CABLE SURGE PROTECTOR



\$50,000 Warranty. 540 Joules, 36 kA Max Peak Current, 330 V Clamping Voltage, EMI/RFI Noise Filter up to 40dB, 125 Vac, 15A, 60Hz, 1875W, UL/cUL Listed.

Locke#

P8586 SMICRO1C Single AC & Coax Wall Mount Surge



Powering Business Worldwide

AC POWER/PHONE SURGE PROTECTOR



\$50,000 Warranty. 540 Joules, 36 kA Max Peak Current, 330 V Clamping Voltage, EMI/RFI Noise Filter up to 40dB, 125 Vac, 15A, 60Hz, 1875W, UL/cUL Listed.

Locke#

P8585 SMICRO1T Single AC & Phone Wall Mount Surge



Powering Business Worldwide

AC POWER/PHONE SURGE PROTECTOR



\$50,000 Warranty. 540 Joules, 36 kA Max Peak Current, 330 V Clamping Voltage, EMI/RFI Noise Filter up to 40dB, 125 Vac, 15A, 60Hz, 1875W, UL/cUL Listed. Wall Mount

Locke#

P8588 SMICRO6T AC & Phone Surge



Powering Business Worldwide

AC POWER/PHONE SURGE PROTECTOR



Cord Length of 6' and offer a *\$150,000 Warranty. Ratings include: 330 V Clamping Voltage, EMI/RFI Noise Filter up to **58dB, 125 Vac, 15A, 60Hz, 1875W, UL/cUL Listed.

- 2160 Joules
- 144 kA Max Peak Current
- Protects AC Power/ Phone
- 8 Rotating Outlets (for extra plug-in space)

Locke#

P8581 SULT8T AC/Phone Surge



Powering Business Worldwide

AC SURGE PROTECTOR CONSTRUCTION SERIES DURABLE METAL HOUSING



7 Outlets and a Cord Length of 6'. Ratings include: 1080 Joules, 72 kA Max Peak Current, 330 V Clamping Voltage, EMI/RFI Noise Filter up to 40dB, 125 Vac, 15A, 60Hz, 1875W, UL/cUL Listed.

Locke#

P8589 SCONST7 Surge Protector

P / ELECTRIC



Powering Business Worldwide

WHOLE HOME AC SURGE PROTECTION



AC Power Protection, LED Status Indication, a Limited Lifetime Warranty, and are suitable for Indoor/Outdoor applications when properly installed. Ratings include: 400 V Clamping Voltage, UL/cUL® Listed, <1 Nanosecond response time, 120/240 Vac, 50/60 Hz.

*\$75,000 connected equipment 2,880 Joules (Total) 180,000 Amps (Max surge current)

Locke#

P6858 CHSPT2ULTRA Whole Home Surge Protection

P6859 CHSPFMKIT Flush Mount kit for **P6858**



Powering Business Worldwide

WHOLE HOME SURGE PROTECTION 3-PACK AC/Cable/Phone



Limited Lifetime Warranty and are suitable for Indoor cable or phone applications when properly installed. Ratings include: UL/cUL Listed, <1 Nanosecond response time.

AC \$75,000 connected equipment 2,880 Joules (Total) 180,000 Amps (Max surge current)

Cable Protects 2 quad shield cables
 • 20 kA Max Surge Current
 • DC breakdown voltage 145 V
 • *\$10,000 Warranty

Phone Protects 4 telephone lines
 • 80 kA Max Surge Current
 • DC breakdown voltage 230 V
 • Ring 90–120 Vac / Tone 48–52 Vdc
 • *\$10,000 Warranty

Locke#

P6854 CHSPT23PACK Whole Home Surge Protection 3-Pack



Powering Business Worldwide

SURGE ARRESTER BREAKER




For use on single-phase, 120/240v AC systems. This surge arrester plugs into a single-phase PowerMaster loadcenter & occupies two 1" pole spaces. When the green LED light goes out, the device needs to be replaced. This device is suitable for Category "C" service entry locations installed in accordance with NEC Article 280. The CSA2P is ideal for protecting appliances such as: refrigerators, microwaves & home computers.

Locke#

P6283 BRSURGE TVSS Circuit Breaker, Surge Arrester

EATON | Cutler-Hammer GFCI BREAKERS 120 VOLTS AC - 10,000 AIC TYPE GFCB

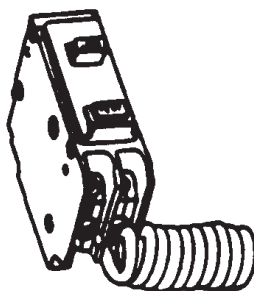

1 Pole Breakers, 1" Wide


Locke#		Amp Rating
P3911	GFCB115	15 Amp
P0170	GFCB120	20 Amp
P0174	GFCB30	30 Amp

120/240V AC 10,000 AIC - GFCB

2 Pole Breakers - 2" Wide

Locke#		Amp Rating
P0188	GFCB220	20 Amp
P0189	GFCB230	30 Amp
P3106	GFCB240	40 Amp
P5033	GFCB250	50 Amp
P5094	GFCB260	60 Amp


EATON | Cutler-Hammer TYPE BW MAIN BREAKERS

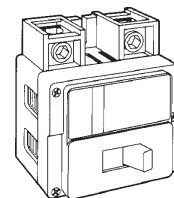

2 Pole Breakers, 2" Wide
 For P5011, P5010, P5009, P5012, P5014, P5015, P5016, P5017

Locke#		Amp Rating
P5018	BW2150	150A 2 pole Main Circuit Breaker 10KAIC
P5019	BW2200	200A 2 pole Main Circuit Breaker 10KAIC
P5060	BW2225	225A 2 pole Main Circuit Breaker 10KAIC
P9028	CSR2200N	200A 2 pole Main Circuit Breaker 25KAIC

EATON | Cutler-Hammer TYPE BJ BREAKER 120/240v AC, 10,000 AIC

 

2 Pole Breakers, 2" Wide, 120/240V AC

Locke#		Amp Rating
P0199	BJ2150	150 Amp
P0190	BJ2200	200 Amp
P0191	BJ2225	225 Amp

EATON | Cutler-Hammer 240V CIRCUIT BREAKERS




Locke#		Amp Rating
P6027	CCV2150	150Amp 2P
P6026	CCV2200	200Amp 2P
P6025	CC3150	150Amp 3P
P6028	CC3200	200Amp 3P
P6029	CC3225	225Amp 3P

P | ELECTRIC

LOAD CENTER CIRCUIT BREAKERS

EATON | Cutler-Hammer PLUG-ON CIRCUIT BREAKERS TYPE A BREAKERS 1 Pole Breakers, 1/2" per Breaker

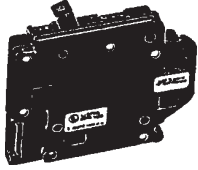

Locke#	Rating
P1675	A-120 20 Amp

Two 1 Pole Breakers, 1" per Breaker, Center Clip



Locke#	Rating
P3905	BD-1515 15/15 Amp
P3906	BD-1520 15/20 Amp
P0152	BD-2020 20/20 Amp
P0153	BD-3020 30/20 Amp
P0176	BR-1515 15/15 Amp
P0175	BR-2020 20/20 Amp

2 Pole Breakers, 1" per Breaker



Locke#	Rating
P1677	A-230 30 Amp
P1678	A-240 40 Amp
P1679	A-250 50 Amp


EATON | Cutler-Hammer TYPE A MULTI-BREAKERS WITH COMMON TRIP CENTER & OUTER POLES



240V AC, 10,000 AIC (1/2" per pole)


Locke#	Rating
P0933	BQC2202120 20 Amp
P0934	BQC2302120 20/30 Amp
P0935	BQC2402120 20/40 Amp
P0936	BQC2502120 20/50 Amp

EATON | Cutler-Hammer TYPE BQC MULTI-BREAKERS WITH COMMON TRIP CENTER AND OUTER POLES 240 VOLTS AC - 10,000 AIC (1/2" per pole)

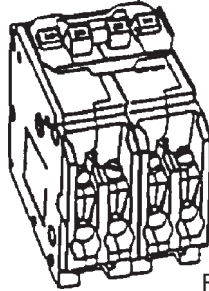

Locke#	Rating
P2765	BQC220220 20/20 Amp
P2766	BQC220230 20/30 Amp
P2767	BQC220240 20/40 Amp
P2768	BQC220250 20/50 Amp
P2769	BQC230230 30/30 Amp
P2770	BQC230240 30/40 Amp
P2771	BQC230250 30/50 Amp

EATON | Cutler-Hammer FILLER PLATE FOR FPE LOADCENTERS

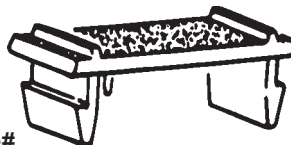


Locke#	Rating
P5850	NCFS 1/2" Filler Plate for FPE Loadcenters

EATON | Cutler-Hammer F.P.E. STAB-LOK CIRCUIT BREAKERS

For Stab-Lok Loadcenters
Stab-In


TYPES NA AND NC BREAKERS
120/240, 240 VOLTS AC - 10,000,
22,000 AIC

1 Pole, Type NA, 1" Per Breaker

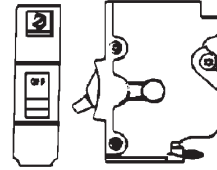


Locke#	Rating
P1738	20 20 Amp
P0196	30 30 Amp

1 Pole, Type NC, 1/2" Per Breaker

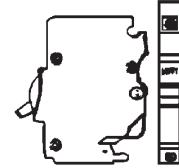


Locke#	Rating
P1744	020 20 Amp
P0197	030 30 Amp

2 Pole, Type NA. 2" Per Breaker

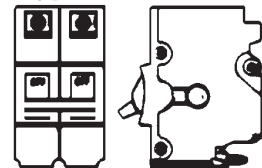

Locke#	Rating
P3975	220 20 Amp
P1782	230 30 Amp
P1783	240 40 Amp
P1784	250 50 Amp
P1785	2P60 60 Amp
P1787	2P100 100 Amp

2 Pole, Type NC, 1" Per Breaker

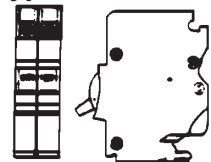

Locke#	Rating
P3977	0220 20 Amp
P1790	0230 30 Amp
P0198	0240 40 Amp
P1792	0250 50 Amp



I Oad CENTER CIRCUIT BREAKERS

ZINSCO PLUG-ON TYPE R BREAKERS 120/240, 240v, 10,000 AIC



Two 1-Pole Breakers in One ¾" Space

Locke#	Rating
P1716 R38-20	20 Amp

2-POLE BREAKERS



Locke#	Rating
P1721 RC38-20	20 Amp
P1722 RC38-30	30 Amp
P0194 RC38-40	40 Amp
P3105 RC38-50	50 Amp
P1725 RC38-60	60 Amp

ZINSCO 2 POLE THICK BREAKERS

Locke#	Rating
P3101 QC-30	30 Amp 2 Pole
P3102 QC-40	40 Amp 2 Pole
P4270 QC-50	50 Amp 2 Pole

ZINSCO 1 POLE THICK BREAKERS

Locke#	Rating	BOLT ON
P3103 QB-20	20 Amp	2 Pole

REPLACEMENT FOR ZINSCO 120/240, 240V AC 10,000 AIC

1-Pole Breakers




Locke#	Rating
P1726 Q-20	20 Amp
P0195 Q-30	30 Amp

2-POLE BREAKERS

Locke#	Rating
P1735 QCAL-60	60 Amp
P1736 QCAL-100	100 Amp

E.T.N | Cutler-Hammer FOR USE AS REPLACEMENT CIRCUIT BREAKERS FOR CERTAIN SQUARE D® TYPE QO®

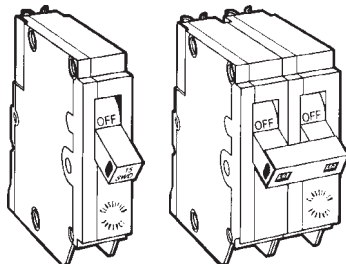

UL LISTED CIRCUIT BREAKERS
UL CLASSIFIED

NOTES:

1. Breaker terminals are Al/Cu and suitable for use with 60°C or 75°C ampacity wire.
2. Caution: Cutler-Hammer Classified Breakers must not be used in series rated systems or in applications above 10,000 AIC. They can only be installed in Square D® Type QO® Load Centers.


Square D® and QO® are registered trademarks of the Square D Company.

FOR USE ONLY IN SQUARE D® QO®

- 3 Position Trip
- One Year Warranty
- HACR Rated 15-60 amps
- SWD Rated 15 and 20 amps, single-pole


Locke#	Amps	Challenger Catalog Number	Replaces Square D® Catalog Number
P4674	15 amp	CHQ155	Q0155
P4675	20 amp	CHQ120	Q0120
P6350	20 amp	CHQ120GF	Q0120GFI
P4676	30 amp	CHQ130	Q0130
P6351	30 amp	CHQ130GF	Q0130GFI
P4677	40 amp	CHQ140	Q0140
P4678	50 amp	CHQ150	Q0150
P4679	15 amp	CHQ215	Q0215
P4680	20 amp	CHQ220	Q0220
P6352	20 amp	CHQ220GF	Q0220GFI
P6346	25 amp	CHQ225	Q0225
P4681	30 amp	CHQ230	Q0230
P6353	30 amp	CHQ230GF	Q0230GFI
P6347	35 amp	CHQ235	Q0235
P4682	40 amp	CHQ240	Q0240
P6348	45 amp	CHQ245	Q0245
P4683	60 amp	CHQ250	Q0250
P6355	50 amp	CHQ250GF	Q0250GFI
P4684	60 amp	CHQ260	Q0260

E.T.N | Cutler-Hammer SQUARE D® SINGLE POLE, 1 SPACE, QO® CIRCUIT BREAKER WITH VISI-TRIP® INDICATOR

 


Locke#	Rating
P1500 QO115C	1 Pole, 15Amp
P1501 QO120C	1 Pole, 20Amp
P1502 QO130L	1 Pole, 30Amp

SQUARE D® 2 POLE, 2 SPACES QO® CIRCUIT BREAKER WITH VISI-TRIP® INDICATOR

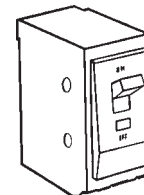

Locke#	Rating
P1503 QO220C	2 Pole 20A
P1504 QO230C	2 Pole 30A
P1505 QO240C	2 Pole 40A
P1506 QO250C	2 Pole 50A
P1507 QO260C	2 Pole 60A
P1508 QO2100	2 Pole 100A

SQUARE D® TWIN CIRCUIT BREAKERS QO® TANDEM CIRCUIT BREAKER 2-SINGLE POLES, 1 SPACE

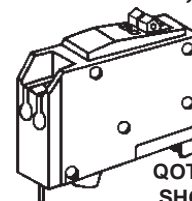

Locke#	Rating
P1509 QOT2020	1 Pole Twin 20A (New Style)

P / ELECTRIC

LOAD CENTER CIRCUIT BREAKERS

EATON | Cutler-Hammer CUTLER-HAMMER CL BREAKERS

Have been classified by UL
for use "in the following

loadcenters:

Crouse - Hinds


General Electric

ITE / Siemens

Murray

Thomas & Betts

Square D Homeline

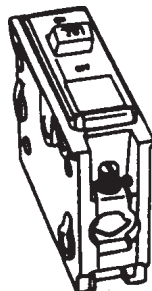

Locke#	Model#	DESCRIPTION
P1316	CL115	1P 15A
P1317	CL120	1P 20A
P1318	CL220	2P 20A
P1319	CL230	2P 30A
P1320	CL240	2P 40A
P1321	CL250	2P 50A
P1322	CL115AF	1P 15A Arc Fault
P1323	CL120AF	1P 20A Arc Fault
P1324	CL120GF	1P 20A GFCI

SQUARE D® TYPE HOM®



Locke#	Model#	DESCRIPTION
P6901	HOM115	1 Pole 15a Homeline
P6902	HOM120	1 Pole 20a Homeline
P6907	HOMT2020	2 Pole 20a TWIN Homeline
P6903	HOM220	2 Pole 20a Homeline
P6904	HOM230	2 Pole 30a Homeline
P6905	HOM240	2 Pole 40a Homeline
P6906	HOM250	2 Pole 50a Homeline
P6915	HOM260	2 Pole 60a Homeline
P6916	HOM2100	2 Pole 100a Homeline

EATON | Cutler-Hammer BAB TYPE BOLT-ON CIRCUIT BREAKERS

Single Pole 120/240 Volts AC



Locke#	Model#	DESCRIPTION
P3083	BAB-1020	20 Amp
P3084	BAB-1030	30 Amp

Two Pole 120/240 Volts AC



Locke#	Model#	DESCRIPTION
P3081	BAB2020	20A
P3085	BAB2030	30A
P3086	BAB2040	40A
P5350	BAB2050	50A
P6365	BAB2060	60A
P6366	BAB2100	100A

Three Pole 240 Volts AC



Locke#	Model#	DESCRIPTION
P5059	BAB-3020H	20A
P3087	BAB-3030H	30A
P3088	BAB-3040H	40A
P3089	BAB-3050H	50A
P6367	BAB-3060H	60A
P6368	BAB-3100H	100A

EATON | Cutler-Hammer REPLACEMENT FOR PUSHMATIC CIRCUIT BREAKERS




Locke#	Model#	DESCRIPTION
P6908	UBIP115	1 Pole 15 Amp Pushmatic Replacement
P6909	UBIP120	1 Pole 20 Amp Pushmatic Replacement
P6913	UBIP2020	20 Amp TWIN Pushmatic Replacement
P6910	UBIP220	2 Pole, 20A Pushmatic Replacement
P6911	UBIP230	2 Pole, 30A Pushmatic Replacement
P6912	UBIP240	2 Pole, 40A Pushmatic Replacement
P6917	UBIP250	2 Pole, 50A Pushmatic Replacement
P6918	UBIP260	2 Pole, 60A Pushmatic Replacement

Q LINE PLUG-IN CIRCUIT BREAKERS

SINGLE POLE

 
Type THQP
½" Module



Locke#	Model#	DESCRIPTION
P3435	THQP115	15 Amp 120/240VAC
P3436	THQP120	20 Amp 120/240VAC
P3437	THQP130	30 Amp 120/240VAC

TWO POLE 1"

 
Type THQP
1" Module
TWO POLE: Incorporates
Internal Common Trip Bar



Locke#	Model#	DESCRIPTION
P3438	THQP220	20 Amp 120/240VAC
P3439	THQP230	30 Amp 120/240VAC
P3440	THQP240	40 Amp 120/240VAC
P3441	THQP250	50 Amp 120/240VAC

TWO POLE 2"

 Type THQP
2" Module
TWO POLE: Incorporates
Internal Common Trip Bar



Locke#	Model#	DESCRIPTION
P3442	THQL2160	60 Amp 120/240VAC
P3443	THQL2100	100 Amp 120/240VAC



E.T.N | Cutler-Hammer METER PACK


Main Lugs Required. Use P5056 or P5057
1 Per Phase & Neutral
Single Phase, 3 Wire, 120/240
Volts AC
For use with Plug-On Tenant
Mains
125 & 200 Amp Meter
Stations, Ringless.
Underground Only



Locke#

- P3052** 1MP2122RRL 2 Meter Stations
125 Amp Main
use **P0162** or **P0163** breaker
- P3053** 1MP4124RRL 4 Meter Stations
125 Amp Main
use **P0162** or **P0163** breaker
- P6645** 1MP6126RRL 6 Meter Stations
125 Amp Main
use **P0162** or **P0163** breaker
- P6791** 1MP6206RRL 6 Meter Stations
200 Amp Main
use **P6026** or **P6027** breaker
- P6361** 1MP4206RRL 4 Meter Stations
200 Amp Main
use **P6026** or **P6027** breaker
- P6362** 1MP2204RRL 2 Meter Stations
200 Amp Main
use **P6026** or **P6027** breaker

E.T.N | Cutler-Hammer METER/PANEL COMBINATION 1P-100A, 1P-200A

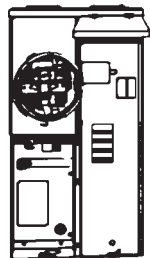


Main Breaker Factory
Installed
Single Phase, 3 Wire,
120/240 Volts AC
10,000 AIC, NEMA 3R, Ring
Style

Locke#

- P3056** MBE48B200BTS 4/8, 2/4
200A Main Ampacity
- P2721** MBEB200BTS **200A** Main
breaker included, 10KAIC, No
Distribution
- P5949** MBT48B150BTS **150A**, 4/8
Meter Breaker, Overhead Or
Underground Feed
- P5948** MBE1224B100BTS **100A**,
12/24 Meter Breaker, OH/UG.
- P5951** MBT48B200BTS **200A**, 4/8
Meter Breaker, OH/UG
- P5953** MBT48B125BTS **125A**, 4/8
Meter Breaker, OH/UG

E.T.N | Cutler-Hammer METER-BREAKER

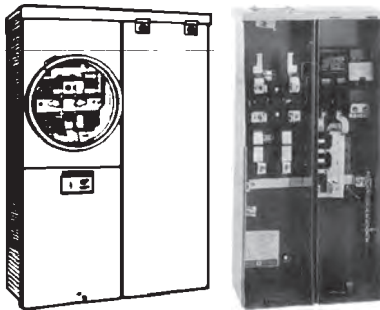

P5511

P6285


Single Phase, 3 Wire, 120/240, 120/208 Volts
AC
10,000 AIC, NEMA 3R, Rainproof, with Hub
Provisions- Overhead or Underground
Service. Order Main Breaker Separately

Locke#

	1 Pole	2 Pole
	BR/BD	BR/BD

- P5511** MBE24L125BTS 2/4 1/2
125A Main Ampacity, MLO, AIC
Dependent, No Main
- P6285** MBE816P200BTS
200A
Uses **P5018** or **P5019** Main,
Provision for Main, AIC
Dependent

E.T.N | Cutler-Hammer METER SOCKET

 

Locke#

- P4019** UGTE4213BCH
200A, 5 Terminal, SM Hub
Open, OH/UG, 19"x13"x5"

*CoMPare our
PriCes and
save!
WhY PaY More?*

E.T.N | Cutler-Hammer MECHANICAL LUG KITS FOR METER PACKS Cu/Al, 1 Per Package

Locke#

- P5056** IMPLK1 (2) #2/0-250 MCM,
or (1) #6-600 MCM per O & N
- P5057** IMPLK3 (2) 250 - 500
MCM per O & N

E.T.N | Cutler-Hammer LABELS FOR LOADCENTERS

Locke#

- P6857** BRMS circuit ID strip

E.T.N | Cutler-Hammer SCREWS FOR LOADCENTERS

Locke#

- P6856** LCCSCS 6 pk screws for
loadcenter cover

E.T.N | Cutler-Hammer CIRCUIT DIRECTORY FOR BR LOADCENTER

Locke#

- P0148** TCD 4 in x 4 in x .5 in,
adhesive backed

E.T.N | Cutler-Hammer SPA PANEL GFCI BREAKER



Locke#

- P4342** CH60SPA Spa Panel with
2P60 GFCI Breaker
- P6884** CH50SPA Spa Panel with
50A CH GFCI Breaker



Locke Supply/ Eaton Electrical Panelboard Stocking Program.

**QUESTIONS THAT MUST
BE ANSWERED BEFORE
QUOTING A PANELBOARD
FROM STOCK.**

Ampere Rating?

Main Breaker or Main Lug?

Top Feed or Bottom Feed?

Single Phase or 3 Phase?

Voltage?

Aluminum or Copper Bus?
(We stock Aluminum; Copper is Special Order)

Branch Breakers?

Sub-Feed Breaker or Lugs?

**NEMA 1 Indoor or NEMA 3R
Outdoor Enclosure?**

If NEMA 1; Surface or Flush Trim?

Service Entrance Rated?

Interrupting Capacity (AIC)?
(If an AIC rating larger than we stock is required the panel must be custom built)

**System Rating (AIC) Fully Rated
or Series Rated?**



EATON | Cutler-Hammer NEMA 1 PANELBOARD ENCLOSURE



Locke#	Model	Dimensions
P1559	EZB2036RBS	20x36" Panelboard Enclosure Nema 1
P1660	EZB2042RBS	20x42" Panelboard Enclosure Nema 1
P1661	EZB2048RBS	20x48" Panelboard Enclosure Nema 1
P1662	EZB2060RBS	20x60" Panelboard Enclosure Nema 1
P1663	EZB2072RBS	20x72" Panelboard Enclosure Nema 1
P1664	EZB2090RBS	20x90" Panelboard Enclosure Nema 1

EATON | Cutler-Hammer NEMA 1 TRIMS



Locke#	Model	Dimensions
P8531	EZT2036S	36" Surface Mount Panelboard Trim
P8532	EZT2036F	36" Flush Mount Panelboard Trim
P8533	EZT2048S	48" Surface Mount Panelboard Trim
P8534	EZT2048F	48" Flush Mount Panelboard Trim
P8535	EZT2060S	60" Surface Mount Panelboard Trim
P8536	EZT2060F	60" Flush Mount Panelboard Trim
P8537	EZT2072S	72" Surface Mount Panelboard Trim
P8538	EZT2072F	72" Flush Mount Panelboard Trim

EATON | Cutler-Hammer NEMA 3R ENCLOSURES

Locke#	Model	Dimensions
P8539	GWP2036PR	36" Nema 3R Panelboard Enclosure
P8540	GWPBQ2048PR	48" Nema 3R Panelboard Enclosure
P8592	GWPBQ2060PR	60" Nema 3R Panelboard Enclosure
P8541	GWPBQ2072PR	72" Nema 3R Panelboard Enclosure

EATON | Cutler-Hammer PANELBOARD INTERIORS



**(ALUMINUM BUS
ONLY; COPPER BUS
SPECIAL ORDER)**

Locke#	Model	Dimensions
P8520	PRL1A1100X18A	1 PH 100A 240V 18 Circuit Interior
P8521	PRL1A1225X30A	1 PH 225A 240V 30 Circuit Interior
P8522	PRL1A1225X42AS	1 PH 225A 240V 42 Circuit Interior Short *
P8523	PRL1A1400X42A	1 PH 400A 240V 42 Circuit Interior
P8524	PRL1A3100X18A	3 PH 100A 120/208V or 120/240V B Phase Hi Leg 18 Circuit Interior
P8525	PRL1A3225X30A	3 PH 225A 120/208V or 120/240V B Phase Hi Leg 30 Circuit Interior
P8526	PRL1A3225X42AS	3 PH 225A 120/208V or 120/240V B Phase Hi Leg 42 Circuit Interior Short*
P8527	PRL1A3225X42A	3 PH 225A 120/208V or 120/240V B Phase Hi Leg 42 Circuit Interior
P8528	PRL1A3400X42A	3 PH 400A 120/208V or 120/240V B Phase Hi Leg 42 Circuit Interior
P8578	PRL2A3100X18A	3 PH 100A 480V 18 Circuit Interior
P8579	PRL2A3225X30A	3 PH 225A 480V 30 Circuit Interior
P8529	PRL2A3225X42AS	3 PH 225A 480V 42 Circuit Interior Short *
P8530	PRL2A3400X42A	3 PH 400A 480V 42 Circuit Interior

* Will Not Accept Sub-Feed Lugs or Bottom Feed Breakers

P / ELECTRIC

EATON | Cutler-Hammer MAIN OR SUB-FEED BREAKER KITS

Locke#

P8542	BKED100T	100A 240V 2 or 3 Pole Top Feed Main Breaker Kit 65K AIC
P8543	BKED125T	125A 240V 2 or 3 Pole Top Feed Main Breaker Kit 65K AIC
P8544	BKED150T	150A 240V 2 or 3 Pole Top Feed Main Breaker Kit 65K AIC
P8545	BKED200T	200A 240V 2 or 3 Pole Top Feed Main Breaker Kit 65K AIC
P8546	BKED225T	225A 240V 2 or 3 Pole Top Feed Main Breaker Kit 65K AIC
P8547	BKED200B	200A 240V 2 or 3 Pole Bottom Feed Main Breaker Kit 65K AIC
P8548	BKED225B	225A 240V 2 or 3 Pole Bottom Feed Main Breaker Kit 65K AIC
P8549	BKFD100T	100A 480V 2 or 3 Pole Top Feed Main Breaker Kit 35K AIC
P8550	BKFD200T	200A 480V 2 or 3 Pole Top Feed Main Breaker Kit 35K AIC
P8551	BKFD225T	225A 480V 2 or 3 Pole Top Feed Main Breaker 35K AIC
P8552	BKFD200B	200A 480V 2 or 3 Pole Bottom Feed Main Breaker Kit 35K AIC
P8553	BKFD225B	225A 480V 2 or 3 Pole Bottom Feed Main Breaker Kit 35K AIC
P8554	BKGD400T	400A 240/480V 2 or 3 Pole Top Feed Main Breaker Kit 35K AIC
P8555	BKGD400B	400A 240/480V 2 or 3 Pole Bottom Feed Main Breaker Kit 35K AIC

EATON | Cutler-Hammer MAIN OR SUB-FEED LUG KITS

Locke#

P8556	LUGKIT100	100A 2 or 3 Pole Lug Kit
P8557	LUGKIT225	225A 2 or 3 Pole Lug Kit
P8558	LUGKIT400	400A 2 or 3 Pole Lug Kit

EATON | Cutler-Hammer SERVICE ENTRANCE KITS

Locke#

P8559	SEK1/2	Service Entrance Kit For 100A-225A Panelboards
P8560	SEK4/6	Service Entrance Kit For 400A Panelboards

EATON | Cutler-Hammer BRANCH CIRCUIT BREAKERS

*120/208V OR 120/240V B PHASE HI
LEG*

Locke#

P3083	BAB1020	1 Pole 20A Bolt On Breaker 10K AIC
P8561	BAB1015	1 Pole 15A Bolt On Breaker 10K AIC
P3084	BAB1030	1 Pole 30A Bolt On Breaker 10K AIC
P3081	BAB2020	2 Pole 20A Bolt On Breaker 10K AIC
P3085	BAB2030	2 Pole 30A Bolt On Breaker 10K AIC
P8562	BAB2035	2 Pole 35A Bolt On Breaker 10K AIC
P3086	BAB2040	2 Pole 40A Bolt On Breaker 10K AIC
P8563	BAB2045	2 Pole 45A Bolt On Breaker 10K AIC
P5350	BAB2050	2 Pole 50A Bolt On Breaker 10K AIC
P6365	BAB2060	2 Pole 60A Bolt On Breaker 10K AIC
P6366	BAB2100	2 Pole 100A Bolt On Breaker 10K AIC
P5059	BAB3020H	3 Pole 20A Bolt On Breaker 10K AIC
P3087	BAB3030H	3 Pole 30A Bolt On Breaker 10K AIC
P3088	BAB3040H	3 Pole 40A Bolt On Breaker 10K AIC
P3089	BAB3050H	3 Pole 50A Bolt On Breaker 10K AIC
P6367	BAB3060H	3 Pole 60A Bolt On Breaker 10K AIC
P6368	BAB3100	3 Pole 100A Bolt On Breaker 10K AIC

EATON | Cutler-Hammer BRANCH CIRCUIT BREAKERS

277/480V

Locke#

P8564	GHQ1020	1 Pole 20A Bolt On Breaker 14K AIC
P8565	GHB2020	2 Pole 20A Bolt On Breaker 14K AIC
P8566	GHB2030	2 Pole 30A Bolt On Breaker 14K AIC
P8567	GHB2040	2 Pole 40A Bolt On Breaker 14K AIC
P8568	GHB2050	2 Pole 50A Bolt On Breaker 14K AIC
P8569	GHB2060	2 Pole 60A Bolt On Breaker 14K AIC
P8570	GHB2100	2 Pole 100A Bolt On Breaker 14K AIC
P8571	GHB3020	3 Pole 20A Bolt On Breaker 14K AIC
P8572	GHB3030	3 Pole 30A Bolt On Breaker 14K AIC
P8573	GHB3040	3 Pole 40A Bolt On Breaker 14K AIC
P8574	GHB3050	3 Pole 50A Bolt On Breaker 14K AIC
P8575	GHB3060	3 Pole 60A Bolt On Breaker 14K AIC
P8576	GHB3100	3 Pole 100A Bolt On Breaker 14K AIC



MOTOR CONTROL S & pARTS

E.T.N | Cutler-Hammer MOTOR STARTER



120v Coil
3-phase Magnetic Freedom Series

Locke#

P2895	ECN05A1AAA	00 Motor Starter
P2896	ECN0501AAA	0 Motor Starter
P2897	ECN0511AAA	1 Motor Starter
P2898	ECN0521AAA	2 Motor Starter
P2899	ECN0531AAA	3 Motor Starter

E.T.N | Cutler-Hammer COVER MOUNTED CONTROLS



Fig. 1



Fig. 2

Locke#

P2900	C400GK3	Hand Off Auto Kit (Fig. 1)
P2901	C400GK1	Start Stop Kit (Fig. 1)
P2902	C400T3	Flush Mount Start Button (Fig. 2)

E.T.N | Cutler-Hammer START STOP STATION



Locke#

P2903	10250H5200	Nema 1 Start Stop Station
--------------	------------	---------------------------

E.T.N | Cutler-Hammer COIL FOR STARTERS

Locke#

P2918	9-2703-1	120V Coil for size 1-2 Starter
P2919	9-2703-2	240V Coil for size 1-2 Starter
P2920	9-2703-3	480V Coil for size 1-2 Starter
P2921	9-2756-1	120V Coil for size 3 Starter

E.T.N | Cutler-Hammer PUMP PANEL

3-phase Magnetic Freedom Series



Locke#

P2904	ECN5412AAC	30A Size 1 Pump Panel 120v
P2905	ECN5422AAE	60A Size 2 Pump Panel 120v
P2906	ECN5432AAG	100A Size 3 Pump Panel 120v
P1680	ECN5412CAC6	30A Size 1 Pump Panel 480v
P1681	ECN5422CAE6	60A Size 3 Pump Panel 480v
P1682	ECN5432CAG	100A Size 3 Pump Panel 480v

E.T.N | Cutler-Hammer CONTROL TRANSFORMER



240/480 PRI
120 SEC, Type MTE

Locke#

P2909	C0050E2A	50VA Transformer
P2910	C0100E2A	100VA Transformer

E.T.N | Cutler-Hammer BREAKER LOCK OFF



Locke#

P6286	BHLW1	1 Pole Breaker Lock Off
P6287	BHLW2	2 Pole Breaker Lock Off

E.T.N | Cutler-Hammer PADLOCKABLE BREAKER LOCK



Locke#

P0293	BRLW	Padlockable breaker lock
--------------	------	--------------------------

E.T.N | Cutler-Hammer HEATER SELECTION TABLE

Locke Code	Vendor Code	AMPERAGE				Starter Size
		A	B	C	D	
P2925	H2006B-3	1.79	2.16	2.53	2.9	00-2
P2926	H2008B-3	3.23	3.9	4.56	5.23	00-2
P2927	H2009B-3	4.55	5.5	6.45	7.4	00-2
P2928	H2010B-3	6.75	8.17	9.59	11	00-2
P2929	H2011B-3	9.14	10.8	12.4	14	00-2
P2930	H2012B-3	14	16.9	19.9	22.8	00-2
P2931	H2013B-3	18.7	22.7	26.7	30.7	00-2
P2932	H2014B-3	23.5	28.5	33.5	38.5	00-2
P2933	H2015B-3	29	34	39.1	44.1	2
P2934	H2016B-3	39.6	45.5	51.5	57.4	2
P2935	H2017B-3	53.9	60.9	67.9	74.9	2
P2942	H2021-3	45.7	51.2	56.7	62.1	3
P2943	H2022-3	62.2	69.7	77.1	84.6	3

E.T.N | Cutler-Hammer BOLT-ON HUBS



NEW STYLE

For Cutler Hammer, Power Master, Safety Switches or 125 Amp NEMA 3R Panels

Locke#

P5026	DS075H1	¾" Bolt-On Hub
P5027	DS100H1	1" Bolt-On Hub
P5028	DS125H1	1¼" Bolt-On Hub
P5029	DS150H1	1½" Bolt-On Hub
P5030	DS200H1	2" Bolt-On Hub
P5031	DS200H2	2" Hub for 200 Amp Panels
P5032	DS250H2	2½" Bolt-On Hub for 200 Amp+ Panels
P5093	DS300H2	3" Bolt-On Hub for 200 Amp+ Panels

E.T.N | Cutler-Hammer BOLT-ON HUBS



OLD STYLE

For 2, 4, 6, and 8 circuit panels and meter breaker panels

Locke#	Conduit Size
P0285	RH75 ¾" Bolt-On Hub
P0286	RH100 1" Bolt-On Hub
P0287	RH125 1¼" Bolt-On Hub
P0288	RH150 1½" Bolt-On Hub
P0289	RH200 2" Bolt-On Hub

P / ELECTRIC

LOAD CENTER ACCESSORIES

EATON | Cutler-Hammer MAIN LUG



For 225 Ampere Max.
Load center

Locke#

P5034 BRL200 200 Amp 2 Pole

EATON | Cutler-Hammer LUG BLOCK



Locke#

P5035 BRSF125 125 Amp

P5036 BRS225 225 Amp, 2 Pole

EATON | Cutler-Hammer 3 POLE LUG BLOCK



Locke#

P5061 3BRSF150 150A #14-#2/0 Cu,
or #8-#3/0 Al

P5037 3BRS225 225A #14-#2/0 Cu,
or #8-#3/0 Al

EATON | Cutler-Hammer 3/0 ADD-A-LUG

Add-on neutral or Ground Lug

Locke#

P1376 NL30 Neutral or Ground Lug

EATON | Cutler-Hammer SOLID NEUTRAL KIT For Safety Switches



Locke#

P0225 DS400NK For P0224 & P0223

P3073 DG200NK For P3071 & P3072

EATON | Cutler-Hammer MECHANICAL INTERLOCK FOR BR BREAKERS



Intended to lock out a BR
style Main Breaker when
backfeeding a BR style
breaker from a generator.

**Will not work with 150A and
200A BW style Main Breakers!**

Locke#

P0291 BRML BR Interlock

EATON | Cutler-Hammer DOOR LOCK FOR BR & CH LOADCENTERS



Locke#

P0292 TDL Door lock for BR & CH

EATON | Cutler-Hammer GROUND BAR



Locke#

P6288 GBK5 5 Count

P5022 GBK10 10 Count

P5023 GBK14 14 Count

P6290 GBK1420 14 Count

P6291 GBK2120 20 Count

P6296 17-21110 125A Neutral Base,
2 Needed Per Ground Bar

P6297 17-21109 225A Neutral Base,
2 Needed Per Ground Bar

EATON | Cutler-Hammer BR TYPE HANDLE TIE BAR



Type BR

Locke#

P0290 BHT Handle Tie Bar

EATON | Cutler-Hammer FILLER PLATE



Locke#

P0940 BRFP Filler Plate for 1 Type
BR 1" Space

P1346 CHFP Filler Plate for 1 Type
CH ¾" Space

EATON | Cutler-Hammer CIRCUIT BREAKER HOLD DOWN KIT

Locke#

P5024 BRHDK125 150/200A Kit

P5025 BREQS125 125A Kit



ARC WARNING LABEL

Warning
Potential Arc-Flash
hazards exist while
working on this
energized equipment

Locke#

P5433 VL-7 Arc Flash labels, 2 per

EATON | Cutler-Hammer 3PH 480V TP-1 DELTA TRANSFORMERS



Aluminum Windings

Locke#

P8502 V48M28T45EE 45 KVA NEMA
1, 3 Phase, 4B0D x 208Y1120.

P8503 V48M28T75EE 75 KVA NEMA
1, 3 Phase, 480D x 208Y1120.

P8504 V48M28T12EE 112 KVA
NEMA 1, 3 Phase, 480D x
208Y1120.

P8506 V48M28T15EE 15 KVA NEMA
1, 3 Phase, 480D x 208Y1120.

P8507 V48M28T30EE 30 KVA NEMA
1, 3 Phase, 480D x 208Y1120.


P9907 WS38 15, 30, & 45 KVA
Weather Shield For N3R Rating

P9908 WS39 75 KVA Weather
Shield For N3R Rating

P9909 WS19 112 KVA Weather
Shield For N3R Rating

CIRCUIT BREAKERS

SIEMENS TYPE Q PLUG ON CIRCUIT BREAKERS

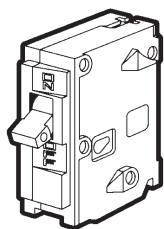


TYPE Q 120/240 Volts AC
10,000A IR

1 Pole Breakers 1" Per Breaker

Locke#

P5168	Q115	15 Amp
P5169	Q120	20 Amps
P5170	Q130	30 Amps

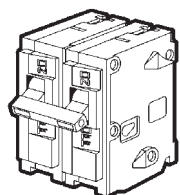

2 Pole Breakers 2" Per Breaker

Locke#

P5174	Q220	20 Amps
P5175	Q230	30 Amps
P5176	Q240	40 Amps
P5177	Q250	50 Amps
P5178	Q260	60 Amps
P5187	Q2100	100 Amps
P5188	Q2125	125 Amps

SIEMENS COMBINATION ARC FAULT BREAKERS



Detects all three possible types of arc fault: line-to-ground, line-to-neutral and series

Locke#

P6798	Q115AFC	15A, 1P Comb AFCI
P6799	Q120AFC	20A, 1P Comb AFCI

SIEMENS TYPE Q PLUG ON CIRCUIT BREAKERS



120/240 Volts AC, 10,000A IR 2" Per Breaker,
(CT= Common Trip)

Locke#

P5189	Q22020	2-2 Pole 20 Amp
P5190	Q23030	2-2 Pole 30 Amp
P5191	Q24030	1-2 Pole 30A - 1-2 Pole 40A
P5193	Q22030CT	2-1 Pole 20A - 1-2 Pole 30A
P5194	Q22040CT	2-1 Pole 20A - 1-2 Pole 40A
P5195	Q22050 CT	2-1 Pole 20A - 1-2 Pole 50A

SIEMENS 1 POLE ARC FAULT BREAKER



Locke#

P6756	Q115AF	15A, 1P ARC Fault
P6757	Q120AF	20A, 1P ARC Fault


SIEMENS PLUG ON BREAKER CROSSOVER



Locke#

P5198	QN2200R	200 Amp Main Circuit Breaker
-------	---------	------------------------------


SIEMENS DUAL 1 POLE BREAKER 1" PER BREAKER

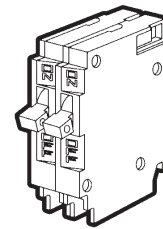

Locke#

P5184	Q2020	20 Amps
P5186	Q2020NC	Non-Interchangeable

SIEMENS GFCI CIRCUIT BREAKERS TYPE QF 120/240 VOLTS AC 10,000A IR

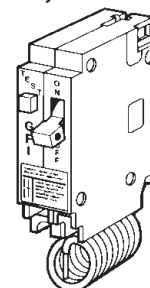

1 POLE BREAKERS 1" PER BREAKER

Locke#

P5217	QF120	20 Amp, 1 Pole, 1" Per Breaker, Type QF
-------	-------	---

2 POLE BREAKERS 2" PER BREAKER

Locke#

P6602	QF260	60 Amp, 2 Pole, 1" Per Breaker, Type QF
-------	-------	---

SIEMENS 277/480V BRANCH BREAKERS


Locke#

P5797	BQD320	3 Pole 20 Amp Breaker 480V
P5800	BQD350	3 Pole 50 Amp Breaker 480V
P5803	BQD3100	3 Pole 100 Amp Breaker 480V

P / ELECTRIC

SIEMENS

BOLT-ON CIRCUIT BREAKERS TYPE B 120/240 VOLTS AC 10,000A IR

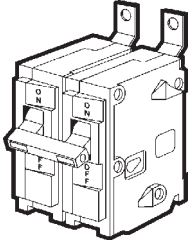

1 POLE BREAKERS 1" PER BREAKER

Locke#

P5208	B120	20 Amp, 1 Pole, 1" Per Breaker, Type B
P5209	B130	30 Amp, 1 Pole, 1" Per Breaker, Type B

2 POLE BREAKERS 2" PER BREAKER

Locke#

P5210	B230	30 Amp, 2 Pole, 2" Per Breaker, Type B
P5211	B240	40 Amp, 2 Pole, 2" Per Breaker, Type B

3 POLE BREAKERS 3" PER BREAKER

Locke#

P5212	B320	20 Amp, 3 Pole, 3" Per Breaker, Type B
P5213	B330	30 Amp, 3 Pole, 3" Per Breaker, Type B
P5214	B340	40 Amp, 3 Pole, 3" Per Breaker, Type B
P5215	B350	50 Amp, 3 Pole, 3" Per Breaker, Type B

SIEMENS


120/240V 120/208V BRANCH BREAKERS

Locke#

P5816	B220	2 Pole 20 Amp Breaker 208/240V
P5817	B250	2 Pole 50 Amp Breaker 208/240V
P5818	B260	2 Pole 60 Amp Breaker 208/240V
P5823	B310	3 Pole 100 Amp Breaker 208/240V



ALUMINUM ISOLATED GROUND BAR

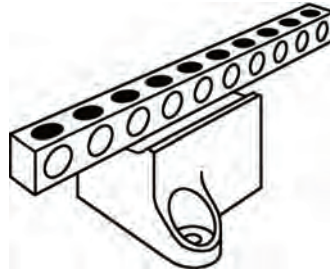

7 Tap; 14 to 2/0 awg; 6061.T6 aluminum alloy; 4.61 Inch; 2.31 Inch w x 2.13 Inch

Locke#

P5434	GBA20-7	Aluminum isolated ground bar
--------------	---------	------------------------------



TYPE 1 AND TYPE 3R CONTROL CABINETS Double Door



- Low carbon steel
- Hinged doors

Locke#

P3090	MO363616DDCT	NEMA 3R 36x36x16 Double Door Control Cabinet
P3091	MO484816DDCT	NEMA 3R 48x48x16 Double Door Control Cabinet



LIGHTNING ARRESTERS



CASE DIMENSIONS: 4 1/2" x 2 1/4"

SPECIFICATIONS

Type of Design: Silicon Oxide Varistor
 Maximum current: 100,000 amps
 Maximum energy: 1500 joules
 Maximum number of surge: Unlimited
 Response time 1 milliamper test: 5 nanoseconds
 Response time to clamp 10,000 amps: 10 nanoseconds
 Response time to clamp 50,000 amps: 25 nanoseconds
 Leak current at double rated voltage: none
 Leads: 36" #12 3kv Str.
 Case material: PVC
 Nipple: 1/2" Thread
 Lock nut and Washer furnished


Locke#

P1314	LA302R	Lightning Arrester for 110/240 Volt Residential use
P1315	LA603	Arrester for 440-600v 3 Phase, 3 or 4 Wire Service



SINGLE PHASE LIGHTNING ARRESTER

2 POLE, 3 PHASE

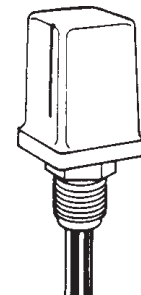

Locke#

P4801	AG2401C	120/240 single phase lightning arrester
--------------	---------	---

Thank You For Your Business!

P / ELECTRIC