


Incandescent Emergency Lights

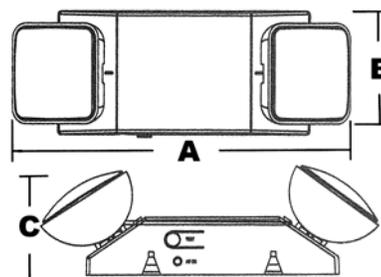

- ▶ Decorative & Economical Units with Modern Appearance & Low Maintenance
- ▶ Completely Self-Contained
- ▶ Fully Automatic Operation
- ▶ Compact, Low Profile Designs in Neutral Finish
- ▶ Push to Test Switch
- ▶ 6-Volt, Pure Lead, Maintenance Free Battery
- ▶ Environmentally Coated, Solid State Charger
- ▶ 2 x 5.4 Watt Incandescent Lamps
- ▶ Automatic, Low Voltage Disconnect (LVD)
- ▶ Universal Transformer for 120 or 277 VAC
- ▶ Replacement bulb: GE 939 or equal
- ▶ Universal Mounting Plate


- ▶ Injection Molded, V-O Flame Retardant, High Impact, Thermoplastic Housing
- ▶ Charge Rate/Power on LED Indicator Light
- ▶ 90 Minute Emergency Operation
- ▶ ETL Rated Damp Location
- ▶ Model #73122 has Remote Capability for up to 2 Additional Standard Remote Lighting Fixtures
- 2 heads - 4 hours operation
- 3 heads - 2 hours operation
- 4 heads - 1.5 hours operation
- ▶ Replacement Battery Specs:
Standard Units: 6V 5.4Ah
Remote Capable: 6V 7Ah
- ▶ 5 Year Warranty

Only Use with Incandescent Remote Lamp Heads (Not LED Lamp Heads)

Cat. No.	Style	Color	A	B	C	Case Qty
Standard						
73120	Low Profile Side Lights	White	16"	5"	3-1/2"	6
73121	Low Profile Side Lights	Black	16"	5"	3-1/2"	6
Remote Capable (Use only Incandescent Remote Heads)						
73122	Low Profile Side Lights	White	16"	5"	3-1/2"	6

DD10

MR-16 Emergency Lights

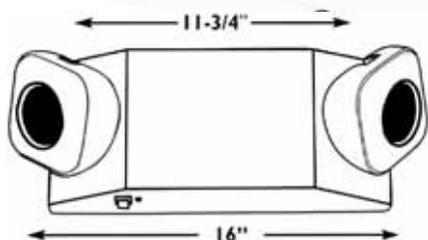

- ▶ Completely self-contained
- ▶ Fully automatic operation
- ▶ Compact, low profile design in neutral finish
- ▶ Universal mounting plate with "EZ" quick connect for rapid labor saving installation
- ▶ Push to test switch
- ▶ 6-volt, pure lead, maintenance-free battery
- ▶ Environmentally-coated, solid state charger
- ▶ Automatic, low voltage disconnect (LVD)
- ▶ Universal transformer for 120 or 277 VAC
- ▶ Injection-molded, V-O flame retardant, high impact, thermoplastic housing
- ▶ Charge rate/power on LED indicator light
- ▶ Lamp wattage 2X5 watt
- ▶ Emergency operation 90 minutes
- ▶ Replacement Battery Specifications:
Standard Units: 6V 5.4Ah
Remote Capable: 6V 7Ah
- ▶ 5 Year Warranty

* Hours Based on 5 watt lamps

Cat. No.	Color	Watts Per Unit	Maximum Heads for 4 Hours Operation*	Maximum Heads for 2 Hours Operation*	Maximum Heads for 1.5 Hours Operation*	Case Qty
Standard						
73152	White	10	N/A	N/A	N/A	6
73154	Black	10	N/A	N/A	N/A	6
Remote Capable (Use only MR16 Remote Heads)						
73156	White	22	2	3	4	6
73157	Black	22	2	3	4	6