



2016  
INTRODUCTION



**NEW**  
F617L-GM



**NEW**  
F617L-BN



## RAPTOR

This contemporary design is coupled with the energy saving advancements of DC motor technology and an integrated 17 watt **LED** light source. An option of three transitional finishes.

### FEATURES

- 14° Blade Pitch • 60" 5-Blades • 172x12mm DC Motor
- Special Hand Held Remote Control System - RC600 Incl.
- Integrated LED Light Uses 17W LED Incl., 3 Year Warranty • 1,100 Lumens • 3000 Kelvin • CRI 80

### ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 6,000 • Electricity Used Watts: 30 • Airflow Efficiency CFM/Watts: 200

# RAPTOR

LED



**NEW**  
**F617L-ORB/AB**

**F617L-GM** • Gun Metal Finish • Gun Metal Blades • Etched Opal Glass

**F617L-BN** • Brushed Nickel Finish • Silver Blades • Etched Opal Glass

**F617L-ORB/AB** • Oil Rubbed Bronze/Antique Brass Finish • Tobacco Blades • Tinted Opal Glass

# CONTRACTOR UNI-PACK LED

WITH LIGHT KIT

LED



**NEW**  
F656L-BN/DW

## FEATURES

- 12° Blade Pitch • 52" 5-Blades • 172x14mm Motor • 3-Speed Pull Chain
- Low Profile LED Light Uses 26W LED Incl., 3 Year Warranty • 1,899 Lumens • 3,000 Kelvin • CRI 81

## ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 5,966 • Electricity Used Watts: 66.5 • Airflow Efficiency CFM/Watts: 89.71



**NEW**  
F656L-ORB



**NEW**  
F656L-WH

## CONTRACTOR UNI-PACK LED

Introducing a full feature LED Contractor 52-inch fan. Featuring the incredible 26 watt LED, 1,899 Lumens, 3,000 Kelvin light source and a 172x14mm heavy duty motor.

**F656L-BN/DW** • Brushed Nickel Finish • Reversible Medium Maple/Dark Walnut Blades  
(Shown with Dark Walnut Blades) • Frosted White Glass

**F656L-ORB** • Oil Rubbed Bronze Finish • Reversible Medium Maple/Dark Walnut Blades  
(Shown with Dark Walnut Blades) • Frosted White Glass

**F656L-WH** • White Finish • White Blades • Frosted White Glass



*Indoor/Outdoor*

**NEW**  
**F624-ABD**



**NEW**  
**F624-WHF**



## ROTO XL

Roto XL features a sleek and contemporary design with a classic industrial look. Well edited and an impeccably executed design features a slight "fold" construction along the length of the blades to increase the flow of air. A perfect marriage of form and function. Roto XL features a full 62-inch spread combined with a wet location specification use for indoor or outdoors.

**F624-ABD** • Brushed Aluminum Finish • Silver Blades

**F624-WHF** • Flat White Finish • Flat White Blades

**F624-ORB** • Oil Rubbed Bronze Finish • Oil Brushed Bronze Blades

# ROTO XL

*Indoor/Outdoor*

**NEW**  
**F624-ORB**

*Indoor/Outdoor*

## FEATURES

- 20° Blade Pitch • 62" 3-Blades • 172x16mm Motor • Aluminum Construction
- 2-Wire Installation Wall Control Converts to Electronic Control System - WC105-WH Incl.
- Indoor/Outdoor Use - UL Listed for Wet Locations

U.S. Patent(s): Pending

## ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 7,567 • Electricity Used Watts: 70.69 • Airflow Efficiency CFM/Watts: 107.04



\* Estimated

WWW.MINKAIRE.COM

minkaAire®

**NEW**  
**F753L-BNW**



**NEW**  
**F753L-WHF**



**NEW**  
**F753L-PN**  
*(Indoor Use Only)*



## *Indoor/Outdoor*

**F753L-BNW** • Brushed Nickel Wet Finish • Silver Blades • Etched Opal Glass

**F753L-WHF** • Flat White Finish • Flat White Blades • Etched Opal Glass

**F753L-PN** • Polished Nickel Finish • Silver Blades • Etched Opal Glass • *(Indoor Use Only)*

**F753L-KA** • Kocoa Finish • Kocoa Blades • Etched Opal Glass





# JAVA LED

*Indoor/Outdoor*

**NEW**  
**F753L-KA**

## JAVA LED

Minka-Aire's "everywhere" fan with a unique contemporary twist that is suitable for all environments. The Java LED features an integrated 16 watt LED light. Features indoor or outdoor usage.

### FEATURES

- 14° Blade Pitch • 54" 3-Blades • 153x18mm Motor
- Hand Held Remote Control System - RCS213 Incl.
- Integrated LED Light Uses 16W LED Incl., 3 Year Warranty • 1,550 Lumens • 3,000 Kelvin • CRI 80
- Indoor/Outdoor Use - UL Listed for Wet Locations

### ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 5,681 • Electricity Used Watts: 60 • Airflow Efficiency CFM/Watts: 94



# NINETY-NINE

LED



**NEW**  
F899L-BN/SL

## FEATURES

- Variable Blade Pitch • 99" 9-Blades • 172x25mm DC Motor
- Special Hand Held Remote Control System - RC600 Incl.
- Integrated LED Light Uses 26W LED Incl., 3 Year Warranty • 1,899 Lumens • 2,700 Kelvin • CRI 81

## ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 13,000 • Electricity Used Watts: 30 • Airflow Efficiency CFM/Watts: 433

## *Ninety-Nine*

# NINETY-NINE

Minka-Aire® introduces our Ninety-Nine fan, featuring a total circumference of 99-inches in diameter! A refreshing transitional design featuring 9-blades, 26 watt **LED** and a DC motor. Ideal for residential and commercial use where air movement is required. A hand held remote to control six speeds and is reversible to use in winter and summer.

**F899L-BN/SL** • Brushed Nickel Finish • Silver Blades • Etched Opal Glass

# NINETY-NINE

LED

*Ninety-Nine*



**NEW**  
**F899L-ORB**

**F899L-ORB** • Oil Rubbed Bronze Finish • Tobacco Blades • Etched Opal Glass  
**F899L-DK** • Distressed Koa Finish • Distressed Koa Blades • Etched Opal Glass





**NEW**  
**F899L-DK**

## FEATURES

- Variable Blade Pitch • 99" 9-Blades • 172x25mm DC Motor
- Special Hand Held Remote Control System - RC600 Incl.
- Integrated LED Light Uses 26W LED Incl., 3 Year Warranty • 1,899 Lumens • 2,700 Kelvin • CRI 81

## ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 13,000 • Electricity Used Watts: 30 • Airflow Efficiency CFM/Watts: 433

**NEW**  
**F727-DK**



**NEW**  
**F727-BN/SL**



**NEW**  
**F727-ORB**



**F727-DK** • Distressed Koa Finish • Distressed Koa Blades

**F727-BN/SL** • Brushed Nickel Finish • Silver Blades

**F727-ORB** • Oil Rubbed Bronze Finish • Tobacco Blades

**F727-BN/MM** • Brushed Nickel Finish • Medium Maple Blades





# RUDOLPH

**NEW**  
F727-BN/MM

## RUDOLPH

Inspired by a contemporary architect of the 50's, this clean three blade design best exemplifies today's trend in home furnishings. Included is a wall control, cast blade holders, 172x16mm motor for great air movement.

### FEATURES

- 21° Blade Pitch • 52" 3-Blades • 172x16mm Motor
- 2-Wire Installation Wall Control Converts to Electronic Control System - WC105-WH Incl.
- Universal Light Kit Adaptable (Sold Separately)

### ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 5,500 • Electricity Used Watts: 50 • Airflow Efficiency CFM/Watts: 110

\* Estimated

WWW.MINKAIRE.COM

minkaAire®

# CAGE FREE GYRO™

LED



**NEW**  
F304L-BN/SL


*Gyro Fans  
Rotate 360°*

## FEATURES

- High Performance Twin Turbofans Total Sweep 42" • 23° Blade Pitch • 70x16mm Motor
- Full Function Wall Control System - WCS212 Incl. • LED Light Uses 17W LED Incl., 3 Year Warranty
- 1,550 Lumens • 3,000 Kelvin • CRI 80

## ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 3,000 • Electricity Used Watts: 45 • Airflow Efficiency CFM/Watts: 66

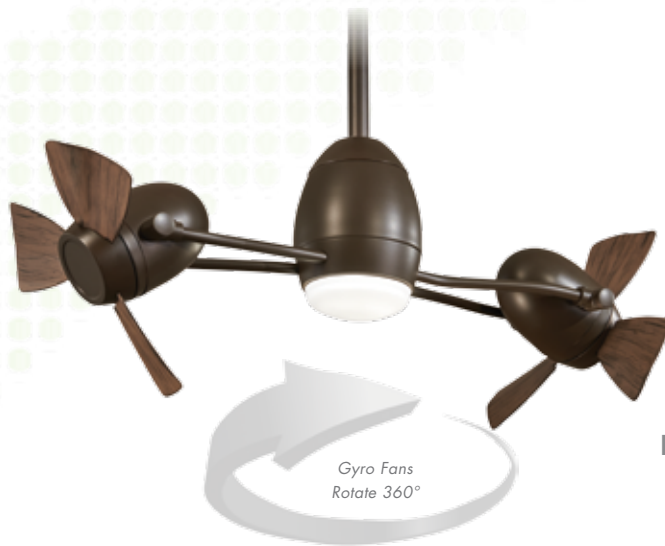

**NEW**  
**F304L-ORB/MM**

## CAGE FREE GYRO™

A wonderful addition to our Gyro™ series. Simple, clean design featuring twin turbo fans, 17 watt **LED** and cage free blades allow for a classic transitional spirit.

**F304L-BN/SL** • Brushed Nickel Finish • Silver Blades • Etched Opal Glass  
**F304L-ORB/MM** • Oil Rubbed Bronze Finish • Medium Maple Blades • Etched Opal Glass

# ELEMENTAL GYRO™

LED



**NEW**  
F306L-BS/SL

*Gyro Fans  
Rotate 360°*

## FEATURES

- High Performance Twin Turbofans Total Sweep 42" • 23° Blade Pitch • 70x16mm Motor
- Full Function Wall Control System - WCS212 Incl. • LED Light Uses 17W LED Incl., 3 Year Warranty
- 1,550 Lumens • 3,000 Kelvin • CRI 80

## ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 3,000 • Electricity Used Watts: 45 • Airflow Efficiency CFM/Watts: 66





**NEW**  
**F306L-ORB/MM**

## ELEMENTAL GYRO™

Elemental Gyro™ by Minka-Aire® is our newest addition of our Gyro™ series. A clean, industrial spirit combined with a **LED** light source and etched opal glass. The Gyro™ series continues to offer air movement throughout the entire room, or stopped to position air in only one area. Adjustment of the actual fan cages is a feature to further enhance air movement.

**F306L-BS/SL** • Brushed Steel Finish • Silver Blades • Etched Opal Glass

**F306L-ORB/MM** • Oil Rubbed Bronze Finish • Medium Maple Blades • Etched Opal Glass

# FORCE

LED



**NEW**  
**F838L-DK**


## FEATURES

- Variable Blade Pitch • 60" 3-Blades • 168x12mm DC Motor
- Special Hand Held Remote Control System - RC400 Incl.
- Integrated LED Light Uses 15W LED Incl., 3 Year Warranty • 1,100 Lumens • 3,000 Kelvin • CRI 80
- Optional LED Light Kit, Sold Separately. Part #: 6F838LLK01

## ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 6,600 • Electricity Used Watts: 26 • Airflow Efficiency CFM/Watts: 253



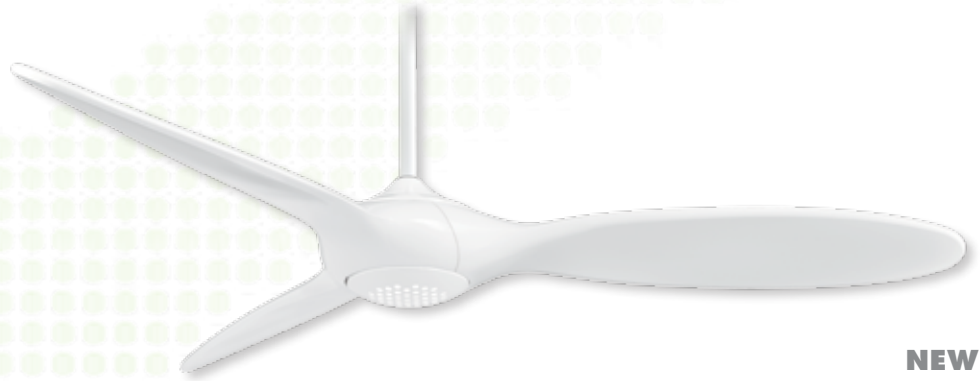

**NEW**  
**F838L-WH**



**NEW**  
**F838L-SL**

*Shown with  
Optional Light Kit  
Part #: 6F838LLK01*

## FORCE

A sleek, well proportioned, contemporary design featuring an integrated 15 watt **LED** with a 60-inch blade sweep. The Force by Minka-Aire® will make a design statement in any décor.

**F838L-DK** • Distressed Koa Finish • Distressed Koa Blades • Etched Lens

**F838L-WH** • White Finish • White Blades • Etched Lens

**F838L-SL** • Silver Finish • Silver Blades • Etched Lens • Shown with Optional Light Kit



**NEW**  
F681-GL/WS



**NEW**  
F681-BK/WS



**NEW**  
F681-PN

- F681-GL/WS** • Galvanized/Weathered Steel Finish • Dark Pine Blades • Clear Fresnel Lens
- F681-BK/WS** • Black/Weathered Steel Finish • Charcoal Driftwood Blades • Clear Fresnel Lens
- F681-PN** • Polished Nickel Finish • Silver Blades • Clear Fresnel Lens
- F681-ORB** • Oil Rubbed Bronze Finish • Dark Pine Blades • Clear Fresnel Lens



**NEW**  
**F681-ORB**

## GROTON

Inspired by the clear Fresnel lens used in light houses along the coast of Connecticut, we are introducing our Groton collection. Classic design combined with nautical spirit in various finishes.

### FEATURES

- 14° Blade Pitch • 56" 5-Blades • 188x25mm Motor • Hand Held Remote Control System - RCS212 Incl.
- Integrated Halogen Light Uses 2-50W Mini-Can Halogen Bulbs Incl.

### ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 6,500 • Electricity Used Watts: 90 • Airflow Efficiency CFM/Watts: 72



**NEW**  
**F787-SL**

*Shown with  
Optional Light Kit  
Part #: K9787L-SL*



**NEW**  
**F787-WHF**

*Shown with Optional  
Light Kit  
Part #: K9787L-WHF*

## SIMPLE

So simple! We gave this wonderful design a name that best denotes it's spirit! Incredibly delicate and merely invisible. This design best displays the advancement in technology with indoor/outdoor use, DC motor, optional **LED** light kit and a hand held remote.

**F787-SL** • Silver Finish • Silver Blades • Shown with Optional Light Kit

**F787-WHF** • Flat White Finish • Flat White Blades

**F787-ORB** • Oil Rubbed Bronze Finish • Medium Maple Blades

# SIMPLE



**NEW**  
**F787-ORB**

## FEATURES

- 14° Blade Pitch • 52" 3-Blades • 123x30mm DC Motor
- Special Hand Held Remote Control System - RC600 Incl.
- Optional 15W LED Light Kit, Sold Separately. Part #: K9787L-ORB, K9787L-SL, K9787L-WHF
- Indoor/Outdoor Use - ETL Listed for Wet Locations




## ENERGY INFORMATION\* (Excludes Lights)

- Airflow CFM: 6,600 • Electricity Used Watts: 25 • Airflow Efficiency CFM/Watts: 264

\* Estimated

[WWW.MINKAAIRE.COM](http://WWW.MINKAAIRE.COM)

**minkaAire**

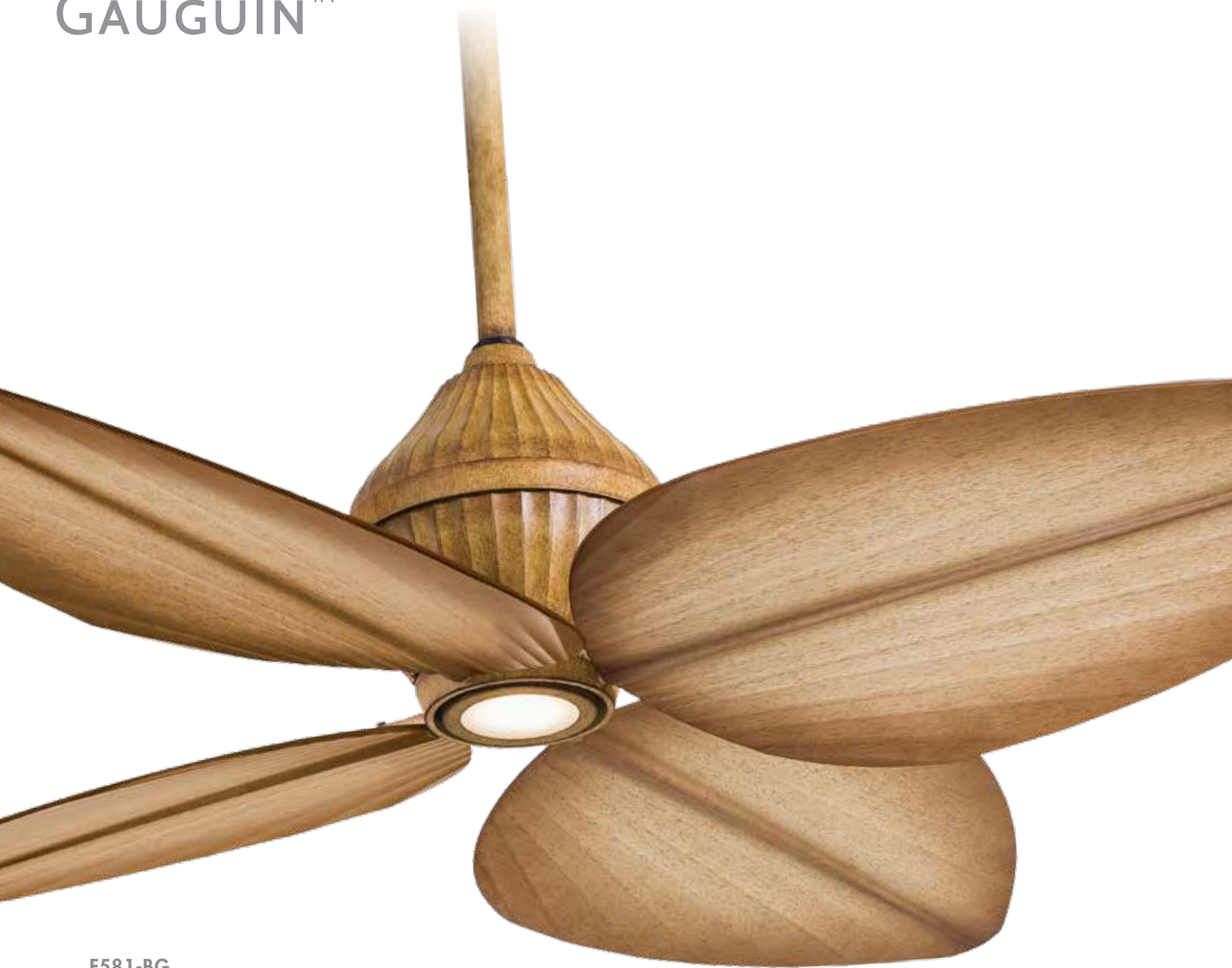

F581-BG



## FEATURES

- 14° Blade Pitch • 52" 4-Blades • 188x20mm Motor
- Stainless Steel Hardware and All Weather Blades
- Full Function Wall Control System - WCS212 Incl.
- Integrated Halogen Light Uses 1-50W MR16 120V 2-Pin Halogen Bulb Incl.
- Indoor/Outdoor Use - UL Listed for Wet Locations • Cap for Non-Light Use Incl.
- Optional Low Ceiling Adapter, Sold Separately. Part #: A581-BG, A581-ORB, A561-WHF

U.S. Patent(s): D513,319; D514,691; D514,692; D516,703; D517,201; D519,199

## ENERGY INFORMATION (Excludes Lights)

- Airflow CFM: 4,834 • Electricity Used Watts: 52 • Airflow Efficiency CFM/Watts: 92.97





**F581-BG**

*Shown with Optional  
Low Ceiling Adapter  
Part #: A581-BG*



**F581-ORB**

*Shown with Optional  
Low Ceiling Adapter  
Part #: A581-ORB*



**F581-WHF**

*Shown with Optional  
Low Ceiling Adapter  
Part #: A581-WHF*

## GAUGUIN™

Tropical style influences the Gauguin™ by incorporating a remarkable combination of performance and unique design elements.

**F581-BG** • Bahama Beige™ Finish • Bahama Beige™ Blades • Etched Glass

**F581-ORB** • Oil Rubbed Bronze Finish • Bahama Beige™ Blades • Etched Glass

**F581-WHF** • Flat White Finish • Flat White Blades • Etched Glass

# PANCAKE



F738-DK

## PANCAKE

Our Pancake ceiling fan magically houses all the needed components of a high performance ceiling fan into a slim 3" deep body. Minimal, elegant and smooth, the profile is narrow, allowing for an unobtrusive, non-competing addition to any room.



### FEATURES

- 12° Blade Pitch • 52" 4-Blades • 6" Internally Threaded Downrod • 153x18mm Motor
- Full Function Hand Held Control System - RCS212 Incl. • Max Ceiling Slope Angle 18°

U.S. Patent(s): Pending

### ENERGY INFORMATION (Excludes Lights)

- Airflow CFM: 5,405 • Electricity Used Watts: 63.9 • Airflow Efficiency CFM/Watts: 84.58



**NEW**  
**F738-SL**



**F738-ORB**



**F738-WHF**

**F738-DK** • Distressed Koa Finish • Distressed Koa Blades

**F738-SL** • Silver Finish • Silver Blades

**F738-ORB** • Oil Rubbed Bronze Finish • Oil Rubbed Bronze Blades

**F738-WHF** • Flat White Finish • Flat White Blades




• **Cage Free Gyro™**  
F304  
Pages 16 - 17



• **Contractor Uni-Pack LED**  
F656  
Pages 4 - 5



• **Elemental Gyro™**  
F306  
Pages 18 - 19

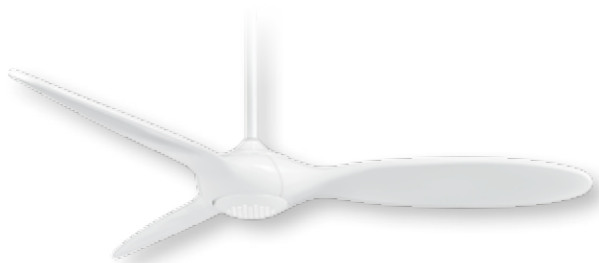

• **Force**  
F838  
Pages 20 - 21



**Gauguin™**  
F581  
Pages 26 - 27




**Groton**  
F681  
Pages 22 - 23



• **Java LED**  
F753  
Pages 8 - 9



• **Ninety-Nine**  
F899  
Pages 10 - 13

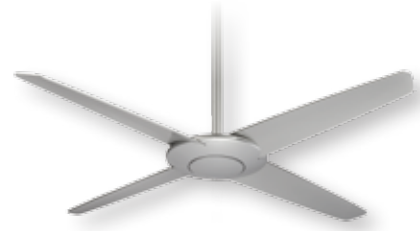

• **Pancake**  
F738  
Pages 28 - 29




• **Raptor**  
F617  
Pages 2 - 3



**Roto XL**  
F624  
Pages 6 - 7



**Rudolph**  
F727  
Pages 14 - 15

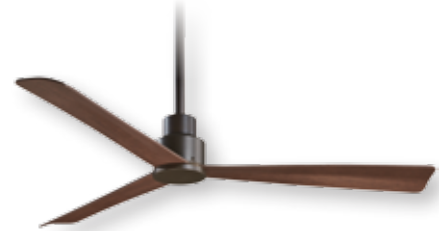

**Simple**  
F787  
Pages 24 - 25



World Headquarters  
1151 West Bradford Court, Corona, California 92882

Showroom  
Dallas Market Center  
2100 Stemmons, Suite 3725, Dallas, TX 75207

951.278.3267 (FANS) 800.307.3267 Fax: 951.278.2828

[sales@minkagroup.net](mailto:sales@minkagroup.net) | [www.minkaaire.com](http://www.minkaaire.com) | [www.minkagroup.net](http://www.minkagroup.net)

MKADALLAS2016-01