

# Beam Clamps - Steel PC 5260, 5265




- Zinc Plated Steel or High Strength Malleable Iron
- Case Hardened Steel Bolt
- Tapped Threads Back & Bottom

Beam Clamps when secured to an I-beam, girder or other structural member, provide a mounting base for the attachment of conduit hangers, either directly or by using threaded rod.

CAT NO	UPC	SIZE	TYPE	STD	MSTR	WT/STD	UNIT
<b>Steel - PC 5260</b>							
BK14	10090	1/4-20	Steel	50	250	6.03#	C
BK38	10095	3/8-16	Steel	25	100	6.62#	C

<b>Malleable - PC 5265</b>							
BK14M	10092	1/4-20	Malleable	50	250	11.44#	C
BK38M	10097	3/8-16	Malleable	25	100	18.22#	C
BK50M	10099	1/2-13	Malleable	10	50	12.96#	C

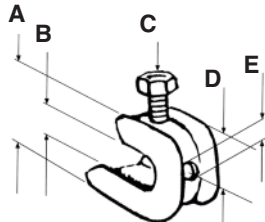

	A	B	C	D	E*
BK-14	1.39	.672	1/4 x 1"	.695	1/4-20
BK-14M	1.39	.750	5/16 x 1"	.625	1/4-20
BK-38	1.95	.781	5/16 x 1 3/8"	.979	3/8-16
BK-38M	1.75	.875	3/8 x 1 1/4"	.625	3/8-16
BK-50M	2.47	1.109	3/8 x 1 1/2"	.812	1/2-13

\* Bottom & Back

## Floor Flanges PC 5270

- High Strength Malleable Iron
- Zinc Plated

Floor flanges are secured to floors or walls and threaded conduit is then inserted as a post or divider.



CAT NO	UPC	SIZE	STD	MSTR	WT/STD	UNIT
FF50	60350	1/2"	25	25	6.79#	C
FF75	60351	3/4"	25	25	7.64#	C
FF100	60352	1"	10	10	4.50#	C
FF125	60353	1-1/4"	5	5	3.15#	C
FF150	60354	1-1/2"	5	5	3.85#	C
FF200	60355	2"	5	5	6.46#	C

## Switch Box Supports PC 5290

- Quick Installation
- Supports Box, No Stud Needed
- Prevents Box Pull Out
- Galvanized Steel

Switch box supports are used in pairs in old work. The tongues are bent over the lip of the box and the bar is inserted into the opening to prevent the box from falling back out of the opening. The ears of the box keep it from falling into the opening.



CAT NO	UPC	DESCRIPTION	STD	MSTR	WT/STD	UNIT
SBS165	59850	Galvanized Box Support	100 Pair	500 Pair	5.30#	100 Pair

## Ceiling Cover Plate PC 5280

- Steel
- White
- Adjustable Strap For 3" or 4" Boxes

Ceiling cover plates, 5 1/4" canopy with adjustable strap and screws for 3" or 4" outlet boxes. White color blends with most installations. Temporary or permanent.



CAT NO	UPC	SIZE	DESCRIPTION	STD	MSTR	WT/STD	UNIT
CP5	27545	5-1/4"	White Universal Cover Plate	10	50	7.11#	C