



PC 5460

Liquid-Tite Connectors

zincDieCa«

Fittings

Cat. No.	UPC	Size	Type	Unit	Std.
Straight					
LT38	11000	3/8"	Straight	25	250
LT50	11005	1/2"	Straight	25	250
LT75	11010	3/4"	Straight	10	100
LT100	11015	1"	Straight	5	50
LT125	11020	1-1/4"	Straight	5	50
LT150	11025	1-1/2"	Straight	2	20
LT200	11030	2"	Straight	2	20
90°					
LT9038	11200	3/8"	90°	10	100
LT9050	11205	1/2"	90°	10	100
LT9075	11210	3/4"	90°	10	100
LT90100	11215	1"	90°	5	50
LT90125	11220	1-1/4"	90°	5	50
LT90150	11225	1-1/2"	90°	2	20
LT90200	11230	2"	90°	2	20
Straight Insulated					
LT38-I	11100	3/8"	Straight Insulated	25	250
LT50-I	11105	1/2"	Straight Insulated	25	250
LT75-I	11110	3/4"	Straight Insulated	10	100
LT100-I	11115	1"	Straight Insulated	5	50
LT125-I	11120	1-1/4"	Straight Insulated	5	50
LT150-I	11125	1-1/2"	Straight Insulated	2	20
LT200-I	11130	2"	Straight Insulated	2	20
LT250-I	11135	2-1/2"	Straight Insulated	1	1
LT300-I	11140	3"	Straight Insulated	1	1
LT350-I	11145	3-1/2"	Straight Insulated	1	1
LT400-I	11150	4"	Straight Insulated	1	1
90° Insulated					
LT9038-I	11300	3/8"	90° Insulated	10	100
LT9050-I	11305	1/2"	90° Insulated	10	100
LT9075-I	11310	3/4"	90° Insulated	10	100
LT90100-I	11315	1"	90° Insulated	5	50
LT90125-I	11320	1-1/4"	90° Insulated	5	50
LT90150-I	11325	1-1/2"	90° Insulated	2	20
LT90200-I	11330	2"	90° Insulated	2	20
LT90250-I	11235	2-1/2"	90° Insulated	1	1
LT90300-I	11240	3"	90° Insulated	1	1
LT90350-I	11245	3-1/2"	90° Insulated	1	1
LT90400-I	11250	4"	90° Insulated	1	1

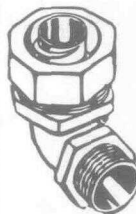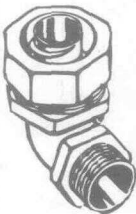

PC 5470

Steel Combo Coupling

Liquid-Tite Flex
to E.M.T.

Cat. No.	UPC	Size	Unit	Std.
CF1	40750	1/2" Liquid tite flex to EMT	25	125
CF2	40755	3/4" Liquid tite flex to EMT	10	50
CF3	40760	1" Liquid tite flex to EMT	10	20

"Now
up to
1 inch!"

