

L. H. D O T T I E

# Carded Drill & Driver Bits

Full Line of  
Drill Bits, Driver Bits  
and Accessories





## Carded Driver Bits

### Carded Bits - PC 6751

- Insert and power bits are available in a variety of configurations.
- Bits of 1" length are insert bits; bits 2" and longer are power bits.
- Packed 2 Per Display Card
- Precision Fit Prevents Wear
- Maximum Durability

Note: MBH Tool is used with insert bits only. Not to be used with power bits.

CAT NO	TYPE	SCREW SIZE	POINT SIZE / LENGTH	STD	UNIT
<b>Phillips Pt. Size 0 &amp; 1</b>					
IB0PC	Insert Bit	#4	#0 x 1"	10	Ea. Card
IB1PC	Insert Bit	#6	#1 x 1"	10	Ea. Card
IB1PLC	Power Bit	#6	#1 x 2"	10	Ea. Card
IB1PXC	Power Bit	#6	#1 x 3"	5	Ea. Card
IB1P4C	Power Bit	#6	#1 x 4"	5	Ea. Card
IB1P6C	Power Bit	#6	#1 x 6"	5	Ea. Card
<b>Phillips Pt. Size 2</b>					
IB2PC	Insert Bit	#8-10	#2 x 1"	10	Ea. Card
IB2PLC	Power Bit	#8-10	#2 x 2"	10	Ea. Card
IB2PXC	Power Bit	#8-10	#2 x 3"	5	Ea. Card
IB2P4C	Power Bit	#8-10	#2 x 4"	5	Ea. Card
IB2P6C	Power Bit	#8-10	#2 x 6"	5	Ea. Card
<b>Phillips Pt. Size 3</b>					
IB3PC	Insert Bit	#12-14	#3 x 1"	10	Ea. Card
IB3PLC	Power Bit	#12-14	#3 x 2"	5	Ea. Card
IB3PXC	Power Bit	#12-14	#3 x 3"	5	Ea. Card
IB3P4C	Power Bit	#12-14	#3 x 4"	5	Ea. Card
IB3P6C	Power Bit	#12-14	#3 x 6"	5	Ea. Card
<b>Slotted Pt. Size 0 &amp; 1</b>					
IB0SC	Insert Bit	#4	#0 x 1"	10	Ea. Card
IB1SC	Insert Bit	#6	#1 x 1"	10	Ea. Card
IB1SLC	Power Bit	#6	#1 x 2"	10	Ea. Card
IB1SXC	Power Bit	#6	#1 x 3"	5	Ea. Card
IB1S4C	Power Bit	#6	#1 x 4"	5	Ea. Card
IB1S6C	Power Bit	#6	#1 x 6"	5	Ea. Card
<b>Slotted Pt. Size 2</b>					
IB2SC	Insert Bit	#8-10	#2 x 1"	10	Ea. Card
IB2SLC	Power Bit	#8-10	#2 x 2"	10	Ea. Card
IB2SXC	Power Bit	#8-10	#2 x 3"	5	Ea. Card
IB2S4C	Power Bit	#8-10	#2 x 4"	5	Ea. Card
IB2S6C	Power Bit	#8-10	#2 x 6"	5	Ea. Card
<b>Slotted Pt. Size 3</b>					
IB3SC	Insert Bit	#12-14	#3 x 1"	10	Ea. Card
IB3SLC	Power Bit	#12-14	#3 x 2"	10	Ea. Card
IB3SXC	Power Bit	#12-14	#3 x 3"	5	Ea. Card
IB3S4C	Power Bit	#12-14	#3 x 4"	5	Ea. Card
IB3S6C	Power Bit	#12-14	#3 x 6"	5	Ea. Card
<b>Square Pt. 0 &amp; 1</b>					
IB0C	Insert Bit	#4	#0 x 1"	10	Ea. Card
IB1C	Insert Bit	#6	#1 x 1"	10	Ea. Card
IB1LC	Power Bit	#6	#1 x 2"	10	Ea. Card
IB1XC	Power Bit	#6	#1 x 3"	5	Ea. Card
IB14C	Power Bit	#6	#1 x 4"	5	Ea. Card
IB16C	Power Bit	#6	#1 x 6"	5	Ea. Card
<b>Square Pt. Size 2</b>					
IB2C	Insert Bit	#8-10	#2 x 1"	10	Ea. Card
IB2LC	Power Bit	#8-10	#2 x 2"	10	Ea. Card
IB2XC	Power Bit	#8-10	#2 x 3"	5	Ea. Card
IB24C	Power Bit	#8-10	#2 x 4"	5	Ea. Card
IB26C	Power Bit	#8-10	#2 x 6"	5	Ea. Card
<b>Square Pt. Size 3</b>					
IB3C	Insert Bit	#12-14	#3 x 1"	10	Ea. Card
IB3LC	Power Bit	#12-14	#3 x 2"	10	Ea. Card
IB3XC	Power Bit	#12-14	#3 x 3"	5	Ea. Card
IB34C	Power Bit	#12-14	#3 x 4"	5	Ea. Card
IB36C	Power Bit	#12-14	#3 x 6"	5	Ea. Card
<b>Combo Pt. Size #2 Square / #2 Phillips</b>					
IB2CLC	Power Bit	#8-10	#2 x 2"	10	Ea. Card






## Carded Drill &amp; Driver Bits

## Carded Driver Bits Tools, Replacement Bits

## Carded Bits &amp; Tools - PC 6701

- Packed 1 Per Card
- Heat Treated To Resist Breakage And Wear
- Hardened Core For Extra Strength And Reduced Breakage
- Specially Designed To Reduce Stripping

CAT NO	TYPE	SCREW SIZE	POINT SIZE / LENGTH	STD	UNIT
<b>Magnetic Hex Tools</b>					
MT8C		#6-8	1/4 x 1-3/4"	1	Ea. Card
MT8LC	1/4"	#6-8	1/4 x 2-9/16"	1	Ea. Card
MT10C		#10-12	5/16 x 1-3/4"	1	Ea. Card
MT10LC	5/16"	#10-12	5/16 x 2-9/16"	1	Ea. Card
MT38C		1/4"	3/8 x 1-3/4"	1	Ea. Card
MT38LC	3/8"	1/4"	3/8 x 2-9/16"	1	Ea. Card




## Magnetic Bit Holder - PC 6711

MBHC	Magnetic Bit Holder	1/4 x 3"	1	Ea. Card
------	---------------------	----------	---	----------

Note: To be used with insert bits only. Not power bits.







## Multi Drive Screw Guide Kit - PC 6712

The Multi Drive Screw Guide Kit contains the most popular screw driving bits for all your fastening jobs. Drive the most difficult lengths of screws with ease using this professionally designed tool.

CAT NO	CONTAINS	STD	UNIT
MDSG	   1-Ea Multi Drive Screw Guide 1-Ea Phillips #1, #2, #3 1-Ea Square #1, #2 1-Ea Slotted #6F-#8R, #8R-10F, #10R-12R	1	Ea. Card




## Nickel Plated Replacement Bits For Multi Bit Drivers- PC 6768

- Packed Two Per Card
- For Multi Bit Drivers
- Resists Corrosion

CAT NO	DESCRIPTION	STD	UNIT
NBT1015C	 T10 & T15 Star	1	Ea. Card
NBT2025C	T20 & T25 Star	1	Ea. Card
NBP03C	 0 & 3 Phillips	1	Ea. Card
NBP12C	1 & 2 Phillips	1	Ea. Card
NBS03C	 0 & 3 Square Recess	1	Ea. Card
NBS12C	1 & 2 Square Recess	1	Ea. Card
NBSL46C	 4 & 6 Slotted	1	Ea. Card
RBVC	 Valve Stem Bit + 5.5 Slotted	1	Ea. Card
SA14C*	 1/4" Socket Adaptor	1	Ea. Card

## Tamper Proof Replacement Bits For Multi Bit Drivers - PC 6769

- Packed Two Per Card
- For Multi Bit Drivers
- Resists Corrosion

CAT NO	DESCRIPTION	STD	UNIT
RTP15C	 T10 & T15 Star Pin	1	Ea. Card
RTP20C	T20 & T25 Star Pin	1	Ea. Card
RTP27C	T27 & T30 Star Pin	1	Ea. Card
RHP18C	 1/8 & 9/64 Hex Pin	1	Ea. Card
RHP532C	5/32 & 3/16 Hex Pin	1	Ea. Card
RSP68C	 6 & 8 Spanner	1	Ea. Card
RSP12C	10 & 12 Spanner	1	Ea. Card





lhdottie.com

L. H. DOTTIE


# Carded Drill & Driver Bits

## High Speed Steel Drill Bits

### Carded High Speed Steel Drill Bits

- Heavy-duty web construction for strength and durability
- Provides accurate drilling without a center punch

**NEW!**

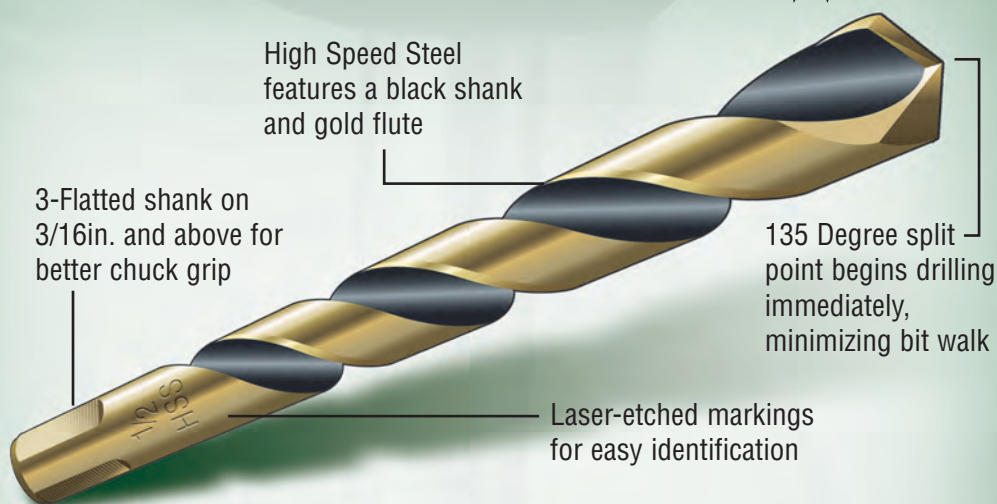

CAT NO	SIZE	DECIMAL	LENGTH	DRILLS PER CARD	STD	MSTR	UNIT
HS4C	1/16"	.0625	1-7/8"	5	1	6	Ea. Card
HS5C	5/64"	.0781	2"	5	1	6	Ea. Card
HS6C	3/32"	.0938	2-1/4"	4	1	6	Ea. Card
HS7C	7/64"	.1094	2-5/8"	4	1	6	Ea. Card
HS8C	1/8"	.1250	2-3/4"	4	1	6	Ea. Card
HS9C	9/64"	.1406	2-7/8"	4	1	6	Ea. Card
HS10C	5/32"	.1562	3-1/8"	3	1	6	Ea. Card
HS11C	11/64"	.1719	3-1/4"	3	1	6	Ea. Card
HS12C	3/16"	.1875	3-1/2"	3	1	6	Ea. Card
HS13C	13/64"	.2031	3-5/8"	2	1	6	Ea. Card
HS14C	7/32"	.2188	3-3/4"	2	1	6	Ea. Card
HS15C	15/64"	.2344	3-7/8"	2	1	6	Ea. Card
HS16C	1/4"	.2500	4"	2	1	6	Ea. Card
HS17C	17/64"	.2656	4-1/8"	1	1	6	Ea. Card
HS18C	9/32"	.2812	4-1/4"	1	1	6	Ea. Card
HS19C	19/64"	.2969	4-3/8"	1	1	6	Ea. Card
HS20C	5/16"	.3125	4-1/2"	1	1	6	Ea. Card
HS21C	21/64"	.3281	4-5/8"	1	1	6	Ea. Card
HS22C	11/32"	.3438	4-3/4"	1	1	6	Ea. Card
HS23C	23/64"	.3594	4-7/8"	1	1	6	Ea. Card
HS24C	3/8"	.3750	5"	1	1	6	Ea. Card
HS25C	25/64"	.3906	5-1/8"	1	1	6	Ea. Card
HS26C	13/32"	.4062	5-1/4"	1	1	6	Ea. Card
HS27C	27/64"	.4219	5-3/8"	1	1	6	Ea. Card
HS28C	7/16"	.4375	5-1/2"	1	1	6	Ea. Card
HS29C	29/64"	.4531	5-5/8"	1	1	6	Ea. Card
HS30C	15/32"	.4688	5-3/4"	1	1	6	Ea. Card
HS31C	31/64"	.4844	5-7/8"	1	1	6	Ea. Card
HS32C	1/2"	.5000	6"	1	1	6	Ea. Card