





WORK AREA OUTLETS - CAT 6A CONNECTORS

CAT 6A 10G UTP Modular Connectors HD Style

The CAT 6A 10Gig UTP modular jacks provide transmission performance beyond 500MHz and Alien Crosstalk requirements exceeding the industry standards set by ANSI/TIA-568-C.2 for supporting the operation of 10Gig Ethernet applications (10GBASE-T). It is designed with a shielded termination cap which minimizes additional AXT from neighboring connectors. It also features twisted pair separation posts which minimizes untwisting of pairs to allow for efficient installation and long-term peak performance. The modular jacks are also backwards compatible supporting current CAT 6, CAT 5e, and phone network applications.



IC1078GABL

JENNE PART NUMBER:

IC1078GAWH 8P8C, UTP, White

IC1078GABL 8P8C, UTP, Blue

IC1078GAIV 8P8C, UTP, Ivory

IC1078GAOR 8P8C, UTP, Orange

IC1078GARD 8P8C, UTP, Red

IC1078GABK 8P8C, UTP, Black

Optional Accessories

CAT 6A UTP Patch Panels

ICMPP246AU 24-Port Panel with 24 CAT 6A UTP Connectors, 1 RMS

IC107PPU6A 24-Port Panel, Unloaded, 1 RMS


CAT 6A 650 MHz 10G UTP Premise Cables

ICCABP6Axx¹ 4-Pair, 23 AWG, UTP, Solid Copper Cable, CMP

ICCABR6Axx¹ 4 -Pair, 23 AWG, UTP, Solid Copper Cable, CMR

¹xx Denotes Color = BL-Blue, WH-White

Permanent Link Performance Test

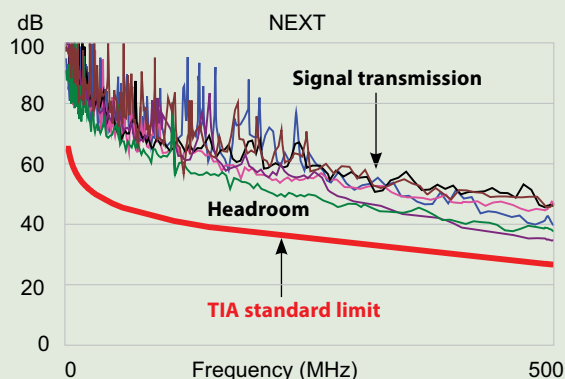

Installed with ICC premise cable and tested per TIA Permanent Link specification

CAT 6A 10G FTP Modular Connector HD Style

CAT 6A FTP Shielded modular jacks (8P8C) is designed to deliver advanced performance and reliability in the most hostile and demanding datacom environments. CAT 6A FTP die-cast connector shields and protects vital network terminations from harmful Electromagnetic Interference (EMI) commonly present around power cables and heavy machinery that causes alien crosstalk along the path of a signal.



IC1078S6A0

JENNE PART NUMBER:

IC1078S6A0 8P8C, FTP

Optional Accessories

CAT 6A FTP Patch Panels

ICMPP246AS 24-Port Panel with 24 CAT 6A FTP Connectors, 1 RMS


IC107PPS6A 24-Port Panel, Unloaded, 1 RMS

CAT 6A 650 MHz 10G FTP Premise Cables

ICCABP6FBL 4-Pair, 23 AWG, FTP, Solid Copper Cable, CMP, Blue

ICCABR6FBL 4 -Pair, 23 AWG, FTP, Solid Copper Cable, CMR, Blue


Permanent Link Performance Test

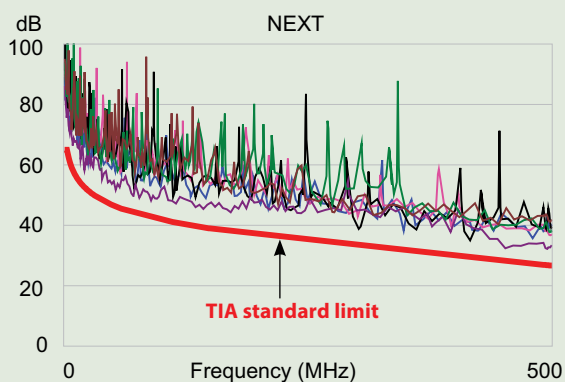

Installed with ICC premise cable and tested per TIA Permanent Link specification

CAT 6A 10G UTP Modular Coupler HD Style

- No termination required; feed-through the front and rear
- Joins two high performance CAT 6A patch cords
- 50 micro-inch gold plated contacts

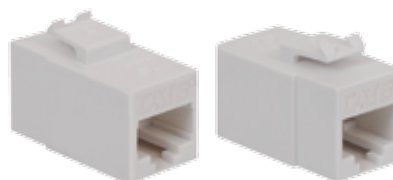

IC107C6AWH

JENNE PART NUMBER:

IC107C6AWH 8P8C/8P8C Coupler, UTP, White


IC107C6ABK 8P8C/8P8C Coupler, UTP, Black

WORK AREA OUTLETS - CAT 6 CONNECTORS



CAT 6 HD and EZ® Style Modular Connectors

- Exceeds TIA-568 CAT 6 performance standard
- Built-in PCB technology for maximum signal quality
- 50 micro-inch gold plated contacts
- Includes a color T568A/B wiring diagram
- Terminate with the JackEasy termination tool

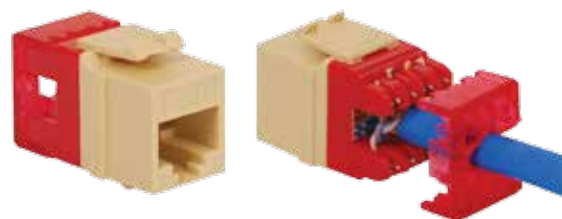

IC1078F6IV

JENNE PART NUMBER:

IC1078F6xx¹	8P8C, HD style Rear split-back IDC
IC1078L6xx¹	8P8C, EZ style Rear in-line IDC makes seating wires easy Pair-to-pair wiring; no splitting

¹xx Denotes Color = WH-White, IV-Ivory, BL-Blue, OR-Orange, RD-Red, YL-Yellow, GY-Gray, BK-Black, AL-Almond, GN-Green, PR-Purple



IC1078L6IV

CAT 6 HD and EZ® Style Modular Connector ValuePacks

- Packaged in a resealable bag for easy storage • Reduces packaging waste • 25 pieces per bag

JENNE PART NUMBER:

IC107F6Cxx¹	8P8C, HD style , 25 pcs.
IC107F6Lxx¹	8P8C, EZ style , 25 pcs.

¹xx Denotes Color = WH-White, IV-Ivory, BL-Blue, OR-Orange, RD-Red, BK-Black



IC107F6CIV



IC107F6IV

CAT 6 Modular Couplers HD Style

- No termination required; feed-through the front and rear
- Exceeds TIA-568 CAT 6 performance standard • 50 micro-inch gold plated contacts

JENNE PART NUMBER:

IC107CP6xx¹	8P8C/8P8C
-------------------------------	-----------

¹xx Denotes Color = WH-White, BK-Black



IC107CP6WH

CAT 6 Modular Coupler HD Style ValuePacks

- Packaged in a resealable bag for easy storage • Reduces packaging waste • 25 pieces per bag

JENNE PART NUMBER:

IC107C6Cxx¹	8P8C/8P8C, 25 pcs.
-------------------------------	---------------------------

¹xx Denotes Color = WH-White, BK-Black



IC107C6CBK


Every effort has been made to ensure the integrity of this catalog. JenNet, Inc. cannot be held responsible for any misrepresentation associated with any products due to omissions, typographic errors or misprints.



WORK AREA OUTLETS - CAT 5E CONNECTORS

CAT 5e HD and EZ® Style Modular Connectors

- Exceeds TIA-568 CAT 5e performance standard
- Built-in PCB technology for maximum signal quality
- 50 micro-inch gold plated contacts
- Includes a color T568A/B wiring diagram
- Compatible with VoIP phone systems
- Terminate with the JackEasy termination tool

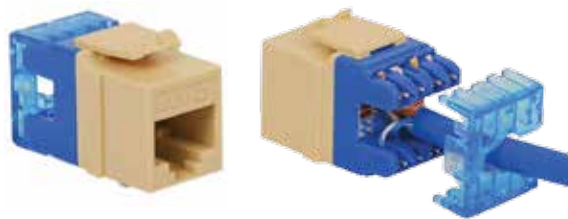

IC1078F5IV

JENNE PART NUMBER:

IC1078F5xx¹	8P8C, HD style Rear split-back IDC
IC1078E5xx¹	8P8C, EZ style Rear in-line IDC makes seating wires easy Pair-to-pair wiring; no splitting

¹xx Denotes Color = WH-White, IV-Ivory, BL-Blue, OR-Orange, RD-Red, YL-Yellow, GY-Gray, BK-Black, AL-Almond, GN-Green, PR-Purple



IC1078E5IV

CAT 5e HD and EZ® Style Modular Connector ValuePacks

- Packaged in a resealable bag for easy storage • Reduces packaging waste • 25 pieces per bag

JENNE PART NUMBER:

IC107F5Cxx¹	8P8C, HD style , 25 pcs.
IC107E5Cxx¹	8P8C, EZ style , 25 pcs.

¹xx Denotes Color = WH-White, IV-Ivory, BL-Blue, OR-Orange, RD-Red, BK-Black



IC107E5CIV



IC107F5CIV

CAT 5e Modular Couplers HD Style

- No termination required; feed-through the front and rear
- Exceeds TIA-568 CAT 5e performance standard • 50 micro-inch gold plated contacts

JENNE PART NUMBER:

IC107C5Exx¹	8P8C/8P8C
-------------------------------	-----------

¹xx Denotes Color = WH-White, BK-Black



IC107C5EWH

CAT 5e Modular Coupler HD Style ValuePacks

- Packaged in a resealable bag for easy storage • Reduces packaging waste • 25 pieces per bag

JENNE PART NUMBER:

IC107C5Cxx¹	8P8C/8P8C, 25 pcs.
-------------------------------	---------------------------


¹xx Denotes Color = WH-White, BK-Black



IC107C5CBK

Voice HD and EZ® Style Modular Connectors

- Supports phone applications
- Compatible with RJ-11 plug
- Accepts category-rated cable and 22~24 AWG solid wire
- 50 micro-inch gold plated contacts
- Includes a color USOC/UTP wiring diagram
- Terminate with the JackEasy termination tool

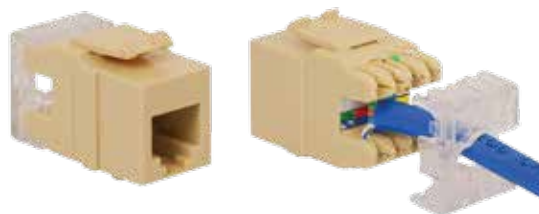


IC1076F0IV

JENNE PART NUMBER:

IC1076F0xx¹	6P6C, HD style Rear split-back IDC
IC1076V0xx¹	6P6C, EZ style Rear in-line IDC makes seating wires easy Pair-to-pair wiring; no splitting

¹xx Denotes Color = WH-White, IV-Ivory, BL-Blue, OR-Orange, RD-Red, YL-Yellow, GY-Gray, BK-Black, AL-Almond, GN-Green, PR-Purple

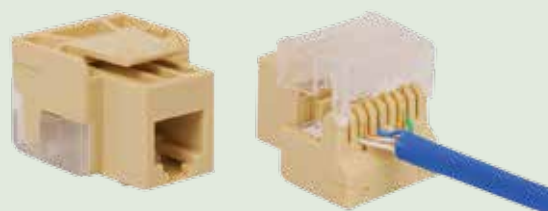

IC1076V0IV


Voice HD and EZ® Style Modular Connector ValuePacks

- Packaged in a resealable bag for easy storage
- Reduces packaging waste
- 25 pieces per bag

JENNE PART NUMBER:

IC1076FCxx¹	6P6C, HD style , 25 pcs.
IC1076VCxx¹	6P6C, EZ style , 25 pcs.

¹xx Denotes Color = WH-White, IV-Ivory

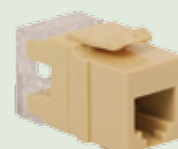

IC1076FCIV



IC1076VCIV

Voice Modular Couplers HD Style

- No termination required; feed-through on the front and rear
- Supports phone applications
- Compatible with RJ-11 plug
- 50 micro-inch gold plated contacts

JENNE PART NUMBER:

IC107C6Sxx¹	6P6C/6P6C, Pin 1-6
IC107C6Rxx¹	6P6C/6P6C, Pin 1-1

¹xx Denotes Color = WH-White, IV-Ivory, GY-Gray, BK=Black



IC107C6SWH



JackEasy™ Termination Tool

Terminates CAT 6A, CAT 6, CAT 5e and Voice Modular Connectors HD and EZ Style

Every effort has been made to ensure the integrity of this catalog. Jenne, Inc. cannot be held responsible for any misrepresentation associated with any products due to omissions, typographic errors or misprints.



WORK AREA OUTLETS - VIDEO CONNECTORS

F-Type Video Modular Connectors HD Style

- Female to female feed-through connector • Threaded connector to secure connection • Works with RG-6 and RG-59 coaxial cable

JENNE PART NUMBER:

IC107B9Fxx¹ F-Type Nickel Plated, 3 GHz (pictured)

 
IC107B9Gxx¹ F-Type Gold Plated, 3 GHz

IC107B5Fxx² F-Type Nickel Plated, 2 GHz

IC107B5Gxx² F-Type Gold Plated, 2 GHz

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond

²xx Denotes Housing Color = WH-White, IV-Ivory, GY-Gray, BK-Black, AL-Almond



IC107B9FIV

F-Type Video Modular Connector HD Style ValuePacks

- Packaged in a resealable bag for easy storage • Reduces packaging waste • 25 pieces per bag

JENNE PART NUMBER:

IC107BFCWH F-Type Nickel Plated, 2 GHz, **25 pcs.**

IC107BGCWH F-Type Gold Plated, 2 GHz, **25 pcs.**

Housing Color = White



IC107BFCWH



IC107BGCWH

F-Type Video Modular Compression Connector HD Style

- Front female nickel plated connector with rear compression connector
- Rear compression connector works with RG-6 quad shield coaxial cable • Not compatible with plenum cable

JENNE PART NUMBER:

IC107FQGWH F-Type, RG-6Q, Blue Band

Housing Color = White



IC107FQGWH

BNC Video Modular Connectors HD Style


- Female to female feed-through nickel plated connector • Supports CCTV, NTSC Analog video signals and satellite link signals

JENNE PART NUMBER:

IC107BNCxx¹ BNC Connector, 75 Ohm

IC107B3Gxx¹ BNC Connector, 50 Ohm

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black

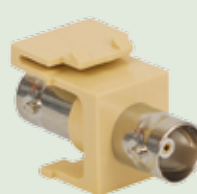

IC107BNCIV

BNC Video Modular Compression Connector HD Style

- Front female nickel plated connector with rear compression connector
- Rear compression connector works with RG-6 quad shield coaxial cable • Not compatible with plenum cable

JENNE PART NUMBER:

IC107BQCWH BNC, Blue Band, 75 Ohm

Housing Color = White



IC107BQCWH

HDMI Modular Couplers HD Style

- Female to female gold plated coupler • Supports high-definition video: 1080p, 3D and HDCP

JENNE PART NUMBER:

IC107HDMxx¹ HDMI connector

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond



IC107HDMIV

USB Modular Couplers HD Style

- Female to female coupler • Supports USB connectivity; backwards compatible
- IC107UABWH is reversible with either the A or B port facing outward

JENNE PART NUMBER:

IC107UAAWH USB coupler, A-to-A

IC107UABWH USB coupler, A-to-B

Housing Color = White



IC107UAAWH



IC107UABWH

3.5mm Stereo Audio Plug Modular Connectors HD Style

- Rear push-pins accept UTP cable or any 22~24 AWG wire • Terminals are marked for correct polarity

JENNE PART NUMBER:

IC107SAPxx¹ 3.5mm connector to push pin

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond



IC107SAPIV

3.5mm Stereo Audio Plug Modular Couplers HD Style

- Female to female nickel plated coupler

JENNE PART NUMBER:

IC107SACWH 3.5mm coupler, feed-through

Housing Color = White



IC107SACWH

S-Video Modular Connectors HD Style

- Front female connector with rear 110-Type IDC termination
- Rear IDC accepts UTP cable or any 22~24 AWG wire • Package includes a termination cap to secure wiring

JENNE PART NUMBER:

IC107SVIxx¹ S-Video connector

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond



IC107SVIIV



WORK AREA OUTLETS - AUDIO AND VIDEO INSERTS


HDMI Décorex™ Inserts with 2 Open High Density Ports

- Female to female gold plated coupler • Package includes 2 blank modular inserts
- Supports high-definition video: 1080p, 3D and HDCP

JENNE PART NUMBER:

IC107DH2xx¹ 1 HDMI coupler, 2 HD ports

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond

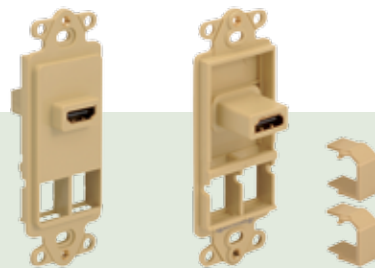

IC107DH2IV


Dual HDMI Décorex™ Inserts with 2 Open High Density Ports

- Female to female gold plated coupler • Package includes 2 blank modular inserts
- Supports high-definition video: 1080p, 3D and HDCP

JENNE PART NUMBER:

IC107DDHxx¹ 2 HDMI couplers, 2 HD ports

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond

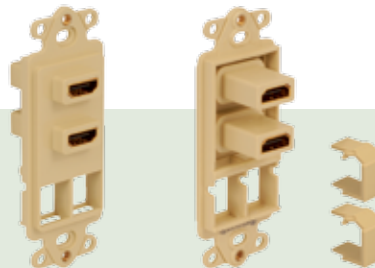

IC107DDHIV

VGA Décorex™ Inserts with Open High Density Ports


- Female to female 15-Pin VGA coupler • Supports high quality analog video
- Package includes blank modular inserts

JENNE PART NUMBER:

IC107DR2xx¹ 1 VGA coupler, 2 HD ports

IC107DR4xx¹ 1 VGA coupler, 4 HD ports

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond

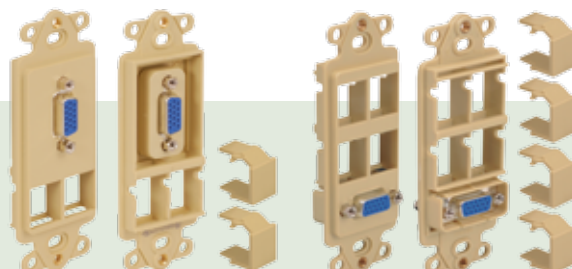

IC107DR2IV

IC107DR4IV

Binding Post Audio Speaker Décorex Inserts

- Front gold plated binding post with female banana plug
- Rear set-screw connection, accepts speaker wire up to 8 AWG

JENNE PART NUMBER:


 
ICRDSSBPxx¹ 2 binding posts

ICRDSDBPxx² 4 binding posts

ICRDSQBPxx² 8 binding posts

¹xx Denotes Housing Color = WH-White, IV-Ivory

²xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond

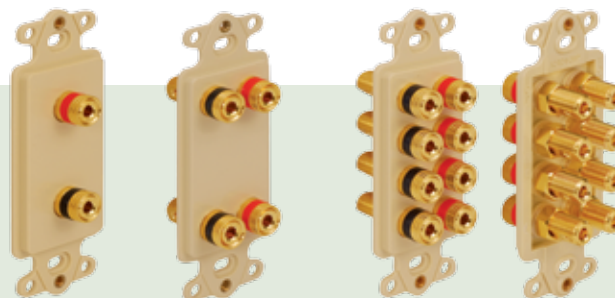

ICRDSSBPIV

ICRDSDBPIV

ICRDSQBPIV

F-Type and RCA Décorex Inserts

- Female to female F-Type connector

JENNE PART NUMBER:


IC630DSFxx¹ F-Type connector

IC630DDFxx¹ 2 F-Type connectors

ICRDS3RFxx² F-Type connector and 3 RCA connectors
3 RCA female connectors with rear F-Type connectors

¹xx Denotes Housing Color = WH-White, IV-Ivory, AL-Almond

²xx Denotes Housing Color = WH-White, IV-Ivory

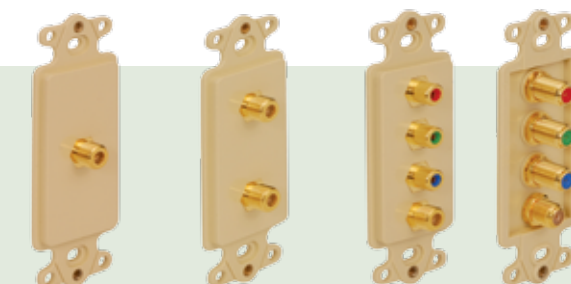

IC630DSFIV

IC630DDFIV

ICRDS3RFIV

RCA Female-to-RCA Female Modular Connectors HD Style

- Female to female feed-through connector

JENNE PART NUMBER:		JENNE PART NUMBER:	
IC107R6Gxx ¹	Red Insert	IC107B6Gxx ¹	White Insert
IC107G6Gxx ¹	Green Insert	IC107Y6Gxx ¹	Yellow Insert
IC107L6Gxx ¹	Blue Insert	IC107K6Gxx ¹	Black Insert

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond



IC107R6GIV

RCA Female-to-F-Type Modular Connectors HD Style

- Front female connector with rear F-Type female connector • Rear connector works with RG-6 and RG-59 coaxial cable

JENNE PART NUMBER:		JENNE PART NUMBER:	
IC107RFGxx ¹	Red Insert	IC107BFGxx ¹	White Insert
IC107GFGxx ¹	Green Insert	IC107YFGxx ¹	Yellow Insert
IC107LFGxx ¹	Blue Insert	IC107KFGxx ¹	Black Insert

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond




IC107RFGIV

RCA Female-to-IDC Modular Connectors HD Style

- Front female connector with rear 110-Type IDC termination • Rear IDC accepts UTP cable or any 22~24 AWG wire
- Package includes a termination cap to secure wiring

JENNE PART NUMBER:		JENNE PART NUMBER:	
IC107R8Gxx ¹	Red Insert	IC107B8Gxx ¹	White Insert
IC107G8Gxx ¹	Green Insert	IC107Y8Gxx ¹	Yellow Insert
IC107L8Gxx ¹	Blue Insert	IC107K8Gxx ¹	Black Insert

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond

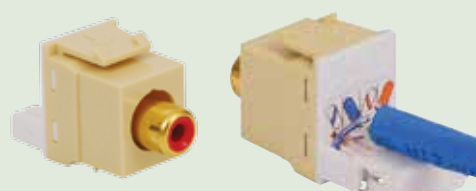

IC107R8GIV

RCA Modular Compression Connectors HD Style

- Front female nickel plated connector with rear compression connector • Not compatible with plenum cable
- Rear compression connector works with RG-6 quad shield coaxial cable

JENNE PART NUMBER:		JENNE PART NUMBER:	
IC107RQRWH	Red Insert	IC107RQWWH	White Insert
IC107RQGWH	Green Insert	IC107RQYWH	Yellow Insert
IC107RQLWH	Blue Insert	IC107RQKWH	Black Insert

Housing Color = White



IC107RQRWH


RCA Solder Tail and Component Pack Modular Connectors

JENNE PART NUMBER:	
IC107B7Gxx ¹	Solder Tail, Black Insert, HD style Front female connector with rear 110-Type IDC termination
IC107RR5xx ²	Female to female connector, HD style, 5 pcs.*
IC107RF5xx ²	Front female with rear F-Type female, HD style, 5 pcs.*
IC107RD5xx ²	Front female with rear 110-Type IDC HD style, 5 pcs.*

*Includes connectors with 2 red, 1 green, 1 blue and 1 white insert

¹xx Denotes Housing Color = WH-White, IV-Ivory, AL-Almond

 ²xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond



IC107B7GWH



IC107RR5IV, IC107RF5IV,
IC107RD5IV

Every effort has been made to ensure the integrity of this catalog. Jenne, Inc. cannot be held responsible for any misrepresentation associated with any products due to omissions, typographic errors or misprints.



WORK AREA OUTLETS - AUDIO SPEAKER CONNECTORS


Dual Audio Speaker Modular Connectors HD Style

- Front push buttons with rear crimp-on wire connector • Black and red push buttons have + and - signs for correct polarity
- Accepts speaker wire up to 16 AWG • Patented design

JENNE PART NUMBER:

IC107DSCxx¹ Front speaker connector

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond

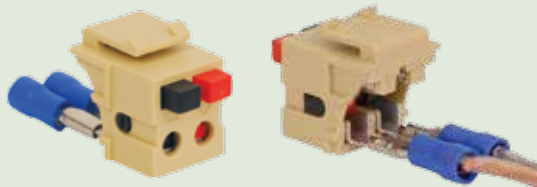

IC107DSCIV


Dual Front & Back Audio Speaker Modular Connectors HD Style

- Front and rear push buttons • Black and red push buttons have + and - signs for correct polarity
- Accepts speaker wire up to 16 AWG • Patented design

JENNE PART NUMBER:

IC107DSBxx¹ Front and rear speaker connector

¹xx Denotes Housing Color = WH-White, IV-Ivory

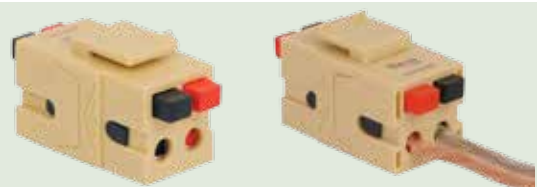

IC107DSBIV


3.5mm Stereo Audio Plug Modular Connectors HD Style

- Front spring clip with rear crimp-on wire connector • Front accepts speaker wire up to 12 AWG • Rear accepts speaker wire up to 16 AWG
- Comes in pairs with red and black clips for correct polarity • Patented design

JENNE PART NUMBER:

IC107BSSBK Spring clip connectors

Housing Color = Black

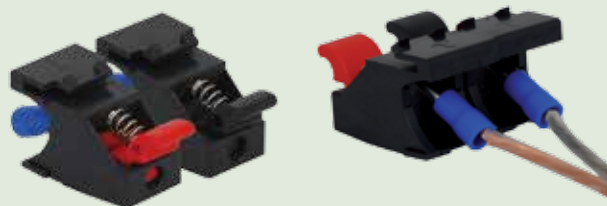

IC107BSSBK

Binding Post Audio Speaker Modular Connectors HD Style

- Front gold plated binding post with female banana plug • Rear set-screw connection • Accepts speaker wire up to 8 AWG
- Comes in pairs with red and black bands for correct polarity

JENNE PART NUMBER:

IC107PMGxx¹ Binding post connectors, gold plated

¹xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black, AL-Almond



IC107PMGIV

Dust Cover

- Works with CAT 6A, CAT 6, CAT 5e and voice modular connectors and patch panels • Snaps on the port opening to prevent dust from entering

JENNE PART NUMBER:

ICACSDCICL Dust cover, **10 pcs.**

ICACSDCVCL Dust cover, **100 pcs.**

Color = Clear



ICACSDCICL

Fiber Optic Modular Couplers HD Style

- Female to female coupler • Feed-through on the front and rear; no termination required
- Designed with ceramic sleeves • Supports multimode and single-mode

JENNE PART NUMBER:

IC107LC2xx¹ LC duplex coupler, ceramic sleeves

IC107SC2xx¹ SC simplex coupler, ceramic sleeve

IC107ST2xx¹ ST simplex coupler, ceramic sleeve

¹xx Denotes Housing Color = WH-White, IV-Ivory



IC107LC2IV



IC107SC2IV



IC107ST2IV

Blank Fill-In Modular Inserts HD Style

- Fills open and unused ports until they are needed

JENNE PART NUMBER:

IC107BN0xx¹ Blank fill-in insert, **10 pcs.**

IC107BNVxx² Blank fill-in insert, **100 pcs.**

¹xx Denotes Housing Color = WH-White, IV-Ivory, GY-Gray, BK-Black, AL-Almond

²xx Denotes Housing Color = WH-White, IV-Ivory, BK-Black



IC107BN0IV



IC107BNVIV

Cable Feed-Through Modular Inserts HD Style

- Allows cable to pass through a 0.30 inch diameter hole

JENNE PART NUMBER:

IC107BN2xx¹ Cable feed-through insert, 10 pcs.

¹xx Denotes Housing Color = WH-White, IV-Ivory, GY-Gray, AL-Almond



IC107BN2IV



WORK AREA OUTLETS - FACEPLATES

Classic Configurable Faceplates

- Flush mount style • Durable ABS plastic

JENNE PART NUMBER:

A. IC107F01xx¹ 1-Port, single gang

B. IC107F02xx¹ 2-Ports, single gang

C. IC107F03xx¹ 3-Ports, single gang

D. IC107F04xx¹ 4-Ports, single gang

E. IC107F06xx¹ 6-Ports, single gang

F. IC107FD8xx¹ 8-Ports, double gang


G. IC107F12xx¹ 12-Ports, double gang

H. IC107FT9xx² 9-Ports, triple gang

I. IC107FT0xx² 12-Ports, triple gang

¹xx Denotes Color = WH-White, IV-Ivory, GY-Gray, BK-Black, AL-Almond

²xx Denotes Color = WH-White, IV-Ivory, GY-Gray

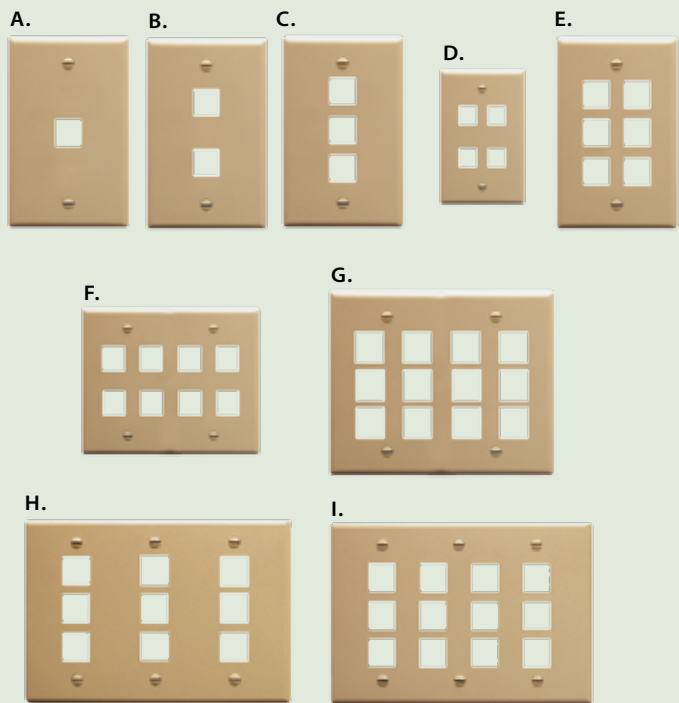

Classic Configurable Faceplate ValuePacks

- Packaged in a resealable box for easy storage • Reduces packaging waste • 25 pieces per box

JENNE PART NUMBER:

IC107F1Cxx¹ 1-Port, single gang, **25 pcs.**

IC107F2Cxx¹ 2-Ports, single gang, **25 pcs.**

IC107F3Cxx¹ 3-Ports, single gang, **25 pcs.**

IC107F4Cxx¹ 4-Ports, single gang, **25 pcs.**

¹xx Denotes Housing Color = WH-White, IV-Ivory



IC107F1CIV

Classic Stainless Steel Configurable Faceplates

- Flush mount style • Corrosion resistant 304 stainless steel

JENNE PART NUMBER:

A. IC107SF1SS 1-Port, single gang

B. IC107SF2SS 2-Ports, single gang


C. IC107SF3SS 3-Ports, single gang

D. IC107SF4SS 4-Ports, single gang

E. IC107SF6SS 6-Ports, single gang

F. IC107DF4SS 4-Ports, double gang

G. IC107DF8SS 8-Ports, double gang

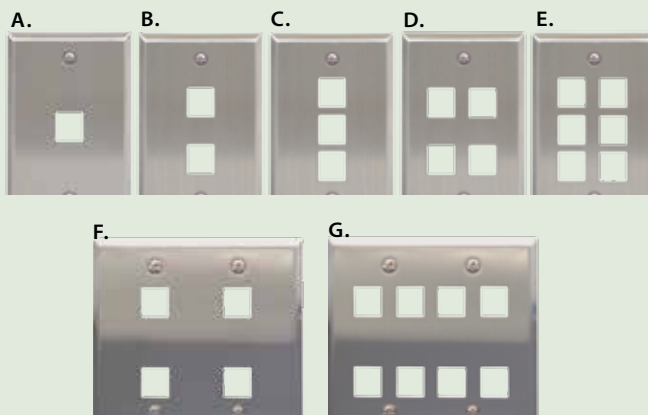

Classic Angled Configurable Faceplates


 
- Angled ports help reduce cable stress
- Flush mount style
- Durable ABS plastic

JENNE PART NUMBER:

- A. IC107DA1xx¹** 1-Port angled, single gang
- B. IC107DA2xx¹** 2-Ports angled, single gang
- C. IC107AF2xx²** 1-Port flat, 1-Port angled, single gang
- D. IC107DA4xx¹** 4-Ports angled, single gang
- E. IC107AF4xx²** 2-Ports flat, 2-Ports angled, single gang
- F. IC107AF8xx²** 4-Ports flat, 4-Ports angled, double gang

¹xx denotes color = WH-White, IV-Ivory, AL-Almond

²xx denotes color = WH-White, IV-Ivory

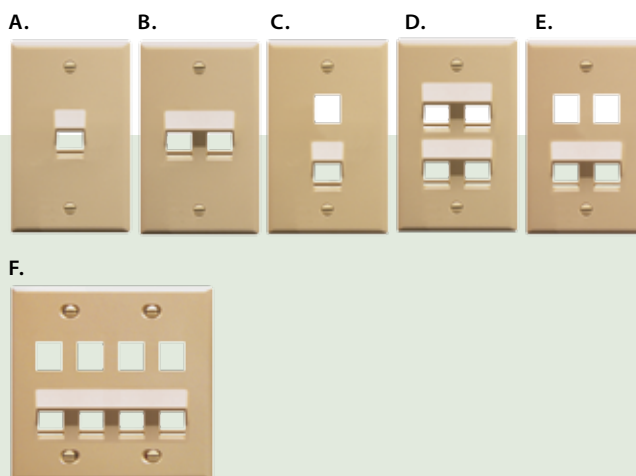


Classic Configurable Faceplates with Station ID

- Flush mount style
- Durable ABS plastic
- Package includes paper labels and clear view covers

JENNE PART NUMBER:

- A. IC107S01xx¹** 1-Port, single gang
- B. IC107S02xx¹** 2-Ports, single gang
- C. IC107S03xx¹** 3-Ports, single gang
- D. IC107S04xx¹** 4-Ports, single gang
- E. IC107S06xx¹** 6-Ports, single gang
- F. IC107SD8xx¹** 8-Ports, double gang
- G. IC107ST9xx¹** 9-Ports, triple gang

¹xx denotes color = WH-White, IV-Ivory

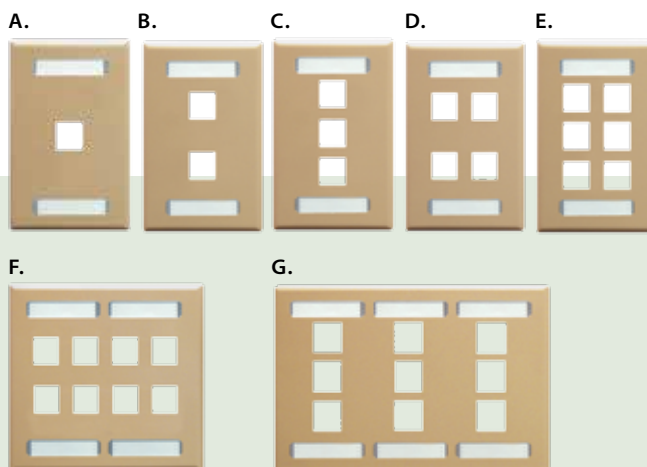


Classic Stainless Steel Configurable Faceplates with Station ID

- Flush mount style • Corrosion resistant 304 stainless steel
- Package includes paper labels and clear view covers

JENNE PART NUMBER:

- A. IC107S01SS** 1-Port, single gang
- B. IC107S02SS** 2-Ports, single gang
- C. IC107S03SS** 3-Ports, single gang
- D. IC107S04SS** 4-Ports, single gang
- E. IC107S06SS** 6-Ports, single gang

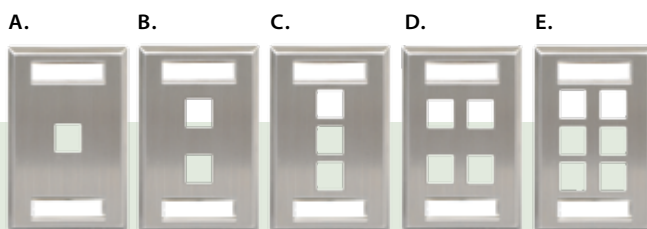


Classic Angled Configurable Faceplates with Station ID

- Angled ports help reduce cable stress
- Flush mount style • Durable ABS plastic
- Package includes paper labels and clear view covers

JENNE PART NUMBER:

- A. IC107AS2xx¹** 1-Port flat, 1-Port angled, single gang
- B. IC107AS4xx¹** 2-Ports flat, 2-Ports angled, single gang
- C. IC107AS8xx¹** 4-Ports flat, 4-Ports angled, double gang

¹xx denotes color = WH-White, IV-Ivory

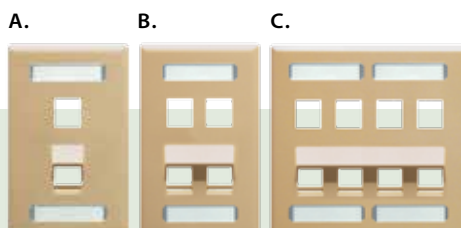


Classic Oversized Configurable Faceplates

- Designed to cover uneven and oversized drywall cuts
- Larger than standard faceplates
- Durable ABS plastic

JENNE PART NUMBER:

- | | |
|----------------------------------|----------------------|
| A. IC107LF1xx¹ | 1-Port, single gang |
| B. IC107LF2xx¹ | 2-Ports, single gang |
| C. IC107LF3xx¹ | 3-Ports, single gang |
| D. IC107LF4xx¹ | 4-Ports, single gang |
| E. IC107LF6xx¹ | 6-Ports, single gang |

¹xx denotes color = WH-White, IV-Ivory, AL-Almond

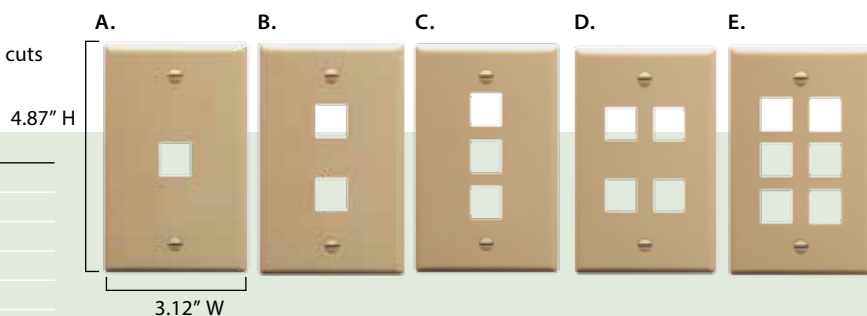

Décorex™ Configurable Inserts


- Inserts are configurable with modular connectors
- Durable ABS plastic

JENNE PART NUMBER:

- | | |
|----------------------------------|--|
| A. IC107DI1xx¹ | 1-Port |
| B. IC107DI2xx¹ | 2-Ports |
| C. IC107DI3xx¹ | 3-Ports |
| D. IC107DI4xx¹ | 4-Ports; works with HD style connectors only |
| E. IC107DI6xx¹ | 6-Ports; works with HD style connectors only |
| F. IC630DIBxx² | Blank insert |

¹xx denotes color = WH-White, IV-Ivory, BK-Black, AL-Almond

²xx denotes color = WH-White, IV-Ivory

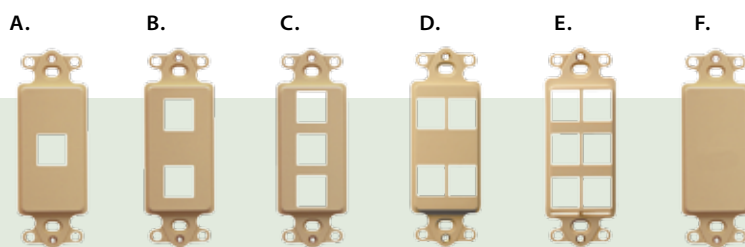


Décorex Configurable Faceplates

- Faceplates are configurable with Décorex inserts

JENNE PART NUMBER:

- | | |
|----------------------------------|---------------------------------|
| A. IC107DFSxx¹ | 1-Insert space, single gang |
| B. IC107DFDxx¹ | 2-Insert spaces, double gang |
| C. IC107DFTxx¹ | 3-Insert spaces, triple gang |
| D. IC107DFQxx¹ | 4-Insert spaces, quad gang |
| E. IC107DFSxx¹ | 1-Insert space, single gang, st |
| F. IC107DFDxx¹ | 2-Insert spaces, double gang |

¹xx denotes color = WH-White, IV-Ivory, BK-Black, AL-Almond

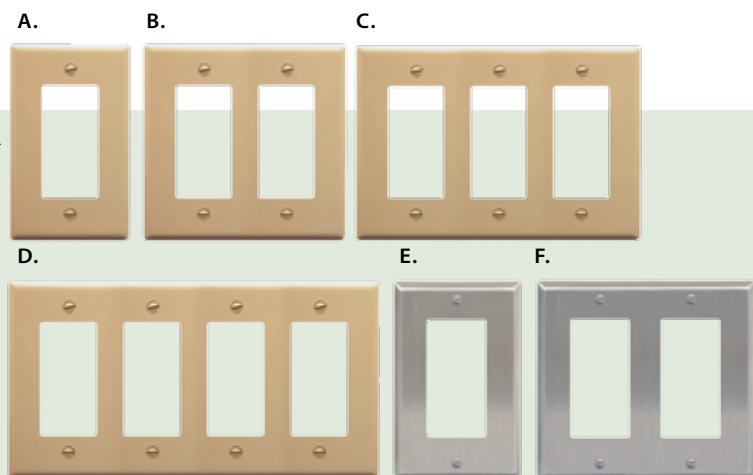

Décorex Configurable Faceplates & Inserts



- Faceplates are configurable with electrical inserts
- Inserts are configurable with modular connectors

JENNE PART NUMBER:

- | | |
|----------------------------------|---|
| A. IC106FP2xx¹ | 2-Ports, single gang faceplate |
| B. IC106FP4xx² | 4-Ports, double gang faceplate |
| C. IC107DPIxx¹ | 2-Ports, insert |
| D. IC1074PIxx¹ | 4-Ports, insert; works with HD style connectors |

¹xx denotes color = WH-White, IV-Ivory, AL-Almond

 ²xx denotes color = WH-White, IV-Ivory

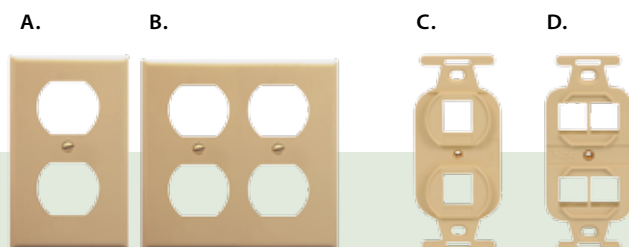

2 Types of Termination

- IDC integrated faceplates allow voice and data signals to be carried over UTP solid cables
- Screw terminated wall plates offer a traditional way of termination
- Wall plates with F-Type connectors provide reliable connections for high quality video



CAT 5e Data, Voice, Video | IDC Integrated Faceplates

- Rear IDC termination for fast and reliable installations
- Includes IDC caps to secure rear terminated wiring
- ABS plastic for durability

JENNE PART NUMBER:

ICRDSV05xx¹ 6P6C & CAT 5e

ICRDSVF0xx¹ 6P6C & F-Type

ICRDS0F5xx¹ CAT 5e & F-Type

¹xx denotes color = AL-Almond, IV-Ivory, WH-White



ICRDSV05AL



ICRDSVF0IV



ICRDS0F5WH

CAT 5e Data, Voice, Video | IDC Integrated Faceplates

- Rear IDC termination for fast and reliable installations
- Includes IDC caps to secure rear terminated wiring
- ABS plastic for durability

JENNE PART NUMBER:

ICRDSVF5xx¹ 6P6C, CAT 5e & F-Type

ICRDSV25xx¹ 6P6C, CAT 5e & (2) F-Type

ICRDS2F5xx¹ (2) CAT 5e & (2) F-Type

¹xx denotes color = AL-Almond, IV-Ivory, WH-White



ICRDSVF5AL



ICRDSV25IV



ICRDS2F5WH

Bulk Wire | Cover Faceplates

- Configured to fit standard single or double gang outlet box
- ABS plastic for durability

JENNE PART NUMBER:

IC640BSSWH Single Gang, 0.90"D x 1.25"W Opening

IC640BDSWH Double Gang, 1.15"D x 2.75"W Opening

color = WH-White



IC640BSSWH



IC640BDSWH

Euro Style | Elite™ Multimedia Boxes

- (1) front Elite™ bezel opening
- Complies with European outlet dimensions (83.5 mm x 83.5 mm)
- Station identification
- Works with Elite bezels
- Compatible with ICRW11 and ICRW12 raceway systems

JENNE PART NUMBER:

IC108CE1xx¹ 1-Port, Euro Style Mounting Box

¹xx denotes color = GY-Gray, IV-Ivory, WH-White



IC108CE1IV



WORK AREA OUTLETS - DÉCOREX FACEPLATES AND WALL PLATES

Recessed | Telephone Wall Plates

- Recessed design to accommodate cable
- Configured to fit standard single gang outlet box
- Two mounting standoffs for wall mount telephone
- Use color ID caps for a clean appearance

JENNE PART NUMBER:

IC107FRWxx¹	1-Port, Recessed, ABS Plastic, Single Gang
IC107FRWSS	1-Port, Recessed, Stainless Steel, Single Gang
IC107FWPxx²	1-Port, Mounting Standoffs, Single Gang

¹xx denotes color = AL-Almond, BK-Black, IV-Ivory, WH-White

²xx denotes color = AL-Almond, IV-Ivory, WH-White



IC107FRWWH



IC107FRWSS



IC107FWPAL

Classic | Screw Terminal Wall Plates

- Voice wall plates are integrated with rear screw down terminals
- No punch down tool required
- ABS plastic for durability

JENNE PART NUMBER:

IC630EGGxx¹	Classic, (2) F-Type
IC630E60xx¹	Classic, 6P6C Rear Screw Terminals
IC630EG0xx¹	Classic, F-Type
IC630E6Gxx¹	Classic, 6P6C Rear Screw Terminals & F-Type
IC630E66xx¹	Classic, (2) 6P6C Rear Screw Terminals

¹xx denotes color = IV-Ivory, WH-White




IC630EGGIV



IC630EG0IV



IC630E66IV

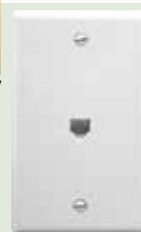

IC630E60WH



IC630E6GWH

Décorex™ Inserts & Integrated Faceplates

Integrated Voice & Video | Décorex Inserts

- Designed for a consistent look with standard decor style faceplates
- Gold plated F-Type connector for CATV and Satellite TV applications
- Provided with traditional screw down terminals for voice connectivity

JENNE PART NUMBER:

IC630DI6xx¹	6P6C, Rear Screw Terminals
IC630DD6xx¹	(2) 6P6C, Rear Screw Terminals
IC630DVFxx¹	(1) 6P6C Rear Screw Terminals & (1) F-Type

¹xx denotes color = AL-Almond, IV-Ivory, WH-White



IC630DI6IV



IC630DD6IV



IC630DVFIV

Telephone & Video | Screw Terminal Wall Plates

- Designed with mounting standoffs for wall mounting telephones
- Configured to fit standard single gang outlet box
- Provided with traditional screw down terminals

JENNE PART NUMBER:

IC630DB6xx¹	6P6C, Rear Screw Terminals
-------------------------------	----------------------------

¹xx denotes color = IV-Ivory, WH-White



IC630DB6IV

Telephone & Video | IDC Terminal Wall Plates

- Designed with mounting standoffs for wall mounting telephones
- Configured to fit standard single gang outlet box
- Provided with IDC terminals

JENNE PART NUMBER:

IC630SS6xx¹	6P6C, Rear 110-Type IDC Termination
IC630DA6SS	6P6C, Rear 110-Type IDC Termination, Stainless Steel

¹xx denotes color = IV-Ivory, WH-White



IC630SS6WH

Classic Surface Mount Boxes Kitted with Voice and CAT 5e Modular Connectors

- Comes with a voice or CAT 5e, EZ® style, modular connector
- Connectors are removable
- Package includes adhesive strips and wood screws for mounting

JENNE PART NUMBER:

- | | |
|----------------------------------|--|
| A. IC625SV1xx¹ | 1-Port box, with voice EZ connector |
| B. IC625SV2xx¹ | 2-Port box with 2 voice EZ connectors |
| C. IC625S51xx¹ | 1-Port box with CAT 5e EZ connector |
| D. IC625S52xx¹ | 2-Port box with 2 CAT 5e EZ connectors |


¹xx denotes color = IV-Ivory, WH-White




A.




B.

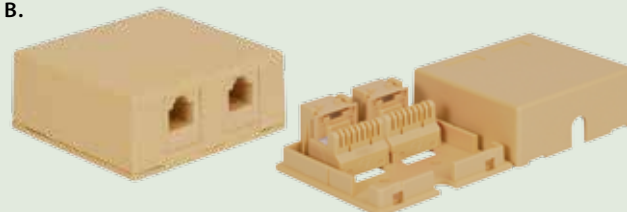

C.

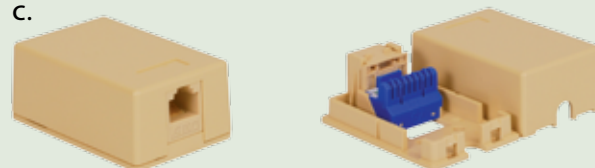

D.

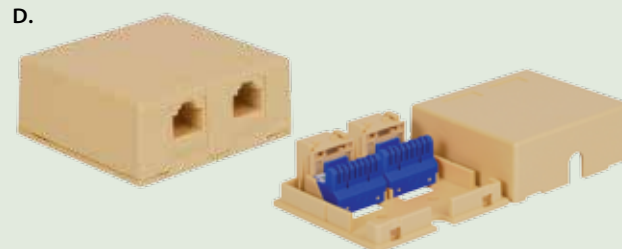

Surface Mount Jacks Integrated with Voice

- Two-piece design; cover and base
- Wiring diagram is molded under the cover
- Designed with rear Phillips screw down terminals
- Package includes adhesive strips and wood screws for mounting

JENNE PART NUMBER:

- | | |
|----------------------------------|------|
| A. IC625SB6xx¹ | 6P6C |
| B. IC625SB8xx¹ | 8P8C |

¹xx denotes color = IV-Ivory, WH-White



A.



B.



Surface Mount Jacks Integrated with Voice

- Two-piece design; cover and base
- Wiring diagram is molded under the cover
- Designed with a keyed RJ31X jack with shorting bar
- Designed with rear Phillips screw down terminals
- Package includes adhesive strips and wood screws for mounting

JENNE PART NUMBER:

- | | |
|----------------------------------|------|
| A. IC635DS4xx¹ | 8P4C |
| B. IC635DS8xx¹ | 8P8C |


¹xx denotes color = IV-Ivory, WH-White



A.



B.

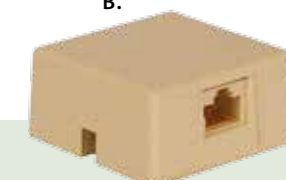




WORK AREA OUTLETS- FURNITURE FACEPLATES

Choose From 4 Different Styles

- Snaps into modular furniture systems including most popular brands such as Herman Miller, Knoll, Hayworth, Steelcase and others
- Compatible with ICC modular connectors

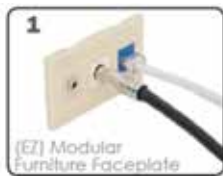

EZ | Configurable Modular Furniture Faceplates

- Modern appearance with an easy to use identification scheme
- Fits openings approximately (1.30" x 2.56")
- ABS plastic for durability

JENNE PART NUMBER:

IC107FM3xx¹ 3-Port, Furniture Faceplate

¹xx denotes color = BK-Black, GY-Gray, IV-Ivory, WH-White



IC107FM3BK

NEMA (HD) | Configurable Modular Furniture Faceplates

- Designed for high density applications
- Fits openings approximately (1.83" x 2.60")
- Designed with station ID's
- ABS plastic for durability

JENNE PART NUMBER:

IC107FN4xx¹ 4-Port, NEMA, Furniture Faceplate

¹xx denotes color = BK-Black, GY-Gray, IV-Ivory, WH-White



IC107FN4GY

TIA (HD) | Configurable Modular Furniture Faceplates

- Designed for high density applications
- Fits openings approximately (1.33" x 2.60")
- Designed with station ID's
- ABS plastic for durability

JENNE PART NUMBER:

IC107FT4xx¹ 4-Port, TIA, Furniture Faceplate

¹xx denotes color = BK-Black, GY-Gray, IV-Ivory, WH-White



IC107FT4IV

Universal | Configurable Modular Furniture Faceplates

- Movable locking tabs adjust to openings from (0.875" x 2.375") to (2.0" x 3.5")
- 2-Piece design (cover and base)
- Designed with station ID's
- ABS plastic for durability

JENNE PART NUMBER:

IC108UF4xx¹ 4-Port, Universal Furniture Faceplate

¹xx denotes color = BK-Black, GY-Gray, IV-Ivory, WH-White



IC108UF4WH

Multimedia Outlets

Single Gang | Elite™ Multimedia Outlets

- (2) front and (2) slim Elite™ bezel openings
- Front loading bezels can be custom configured with ICC modular connectors for voice, data, audio, video, and additional fiber optic connectivity
- Easy system administration with use of enclosed icons
- Works with Elite™ and slim bezels

JENNE PART NUMBER:

IC108WBSxx¹ 4-Port, Single Gang, Cover & Base

¹xx denotes color = GY-Gray, IV-Ivory, WH-White



IC108WBSGY

Double Gang | Elite™ Multimedia Outlets

- (4) front and (3) slim Elite™ bezel openings
- Front loading bezels can be custom configured with ICC modular connectors for voice, data, audio, video, and additional fiber optic connectivity
- Easy system administration with use of enclosed icons
- Works with Elite™ and slim bezels



IC108CE1V

JENNE PART NUMBER:

IC108WBDxx¹ 7-Port, Double Gang, Cover & Base

¹xx denotes color = GY-Gray, IV-Ivory, WH-White

Slim Bezels | Fiber Optic

- Provides (2) or (4) fiber ports per adapter
- Dust caps included
- Compatible with IC108WB multimedia outlets

JENNE PART NUMBER:

ICFOBWTBxx¹ ST/ST, Duplex, Metal Sleeve

ICFOBWCBxx¹ SC/SC, Duplex, Metal Sleeve

ICFOBWLxx¹ LC/LC, Duplex (SFF), Metal Sleeve

ICFOBWMBxx¹ MT-RJ/MT-RJ, Duplex (SFF)

¹xx denotes color = GY-Gray, IV-Ivory, WH-White



ICFOBWTBIV



ICFOBWLBGY



ICFOBWCBGY



ICFOBWMBWH

MUTOA | Elite™ Multimedia Boxes

- (1) front and (6) side Elite bezel openings
- Rear cable entry
- Compatible with standard NEMA single or double gang electric boxes
- Works with Elite™ bezels
- Compatible with ICRW11, ICRW12, ICRW13 raceway systems

JENNE PART NUMBER:

IC108MMBxx¹ 7-Port, Multimedia Box, Cover & Base

¹xx denotes color = GY-Gray, IV-Ivory, WH-White




IC108MMBWH

Elite™ Faceplates & Bezels

Customize with Elite Faceplates

ICC's Elite faceplates can be customized with a wide selection of bezels with integrated or configurable connectors.

- Cost-effective design to provide ease of installation
- Compatible with ICC Elite Bezels, modular connectors and couplers
- Seamless integration between copper and fiber applications
- Easy system administration with color icons and station ID's
- Complete multimedia wall outlet solution from one source

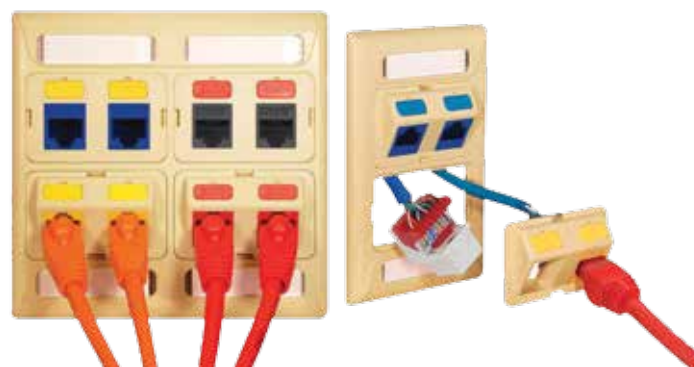

Single & Double Gang | Elite™ Faceplates

- Configured to fit standard single or double gang outlet box
- Station ID labels
- Front loading bezel
- Hidden mounting screws
- Works with Elite™ bezels

JENNE PART NUMBER:

IC108F01xx¹ 1-Bezel Opening, Single Gang

IC108F02xx¹ 2-Bezel Opening, Single Gang

IC108FD4xx¹ 4-Bezel Opening, Double Gang

¹xx denotes color = IV-Ivory, WH-White



IC108F01IV



IC108F02IV



IC108FD4WH



WORK AREA OUTLETS - ELITE™ FACEPLATES & BEZELS

Flat & Angled | Elite Bezels

- Angled design helps cable bend radius
- Icons included, color or special icons available
- Compatible with ICC modular connectors for voice, data, audio, video and fiber connectivity
- Works with Elite™ multimedia boxes and outlets



IC108BFBIV



IC108BF2IV

JENNE PART NUMBER:

IC108BFBxx¹	Blank, Flat
IC108BF1xx¹	1-Port, Flat
IC108BF2xx¹	2-Port, Flat
IC108BA1xx¹	1-Port, Angled
IC108BA2xx¹	2-Port, Angled

¹xx denotes color = IV-Ivory, WH-White



IC108BF1WH



IC108BA1WH

Fiber Optic Multimode | Elite™ Bezels

- Provides routing for up to (2) fiber ports
- Works with Elite™ multimedia boxes and outlets
- Metal sleeves

JENNE PART NUMBER:

IC108BFTxx¹	(2) ST/ST Simplex, Flat
IC108BFCxx¹	SC/SC Duplex, Flat
IC108BACxx¹	SC/SC Duplex, Angled
IC108BFDxx¹	(2) SC/SC Duplex, Flat
IC108BFRxx¹	SC/ST Duplex, Flat

¹xx denotes color = IV-Ivory, WH-White



IC108BFTIV



IC108BFDWH



IC108BACIV



IC108BFRWH

Surface Mount Boxes

Classic | Configurable Surface Mount Boxes

- Configurable with ICC modular connectors
- Multiple mounting options with adhesive backings and screws
- Port labeling area for identification

JENNE PART NUMBER:

IC107SB1xx¹	1-Port Box
IC107SB2xx¹	2-Port Box
IC107SB4xx²	4-Port Box
IC107SB6xx²	6-Port Box
IC107BC1xx²	1-Port Box, 25 pack
IC107BC2xx²	2-Port Box, 25 Pack

¹xx denotes color = GY-Gray, IV-Ivory, WH-White, BK-Black

²xx denotes color = IV-Ivory, WH-White



IC107SB1WH



IC107SB4WH



IC107SB2WH



IC107SB6WH

12-Port | Configurable Surface Mount Boxes

- Configurable with ICC modular connectors
- Multiple mounting options including adhesive backings and screws
- ID window and port labeling area for identification
- Used with ICRW11 and ICRW12 raceway systems

JENNE PART NUMBER:

IC107SBTxx¹	12-Port Box
-------------------------------	-------------

¹xx denotes color = IV-Ivory, WH-White, BK-Black



IC107SBTIV

Surface Mount Boxes

Elite | Configurable Surface Mount Boxes

- Configurable with ICC modular connectors
- Multiple mounting options including adhesive backings and screws
- Icons included, color and special icons sold separately
- Used with ICRW11 and ICRW12 raceway systems

JENNE PART NUMBER:

IC108SB1xx¹	1-Port Box
IC108SB2xx¹	2-Port Box
IC108SB4xx¹	4-Port Box
IC108SB6xx¹	6-Port Box

¹xx denotes color = GY-Gray, IV-Ivory, WH-White



IC108SB1IV



IC108SB4WH



IC108SB2IV



IC108SB6IV

Mounting Boxes

- Compatible with ICC faceplates
- Same size as standard single and double NEMA electrical boxes
- Used with ICRW11, ICRW12, and ICRW13 raceway systems


JENNE PART NUMBER:

IC107MRSxx¹	Single Gang (1.89" Depth)
IC107MRDxx¹	Double Gang (1.89" Depth)
IC250MBSxx¹	Single Gang, Slim design (0.92" Depth)

¹xx denotes color = IV-Ivory, WH-White



IC107MRSWH

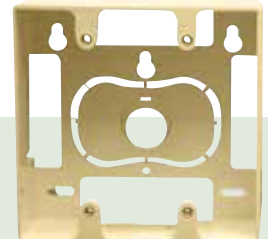

IC107MRDIV

Junction Boxes

- Compatible with ICC faceplates
- Integrated internal routing posts and cable management system
- Rear cable entry for clean external appearance
- Same size as standard single and double NEMA electrical boxes
- Used with ICRW11, ICRW12, and ICRW13 raceway systems

JENNE PART NUMBER:

ICACSMBSxx¹	Single Gang, 2-Piece Design (1.89" Depth)
ICACSMBDxx¹	Double Gang, 2-Piece Design (1.89" Depth)

¹xx denotes color = IV-Ivory, WH-White



ICACSMBSIV



ICACSMBDWH

Mobile Patch Boxes

MOBILE PATCH BOXES ARE GREAT FOR USE IN MANY AREAS!

- Warehouses & Industrial Areas • Trade Shows • Small Offices • Classrooms

Configurable | Mobile Patch Box

- Field configurable with IC107 modular connectors
- Multiple mounting options
- Includes dust cover for data port opening
- Designed with station ID's
- Rugged construction for durability

JENNE PART NUMBER:

IC107MB6BK	6-Port, Unloaded
-------------------	------------------



IC107MB6BK

CAT 6 & CAT 5e | Mobile Patch Box

- Exceeds ANSI/TIA-568 CAT 6 and CAT 5e standards
- PCB module, 110-Type IDC terminations
- Universal T568A and T568B wiring
- Compact design allows for quick and easy installations
- Ideal for: under floor, mobile and multi-user work areas
- Suitable for use with 4-Pair UTP solid cables
- Rugged construction for durability

JENNE PART NUMBER:

ICMPMB606	6-Port, RJ-45, Loaded, CAT 6
ICMPMB506	6-Port, RJ-45, Loaded, CAT 5e



ICMPMB606



PATCH PANELS & CROSS-CONNECT

CAT 6A 10G Unshielded Twisted Pair (UTP) Patch Panel

- Permanent Link performance tested up to 7.3dB headroom at 500 MHz
- Panel comes with 24 CAT 6A UTP HD style black modular connectors
- Fits standard 19" EIA rack mount widths

JENNE PART NUMBER:

ICMPP246AU 24-Port CAT 6A UTP patch panel, 1 RMS




CAT 6A 10G Foiled Twisted Pair (FTP) Patch Panel

- Permanent Link performance tested up to 2.8dB headroom at 500 MHz
- FTP provides excellent protection against EMI/RFI interferences
- Panel comes with 24 CAT 6A FTP HD style modular connectors
- Pre-installed grounding studs
- Fits standard 19" EIA rack mount widths

JENNE PART NUMBER:

ICMPP246AS 24-Port CAT 6A FTP patch panel, 1 RMS

ICACSGK6AS Grounding wire, 18 AWG, 7" length, **10 pcs.**

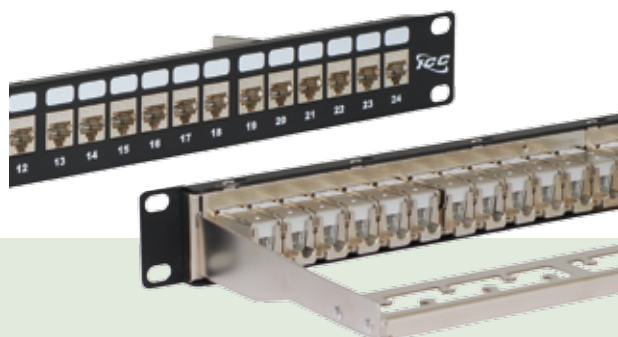

CAT 6, CAT 5e, Voice Patch Panels

- Exceeds TIA performance standard
- Rear 110-Type IDC termination
- Front write-on labeling area or optional color icons for identification
- Cable tie mounts for cable management
- 19" EIA rack mount width

JENNE PART NUMBER:

ICMPP02460 24-Port, RJ-45, 110-Type, T568A/B Wiring, 1 RMS, CAT 6

ICMPP04860 48-Port, RJ-45, 110-Type, T568A/B Wiring, 2 RMS, CAT 6


ICMPP0245E 24-Port, RJ-45, 110-Type, T568A/B Wiring, 1 RMS, CAT 5e

ICMPP0485E 48-Port, RJ-45, 110-Type, T568A/B Wiring, 2 RMS, CAT 5e

ICMPP024U6 24-Port, RJ-11, 110-Type, USOC Wiring, 1 RMS, Voice

ICMPP048U6 48-Port, RJ-11, 110-Type, USOC Wiring, 2 RMS, Voice

1 RMS (Rack Mount Space) = 1.75"

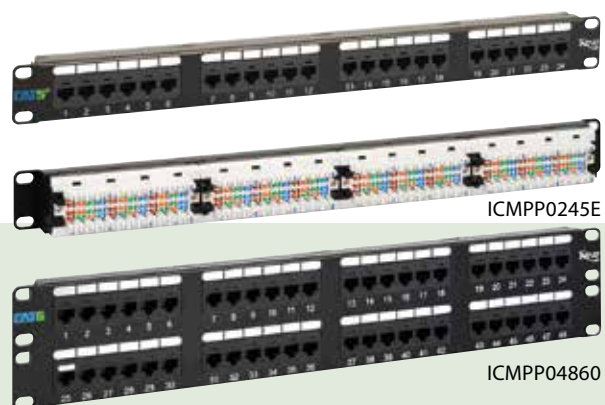

CAT 6, CAT 5e, Voice Vertical Patch Panels

- Exceeds TIA performance standard
- Rear 110-Type IDC termination
- Cable tie mounts for cable management
- Wall mountable, measures (10" H x 3.30" W x 2.40" D)
- Includes removable 89D universal mounting bracket

JENNE PART NUMBER:

ICMPP12V60 12-Port, RJ-45, 110-Type, T568A/B Wiring, CAT 6

ICMPP12V5E 12-Port, RJ-45, 110-Type, T568A/B Wiring, CAT 5e

ICMPP012U6 12-Port, RJ-11, 110-Type, USOC Wiring, Voice



CAT 6 and CAT 5e Front Access Zero-U Patch Panels

- Two-piece design; patch panel with removable cover
- Front access 110-Type IDC terminations
- Designed to mount on walls and distribution racks, uses no rack space

JENNE PART NUMBER:

ICMPP12F6E CAT 6, 12-Ports, 8P8C, front access

ICMPP12F5E CAT 5e, 12-Ports, 8P8C, front access



Blank Patch Panel Solutions


Configurable High Density Blank Patch Panel

- Panel is configurable with HD style modular connectors

JENNE PART NUMBER:

IC107BP481 48-Ports blank, 1 RMS

1 RMS (Rack Mount Space) = 1.75"

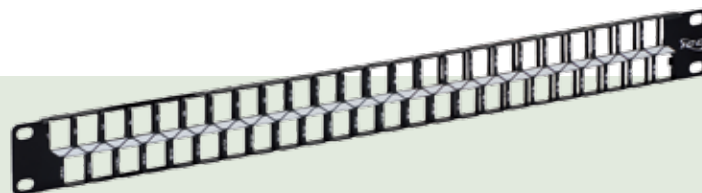


Configurable CAT 6A UTP Blank Patch Panel

- Panel is configurable with CAT 6A UTP modular connectors

JENNE PART NUMBER:

IC107PPU6A 24-Ports blank, 1 RMS

1 RMS (Rack Mount Space) = 1.75"

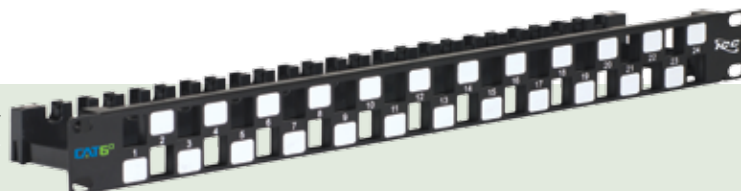


Configurable CAT 6A FTP Blank Patch Panel

- Panel is configurable with CAT 6A FTP modular connectors

JENNE PART NUMBER:

IC107PPS6A 24-Ports blank, 1 RMS

1 RMS (Rack Mount Space) = 1.75"

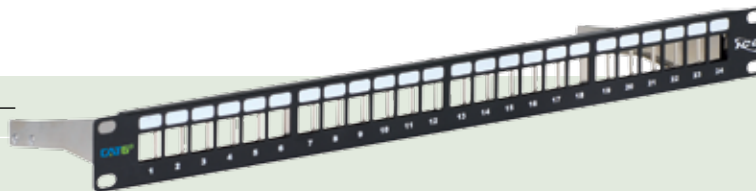

Configurable High Density Blank Patch Panel


- Panel is configurable with HD style modular connectors

JENNE PART NUMBER:

IC107BP241 24-Ports blank, 1 RMS

IC107BP482 48-Ports blank, 2 RMS

1 RMS (Rack Mount Space) = 1.75"

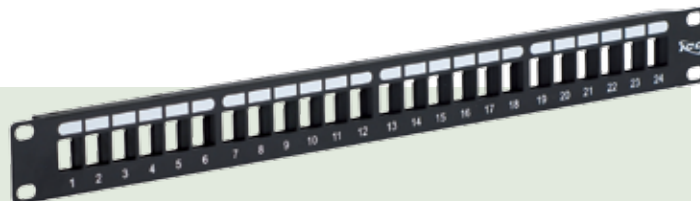


Configurable Blank Patch Panel

- Panel is configurable with EZ style modular connectors

JENNE PART NUMBER:

IC107BE241 24-Ports blank, 1 RMS

1 RMS (Rack Mount Space) = 1.75"

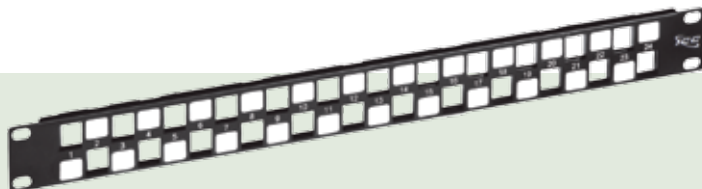

Multimedia Flush Mount | Vertical Blank Patch Panels

- Customize with ICC modular connectors
- Wall mountable and measures (10" H x 3.30" W x 2.80" D)
- Includes removable 89D mounting bracket

JENNE PART NUMBER:

IC107BP12V 12-Port, Configurable (HD Only)

IC107BP8VB 8-Port, Configurable, Flush Mount Style (EZ)



IC107BP12V



IC107BP8VB




PATCH PANELS & CROSS-CONNECT

Feed-Through Patch Panels

- CAT 6 or CAT 5e modular couplers pre-installed
- 19" EIA rack mount width

JENNE PART NUMBER:

ICMPP48C61	48-Ports, CAT 6, 8P8C, 1 RMS
ICMPP48C51	48-Ports, CAT 5e, 8P8C, 1 RMS
ICMPP24CP6	24-Ports, CAT 6, 8P8C, 1 RMS
ICMPP48CP6	48-Ports, CAT 6, 8P8C, 2 RMS
ICMPP24CP5	24-Ports, CAT 5e, 8P8C, 1 RMS
ICMPP48CP5	48-Ports, CAT 5e, 8P8C, 2 RMS

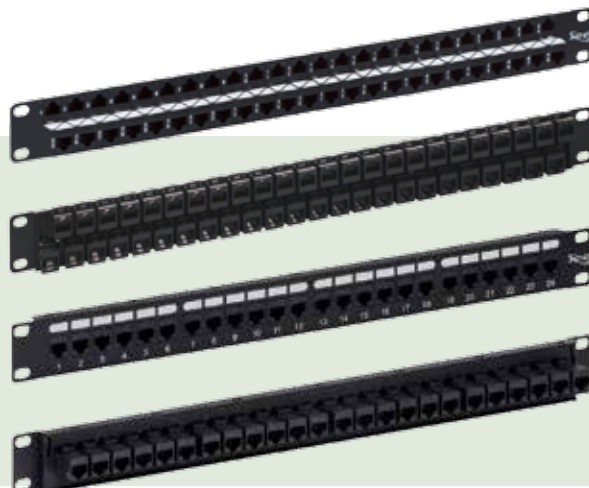

Voice Grade CAT 3 | Telco Patch Panels

- Use 25-Pair Telco cable for quick installation
- 19" EIA rack mount width

JENNE PART NUMBER:

ICMPP24T2C	24-Port, RJ-45, 8P2C, 1 RMS, 1 Male Telco Connector
ICMPP48T2C	48-Port, RJ-45, 8P2C, 2 RMS, 2 Male Telco Connectors
ICMPP24TF2	24-Port, RJ-45, 8P2C, 1 RMS, 1 Female Telco Connector
ICMPP48TF2	48-Port, RJ-45, 8P2C, 2 RMS, 2 Female Telco Connectors
ICMPP24T4C	24-Port, RJ-45, 8P4C, 1 RMS, 1 Male Telco Connector
ICMPP48T4C	48-Port, RJ-45, 8P4C, 2 RMS 2 Male Telco Connectors
ICMPP24TF4	24-Port, RJ-45, 8P4C, 1 RMS, 1 Female Telco Connector
ICMPP48TF4	48-Port, RJ-45, 8P4C, 2 RMS 2 Female Telco Connectors
ICMPP024T2	24-Port, RJ-11, 6P2C, 1 RMS, 1 Male Telco Connector
ICMPP048T2	48-Port, RJ-11, 6P2C, 2 RMS, 2 Male Telco Connectors
ICMPPTF242	24-Port, RJ-11, 6P2C, 1 RMS, 1 Female Telco Connector
ICMPPTF482	48-Port, RJ-11, 6P2C, 2 RMS, 2 Female Telco Connectors
ICMPP024T4	24-Port, RJ-11, 6P4C, 1 RMS, 2 Male Telco Connectors
ICMPP048T4	48-Port, RJ-11, 6P4C, 2 RMS, 4 Male Telco Connectors
ICMPPTF244	24-Port, RJ-11, 6P4C, 1 RMS, 2 Female Telco Connectors
ICMPPTF484	48-Port, RJ-11, 6P4C, 2 RMS, 4 Female Telco Connectors

1 RMS (Rack Mount Space) = 1.75"



ICMPP48T2C

Blank Panels

- Fills empty spaces between mounted equipment

JENNE PART NUMBER:

ICCMSCMPB1	1.75"H x 19"W, 1 RMS
ICCMSCMPB2	3.50"H x 19"W, 2 RMS
ICCMSCMPB3	5.25"H x 19"W, 3 RMS
ICCMSCMPB4	7.00"H x 19"W, 4 RMS
ICCMSCMPC1	Blank panel, 1.75" H x 19" W, 1 RMS, 12 pcs.
ICCMSCMPC2	Blank panel, 1.75" H x 19" W, 2 RMS, 12 pcs.
ICCMSCMPC3	Blank panel, 1.75" H x 19" W, 3 RMS, 6 pcs.
ICCMSCMPC4	Blank panel, 1.75" H x 19" W, 4 RMS, 6 pcs.

1 RMS (Rack Mount Space) = 1.75"



ICCMSCMPB2

Cable Management Bar

- Mountable on the back of 110-Type patch panel for rear cable support
- ABS plastic for durability

JENNE PART NUMBER:

ICMPP25CMB	Rear Cable Management Bar
-------------------	---------------------------



ICMPP25CMB


110 IDC Solutions

CAT 6 | 110 Wiring Kit

- Exceeds ANSI/TIA-568 Category 6 standards
- Includes 4-Pair connecting blocks, labels and holders

JENNE PART NUMBER:

IC110WK966 96-Pair Wiring Kit, CAT 6

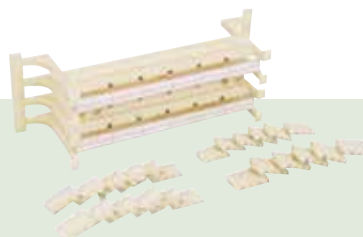

IC110WK966


With Feet | 110 Wiring Blocks

- Feet for rear cable management
- Includes labels and holders
- Compatible with optional 3-Pair, 4-Pair, and 5-Pair connecting blocks

JENNE PART NUMBER:

IC110WF100 100-Pair Base

IC110WF300 300-Pair Base

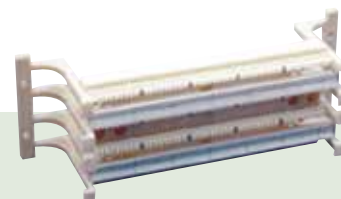

IC110WF100


Without Feet | 110 Wiring Blocks

- Includes labels and holders
- Compatible with optional 3-Pair, 4-Pair, and 5-Pair connecting blocks

JENNE PART NUMBER:

IC110NF100 100-Pair Base

IC110NF300 300-Pair Base

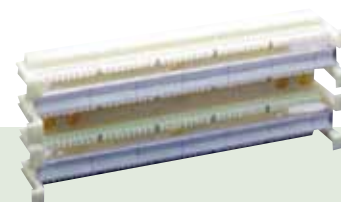


IC110NF100

Hinged | 110 Wiring Block

- Includes labels and holders
- Hinged for rear cable access
- Left and right cable management channels

JENNE PART NUMBER:

IC110WH100 100-Pair Base, Hinged

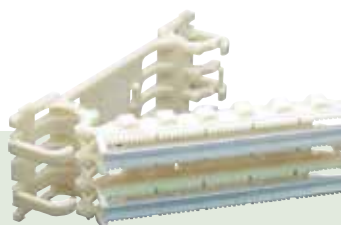

IC110WH100


Rack Mount | 110 Wiring Kit

- Exceeds ANSI/TIA-568 Category 6 standard
- Includes 4-Pair blocks, labels and holders
- 19" EIA rack mount width

JENNE PART NUMBER:

IC110PRK61 96-Pair, 1 RMS, CAT 6 Kit

1 RMS (Rack Mount Space) = 1.75"

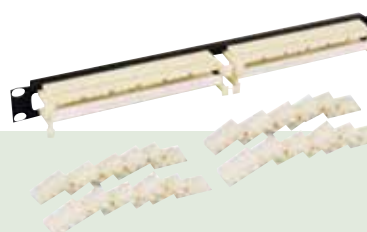

IC110PRK61

Rack Mount | 110 Wiring Blocks

- Compatible with optional 3-Pair, 4-Pair, and 5-Pair connecting blocks
- Rear cable entry
- 19" EIA rack mount width

JENNE PART NUMBER:

IC110RM100 100-Pair Base, 1 RMS

IC110RM200 200-Pair Base, 2 RMS

1 RMS (Rack Mount Space) = 1.75"



IC110RM200



PATCH PANELS & CROSS-CONNECT


110-Type IDC Solutions

CAT 5e | 110 Wiring Kits

- Exceeds ANSI/TIA-568 CAT 5e standards
- Includes 4-Pair connecting blocks, labels and holders

JENNE PART NUMBER:

IC110W1004	100-Pair Wiring Kit
IC110W3004	300-Pair Wiring Kit
IC110H1004	100-Pair Wiring Kit

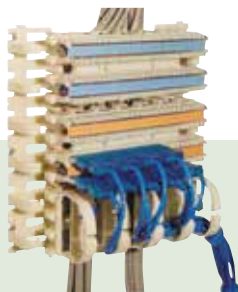

IC110H1004

110 Retention Caps

- Secure and protect terminated wires
- Works with patch panels
- 50 pcs/Pack

JENNE PART NUMBER:

IC110TC450	2-Pair, 110
-------------------	-------------



IC110TC450

110 Cable Management Block

- Organizes cables

JENNE PART NUMBER:

IC110CMBWF	With Feet
IC110CMBNF	Without Feet
IC110WHCMS	Hinged



IC110CMBWF



IC110WHCMS



IC110CMBNF

110 Connecting Blocks

- Supports Category 5e data • Color coded for easy termination

JENNE PART NUMBER:

IC110CB4PR	4-Pair, 10 pcs.
IC110CB5PR	5-Pair, 10 pcs.
IC110CB4PC	4-Pair, 100 pcs.
IC110CB5PC	5-Pair, 100 pcs.



IC110CB4PR



IC110CB5PR



IC110CB4PC

110 Patch Plugs

- Terminate with solid or stranded UTP cable

JENNE PART NUMBER:

ICMP1101PR	Terminates 1-Pair
ICMP1102PR	Terminates 2-Pair
ICMP1103PR	Terminates 3-Pair
ICMP1104PR	Terminates 4-Pair



ICMP1104PR

Cable Management Spools

- Retains and guides cables • 10 pcs/Pack

JENNE PART NUMBER:

ICACSWDS10	Spool Without Screw
ICACSWDS20	Spool With Screw



ICACSWDS10



ICACSWDS20

110 Cable Management Panel

- Organizes cables
- 19" EIA rack mount width

JENNE PART NUMBER:

IC110RMCMB	110 Cable Panel
-------------------	-----------------



IC110RMCMB

Label Holder

- Use with 110 wiring blocks
- Holds and protects labels

JENNE PART NUMBER:

IC110LHLDR	Label Holder, 6 pcs.
-------------------	----------------------



IC110LHLDR

66 Wiring Block and mounting brackets

66 Wiring Block, 50 Pair

- Wall mountable
- Made of high impact flame retardant material UL 94V-0


JENNE PART NUMBER:

A. IC066NB050	66 wiring block
IC066NBC50	66 wiring block, 25 pcs.

Mounting Brackets

JENNE PART NUMBER:

B. ICMB89B0WH	89B bracket, open rear, 10" H x 3.30" W x 1.90" D
ICMB89BCWH	89B mounting bracket, 25 pcs.
C. ICMB89D0WH	89D bracket, open front, 10" H x 3.30" W x 1.90" D
D. ICMB89U0WH	89U bracket, open front, 10" H x 3.30" W x 2.35" D

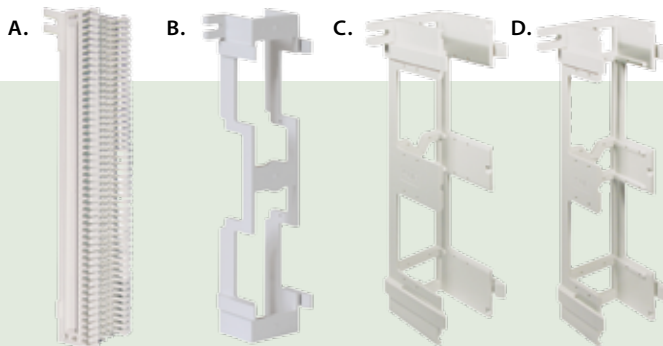

66 Wiring Block Solutions

Pre-Wired | 66 Wiring Blocks

- Pre-wired ports
- Integrated with 89D mounting bracket for wall mounting
- Includes removable hinged cover

JENNE PART NUMBER:

IC06626P4C	Pre-Wired 66 Block, (12) RJ-11 Ports
IC06628P8C	Pre-Wired 66 Block, (12) RJ-45 Ports
IC06686P6C	Pre-Wired 66 Block, (8) RJ-11 Ports



IC06626P4C

With Telco | 66 Wiring Blocks

- (1) or (2) pre-wired female Telco connectors (25/50-Pair)
- Velcro® security straps to maintain integrity of connections
- Integrated with 89D mounting bracket for wall mounting
- Includes removable hinged cover

JENNE PART NUMBER:

IC0665FT25	Pre-Terminated, Single Female Telco Connector
IC066DFT50	Pre-Terminated, Dual Female Telco Connectors



IC066DFT50

66 Wiring Block Cover

- Clear cover protects terminations
- Provides clean appearance
- Snaps on for convenience

JENNE PART NUMBER:

IC066CV050	66 Block Cover
-------------------	----------------




IC066CV050

66 Wiring Block Labeling Strips

- Slide-on strip secures terminated wires

JENNE PART NUMBER:

IC066LS050	Labeling Strips, 10 pcs
-------------------	-------------------------

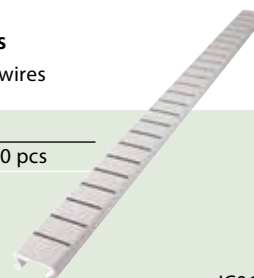

IC066LS050

89 Mounting Brackets

- For wall mounting
- Compatible with blank 66 wiring blocks

JENNE PART NUMBER:

ICMB89B0WH	89B Bracket
ICMB89D0WH	89D Bracket
ICMB89U0WH	89U Bracket



ICMB89B0WH

66 Wiring Block Bridging Clips

- Electrically interconnect adjacent terminals
- Tin plated phosphor bronze

JENNE PART NUMBER:

IC066BRCLP	Clip, 100 pcs/Pack
-------------------	--------------------



IC066BRCLP



Pre-terminated 66 wiring blocks

ICC's 66-Wiring Blocks are pre-terminated and factory tested saving precious termination time and hours of labor. Designed for wall installations, the 66-Wiring Block is pre-mounted on an 89D bracket. They include a hinged orange cover to protect terminations from dust and dirt.



Copper Solutions

CAT 6A UTP 650 MHz 10G Premise Cables

- Pair, 23 AWG, UTP, solid copper cable
- Designed with an X separator
- 0.34" outer diameter
- Packaged on a reel; 13.0" H x 17.3" W
- 1000 feet per reel (305 meters)

JENNE PART NUMBER:

ICCABP6Axx¹ 4-Pair, 23 AWG, UTP, Solid Copper Cable, CMP

ICCABR6Axx¹ 4-Pair, 23 AWG, UTP, Solid Copper Cable, CMR

¹xx denotes jacket color = BL-Blue, WH-White



CAT 6A FTP 650 MHz Premise Cables

- 4-Pair, 23 AWG, FTP, solid copper cable
- Shielded jacket protects from EMI and RFI noise
- Designed with an X separator
- 0.34" outer diameter
- Packaged on a reel; 13.0" H x 17.3" W
- 1000 feet per reel (305 meters)

JENNE PART NUMBER:

ICCABP6FBL 4-Pair, 23 AWG, FTP, Solid Copper Cable, CMP, Blue

ICCABR6FBL 4-Pair, 23 AWG, FTP, Solid Copper Cable, CMR, Blue



CAT 6e UTP 600 MHz Premise Cables

- 4-Pair, 23 AWG, UTP, solid copper cable
- Designed with an X separator
- 0.234" outer diameter
- Packaged in an EZ pull box; 15.55" H x 9.60" W x 15.75" D
- 1000 feet per box (305 meters)

JENNE PART NUMBER:

ICCABP6Exx¹ 4-Pair, 23 AWG, UTP, Solid Copper Cable, CMP

ICCABR6Exx¹ 4-Pair, 23 AWG, UTP, Solid Copper Cable, CMR

¹xx denotes jacket color = BL-Blue, WH-White



CAT 6 UTP 500 MHz Premise Cables

- 4-Pair, 23 AWG, UTP, solid copper cable
- 0.200" outer diameter
- Packaged in an EZ pull box; 15.50" H x 10.25" W x 15.50" D
- 1000 feet per box (305 meters)

JENNE PART NUMBER:

A. ICCABP6Vxx¹ 4-Pair, 23 AWG, UTP, Solid Copper Cable, CMP

B. ICCABR6Vxx¹ 4-Pair, 23 AWG, UTP, Solid Copper Cable, CMR

¹xx denotes jacket color = BL-Blue, WH-White, GY-Gray, YL-Yellow, GN-Green



B.



CAT 5e UTP 350 MHz Premise Cables


- 4-Pair, 24 AWG, UTP, solid copper cable
- 0.177" outer diameter
- Packaged in an EZ pull box; 14.37" H x 8.97" W x 14.56" D
- 1000 feet per box (305 meters)

JENNE PART NUMBER:

ICCABP5Exx¹ 4-Pair, 24 AWG, UTP, Solid Copper Cable, CMP

ICCABR5Exx¹ 4-Pair, 24 AWG, UTP, Solid Copper Cable, CMR

¹xx denotes jacket color = BL-Blue, WH-White, GY-Gray, YL-Yellow, GN-Green

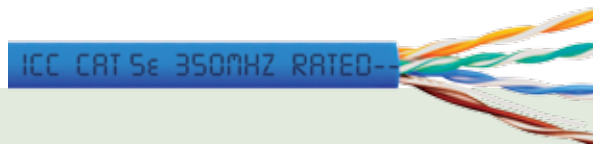

Wall Mountable Equipment

Hinged Wall Mount Brackets, 6" Depth

- Hinged for easy and quick rear access
- Large rear opening for cable entry
- Standard EIA-310-D hole pattern
- 0.2" wall mounting holes
- Steel construction for strength and durability



ICCMSHB4RS

JENNE PART NUMBER:

ICCMSHBVCVR	Optional Wall Mount Hinged Bracket Cover
ICCMSHB1RS	1.75"H x 19"W x 6"D, 1 RMS, 10 lbs. Capacity
ICCMSHB1RC	1.75"H x 19"W x 6"D, 1 RMS, 10 lbs. Capacity, 2 pcs.
ICCMSHB2RS	3.50"H x 19"W x 6"D, 2 RMS, 20 lbs. Capacity
ICCMSHB2RC	3.50"H x 19"W x 6"D, 2 RMS, 20 lbs. Capacity, 2 pcs.
ICCMSHB4RS	5.25"H x 19"W x 6"D, 4 RMS, 40 lbs. Capacity
ICCMSHB4RC	5.25"H x 19"W x 6"D, 4 RMS, 40 lbs. Capacity, 2 pcs.

1 RMS (Rack Mount Space) = 1.75"



Fixed Open Frame | Wall Mount Racks

- Self-squaring design for fast and easy installation
- Standard EIA-310-D hole pattern
- 0.25" wall mounting holes
- Steel construction for strength and durability
- 125 lbs. weight capacity



ICCMSWMR08

JENNE PART NUMBER:

ICCMSWMR08	17.75"H x 19.75"W x 18"D, 8 RMS
ICCMSWMR15	30.00"H x 19.75"W x 18"D, 15 RMS
ICCMSWMR30	56.25"H x 19.75"W x 18"D, 30 RMS

1 RMS (Rack Mount Space) = 1.75"



ICCMSWMR15

Vertical Hinged | Wall Mount Brackets

- Mounting rails tilt downward for easy access to rear equipment
- Large rear opening for cable entry
- Standard EIA-310-D hole pattern
- 0.25" wall mounting holes
- Steel construction for strength and durability




ICCMSVHB06

JENNE PART NUMBER:

ICCMSVHB06	12.75"H x 19.75"W x 12"D, 6 RMS, 40 lbs. Capacity
ICCMSVHB08	16.25"H x 19.75"W x 12"D, 8 RMS, 60 lbs. Capacity
ICCMSVHB18	16.25"H x 19.75"W x 18"D, 8 RMS, 60 lbs. Capacity

1 RMS (Rack Mount Space) = 1.75"

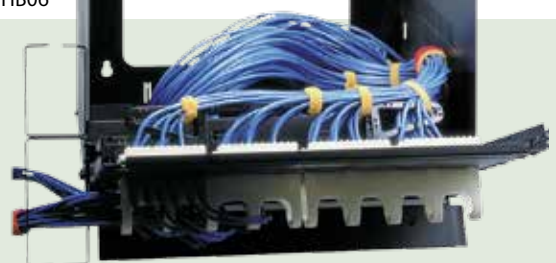

ICCMSVHB08

Wall Mountable Equipment


EZ-FOLD | Wall Mount Brackets

- Designed with heavy duty steel supporting up to 30 lbs. of equipment
- Hinged every 2 rack mount spaces for easy maintenance
- Available in 6" and 15" depths
- Cable tie anchors throughout for organizing cables
- Compatible with standard 19" width equipment and EIA-310-D hole pattern

JENNE PART NUMBER:

ICCMSABR62	19.30" L x 3.50" H x 6.00" D, 2 RMS, 30 lbs.Capacity
ICCMSABR64	19.30" L x 7.00" H x 6.00" D, 4 RMS, 30 lbs.Capacity
ICCMSABR66	19.30" L x 10.50" H x 6.00" D, 6 RMS, 30 lbs.Capacity
ICCMSABR68	19.30" L x 14.00" H x 6.00" D, 8 RMS, 30 lbs.Capacity
ICCMSABRS2	19.30" L x 3.50" H x 15.00" D, 2 RMS, 30 lbs.Capacity
ICCMSABRS4	19.30" L x 7.00" H x 15.00" D, 4 RMS, 30 lbs.Capacity
ICCMSABRS6	19.30" L x 10.50" H x 15.00" D, 6 RMS, 30 lbs.Capacity
ICCMSABRS8	19.30" L x 14.00" H x 15.00" D, 8 RMS, 30 lbs.Capacity
ICCMSHBCVR	6" Depth EZ-Fold Bracket Cover, Top Only
ICCMSABRSC	15" Depth EZ-Fold Bracket Cover, Top and Bottom

1 RMS (Rack Mount Space) = 1.75"

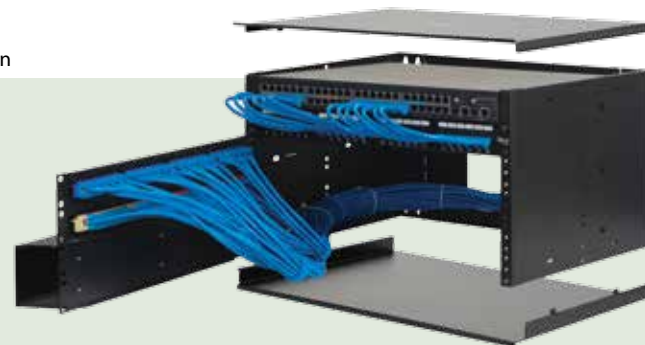

ICCMSABRS6

Swing Gate | Wall Mount Racks

- Swings open left or right for quick and easy access
- "Positive stop" locking mechanism, punch down while fully open
- Standard EIA-310-D hole pattern
- 0.25" wall mounting holes
- Steel construction for strength and durability
- 150 lbs. weight capacity

JENNE PART NUMBER:

ICCMSSSGR21	27"H x 20.5"W x 19"D, 12 RMS
ICCMSSSGR22	41"H x 20.5"W x 19"D, 20 RMS

1 RMS (Rack Mount Space) = 1.75"



ICCMSSSGR21



ICCMSSSGR22

Swing Gate | Wall Mount Racks

- Designed and manufactured with heavy duty steel.
- Can be assembled and installed in four easy steps.
- Supports up to 85 lbs. when properly mounted and fastened.
- Swing out feature allows for easy maintenance and upgrades.
- Rack can be installed to have the swing frame open left to right or vice versa

JENNE PART NUMBER:

ICCMSFFR12	19.50"L x 25.60"H x 18.00"D, 12 RMS, 85 lbs. Capacity
ICCMSFFR25	19.50"L x 49.125"H x 18.00"D, 25 RMS, 100 lbs. Capacity

1 RMS (Rack Mount Space) = 1.75"



ICCMSFFR12



ICCMSFFR25

Utility | Wall Mount Rack

- Suitable for areas where floor or wall space is limited
- Equipment mount in vertical orientation
- Standard EIA-310-D hole pattern
- 0.25" wall mounting holes
- Steel construction for strength and durability
- 75 lbs. weight capacity

JENNE PART NUMBER:

ICCMSWMUR5	Wall Mount Utility Rack, 5 RMS
-------------------	--------------------------------

1 RMS (Rack Mount Space) = 1.75"



ICCMSWMUR5

2-Post & 4-Post Racks



ICC's Rack Mount Numbering System Reduces Installation Time

Integrated RMU numbered markings on the rails of 2-post and 4-post distribution racks allow installers to identify individual mounting locations without the need to measure or count holes.

- Industry standard EIA-310-D RMUs at 1.75" intervals for consistent vertical alignment and spacing of equipment
- Allow users to see available or occupied spaces for future expansion
- Begin from the bottom to the top of rails for consistent positioning regardless of the rack height

2-Post Distribution Racks

- 19" EIA rack mount width
- Side rail holes for linking racks or vertical cable channels
- Supports up to 750 lbs. when properly loaded and floor anchored
- Lightweight aluminum construction
- Mounts to concrete floor with optional anchor kit

JENNE PART NUMBER:

ICCMSR1984 7'H, 45 RMS

ICCMSR1972 6'H, 38 RMS

ICCMSRFLKT Optional anchor kit

1 RMS (Rack Mount Space) = 1.75"



4-Post Distribution Rack


- 19" EIA rack mount width
- Side rail holes for linking racks or vertical cable channels
- Adjustable depth from 27" minimum to 32" maximum
- Supports up to 1500 lbs. when properly loaded and anchored
- Lightweight aluminum construction
- Mounts to concrete floor with optional anchor kit

JENNE PART NUMBER:

ICCMSR4P84 7'H, 45 RMS

ICCMSRFLKT Optional anchor kit

1 RMS (Rack Mount Space) = 1.75"

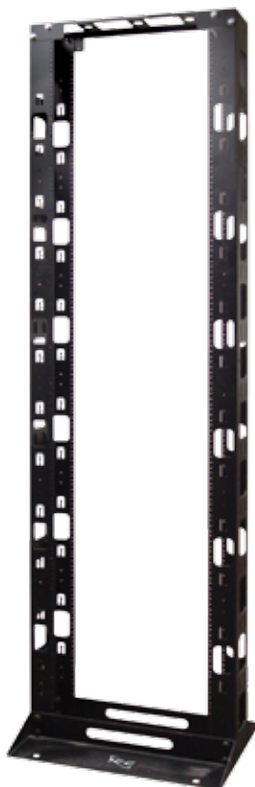

Cable Management Rack

- 19" EIA rack mount width
- Side rail holes for linking racks or vertical cable channels
- Integrated 6" cable channels along both sides of rails
- Supports up to 1000 lbs. when properly loaded and anchored
- Mounts to concrete floor with optional anchor kit

JENNE PART NUMBER:

ICCMSMRH7 7'H, 44 RMS

ICCMSRFLKT Optional anchor kit

1 RMS (Rack Mount Space) = 1.75"

Vertical Cable Channel

- Lightweight and sturdy aluminum construction
- Joins two 2-Post or 4-Post distribution racks together
- Front swivel latches and large rear openings for easy cable routing

JENNE PART NUMBER:

ICCMSCC6BK 6.5' H x 6" W x 6" D Channel



Vertical Cable Channel

- Conceals cables
- (2) pieces required to cover ICCMSCC6BK
- 1 pc/Pack

JENNE PART NUMBER:

ICCMSCCVBK 3'H, Cover


ICCMSCC6BK

Horizontal Cable Managers

Metal Ring and Interbay Panels

JENNE PART NUMBER:

A. ICCMSCMPK1	Ring panel and cover, 1.75" H x 19" W x 3" D, 1 RMS
B. ICCMSCMPK2	Ring panel and cover, 3.50" H x 19" W x 3" D, 2 RMS
C. ICCMSCMP31	Ring panel, 1.75" H x 19" W x 2.83" D, 1 RMS
D. ICCMSCMP32	Ring panel, 3.50" H x 19" W x 2.83" D, 2 RMS
E. ICCMSCMP51	Interbay panel, 1.75" H x 19" W x 3" D, 1 RMS
F. ICCMSCMP52	Interbay panel, 3.50" H x 19" W x 3" D, 2 RMS

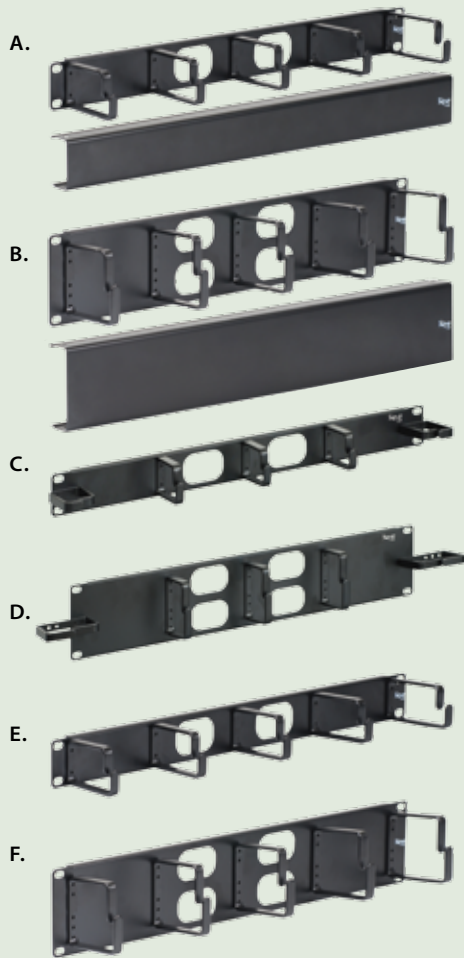


Plastic Ring and Interbay Panels with Covers

JENNE PART NUMBER:

A. ICCMSCMA51	1.75" H x 19" W, 1 RMS, horizontal routing only
B. ICCMSCMA52	3.5" H x 19" W, 2 RMS, horizontal routing only
C. ICCMSCMA31	1.75" H x 19" W, 1 RMS
D. ICCMSCMA32	3.5" H x 19" W, 2 RMS

1 RMS (Rack Mount Space) = 1.75"

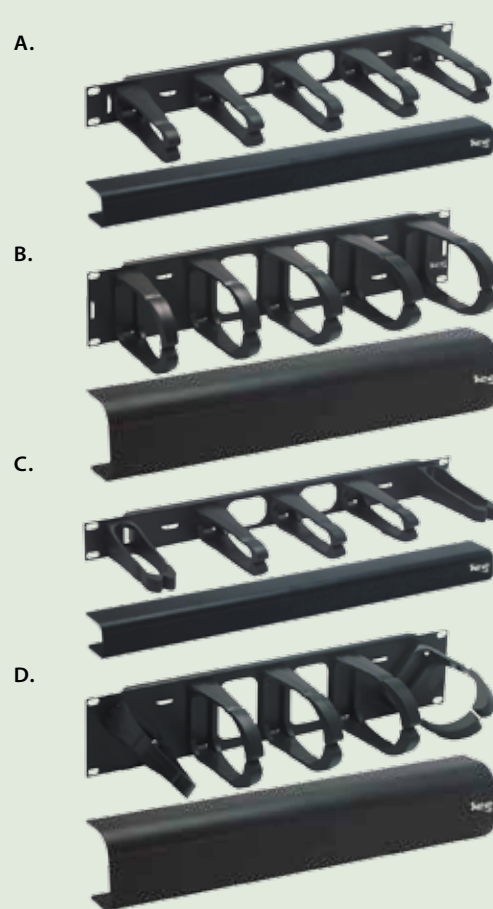

Plastic Rings

- Single or double sided rings

JENNE PART NUMBER:

ICCMSCMPR5	1.25" Single, Vertical
ICCMSCMPR6	1.25" Single, Horizontal
ICCMSCMPR7	3" Single, Universal
ICCMSCMPR8	3" Double, Vertical
ICCMSCMPR9	3" Double, Horizontal



Extended Bracket Panels

- Provides cable support in front or back of patch panels
- No extra RMS needed



JENNE PART NUMBER:


ICCMSFCMRP	Front, 3" Deep
ICCMSRCMRP	Rear, 5" Deep

1 RMS (Rack Mount Space) = 1.75"

Metal Rings

JENNE PART NUMBER:

ICCMSCMPR1	1.70" Single, Vertical
ICCMSCMPT1	1.70" Single, Vertical, 10 pcs.
ICCMSCMPR2	3" Single, Vertical
ICCMSCMPT2	3" Single, Vertical, 10 pcs.
ICCMSCMPR3	3", Double, Vertical
ICCMSCMPR4	6", Double, Vertical

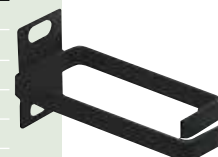

Brackets & panels

"L" Bracket | Panel

- Mounts to any EIA compliant hole spacing for custom vertical or horizontal cable management

JENNE PART NUMBER:

ICCMSCMPL1 Cable Management Bracket, 6"W x 0.95"H

ICCMSCMPLC Cable Management Bracket, 6"W x 0.95"H, **25 pcs.**



ICCMSCMPL1

Blank | Panels

- Fills empty spaces between mounted equipment
- Steel construction for durability

JENNE PART NUMBER:

ICCMSCMPB1 1.75"H x 19"W, 1 RMS

ICCMSCMPB2 3.50"H x 19"W, 2 RMS

ICCMSCMPB3 5.25"H x 19"W, 3 RMS

1 RMS (Rack Mount Space) = 1.75"



ICCMSCMPB2

Shelves



Rack Shelves

ICC offers a wide selection of rack shelves.

- Manufactured from durable steel
- Designed to support bulky equipment
- Vented rack shelves are designed to provide air flow to ventilate mounted equipment
- Deep rack shelves are designed to support heavier load capacities and provide support for both the front and rear of the distribution rack
- ICC's product line of rack shelves are specially designed to exceed the practical weight requirements of any communications closet

10" & 15" Rack Shelf

- Steel construction for durability
- 19" EIA rack mount width
- Standard EIA-310-D hole pattern
- Weight capacity of 75 lbs

JENNE PART NUMBER:

ICCMSRSF10 10", 2 RMS

ICCMSRSFC1 10", 2 RMS, **2 pcs.**

ICCMSRSF15 15", 3 RMS

ICCMSRSFC2 15", 3 RMS, **2 pcs.**

1 RMS (Rack Mount Space) = 1.75"



ICCMSRSF10



ICCMSRSF15

10" & 15" Vented Rack Shelf


- Steel construction for durability
- Vented bottom
- 19" EIA rack mount width
- Standard EIA-310-D hole pattern
- Weight capacity of 50 lbs

JENNE PART NUMBER:


ICCMSRSV10 10", 2 RMS

ICCMSRSV15 15", 3 RMS

1 RMS (Rack Mount Space) = 1.75"

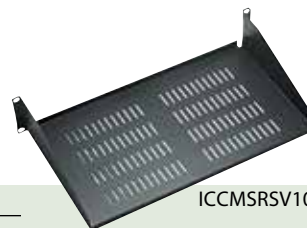

ICCMSRSV10

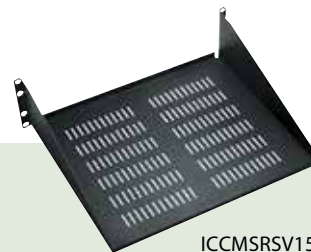

ICCMSRSV15

20" Rack Shelf & 20" Vented Rack Shelf

- Steel construction for durability • Double-sided center mount style
- 19" EIA rack mount width • Standard EIA-310-D hole pattern
- Works with 2-Post racks only (ICCMSR19xx)

JENNE PART NUMBER:

ICCMSRDS20 20", 2 RMS, Weight capacity of 125 lbs

ICCMSRDV20 20", 2 RMS, Vented bottom

1 RMS (Rack Mount Space) = 1.75"



ICCMSRDS20



ICCMSRDV20

Every effort has been made to ensure the integrity of this catalog. Jenne, Inc. cannot be held responsible for any misrepresentation associated with any products due to omissions, typographic errors or misprints.



Shelves

4-Post Rack Shelves

ICC compliments its 7' 4-Post distribution rack with two rack shelves, a vented bottom fixed shelf, and solid bottom adjustable shelf.

These heavy duty shelves are designed to place heavy equipments; such as large servers, UPS, and computer networking equipments.

- ICC's Vented Bottom Fixed Shelf measures a maximum depth of 32" from front to rear. It is designed to provide air flow to ventilate equipment underneath and is compliant with the EIA-310-D standard
- ICC's Solid Bottom Adjustable Shelf measures 27" from front to rear. It is designed to be adjusted up to 32" to meet your depth requirement changes and is compliant with the EIA-310-D standard



ICCMSRAS30

4-Post Rack Shelves

- Steel construction for durability
- 19" EIA rack mount width
- Standard EIA-310-D hole pattern
- Weight capacity of 125 lbs.

JENNE PART NUMBER:

ICCMSRFV32	32", 2 RMS, Vented bottom
ICCMSRAS30	Adjustable 27-32", 2 RMS

1 RMS (Rack Mount Space) = 1.75"



30" Rack Shelf & 30" Vented Rack Shelf

- Steel construction for durability
- Double-sided center mount style
- 19" EIA rack mount width
- Standard EIA-310-D hole pattern
- Works with 2-Post racks only (ICCMSR19xx)

JENNE PART NUMBER:

ICCMSRDS30	30", 3 RMS, 125 lbs weight capacity
ICCMSRDV30	30", 3 RMS, Vented bottom, 100 lbs weight capacity

1 RMS (Rack Mount Space) = 1.75"



ICCMSRDS30



ICCMSRDV30

Sliding Keyboard Shelf

- Keyboard tray slides out an additional 10" and holds a full size keyboard
- Shelf space for monitor and mouse
- Weight capacity of 25 lbs

JENNE PART NUMBER:

ICCMSRKLST	10", 3 RMS
-------------------	------------

1 RMS (Rack Mount Space) = 1.75"



ICCMSRKLST

Heavy Duty Rack Shelf

- Steel construction for durability • Double-sided center mount style
- 19" EIA rack mount width • Standard EIA-310-D hole pattern
- Weight capacity of 250 lbs.

JENNE PART NUMBER:

ICCMSHDS20	20", 3 RMS
-------------------	------------

1 RMS (Rack Mount Space) = 1.75"



ICCMSHDS20

Keyboard Shelf

- Keyboard shelf with sliding mouse tray
- 19" EIA rack mount width
- 18.25" fully extended

JENNE PART NUMBER:

ICCMSRKSM T	10", 3 RMS
--------------------	------------

1 RMS (Rack Mount Space) = 1.75"



ICCMSRKSM T

Slotted Finger Duct Panels

Finger Duct Panels

ICC finger duct panels are designed to route and manage large numbers of patch cords and premise cables.

- Easy to install and maintain with slide-on covers for an organized appearance
- Flexible fingers offer installers an easy way to route and manage patch cords and cables



Tabs on Both Sides
(Center Mount)



Tabs on One Side
(Side Mount)



Flat Tabs on One Side
(Flat Mount)

Single | Vertical Finger Ducts

- Rear cable feed-through holes
- Compatible with ICC distribution racks
- 4"W x 5"D

JENNE PART NUMBER:

ICCMSCMA84	78" Front, Flat mount, brackets on one side
ICCMSCMA81	78" Front, Side mount, brackets on one side
ICCMSCMA21	35" Front, Side mount, brackets on one side

Sizes: (78"H x 4"W x 5"D) & (38"H x 4"W x 5"D)



ICCMSCMA81



ICCMSCMA21

Dual | Vertical Finger Ducts

- Rear cable feed-through holes
- Compatible with ICC distribution racks
- 4"W x 5"D

JENNE PART NUMBER:

ICCMSCMA83	78" Front & Rear, Side mount, brackets one side
ICCMSCMA82	78" Front & Rear, Center mount, brackets both sides
ICCMSCMA23	35" Front & Rear, Side mount, brackets one side
ICCMSCMA22	35" Front & Rear, Center mount, brackets both sides

Sizes: (78"H x 4"W x 5"D) & (38"H x 4"W x 5"D)



ICCMSCMA82



ICCMSCMA23


Single Horizontal Finger Ducts

- For front cable management
- Ideal for concealing copper and fiber patch cords

JENNE PART NUMBER:

ICCMSCMA41	Single-Sided, 1RMS, 1.58"H x 3.15"D (Front Only)
ICCMSCMA42	Single-Sided, 2 RMS, 3.15"H x 3.15"D (Front Only)

1 RMS (Rack Mount Space) = 1.75"

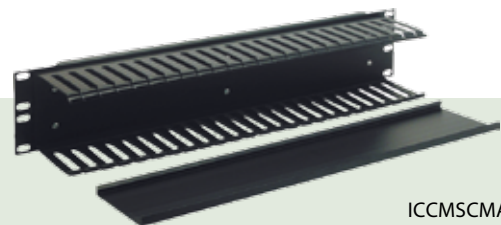

ICCMSCMA42

Dual Horizontal Finger Ducts

- For front and rear cable management

JENNE PART NUMBER:

ICCMSCMA61	Dual Ducts, 1 RMS, 1.58"H x 3.15"D Front, 1.58"H x 3.94"D Rear
ICCMSCMA62	Dual Ducts, 2 RMS, 3.15"H x 3.15"D Front, 3.15"H x 3.94"D Rear


1 RMS (Rack Mount Space) = 1.75"



ICCMSCMA62

Ladder Rack System

1.

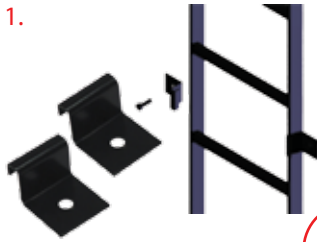


Wall Bracket

- Used to secure runway sections flat against the wall

JENNE PART NUMBER:
ICCMSLVWBK

2.

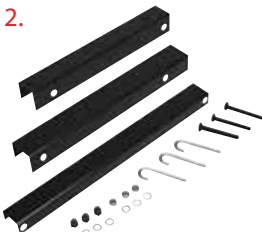

Wall Support Kit

- Forms a triangle wall mounting support after assembly which holds the ladder rack runway to the wall

JENNE PART NUMBER:
ICCMSLTWSK

3.




Radius Drop

- Designed to be attached to the rungs of ladder rack to maintain bend radius at drop points

JENNE PART NUMBER:
ICCMSLCRDK

4.

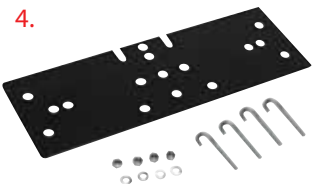

Relay Rack Bracket

- Designed to be mounted over 19" distribution and cable management racks

JENNE PART NUMBER:
ICCMSLRBBK

5.



Butt Splice Kit

- Joins ladder rack runway sections at ends

JENNE PART NUMBER:
ICCMSLEBSK

6.



End Caps

- Cover and protect runway ends
- Includes 2 each

JENNE PART NUMBER:
ICCMSLPECK

7.



Ladder Rack Runway

- Used to change horizontal running cable to vertical direction

JENNE PART NUMBER:
ICCMSLIR90 90° Inside Corner

8.



Ladder Rack Runway

- Used for a gradual sweeping bend

JENNE PART NUMBER:
ICCMSLFT90 90° Flat Turn


9.



Cable Post Kit

- Prevents cable from falling
- Includes 2 each

JENNE PART NUMBER:
ICCMSLCRPK

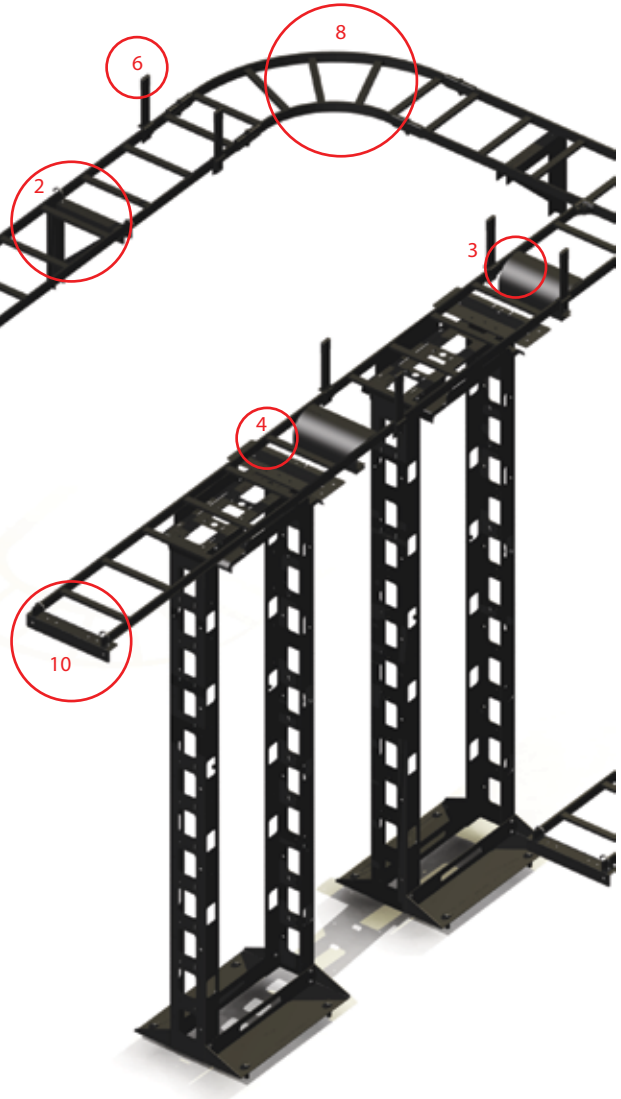

Ladder Rack System

ICC ladder rack system offers a complete set of cable installation, routing, and management components that are engineered for installation versatility.

- Designed with durable steel construction, black powder coated
- Provides strength and stability for long lasting use
- Designed to run cable overhead

10.



Wall Support Angle

- For wall mounting runway

JENNE PART NUMBER:

ICCMSLAWSK

11.




Ladder Rack Runway

- Used to change horizontal running cable to vertical direction

JENNE PART NUMBER:

ICCMSLOR90 90° Outside Corner

12.

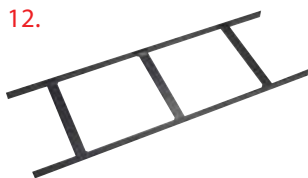

Ladder Rack Runway

- Supports horizontal running cable
- 1.5"H x 12.5"W, 9" rung spacing

JENNE PART NUMBER:

ICCMSLST05 5 Ft.

ICCMSLST10 10 Ft.

13.




Ceiling Rod Kit

- Designed to sustain over-hanging runway sections

JENNE PART NUMBER:

ICCMSLCMRK

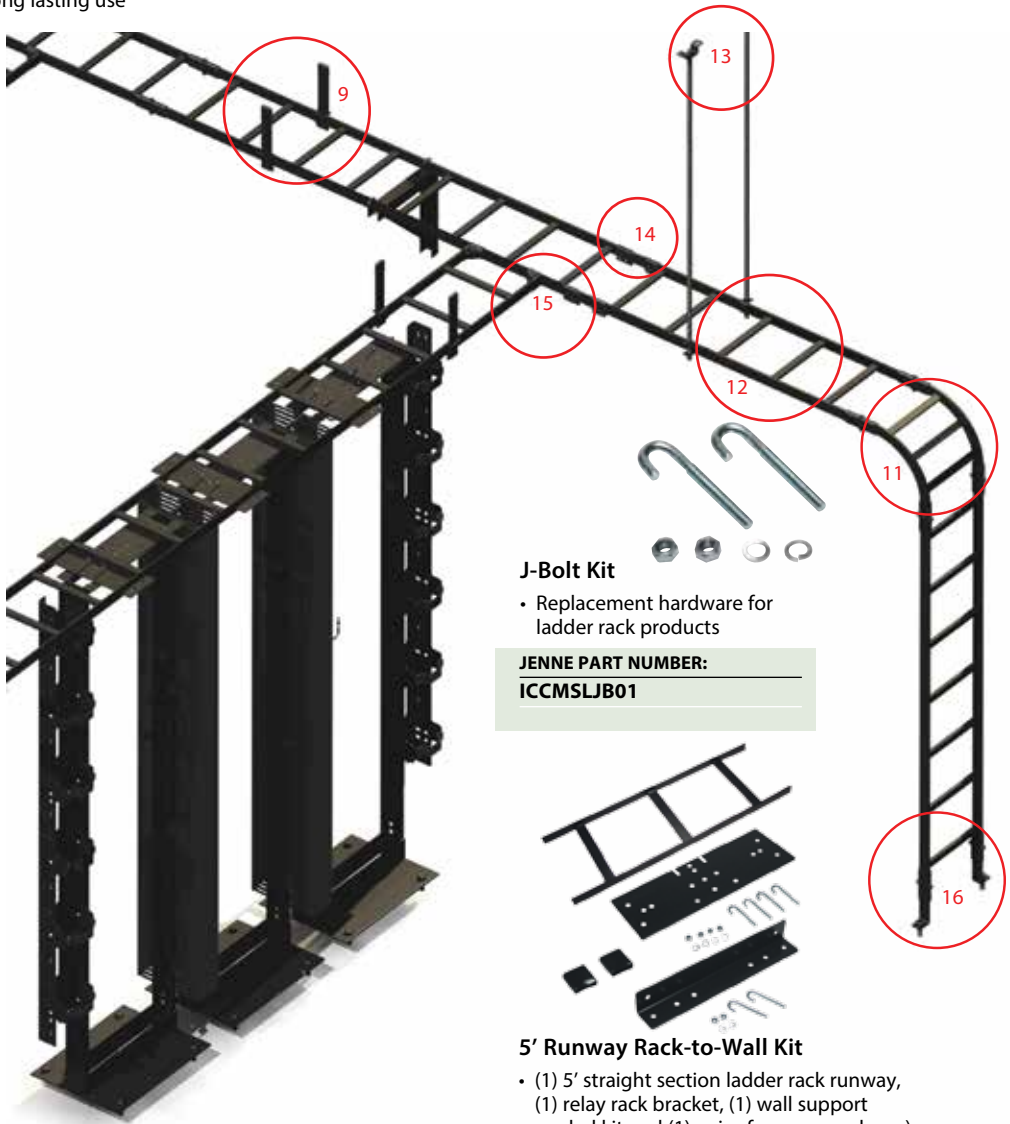

J-Bolt Kit

- Replacement hardware for ladder rack products

JENNE PART NUMBER:

ICCMSLJB01


5' Runway Rack-to-Wall Kit

- (1) 5' straight section ladder rack runway, (1) relay rack bracket, (1) wall support angled kit and (1) pair of runway end cap.)

JENNE PART NUMBER:

ICCMSLRW05

14.

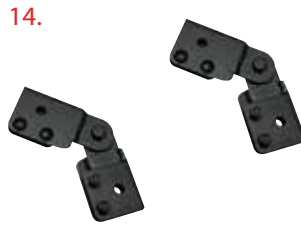

Swivel Butt Splice Kit

- Enables ends to be adjusted in various angles

JENNE PART NUMBER:

ICCMSLESSK

15.



Tee-Junction Splice Kit

- Used to fasten runway sections together in a tee intersection

JENNE PART NUMBER:

ICCMSLTJSK

16.



Floor Foot Kit

- Kit includes mounting feet and butt splice to secure runway to the floor

JENNE PART NUMBER:

ICCMSLMFFK



RACKS & CABLE MANAGEMENT

J-Hooks & Rack Accessories

Wall Mount | J-Hooks

- Secure cables with retaining clip
- Alternative solution to cable trays or ladder runway rack systems

JENNE PART NUMBER:

ICCMSJHK22	J-Hook, 3/4"
ICCMSJHK33	J-Hook, 1 5/16"
ICCMSJHK44	J-Hook, 2"
ICCMSJHK55	J-Hook, 4"




ICCMSJHK55

Ceiling Mount | J-Hooks

- Secure cables with retaining clip
- Alternative solution to cable trays or ladder runway rack systems

JENNE PART NUMBER:

ICCMSJH922	J-Hook, 3/4" 90°
ICCMSJH933	J-Hook, 1 5/16" 90°
ICCMSJH944	J-Hook, 2" 90°
ICCMSJH955	J-Hook, 4" 90°

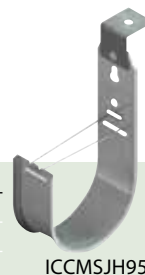

ICCMSJH955

4-Post Relay Rack Bracket

- Two sizes 1.25" and 2.50"
- Constructed of 12-Gauge steel
- Secure straight ladder runway over 4-Post rack



ICCMSL4PBK

JENNE PART NUMBER:

ICCMSL4PBK	4-Post Runway Kit
-------------------	-------------------

Rack Screws

- Secure equipment on racks and wall mount products



ICACSS01BK

JENNE PART NUMBER:

ICACSS01BK	#12-24 x 5/8" 25 Pk
-------------------	---------------------

Rack Floor Mount Kit

- Secure racks to concrete floors
- 1200 lbs. of load tension when properly installed
- Self expanding, no caulking required



ICCMSRFLKT

JENNE PART NUMBER:

ICCMSRFLKT	Mount Kit, Concrete
-------------------	---------------------

Grounding Kit

- Designed to terminate grounding cables to patch panels and racks
- Accepts 6~14 Gauge wires



ICACSGKS00

JENNE PART NUMBER:

ICACSGKS00	Grounding Kit
-------------------	---------------

Radius Management Unit

A slot mount design enables this unit to seat on the sides of racks and brackets. It may also be mounted directly to the wall.

- Designed to mount on the sides of racks and wall mount brackets
- Provide proper support for cable bend radius
- Used with ICCMS racks and brackets
- Can also be used on walls and in ceilings for overhead cable management



ICCMSRMU02

JENNE PART NUMBER:

ICCMSRMU02	Radius Control, 2 pcs.
ICCMSRMU1C	Radius Control, 20 pcs.

Conversion Brackets

ICC Rack Conversion Brackets are an ideal solution for mounting EIA 19" equipments such as patch panels, cable management panels and networking equipments onto 23" racks and cabinets.

- Convert 19" to fit 23" applications
- For use with patch panels
- Offset bracket design maintains flush mounting of panels



JENNE PART NUMBER:

ICCMSCBARM	19"- 23" 1 RMS, 2 pcs.
ICCMSCBARC	19"- 23" 1 RMS, 20 pcs.
ICCMSCBBRM	19"- 23" 2 RMS, 2 pcs.
ICCMSCBBRC	19"- 23" 2 RMS, 20 pcs.

1 RMS (Rack Mount Space) = 1.75"



ICCMSCBARM

Patch Cords

ICC Patch Cords

ICC has eight different colors patch cords to choose from.

ICC's component-rated RJ-45 molded boot patch cords are available in various lengths and colors. They are constructed with 4-Pair 24 AWG bare copper stranded wire and CMG/FT4 fire rated jackets. These cords are tested to the highest performance standards under TIA-568.

- UL listed, factory tested, 50 micro inch gold plated contacts
- Component-rated and exceeds ANSI/TIA-568 requirements
- Slim molded boots on CAT 6 and CAT 5e cords for high density applications



26 AWG | FTP 10G Patch Cords

- Exceeds ANSI/TIA-568 26 AWG standard
- Supports 10G bandwidth
- Shielded construction reduces EMI/RFI interference
- Flexible snag-free strain relief boots help maintain proper bend radius
- RJ-45 plugs with 50 micro inch gold plated contacts for best performance
- UL listed, factory tested and wired T568

JENNE PART NUMBER:

ICPCSGzzxx¹ 4-Pair, FTP, 24 AWG, Stranded Conductors

¹xx denotes color = BL-Blue, WH-White, YL-Yellow, BK-Black

²zz denotes length = 03, 05, 07, 10, 15 and 25 feet



ICPCSG03BL

CAT 6 | UTP Patch Cords

- Exceeds ANSI/TIA-568 Category 6 standard
- Slim boots fit narrow port spacing
- Flexible snag-free strain relief boots help maintain proper bend radius
- RJ-45 plugs with 50 Micro inch gold plated contacts for best performance
- UL listed, factory tested and wired T568

JENNE PART NUMBER:


ICPCSKzzxx¹ 4-Pair, UTP, 24 AWG, Stranded Conductors

ICPCSDzzBL² 4-Pair, UTP, 24 AWG, Stranded Conductors, 25 Pack

¹xx denotes color = BK-Black, BL-Blue, GN-Green, GY-Gray, OR-Orange, RD-Red, WH-White, YL-Yellow

²zz denotes length = 01, 03, 05, 07, 10, 14, 25 feet

²zz denotes length = 01, 03, 05, 07, 10 feet (BL-Blue)

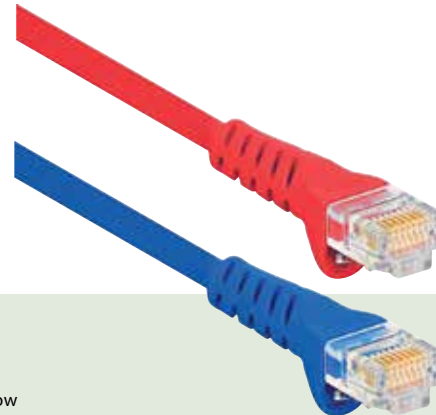

ICPCSK03RD

CAT 5e | UTP Patch Cords

- Exceeds ANSI/TIA-568 Category 5e standard
- Slim boots fit narrow port spacing
- Flexible snag-free strain relief boots help maintain proper bend radius
- RJ-45 plugs with 50 Micro inch gold plated contacts for best performance
- UL listed, factory tested and wired T568

JENNE PART NUMBER:


ICPCSJzzxx¹ 4-Pair, UTP, 24 AWG, Stranded Conductors

ICPCSCzzBL² 4-Pair, UTP, 24 AWG, Stranded Conductors, 25 Pack

¹xx denotes color = BK-Black, BL-Blue, GN-Green, GY-Gray, OR-Orange, RD-Red, WH-White, YL-Yellow

²zz denotes length = 01, 03, 05, 07, 10, 14, 25 feet

²zz denotes length = 01, 03, 05, 07, 10 feet (BL-Blue)

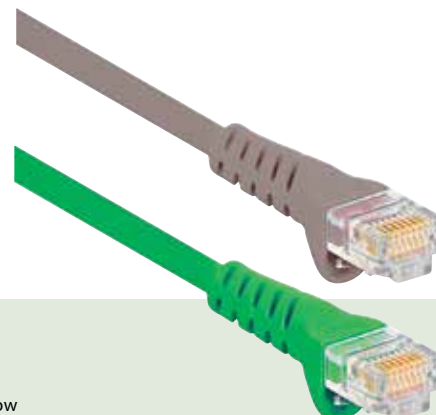

ICPCSJ03BL



CORDS & CABLE ASSEMBLIES

Patch Cords & Accessories

110 to RJ-45 CAT 6 and CAT 5e Patch Cords, T568B

- Terminated with 110 to RJ-45 patch plugs
- 4-Pair, 8P8C, wired to T568B
- Exceeds TIA-568 CAT 6 and CAT 5e performance standard

JENNE PART NUMBER:

ICPCSEzzBL¹	110-to-RJ-45 Plug, Wired T568B, 4-Pair, CAT 6
ICPCSBzzBL¹	110-to-RJ-45 Plug, Wired T568B, 4-Pair, CAT 5e

¹zz denotes length = 03, 07, 10 feet
color = BL-Blue



ICPCSE03BL

110 to 110 CAT 6 and CAT 5e Patch Cords, T568B

- Terminated with 110 to 110 patch plugs
- 4-Pair, 8P8C, wired to T568B
- Exceeds TIA-568 CAT 6 and CAT 5e performance standard

JENNE PART NUMBER:

ICPCSQzzBL¹	110-to-RJ-45 Plug, Wired T568B, 4-Pair, CAT 6
ICPCSRzzBL¹	110-to-RJ-45 Plug, Wired T568B, 4-Pair, CAT 5e

¹zz denotes length = 03, 07, 10 feet
color = BL-Blue



ICPCSQ03BL

CAT 3 | 25-Pair Telco Cables

- 90 degree style 50-Pin telco connectors
- 25-Pair 24 AWG (UTP) terminated with RJ-21 connectors
- Can be used as extension cables to simplify connections
- CMR rated PVC jacket
- Works with ICC telco patch panels and pre-wired telco 66 wiring blocks
- Category 3 performance rated

JENNE PART NUMBER:

ICPCSTMMzz¹	Male-to-Male, 25-Pair Cable Assembly
ICPCSTFFzz¹	Female-to-Female, 25-Pair Cable Assembly
ICPCSTFMzz¹	Female-to-Male, 25-Pair Cable Assembly

¹zz denotes length = 05, 10, 15, 25, 75, 00 (00 = 100) feet



ICPCSTMM05

Male/Female-to-Blunt | CAT 3 25-Pair Telco Cables

- 90 degree style 50-Pin telco connectors
- 25-Pair 24 AWG (UTP) terminated with RJ-21 connector
- CMR rated PVC jacket
- Works with ICC telco patch panels and pre-wired telco 66 wiring blocks
- Category 3 performance rated

JENNE PART NUMBER:

ICPCSTMBzz¹	Male-to-Blunt, 25-Pair Cable Assembly
ICPCSTFBzz¹	Female-to-Blunt, 25-Pair Cable Assembly

¹zz denotes length = 05, 10, 15, 25 feet



ICPCSTMB05

Telephone Line Cords

- 4-Conductor and 6-Conductor
- Designed for voice connectivity applications

JENNE PART NUMBER:

ICLC4zzFSV¹	Pin 2-5, 6P4C
ICLC6zzFSV¹	Pin 1-6, 6P6C

¹zz denotes length = 07, 14, 25 feet



ICLC407FSV


Plugs & Patch Cord Accessories

CAT 6 & CAT 5e RJ-45 Modular Plugs use a Loading Bar for Easier Insertion

Stranded vs. Solid

- Choose solid plugs for solid cables
- Choose stranded plugs for stranded cables
- Choose oval plugs for round cables
- Choose fl at plugs for fl at cables
- Always ensure that you identify the cable before selecting the appropriate plug

Factory terminated patch cords or cable assemblies are recommended for consistent channel compliance

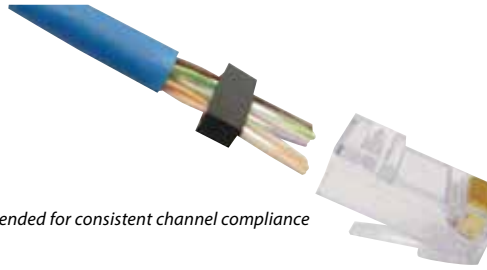

Each bag contains 100 plugs

Solid & Stranded | CAT 6

- Loading bar for easy insertion
- Accepts 24~26 AWG solid/stranded wires
- Oval cable entry

JENNE PART NUMBER:

ICMP8P8C6E	CAT 6
ICMP8P8C6S	CAT 6 Shielded



ICMP8P8C6E

Stranded | CAT 5e Plug

- Loading bar for easy insertion
- Accepts 24~26 AWG stranded wires
- Oval cable entry

JENNE PART NUMBER:

ICMP8P8C5E	CAT 5e
-------------------	--------



ICMP8P8C5E

Solid or Stranded | 8P8C Oval Plug

- Ideal for customizing cords for data or voice
- Accepts 24~28 AWG solid or stranded wires
- Oval cable entry

JENNE PART NUMBER:

ICMP8P8SRD	8P8C, Oval Entry Solid
ICMP8P8CRD	8P8C, Oval Entry Stranded



ICMP8P8SRD

Stranded | 8P8C Flat Plug

- Ideal for customizing cords for data or voice
- Accepts 24~28 AWG stranded wires
- Flat cable entry

JENNE PART NUMBER:

ICMP8P8CFT	8P8C, Flat
-------------------	------------



ICMP8P8CFT

Solid or Stranded | 6P6C Oval Plug

- Ideal for customizing cords for voice connectivity
- Accepts 24~28 AWG solid or stranded wires
- Oval cable entry

JENNE PART NUMBER:

ICMP6P6SRD	6P6C, Oval Entry Solid
ICMP6P6CRD	6P6C, Oval Entry Stranded



ICMP6P6SRD

Stranded | 6P6C Flat Plug

- Ideal for customizing cords for voice connectivity
- Accepts 24~28 AWG stranded wires
- Flat cable entry

JENNE PART NUMBER:

ICMP6P6CFT	6P6C, Flat
-------------------	------------



ICMP6P6CFT

Stranded | 6P4C Flat Plug

- Ideal for customizing cords for voice connectivity
- Accepts 24~28 AWG stranded wires
- Flat cable entry

JENNE PART NUMBER:

ICMP6P4CFT	6P4C, Flat
-------------------	------------



ICMP6P4CFT

Stranded | 4P4C Flat Plug

- Ideal for customizing cords for voice connectivity
- Accepts 24~28 AWG stranded wires
- Flat cable entry

JENNE PART NUMBER:

ICMP4P4CHS	4P4C, Flat
-------------------	------------



ICMP4P4CHS

Velcro® | Cable Ties

- Comes individually perforated
- Designed to facilitate the fastening of cables
- Tear off as needed
- (0.5"W by 8"L) and (0.5"W by 12"L)



ICACSV08BL

JENNE PART NUMBER:

ICACSV08xx¹	8" 10 pcs/Pack
ICACSV12xx¹	12" 10 pcs/Pack
ICACSVB8BK	8" 100 pcs/Pack
ICACSVBTBK	12" 100 pcs/Pack

¹xx denotes color = BK-Black, BL-Blue, GN-Green, GY-Gray, IV-Ivory, OR-Orange, RD-Red, WH-White, YL-Yellow

Bulk Velcro® | Cable Ties

- Makes cable management and color identification easy and quick
- Durable Velcro® material
- Designed for repeated use
- Continuous roll



ICACSV75BL

JENNE PART NUMBER:


ICACSV75xx¹	75' x 0.5" Roll
-------------------------------	-----------------

¹xx denotes color = BK-Black, BL-Blue

MPO Fiber Optic Cassettes

ICC's pre-terminated fiber optic MPO cassette modules are designed with a simple "Plug and Play" system that requires no field termination or splicing.

- Saves significant time and reduces overall installation costs
- Factory terminated and tested, eliminate splicing, polishing, and testing
- "Plug and Play" solution
- 10G, SC, LC Duplex configurations
- Numbered port ID labels for easy port identification
- Connectivity exceeds TIA-568 performance
- Easily snap into ICC fiber optic enclosures
- MPO adapters for quick plug and play with 12 fibers per adapter

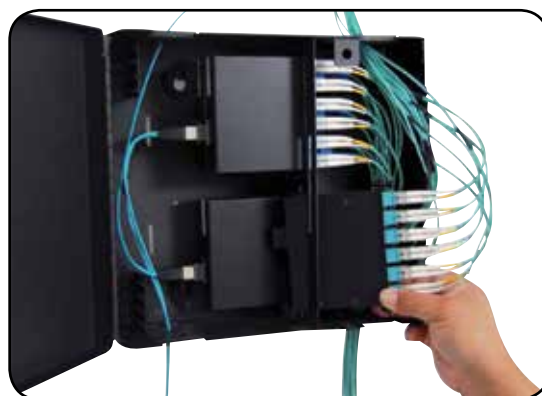


LC 12/24-Fiber | MPO Fiber Optic Plug & Play Cassettes

- 100% factory terminated and tested
- Modular design for easy Moves, Adds, Changes
- Compatible with ICC rack and wall mount fiber optic enclosures and fiber optic blank patch panels
- Low Insertion Loss of <0.5dB

JENNE PART NUMBER:

ICFC24ML1G	6-Quad LC, 24 Fiber, Multimode, 10G, 50/125µm (OM3)
ICFC24ML50	6-Quad LC, 24 Fiber, Multimode, 50/125µm (OM2)
ICFC24MLD6	6-Quad LC, 24 Fiber, Multimode, 62.5/125µm (OM1)
ICFC24SLD9	6-Quad LC, 24 Fiber, Single-mode, 9/125µm
ICFC12ML1G	6-LC Duplex, Multimode, 10G, 50/125µm (OM3)
ICFC12ML50	6-LC Duplex, Multimode, 50/125µm (OM2)
ICFC12MLD6	6-LC Duplex, Multimode, 62.5/125µm (OM1)
ICFC12SLD9	6-LC Duplex, Single-mode, 9/125µm

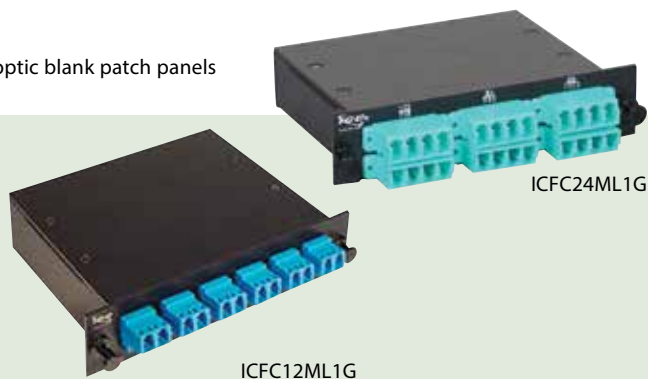

SC 12-Fiber | MPO Fiber Optic Plug & Play Cassettes

- 100% factory terminated and tested
- Modular design for easy Moves, Adds, Changes
- Compatible with ICC rack and wall mount fiber optic enclosures and fiber optic blank patch panels
- Low Insertion Loss of <0.5dB

JENNE PART NUMBER:

ICFC12MS1G	6-SC Duplex, Multimode, 10G, 50/125µm (OM3)
ICFC12MS50	6-SC Duplex, Multimode, 50/125µm (OM2)
ICFC12MSD6	6-SC Duplex, Multimode, 62.5/125µm (OM1)
ICFC12SSD9	6-SC Duplex, Single-mode, 9/125µm



Fiber Optic Adapter Panels

LC/LC | Adapter Panel

- Compatible with 10G applications
- 6-Duplex LC adapters
- Push-pin style for quick installation without special tools




JENNE PART NUMBER:

ICFOPL16BK	Ceramic, MM/SM
-------------------	----------------

MM = Multimode, SM = Single-mode

ST/ST | Adapter Panels

- 6-Simplex ST adapters
- Push-pin style for quick installation without special tools
- Metal sleeves for multimode or, ceramic sleeves for precision

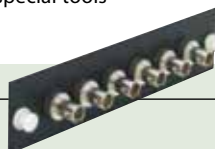

JENNE PART NUMBER:

ICFOPT16BK	Metal, MM
ICFOPT26BK	Ceramic, MM/SM

MM = Multimode, SM = Single-mode

Quad LC/Quad LC | Adapter Panels

- Compatible with 10G applications
- 6-Quad LC adapters
- Push-pin style for quick installation without special tools



JENNE PART NUMBER:

ICFOPL161G	Ceramic MM/SM, 24 Fiber, Aqua, 10G
ICFOPL1650	Ceramic MM/SM, 24 Fiber, Beige
ICFOPL2609	Ceramic MM/SM, 24 Fiber, Blue

SC/SC | Adapter Panels

- Push-pin style for quick installation without special tools
- Compatible with 10G applications
- 6-Duplex or 6-Simplex SC adapters
- Metal sleeves for multimode or, ceramic sleeves for precision



JENNE PART NUMBER:

ICFOPC16BK	Metal, MM, Duplex
ICFOPC26BK	Ceramic, MM/SM, Duplex
ICFOPS16BK	Metal, MM, Simplex
ICFOPS26BK	Ceramic, MM/SM, Simplex

MM = Multimode, SM = Single-mode



Fiber Optic Adapter Panels

ST/ST | Adapter Panels

- 8-Simplex ST adapters
- Push-pin style for quick installation without special tools
- Metal sleeves for multimode or, ceramic sleeves for precision

JENNE PART NUMBER:

ICFOPT18BK	Metal, MM
ICFOPT28BK	Ceramic, MM/SM

MM = Multimode, SM = Single-mode



ICFOPT28BK

SC/ST | Adapter Panels

- 6-Duplex SC to ST adapters
- Push-pin style for quick installation without special tools
- Metal sleeves for multimode or, ceramic sleeves for precision

JENNE PART NUMBER:

ICFOPR16BK	Metal, MM
ICFOPR26BK	Ceramic, MM/SM

MM = Multimode, SM = Single-mode



ICFOPR26BK

MPO | Adapter Panels

- (6) MPO aqua adapters
- MPO to MPO

JENNE PART NUMBER:

ICFOPM261G	6-Port, MM/SM
-------------------	---------------

MM = Multimode, SM = Single-mode



ICFOPM261G

MPO | Adapter Panels

- (4) or (6) MPO adapters
- Push-pin style for quick installation without special tools
- For joining MPO cables together

JENNE PART NUMBER:

ICFOPM24BK	4-Port, MM/SM
ICFOPM26BK	6-Port, MM/SM

MM = Multimode, SM = Single-mode



ICFOPM26BK

Fiber Optic Patch Panels

- Accommodates ICFOP fiber optic adapter panels
- Works with ICC MPO Cassettes
- 19" EIA rack mount width




ICFORPP1RM

JENNE PART NUMBER:

ICFORPP1RM	3-Panel, 1 RMS
ICFORPP2RM	6-Panel, 2 RMS

1 RMS (Rack Mount Space) = 1.75"

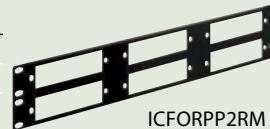


ICFORPP2RM

Blank | Adapter Panels

ICFOPJ04BK 4-Port, Unloaded


- Works with IC107 modular connectors
- Customize data, voice, audio/video and fiber optic connectivity in one panel

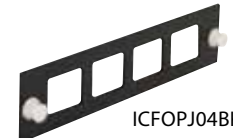

ICFOPJ04BK

ICFOPB00BK Blank

- Covers unused openings
- Compatible with ICC fiber optic rack/wall mount enclosures, and blank patch panels

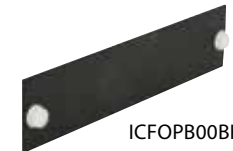

ICFOPB00BK


HD Fiber patch panels

- For high-density fiber connectivity • Pre-numbered ports
- Install on ICC's racks • 19" width

JENNE PART NUMBER:

ICFP24MP1G	24-Port, MPO, 10G
ICFP24MPBK	24-Port, MPO, Black
ICFP48MS1G	48-Port, SC, MM, 10G
ICFP48MS50	48-Port, SC, MM, 50µm
ICFP96ML1G	96-Port, Quad LC, MM, 10G
ICFP96ML50	96-Port, Quad LC, MM, 50µm
ICFP96SL09	96-Port, Quad LC, SM

1 RMS (Rack Mount Space) = 1.75"

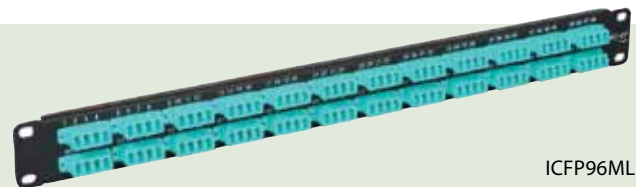

ICFP96ML1G

Fiber Optic Rack Mount Enclosures

Fixed-Panel | Fiber Optic Rack Mount Enclosures

- Integrated cable slack management spools
- Built-in knockout grommet seals
- Integrated Velcro® tie loops
- Removable front transparent flexi-panel door
- 19" EIA rack mount width



ICFORE62RM


JENNE PART NUMBER:

ICFORE31RM	3-Panel, Fixed Panel, 1.75"H x 17"W x 12.6"D, 1 RMS
ICFORE62RM	6-Panel, Fixed Panel, 3.50"H x 17"W x 12.6"D, 3 RMS

1 RMS (Rack Mount Space) = 1.75"

12-Panel | Fiber Optic Rack Mount Enclosure

- Integrated cable slack management spools
- Built-in knockout grommet seals
- Integrated Velcro® tie loops
- Removable front transparent flexi-panel door
- 19" EIA rack mount width

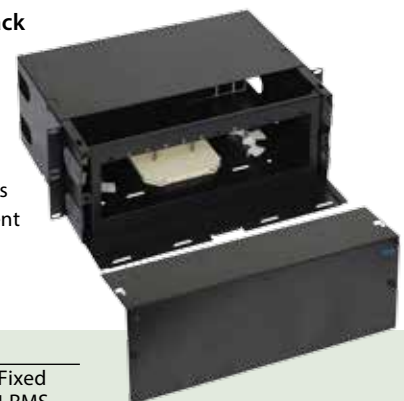

JENNE PART NUMBER:

ICFORET4RM	12-Panel, Fixed Panel, 7"H x 17"W x 12.6"D, 4 RMS
-------------------	---

1 RMS (Rack Mount Space) = 1.75"

Fiber Optic Rack & Wall Mount Enclosures

Slide-Out | Fiber Optic Rack Mount Enclosures

- A.
- Swing-out tray with open front, no cover, no management spools
- B.
- Integrated Velcro® tie loops and plastic fiber saddles
 - Front flexi-panel door
 - Slide-out tray allows for easy installation
 - Holds optional large splice tray



ICFOR102BK



ICFOR306BK

JENNE PART NUMBER:

A.	
ICFOR102BK	2-Panel, Swing-Out Style, 1.75"H x 17"W x 11"D, 1 RMS
B.	
ICFOR103BK	3-Panel, Slide-Out Style, 1.75"H x 17"W x 14"D, 1 RMS
ICFOR204BK	4-Panel, Slide-Out Style, 3.50"H x 17"W x 14"D, 2 RMS
ICFOR306BK	6-Panel, Slide-Out Style, 5.25"H x 17"W x 14"D, 3 RMS
ICFOR412BK	12-Panel, Slide-Out Style, 7.00"H x 17"W x 14"D, 4 RMS
1 RMS (Rack Mount Space) = 1.75"	

Splice | Fiber Optic Rack Mount Enclosures

- A.
- (2) slide-out trays, (1) tray for patching, (1) tray for splicing
- B.
- Universal splice tray(s) included
 - Integrated Velcro® tie loops and plastic fiber saddles
 - Slide-out trays allows for an easy installation
 - Holds optional large splice tray
 - 19" EIA rack mount width



ICFOR444BK




ICFORS4192

JENNE PART NUMBER:


A.	
ICFOR444BK	4-Panel, 96-Splice (1 Splice Tray) 7.00"H x 17"W x 14"D, 4 RMS
B.	
ICFORS3096	6-Panel, 96-Splice (2 Splice Trays) 5.25"H x 17"W x 14"D, 3 RMS
ICFORS4192	8-Panel, 192-Splice (6 Splice Trays) 7.00"H x 17"W x 14"D, 4 RMS
1 RMS (Rack Mount Space) = 1.75"	

Loaded | Fiber Optic Rack Mount Enclosures

- Includes fiber cable management spools
- Holds optional large splice tray
- Slide-out tray allows for easy installation
- Removable front flexi-panel door
- 19" EIA rack mount width

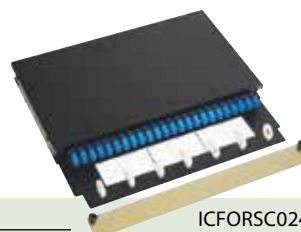

ICFORSC024

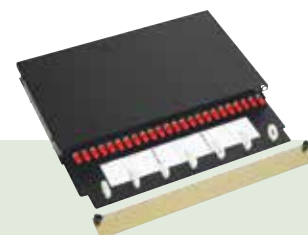

ICFORST024

JENNE PART NUMBER:


ICFORSC024	24-Simplex SC Adapters, 1.75"H x 17"W x 14"D, 1 RMS
ICFORST024	24-Simplex ST Adapters, 1.75"H x 17"W x 14"D, 1 RMS
1 RMS (Rack Mount Space) = 1.75"	

Lockable | Fiber Optic Wall Mount Enclosure

- Integrated cable slack management spools
- Built-in knockout grommet seals
- Built-in cable tie or Velcro® tie anchor points
- Locking door provide added security and prevent unwanted access
- Holds up to (4) adapter panels

JENNE PART NUMBER:

ICFODE41WM	4-Panel, Single Door With Lock, 10.75"H x 13"W x 3.5"D
ICFOSKFM12	(Optional) 12-Splice, Splice Tray

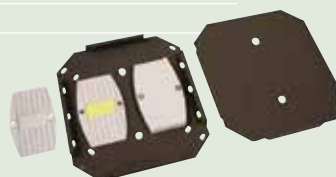

ICFOSKFM12



ICFODE41WM

Fiber Optic Wall Mount Enclosures

Single Door | Fiber Optic Wall Mount Enclosures

- Integrated adjustable cable slack management spools
- Built-in top and bottom plugs to prevent dust from entering the system
- Single door design
- Holds (2) to (4) adapter panels, and (1) small splice tray

JENNE PART NUMBER:

ICFOD102BK	2-Panel, Single Door, 13"H x 9.25"W x 3.5"D
ICFOD104BK	4-Panel, Single Door, 13"H x 11.5"W x 3.5"D



ICFOD102BK



ICFOD104BK

Dual Door | Fiber Optic Wall Mount Enclosures

- Integrated adjustable cable slack management spools
- Built-in top and bottom plugs to prevent dust from entering the system
- Locking doors provide added security and prevent unwanted access
- Holds (2) to (4) adapter panels, and (1) small splice tray

JENNE PART NUMBER:

ICFOD202BK	2-Panel, Dual Doors, 10.2"H x 12"W x 3.5"D
ICFOD204BK	4-Panel, Dual Doors, 10.8"H x 12"W x 4.0"D



ICFOD202BK



ICFOD204BK

Splice Tray Kits

- A.
- Includes left and right side holders for bare fusion, fusion with sleeve, and mechanical splice ribbon fusion
 - Designed to fit fiber rack mount enclosures and fiber optic wall mount enclosures
- B.
- Compatible with ICC's fiber splice enclosures
 - Includes: (2) left and (2) right mechanical fusion sleeves
 - (2) left and (2) right position fusion sleeves
 - (4) tie wraps

JENNE PART NUMBER:

A.	
ICFOSTFM12	12-Splice, Small Splice Tray, Supports Rack and Wall Mount
ICFOSTFM24	24-Splice, Large Splice Tray, Supports Rack Mount Only
B.	
ICFOSTUF24	24-Splice, Universal Tray



ICFOSTFM12



ICFOSTUF24

Fiber Optic Cable Assemblies


LC | Fiber Optic Jumpers

- TIA-568 compliant
- OFNR riser rated fiber optic cable
- Factory tested, includes test results
- Precision ceramic ferrule on LC, SC, and ST connectors

JENNE PART NUMBER:

ICFOJ1G6zz¹	OM3/10G, LC/LC, Simplex
ICFOJ1G7zz¹	OM3/10G, LC/LC, Duplex
ICFOJ2G6zz¹	OM3/10G, LC/SC, Simplex
ICFOJ2G7zz¹	OM3/10G, LC/SC, Duplex
ICFOJ3M5zz¹	Single-mode, LC/ST, Duplex
ICFOJ3M7zz¹	50/125µm, LC/ST, Duplex
ICFOJ0M3zz¹	62.5/125µm, LC/MT-RJ, Duplex
ICFOJ3M3zz¹	62.5/125µm, LC-ST, Duplex
ICFOJ1Myzz¹	LC/LC, (Reference Below Options)
ICFOJ2Myzz¹	LC/SC, (Reference Below Options)

¹y denotes Fiber Type (number of strands) and Cable Core/Clad (core diameter)
 2 = Simplex, 62.2/125µm 4 = Simplex, 9/125µm Single-mode 6 = Simplex, 50/125µm
 3 = Duplex, 62.2/125µm 5 = Duplex, 9/125µm Single-mode 7 = Duplex, 50/125µm
²zz denotes length = 01, 02, 03, 05, 07, and 10 meters (1 meter = 3.28 Ft.)

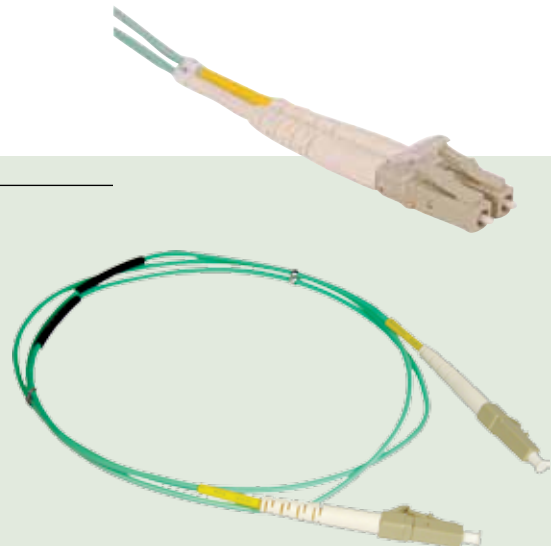

ICFOJ1G605

Fiber Optic Cable Assemblies

SC | Fiber Optic Jumpers

- TIA-568 compliant
- OFNR riser rated fiber optic cable
- Factory tested, includes test results
- Precision ceramic ferrule on LC, SC, and ST connectors

JENNE PART NUMBER:


ICFOJ8G6zz¹	OM3/10G, SC/SC, Simplex
ICFOJ8G7zz¹	OM3/10G, SC/SC, Duplex
ICFOJ2G6zz¹	OM3/10G, SC/LC, Simplex
ICFOJ2G7zz¹	OM3/10G, SC/LC, Duplex
ICFOJ5T6zz¹	62.5/125µm, SC/MT-RJ, Duplex
ICFOJ2Myzz¹	SC/LC, (Reference Below Options)
ICFOJ8Cyzz¹	SC/SC, (Reference Below Options)
ICFOJ9Cyzz¹	SC/ST, (Reference Below Options)

¹y denotes Fiber Type (number of strands) and Cable Core/Clad (core diameter)

2 = Simplex, 62.2/125µm 4 = Simplex, 9/125µm Single-mode 6 = Simplex, 50/125µm

3 = Duplex, 62.2/125µm 5 = Duplex, 9/125µm Single-mode 7 = Duplex, 50/125µm

¹zz denotes length = 01, 02, 03, 05, 07, and 10 meters (1 meter = 3.28 Ft.)

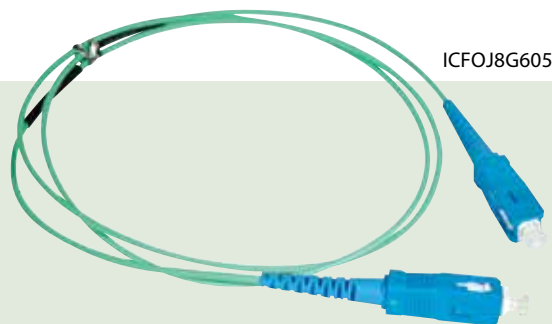

ICFOJ8G605

ST | Fiber Optic Jumpers

- TIA-568 compliant
- OFNR riser rated fiber optic cable
- Factory tested, includes test results
- Precision ceramic ferrule on LC, SC, and ST connectors

JENNE PART NUMBER:

ICFOJ3M5zz¹	Single-mode, ST/LC, Duplex
ICFOJ3M7zz¹	50/125µm, ST/LC, Duplex
ICFOJ3M3zz¹	62.5/125µm, ST/LC, Duplex
ICFOJ6T6zz¹	62.5/125µm, ST/MT-RJ, Duplex
ICFOJ7Cyzz¹	ST/ST, (Reference Below Options)
ICFOJ9Cyzz¹	ST/SC, (Reference Below Options)

¹y denotes Fiber Type (number of strands) and Cable Core/Clad (core diameter)

2 = Simplex, 62.2/125µm 4 = Simplex, 9/125µm Single-mode 6 = Simplex, 50/125µm

3 = Duplex, 62.2/125µm 5 = Duplex, 9/125µm Single-mode 7 = Duplex, 50/125µm

¹zz denotes length = 01, 02, 03, 05, 07, and 10 meters (1 meter = 3.28 Ft.)



ICFOJ3M305


MPO | Fiber Optic Jumpers

- TIA-568 compliant
- OFNP plenum rated fiber optic cable
- Factory tested, includes test results

JENNE PART NUMBER:

ICFOJATGzz¹	OM3/10G, MPO/MPO, 12-Fiber
ICFOJATMzz¹	50/125µm, MPO/MPO, 12-Fiber
ICFOJATNzz¹	62.5/125µm, MPO/MPO, 12-Fiber

¹zz denotes length = 05, 10, 15, 20, 30, and 50 meters (1 meter = 3.28 Ft.)

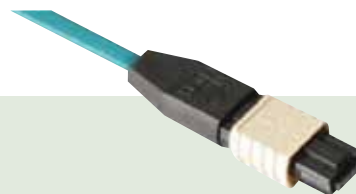

ICFOJATG05

MT-RJ | Fiber Optic Jumpers

- TIA-568 compliant
- OFNR riser rated fiber optic cable
- Factory tested, includes test results

JENNE PART NUMBER:

ICFOJ4T6zz¹	62.5/125µm, MT-RJ/MT-RJ, Duplex
-------------------------------	---------------------------------

¹zz denotes length = 01, 02, 03, 05, 07, and 10 meters (1 meter = 3.28 Ft.)



ICFOJ4T601

Fiber Optic Adapters and Bezels

Fiber Optic Adapters

- Ceramic sleeves for precision
- Small form factor (SFF)
- Joins (2) fiber cables

JENNE PART NUMBER:
ICFOA5MM02 LC/LC, Duplex




ICFOA5MM02

Fiber Optic Adapters

- Metal sleeves
- Compatible with Multimode only
- Joins (2) fiber cables

JENNE PART NUMBER:
ICFOA8MM01 SC/SC, Simplex

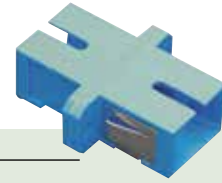


ICFOA8MM01

Fiber Optic Adapters

- Ceramic sleeves for precision
- Joins (2) fiber cables

JENNE PART NUMBER:
ICFOA8SM01 SC/SC, Simplex

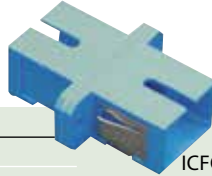


ICFOA8SM01

Fiber Optic Adapters

- Metal sleeves
- Compatible with Multimode only
- Joins (2) fiber cables

JENNE PART NUMBER:
ICFOA8MM02 SC/SC, Duplex

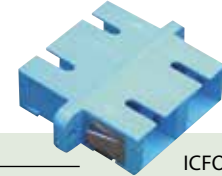


ICFOA8MM02

Fiber Optic Adapters

- Ceramic sleeves for precision
- Joins (2) fiber cables

JENNE PART NUMBER:
ICFOA8SM02 SC/SC, Duplex

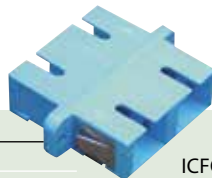


ICFOA8SM02

Fiber Optic Adapters

- Metal sleeves
- Compatible with Multimode only
- Joins (2) fiber cables

JENNE PART NUMBER:
ICFOA7MM01 ST/ST, Simplex

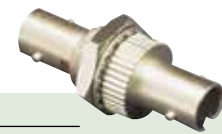

ICFOA7MM01

Fiber Optic Adapters

- Ceramic sleeves for precision
- Joins (2) fiber cables

JENNE PART NUMBER:
ICFOA7SM01 ST/ST, Simplex




ICFOA7SM01

Fiber Optic Adapters

- Metal sleeves
- Compatible with Multimode only
- Joins (2) fiber cables

JENNE PART NUMBER:
ICFOA9MM02 SC/ST, Duplex

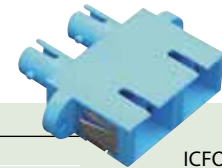


ICFOA9MM02

Fiber Optic Adapters

- Ceramic sleeves for precision
- Joins (2) fiber cables

JENNE PART NUMBER:
ICFOA9SM02 SC/ST, Duplex

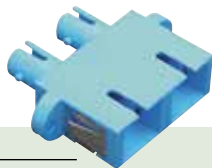

ICFOA9SM02

Fiber Optic Multimode | Elite™ Bezels

- Provides routing for up to (2) fiber ports • Metal sleeves
- Works with Elite™ multimedia boxes and outlets

JENNE PART NUMBER:
IC108BFTxx¹ (2) ST/ST Simplex, Flat
IC108BFCxx¹ SC/SC Duplex, Flat
IC108BACxx¹ SC/SC Duplex, Angled
IC108BFDxx¹ (2) SC/SC Duplex, Flat
IC108BFRxx¹ SC/ST Duplex, Flat

¹xx denotes color = IV-Ivory, WH-White



IC108BFTIV



IC108BFDWH



IC108BACIV



IC108BFRWH

Flat & Angled | Elite™ Bezels

- Angled design helps cable bend radius • Icons included, color or special icons available
- Compatible with ICC modular connectors for voice, data, audio, video and fiber connectivity
- Works with Elite™ multimedia boxes and outlets

JENNE PART NUMBER:
IC108BFBxx¹ Blank, Flat
IC108BF1xx¹ 1-Port, Flat
IC108BF2xx¹ 2-Port, Flat
IC108BA1xx¹ 1-Port, Angled
IC108BA2xx¹ 2-Port, Angled

¹xx denotes color = IV-Ivory, WH-White



IC108BFBIV



IC108BF1IV



IC108BF1WH



IC108BA1WH



IC108BA2WH

Every effort has been made to ensure the integrity of this catalog. Jenne, Inc. cannot be held responsible for any misrepresentation associated with any products due to omissions, typographic errors or misprints.



RESIDENTIAL ENCLOSURES

14", 21" and 28" combos

- Ideal solution for small and single-family homes
- Designed to be stud mounted
- Cables pictured are optional
- Enclosures come with hinged doors
- Modules packaged separately



14" Size: 14" H x 14.25" W x 3.68" D

21" Size: 21" H x 14.25" W x 3.68" D

28" Size: 28" H x 14.25" W x 3.68" D

JENNE PART NUMBER:

ICRESDC14K Comes with voice, CAT 6 data and 1 x 6 video splitter modules

ICRESDC14D Comes with voice and 1 x 6 video splitter modules

ICRESDC14E Enclosure and hinged door

ICRESDC14H Hinged door

JENNE PART NUMBER:

ICRESDC21K Comes with voice, CAT 6 data and 1 x 6 video splitter modules

ICRESDC21E Enclosure and hinged door

ICRESDC21H Hinged door

JENNE PART NUMBER:

ICRESDC28K Comes with voice, CAT 6 data and 1 x 6 video splitter modules

ICRESDC28E Enclosure and hinged door

ICRESDC28H Hinged door

9" and 8" combos

- Ideal solution for apartments, condos, remodels and retrofits
- Can be surface or stud mounted
- Cables pictured are optional
- Modules packaged separately



9" Size: 9.4" H x 15.10" W x 4.9" D

JENNE PART NUMBER:

ICRESDC9PK Cover and base with voice, CAT 6 data and 1 x 6 video splitter modules

ICRESDC9PD Cover and base with voice and 1 x 6 video splitter modules

8" Combo 6 Pack

Size: 8" H x 15.10" W x 4.9" D

JENNE PART NUMBER:

ICRDSMMBK8 Cover and base with (6) voice and (6) 1 x 6 video splitter modules (Only available in 6 pack)

Mini Combos

- Ideal solution for apartments, condos, remodels and retrofits
- Can be surface mounted
- Cables pictured are optional

Mini Size: 7.5" H x 6.5" W x 3.5" D

JENNE PART NUMBER:

ICRDSMMBK1 Comes with voice, CAT 5e data and 1 x 4 video splitter modules

ICRDSMMBD1 Comes with voice and 1 x 4 video splitter modules



Enclosure Modules

Voice Modules

- 8-Ports, bridged IDC • Supports up to 4 incoming phone lines and up to 8 extensions per line • Built-in RJ31X and expansion port



JENNE PART NUMBER:

ICRESVPA3C
PCB board design



ICRESVPA2C
ABS plastic bracket



ICRESVPA1C
Steel bracket

CAT 6 Data Modules

- 8-Ports, 110-Type IDC • Supports up to 8 computers • Exceeds TIA Category 6 performance standards



JENNE PART NUMBER:

ICRESDPB3C
PCB board design



ICRESDPB2C
ABS plastic bracket



ICRESDPB1C
Steel bracket

CAT 5e Data Modules

- 8-Ports, 110-Type IDC • Supports up to 8 computers • Exceeds TIA Category 5e performance standards



JENNE PART NUMBER:

ICRESDPA3C
PCB board design



ICRESDPA2C
ABS plastic bracket



ICRESDPA1C
Steel bracket


Video Splitter Modules

- Supports 2 GHz, 5~2300 MHz bandwidth • Light weight metal bracket



JENNE PART NUMBER:

ICRESAV42L
1 input x 4 outputs

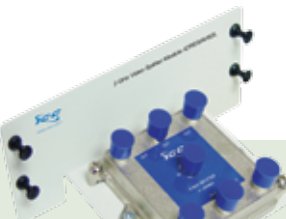

ICRESAV62L
1 input x 6 outputs



ICRESAV82L
1 input x 8 outputs

Every effort has been made to ensure the integrity of this catalog. Jenne, Inc. cannot be held responsible for any misrepresentation associated with any products due to omissions, typographic errors or misprints.

Raceway Sections & Wall Ducts

3/4" W | Raceway Sections

- One-piece self-locking latch design with adhesive backing
- Organizes, conceals and routes low-voltage cabling
- Designed to work with a wide variety of wall outlet boxes

JENNE PART NUMBER:

ICRWR11Sxx¹	1 Ft. (Order by 6 Ft. Increments)
ICRWR118xx¹	1 Ft. (Order by 8 Ft. Increments)
ICRW22R6xx¹	Single Pack in retail tube bag, 3/4"W x 1/2"H x 6'L
ICRW22R8xx¹	Single Pack in retail tube bag, 3/4"W x 1/2"H x 8'L

¹xx denotes color = IV-Ivory, WH-White



ICRWR11SIV



ICRWR118WH

1-1/4" W | Raceway Sections

- One-piece self-locking latch design with adhesive backing
- Organizes, conceals and routes low-voltage cabling
- Designed to work with a wide variety of wall outlet boxes

JENNE PART NUMBER:

ICRWR12Sxx¹	1 Ft. (Order by 6 Ft. Increments)
ICRWR128xx¹	1 Ft. (Order by 8 Ft. Increments)
ICRW33R6xx¹	Single Pack in retail tube bag, 1-1/4"W x 3/4"H x 6'L
ICRW33R8xx¹	Single Pack in retail tube bag, 1-1/4"W x 3/4"H x 8'L

¹xx denotes color = IV-Ivory, WH-White



ICRWR12SWH



ICRWR128IV

1-3/4" W | Raceway Sections

- One-piece self-locking latch design with adhesive backing
- Organizes, conceals and routes low-voltage cabling
- Designed to work with a wide variety of wall outlet boxes

JENNE PART NUMBER:

ICRWR13Sxx¹	1 Ft. (Order by 6 Ft. Increments)
ICRWR138xx¹	1 Ft. (Order by 8 Ft. Increments)
ICRW44R6xx¹	Single Pack in retail tube bag, 1-3/4"W x 1"H x 6'L
ICRW44R8xx¹	Single Pack in retail tube bag, 1-3/4"W x 1"H x 8'L

¹xx denotes color = IV-Ivory, WH-White



ICRWR13SIV



ICRW44R8WH

Slotted Style | Wall Ducts

- Slotted style design for cable with various exit or entry locations
- Includes slide-on cover to conceal cables
- Pre-drilled mounting holes
- Designed with base score lines making it easy to cut
- Easy to cut, trim, and paint

JENNE PART NUMBER:

ICRWL226xx¹	1 Ft., 2"W x 2"H (Order by 6 Ft. Increments)
ICRWL246xx¹	1 Ft., 2"W x 4"H (Order by 6 Ft. Increments)

¹xx denotes color = BK-Black, GY-Gray, WH-White



ICRWL226WH



ICRWL246GY

Solid Style | Wall Ducts

- Solid style to completely conceal cables for maximum protection
- Includes slide-on cover to conceal cables
- Pre-drilled mounting holes
- Easy to cut, trim, and paint

JENNE PART NUMBER:

ICRWS226xx¹	1 Ft., 2"W x 2"H (Order by 6 Ft. Increments)
ICRWS246xx¹	1 Ft., 2"W x 4"H (Order by 6 Ft. Increments)

¹xx denotes color = BK-Black, GY-Gray, WH-White



ICRWS226GY




ICRWS246WH

Connecting Accessories

90° Flat Elbows

- Designed to allow left or right turns
- Retail ready packaging, 1 pc

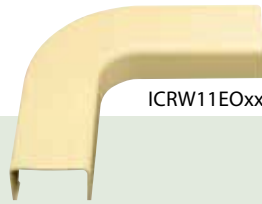

ICRW11EOxx


JENNE PART NUMBER:

ICRW11EOxx ¹	3/4" 10 pcs
ICRW12EOxx ¹	1-1/4" 10 pcs
ICRW13EOxx ¹	1-3/4" 10 pcs
ICRW22FExx ¹	3/4" 1 pc
ICRW33FExx ¹	1-1/4" 1 pc
ICRW44FExx ¹	1-3/4" 1 pc

¹xx denotes color = IV-Ivory, WH-White

90° Flat Elbows & Bases

- Supports left or right turns and includes base for cable management
- Retail ready packaging, 1 set

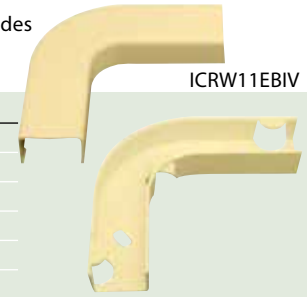

ICRW11EBIV

JENNE PART NUMBER:

ICRW11EBxx ¹	3/4" 10 sets
ICRW12EBxx ¹	1-1/4" 10 sets
ICRW13EBxx ¹	1-3/4" 10 sets
ICRW22EBxx ¹	3/4" 1 set
ICRW33EBxx ¹	1-1/4" 1 set
ICRW44EBxx ¹	1-3/4" 1 set

¹xx denotes color = IV-Ivory, WH-White

Tees

- Designed to maintain bend radius
- Retail ready packaging, 1 pc



ICRW11TOWH


JENNE PART NUMBER:

ICRW11TOxx ¹	3/4" 10 pcs
ICRW12TOxx ¹	1-1/4" 10 pcs
ICRW13TOxx ¹	1-3/4" 10 pcs
ICRW22TExx ¹	3/4" 1 pc
ICRW33TExx ¹	1-1/4" 1 pc
ICRW44TExx ¹	1-3/4" 1 pc

¹xx denotes color = IV-Ivory, WH-White

Tees & Bases

- Includes base to support cable management
- Retail ready packaging, 1 set

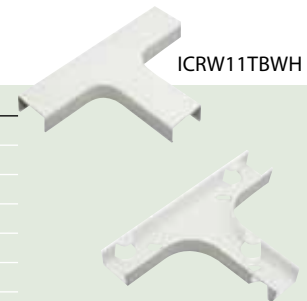

ICRW11TBWH

JENNE PART NUMBER:

ICRW11TBxx ¹	3/4" 10 sets
ICRW12TBxx ¹	1-1/4" 10 sets
ICRW13TBxx ¹	1-3/4" 10 sets
ICRW22TBxx ¹	3/4" 1 set
ICRW33TBxx ¹	1-1/4" 1 set
ICRW44TBxx ¹	1-3/4" 1 set

¹xx denotes color = IV-Ivory, WH-White

Outside Corner Covers

- Designed to facilitate cable bend radius
- Retail ready packaging, 1 pc



ICRW11OCIV


JENNE PART NUMBER:

ICRW11OCxx ¹	3/4" 10 pcs
ICRW12OCxx ¹	1-1/4" 10 pcs
ICRW13OCxx ¹	1-3/4" 10 pcs
ICRW22CCxx ¹	3/4" 1 pc
ICRW33CCxx ¹	1-1/4" 1 pc
ICRW44CCxx ¹	1-3/4" 1 pc

¹xx denotes color = IV-Ivory, WH-White

Outside Corner Cover & Base

- Designed to facilitate cable bend radius and support cable management
- Retail ready packaging, 1 set

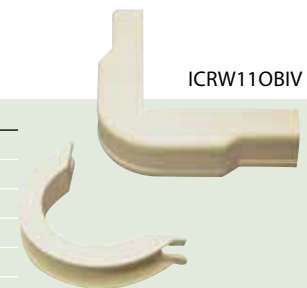

ICRW11OBIV

JENNE PART NUMBER:

ICRW11OBxx ¹	3/4" 10 sets
ICRW12OBxx ¹	1-1/4" 10 sets
ICRW13OBxx ¹	1-3/4" 10 sets
ICRW22UCxx ¹	3/4" 1 set
ICRW33UCxx ¹	1-1/4" 1 set
ICRW44UCxx ¹	1-3/4" 1 set

¹xx denotes color = IV-Ivory, WH-White

Inside Corner Covers

- Designed to facilitate cable bend radius
- Retail ready packaging, 1 pc



ICRW11ICWH


JENNE PART NUMBER:

ICRW11ICxx ¹	3/4" 10 pcs
ICRW12ICxx ¹	1-1/4" 10 pcs
ICRW13ICxx ¹	1-3/4" 10 pcs
ICRW22NCxx ¹	3/4" 1 pc
ICRW33NCxx ¹	1-1/4" 1 pc
ICRW44NCxx ¹	1-3/4" 1 pc

¹xx denotes color = IV-Ivory, WH-White

Joint Covers

- Designed to join (2) raceway straight sections
- Retail ready packaging, 1 set

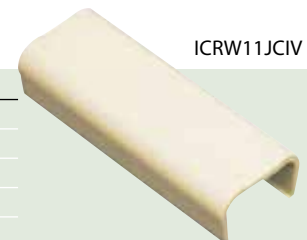

ICRW11JCIV

JENNE PART NUMBER:

ICRW11JCxx ¹	3/4" 10 pcs
ICRW12JCxx ¹	1-1/4" 10 pcs
ICRW13JCxx ¹	1-3/4" 10 pcs
ICRW22JCxx ¹	3/4" 1 pc
ICRW33JCxx ¹	1-1/4" 1 pc
ICRW44JCxx ¹	1-3/4" 1 pc

¹xx denotes color = IV-Ivory, WH-White



RACEWAY

Connecting Accessories

Ceiling Entry & Mounting Clips

- Designed to use with cables entering the ceiling
- Retail ready packaging, 1 set

JENNE PART NUMBER:

ICRW11CExx ¹	3/4" 10 sets
ICRW12CExx ¹	1-1/4" 10 sets
ICRW13CExx ¹	1-3/4" 10 sets
ICRW22CExx ¹	3/4" 1 set
ICRW33CExx ¹	1-1/4" 1 set
ICRW44CExx ¹	1-3/4" 1 set

¹xx denotes color = IV-Ivory, WH-White



Reducer & End Caps

JENNE PART NUMBER:

A.

ICRW11ROxx ¹	1-1/4" to 3/4" 10 pcs
ICRW12ROxx ¹	1-3/4" to 3/4" 10 pcs
ICRW13ROxx ¹	1-3/4" to 1-1/4" 10 pcs
ICRW22RExx ¹	1-1/4" to 3/4" 1 pc
ICRW33RExx ¹	1-3/4" to 3/4" 1 pc
ICRW44RExx ¹	1-3/4" to 1-1/4" 1 pc

B.

ICRW11ECxx ¹	3/4" 10 pcs
ICRW12ECxx ¹	1-1/4" 10 pcs
ICRW13ECxx ¹	1-3/4" 10 pcs
ICRW22ECxx ¹	3/4" 1 pc
ICRW33ECxx ¹	1-1/4" 1 pc
ICRW44ECxx ¹	1-3/4" 1 pc

¹xx denotes color = IV-Ivory, WH-White



ICC Raceway System Solutions


Easy and flexible installations regardless of the environment!

ICC's Raceway System is the perfect solution for saving time and money. No more cutting and routing cables behind finished walls. You can install it in any open architectural environment for true flexibility.




Raceway System

- Complete end-to-end
- Route copper and fiber optic cables
- Flexible installations regardless of environment
- UL® listed to ensure highest quality
- Install in commercial offices, warehouses, and homes
- Wide selection of workstation outlets available.

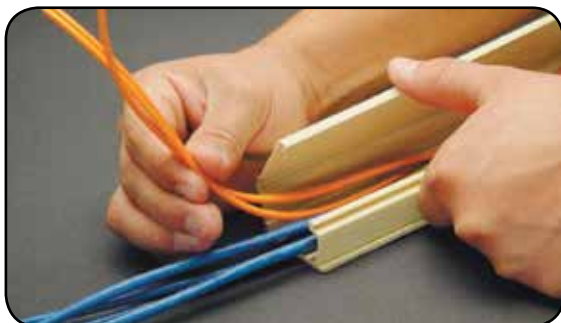

Raceway Sections


ICC's raceway sections are available in 6 and 8 foot lengths and come in either ivory or white. Raceway sections come in one-piece and have a flexible hinge latch design that makes installing cable easy. Raceway sections and components are designed to maintain a minimum one inch cable bend radius and are made of 94V-0 rigid vinyl for low-voltage (under 50V) communication cabling.

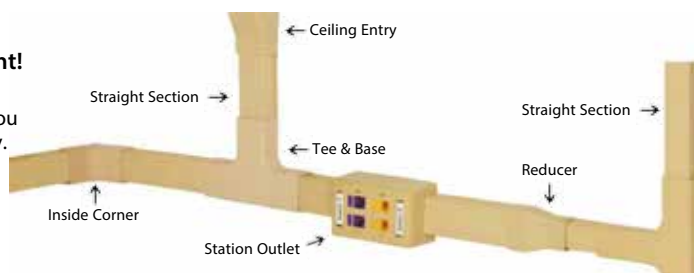

Raceway Single Packs

ICC's raceway sections and connecting accessories are available in single packs. They come in thick plastic bags preventing unwanted product damage. The bags perforated edge simplifies opening the package, eliminating the need for a knife or scissors. Single packs are ideal for small and medium size installations leaving installers with no unused parts.

Raceway Cutting Tool

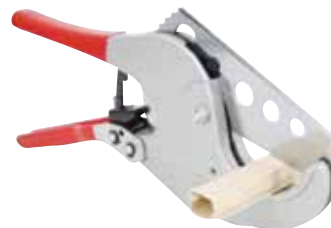


JENNE PART NUMBER:

ICACSTPE60 Raceway Cutting Tool

- Designed with ratchet mechanism allowing safe controlled cuts
- Cuts raceway, wall ducts, straight sections, and adhesive backings
- Steel frame construction with cushioned grip
- 2.5" maximum jaw opening capacity
- Compatible with ICC raceway sections and wall ducts

JackEasy™ Termination Tool

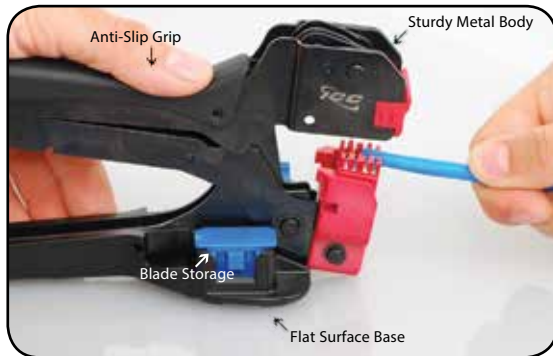

The JackEasy™ Tool Makes Terminating Faster & Easier!

Features:

- Sturdy Metal Body - Manufactured with a steel frame for durability
- Anti-Slip Grip - Easy to hold and terminate, giving maximum control
- Blade Storage - Holds extra blades so they are easily accessible
- Floor Base - Use the floor or any flat surface for support when terminating
- Switchable Blade - Easily switch between HD and EZ blades during installation
- Ergonomic Body - Sleek body design makes using the tool more comfortable


Cut down 75% of termination time! One simple squeeze of the handle simultaneously cuts all wires.

JackEasy™ | Termination Tool

- Terminates and cuts 4-Pairs of UTP wires
- Interchangeable termination heads to punch-down both HD and EZ style modules
- Durable steel body
- Ergonomic design with a comfortable grip
- Terminates on flat surfaces such as walls or floors

JENNE PART NUMBER:

ICACSPDTEH	Termination Tool for EZ & HD Connectors
ICACS8WUEH	Replacement Head for EZ & HD
ICACSBAGJE	Holster bag

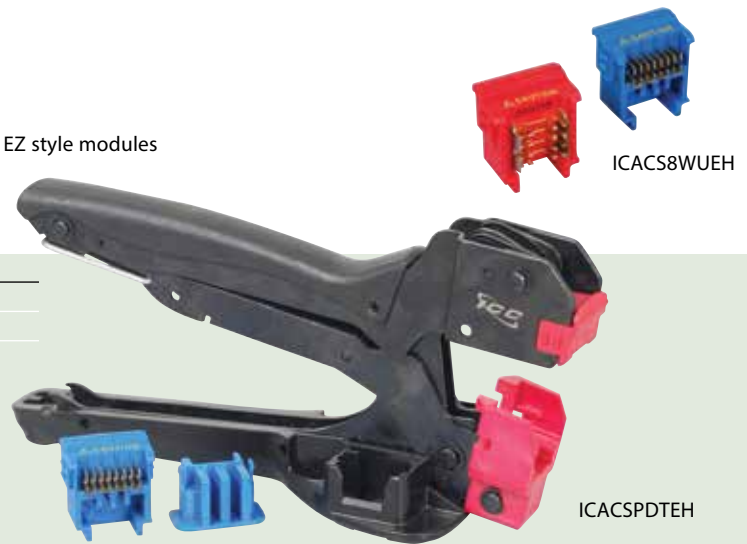

Easy to Terminate with the JackEasy™

TERMINATE ON THE FLOOR OF ANY JOB SITE TO MAKE THE INSTALLATION EASIER AND MORE CONVENIENT!

The easy grip handle helps to terminate connectors with ease, and makes the job more time efficient.

- Can be terminated with one hand or on a flat surface
- Reduces installation time
- User-friendly squeeze handle
- Terminates HD and EZ modular connectors
- Seats and cuts 4-Pairs (UTP and FTP) wires at once
- Consistent high quality terminations
- Unique proprietary design
- Replacement blades available



JackEasy™

Termination Tool

Punch-Down Tools

Choose From 3 Different Punch-Down Tools!

- Whether it's a single blade, 4-Pair, or 5-Pair punch-down tool, ICC has the choices that will best suit your job!



Single Blade | Punch-Down Tool

- Designed for both 110-Type IDC and 66 single-wire termination, both blades included
- Ergonomic design for fast, comfortable, and reliable termination
- Low impact settings allows punching down on 110-Type IDC termination, and high impact setting is used when seating 110 connecting blocks into wiring blocks

JENNE PART NUMBER:

ICACSPDT00	Single Blade Tool
ICACS110RB	110 Single-Wire Replacement Blade
ICACS066RB	66 Single-Wire Replacement Blade



50 kgs | 110 Punch-Down Tool

- 50 kgs of impact
- Tip of the shaft engages the blade set eliminating the possibility of blade misalignment
- Anti-slip rubber with raised grip design prevents hand slippage

JENNE PART NUMBER:

ICACSPDT4P	Blade Tool
ICACS04PH5	4-Pair, Tool Head



80 kgs | 110 Punch-Down Tool

- Designed to provide 80 kgs of impact in order to properly seat connecting blocks onto wiring blocks and terminates wires simultaneously
- The blade can be reversed to hide the cutting edge, permitting the tool to be used for seating connecting blocks without trimming wires
- Tip of the shaft engages the blade set eliminating the possibility of blade misalignment

JENNE PART NUMBER:

ICACSPDT05	Blade Tool
ICACS05PRH	5-Pair, Replacement Tool Head



Handheld Termination Aid

- Helps terminate ICC modular connectors
- Designed to provide a base for fast, secure, and reliable terminations
- Prevents modules or plugs from slipping out of hands, or off the work surface, prior to termination
- Compatible with ICC CAT 6, CAT 5e, voice modules and 110-Type patch plugs

JENNE PART NUMBER:

ICACSHTA01	Termination Aid
-------------------	-----------------



Stripping, Cutting and Crimping Tools

Deluxe | Stripper Tool

- Ergonomically designed for fast and easy UTP and STP cable stripping
- Outer jacket stripping blade for various twisted pair cable diameter
- Removable and reversible blade cassette with one side for RG-59/6 coaxial cables and another side for RG-7/11 coaxial cables

JENNE PART NUMBER:

ICACSTSUCD UTP & Coax Combo Cable Stripper



ICACSTSUCD

Economy | Stripper Tool

- Knife-like cutting blades provide high quality stripping
- Ergonomically designed for fast and easy UTP and STP cable stripping
- Stripping cavity accommodates five different cable diameters
- For stripping wire diameter from 5 ~ 6.2mm
- The tip is designed to help insert wires into 110-Type IDCs and 66 wiring blocks

JENNE PART NUMBER:

ICACSTSUS1 Cable Stripper



ICACSTSUS1

CATV Coax Cable | Stripper Tool

- Knife-like cutting blades provide high quality stripping
- Ergonomically designed for fast and easy coaxial cable stripping
- No cassettes needed, 3 blade types
- Strips and prepares coax cables in one pass
- Includes an allen wrench for adjusting blade positions
- For RG-58, RG-59, RG-6, and RG-6 quad coax cables

JENNE PART NUMBER:

ICACSCSCTV Coax Cable Stripper



ICACSCSCTV

Wire Cutting Tools

- Knife-like cutting blades provide high quality stripping
- Stripper and wire cutter tool strips various cable diameters

JENNE PART NUMBER:

ICACSCTRST Wire Cutter & Stripper

ICACSWRCTR Wire Cutter



ICACSCTRST



ICACSWRCTR

8P8C | Heavy Duty Modular Plug Crimping Tool

- Professional grade crimping with integrated stripper and cutter
- Ergonomic design provides a firm and comfortable grip which prevents hands from slipping
- Use with 8P8C modular data plugs

JENNE PART NUMBER:

ICACSCT845 Crimp, Strip & Cut, 8P8C, RJ-45



ICACSCT845

Universal | Modular Plug Crimping Tool

- Universal crimping for 4, 6, and 8-Position modular plugs
- Ergonomic design provides a firm and comfortable grip which prevents hands from slipping
- Integrated stripper and cutter

JENNE PART NUMBER:

ICACSCT864 Crimp, 4, 6, & 8-Position Modular Plug



ICACSCT864

Compression Tools

Universal | Compression Tool

- Designed to compress F-Type, RCA, BNC compression connectors and modular compression connectors
- Ergonomic handle design prevents slippage during compression
- Avoids over crimping by pressing the connector vertically onto the cable without causing bends

JENNE PART NUMBER:

ICACSCT01U Universal Compression Tool (Crimps Modular F-Type, RCA, BNC)



F-Type | Compression Tool

- Designed with ratchet mechanism preventing release of the connector prior to full compression
- Ergonomic handle design prevents slippage during compression
- Avoids over crimping by pressing the connector vertically onto the cable without causing bends
- Steel frame construction for added strength and durability
- Suitable for use with RG-59, RG-6, and RG-6 quad cables

JENNE PART NUMBER:

ICACSCT02F Compression Tool (Crimps F-Type Connectors)



Economic | Compression Tool

- Ergonomic design prevents slippage during compression
- Avoids over crimping by pressing the connector vertically onto the cable without causing bends
- Steel body constructions for added strength and durability
- Works with RG-59, RG-6 and RG-6 quad cables

JENNE PART NUMBER:

ICACSCT01E Compression Tool (Crimps F-Type, RCA, BNC)



F-Type | Connector Removal Tools

- Ergonomically designed for ease of use
- Carbon steel material for durability and strength
- Convenient for installing and removing F-Type Connectors from hard to reach locations
- Works with F-Type connectors; RG-59, RG-6, and RG-6Q

JENNE PART NUMBER:

ICACSF06RT 6" Length

ICACSF12RT 12" Length



voice couplers

Voice | Telephone Couplers

- Compatible with ICLC4, ICLC6 telephone line cords

JENNE PART NUMBER:

ICMA350A6C RJ-11 6P6C, Pin 1-6, Female-to-Female

ICMA3508DR RJ-45 8P8C, Pin 1-1, Female-to-Female, Keyed

ICMA267D66 RJ-11 6P6C, Pin 1-1, 1-Male-to-2-Females



Compression Connectors & Accessories

F-Type Connectors

- Supports a wide variety of applications such as CCTV, CATV, HDTV, and other audio or video systems
- Used with universal compression tool
- 20 or 100 pcs/Pack

JENNE PART NUMBER:

ICRDSAV01w¹ RG-6, Black Band

ICRDSAV04w¹ RG-6Q, Blue Band

ICRDSAV59w¹ RG-59, Black Band

¹w denotes pcs/Pack = F= 20, C= 100 Not designed for use on plenum cables



ICRDSAV01F

BNC Connectors

- Supports a wide variety of applications such as CCTV, CATV, HDTV, and other audio or video systems
- Used with universal compression tool
- 20 pcs/Pack

JENNE PART NUMBER:

ICRDSB61BC RG-6

ICRDSB51BC RG-59

ICRDSB6RBC RG-6, 90° Angle

Not designed for use on plenum cables



ICRDSB6RBC




ICRDSB61BC

Colored Grounding Wire

- Designed for ICC CAT 6A shielded jack (IC1078S6A0) • 18 AWG wire
- Ground ICC CAT 6A shielded modular connector to metal mounting brackets • 10 pcs/Pack

JENNE PART NUMBER:

ICACSGK6AS Grounding Wire

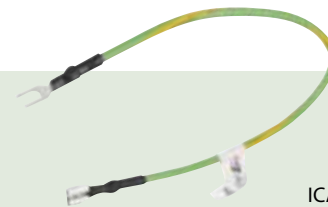

ICACSGK6AS

Magnets

- Designed to mount surface mount boxes on flat metal surfaces


JENNE PART NUMBER:

ICMAGBLOCK Metal magnet, 2 pcs/Pack

IC317MTAPE Magnetic front with rear adhesive, 2 pcs/Pack



ICMAGBLOCK

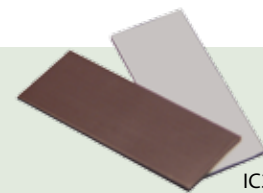

IC317MTAPE

Elite™ | Color Icons

- Molded with text graphic identifications
- Works with Elite surface mount boxes and bezels

JENNE PART NUMBER:

IC108ICDxx¹ Data, 10 pcs

IC108ICVxx¹ Voice, 10 pcs


IC108ICAx¹ Voice & Data, 5 Each, 10 pcs

IC108ICNxx¹ Text & Graphic, 10 pcs

¹xx denotes color = BK-Black, BL-Blue, GN-Green, IV-Ivory, OR-Orange, RD-Red, PR-Purple, WH-White, YL-Yellow



IC108ICDBK

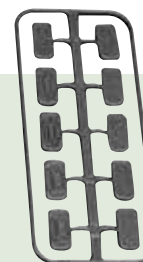

Patch Panel | Color Icons

- Designed to apply to patch panels for easy system administration and station identification

JENNE PART NUMBER:

ICMPPSCIxx¹ Voice & Data, 6 Each, 12 pcs

ICMPPICDxx¹ Data, 12 pcs

ICMPPICVxx¹ Voice, 12 pcs

¹xx denotes color = BL-Blue, GN-Green, GY-Gray, IV-Ivory, OR-Orange, RD-Red, PR-Purple, WH-White, YL-Yellow



ICMPPSCIxx