

FREE-STANDING ENCLOSURE ACCESSORIES

Panels (Full & Half Length) For Single-Door Enclosures

Panels for single-door enclosures can be positioned anywhere along the horizontal mounting channels. Half-length panels can be located in the upper or lower portion of the enclosure. Mounting hardware is included. All panels are made of heavy gauge steel and powder coated white.

Panels (Full & Half Length) For Two-Door Enclosures

Panels for two-door enclosures can be positioned anywhere along the horizontal mounting channels. Half-length panels can be located in the upper or lower portion of the enclosure. Mounting hardware is included. All panels are made of heavy gauge steel and powder coated white.

Side Mount Panels

Designed to provide extra mounting space on the side of an enclosure. Can be securely attached to the mounting channels. Plated mounting hardware is supplied. Bent on vertical sides. Made of heavy gauge steel and powder coated white.

Individual Panel Supports

Individual panel supports are available for additional equipment mounting. All mounting hardware included. Made of heavy gauge steel and plated.

Catalog No.	Panel Height	Panel Width	Enclosure Height	Enclosure Width	Product Code	List Price
Full Panel						
SCE-60P24F1	48.00	20.00	60.00	24.00	P3	173.85
SCE-60P36F1	48.00	32.00	60.00	36.00	P3	226.00
SCE-72P24F1	60.00	20.00	72.00	24.00	P3	196.20
SCE-72P30F1	60.00	26.00	72.00	30.00	P3	228.49
SCE-72P36F1	60.00	32.00	72.00	36.00	P3	258.29
SCE-90P24F1	78.00	20.00	90.00	24.00	P3	228.49
SCE-90P36F1	78.00	32.00	90.00	36.00	P3	310.45
Half Panel						
SCE-60P24F2	24.88	20.00	60.00	24.00	P3	116.72
SCE-60P36F2	24.88	32.00	60.00	36.00	P3	141.56
SCE-72P24F2	30.88	20.00	72.00	24.00	P3	126.66
SCE-72P30F2	30.88	26.00	72.00	30.00	P3	141.56
SCE-72P36F2	30.88	32.00	72.00	36.00	P3	158.95
SCE-90P24F2	39.88	20.00	90.00	24.00	P3	141.56
SCE-90P36F2	39.88	32.00	90.00	36.00	P3	183.79

Catalog No.	Panel Height	Panel Width	Enclosure Height	Enclosure Width	Product Code	List Price
Full Panel						
SCE-60P48F1	48.00	44.00	60.00	48.00	P3	362.60
SCE-72P48F1	60.00	44.00	72.00	48.00	P3	409.79
SCE-72P60F1	60.00	56.00	72.00	60.00	P3	474.36
SCE-72P72F1	60.00	68.00	72.00	72.00	P3	541.42
SCE-90P48F1	78.00	44.00	90.00	48.00	P3	481.82
SCE-90P72F1	78.00	68.00	90.00	72.00	P3	650.69
Half Panel						
SCE-72P48F2	30.88	44.00	72.00	48.00	P3	260.78
SCE-72P60F2	30.88	56.00	72.00	60.00	P3	295.55
SCE-72P72F2	30.88	68.00	72.00	72.00	P3	327.83
SCE-90P48F2	39.88	44.00	90.00	48.00	P3	298.03
SCE-90P72F2	39.88	68.00	90.00	72.00	P3	384.95

Catalog No.	Panel Height	Panel Width	Enclosure Height	Enclosure Width	Product Code	List Price
SCE-60SMP14	48.00	14.00	60.00	18.00	P3	138.74
SCE-72SMP14	60.00	14.00	72.00	18.00	P3	155.72
SCE-72SMP20	60.00	20.00	72.00	24.00	P3	192.53
SCE-90SMP14	78.00	14.00	90.00	18.00	P3	226.51
SCE-90SMP20	78.00	20.00	90.00	24.00	P3	235.00
SCE-90SMP30	78.00	30.00	90.00	36.00	P3	254.81

Catalog No.	Notes	Product Code	List Price
SCE-FSPS4	Set of 4	P2	55.88
SCE-FSPS6	Set of 6	P2	84.44
SCE-FSPS8	Set of 8	P2	126.66


FREE-STANDING ENCLOSURE ACCESSORIES

Swing-Out Panels


Panels are available full length and half length and can be mounted on either side of the enclosure. Panels have heavy gauge steel support frames and heavy gauge continuous hinges to allow the panel to swing completely out of the enclosure. Mounting hardware is included. Made of heavy gauge steel and powder coated white. For technical information, consult our Installation Manual at www.saginawcontrol.com.



Catalog No.	No. of Units	Enclosure Height	Enclosure Width	Product Code	List Price
SCE-7230SOF19	33	72.00	30.00	P2	389.92
SCE-7236SOF19	33	72.00	36.00	P2	419.73
SCE-9036SOF19	43	90.00	36.00	P2	442.08

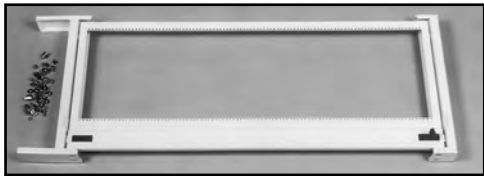

Catalog No.	Height (A)	Width (B)	Depth (C)	Enclosure Depth	Product Code	List Price
SCE-14RMW	6.00	35.00	14.00	18.00	P2	198.69
SCE-20RMW	6.00	35.00	20.00	24.00	P2	223.52

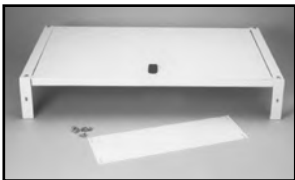

Back to
Free-Standing
Accessory Guide



Phone (989) 799-6871
Fax (989) 799-4524

304 & 316 Stainless Steel
Enviroline® Series
Junction Enclosures

Application -

Designed to house electrical controls, instruments and components in areas, which may be regularly hosed down or are in very wet or oily conditions. Provides protection from dust, dirt, oil, and water. For outdoor application a drip shield is recommended. For installation information, consult our Installation Manual at www.saginawcontrol.com.

Construction -

- 0.063" stainless steel Type 304 & 316/316L.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Oil-resistant gasket.
- Standoffs provided for mounting optional panels.
- Removable hinge.
- Doors open 180 degrees.
- Black mini quarter turn latches.
- Latches are opened or closed with a screwdriver.
- Sealing washers and hole plugs included.
- Ground stud on door & body.
- Mounting feet included.
- Optional latches available.

Finish -

#4 brushed finish on all exterior surfaces. Optional sub-panels are powder coated white.

IS5 - Industry Standards -
NEMA Type 4, 4X, 12 & Type 13
UL Listed Type 4, 4X & 12
CSA Type 4, 4X & 12
IEC 60529 IP66

304 STAINLESS STEEL ENVIROLINE® SERIES
JUNCTION ENCLOSURES

ENCLOSURE PRODUCT CODE S6						SUB-PANEL (P3)			
Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard	List Price	Catalog No.	Panel Height (D)	Panel Width (E)	List Price
SCE-604ELJSS	6.00	4.00	4.00	IS5	135.53	SCE-6P4J	5.00	3.00	3.02
SCE-606ELJSS	6.00	6.00	4.00	IS5	169.40	SCE-6P6J	5.00	5.00	3.62
SCE-806ELJSS	8.00	6.00	4.00	IS5	176.82	SCE-8P6J	7.00	5.00	4.17
SCE-8066ELJSS	8.00	6.00	6.00	IS5	202.17	SCE-8P6J	7.00	5.00	4.17
SCE-1008ELJSS	10.00	8.00	4.00	IS5	260.94	SCE-10P8J	9.00	7.00	5.70
SCE-10086ELJSS	10.00	8.00	6.00	IS5	290.44	SCE-10P8J	9.00	7.00	5.70
SCE-1210ELJSS	12.00	10.00	6.00	IS5	328.93	SCE-12P10J	11.00	9.00	7.72
SCE-12108ELJSS	12.00	10.00	8.00	IS5	352.80	SCE-12P10J	11.00	9.00	7.72
SCE-1212ELJSS	12.00	12.00	6.00	IS5	355.50	SCE-12P12J	11.00	11.00	9.08
SCE-1412ELJSS	14.00	12.00	6.00	IS5	378.21	SCE-14P12J	13.00	11.00	10.13
SCE-14128ELJSS	14.00	12.00	8.00	IS5	400.92	SCE-14P12J	13.00	11.00	10.13
SCE-1614ELJSS	16.00	14.00	6.00	IS5	444.87	SCE-16P14J	15.00	13.00	19.96
SCE-16148ELJSS	16.00	14.00	8.00	IS5	508.38	SCE-16P14J	15.00	13.00	19.96

316 STAINLESS STEEL ENVIROLINE® SERIES
JUNCTION ENCLOSURES

ENCLOSURE PRODUCT CODE S7						SUB-PANEL (P3)			
Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard	List Price	Catalog No.	Panel Height (D)	Panel Width (E)	List Price
SCE-604ELJSS6	6.00	4.00	4.00	IS5	162.64	SCE-6P4J	5.00	3.00	3.02
SCE-606ELJSS6	6.00	6.00	4.00	IS5	203.28	SCE-6P6J	5.00	5.00	3.62
SCE-806ELJSS6	8.00	6.00	4.00	IS5	212.18	SCE-8P6J	7.00	5.00	4.17
SCE-8066ELJSS6	8.00	6.00	6.00	IS5	242.60	SCE-8P6J	7.00	5.00	4.17
SCE-1008ELJSS6	10.00	8.00	4.00	IS5	313.13	SCE-10P8J	9.00	7.00	5.70
SCE-10086ELJSS6	10.00	8.00	6.00	IS5	348.53	SCE-10P8J	9.00	7.00	5.70
SCE-1210ELJSS6	12.00	10.00	6.00	IS5	394.72	SCE-12P10J	11.00	9.00	7.72
SCE-12108ELJSS6	12.00	10.00	8.00	IS5	423.36	SCE-12P10J	11.00	9.00	7.72
SCE-1212ELJSS6	12.00	12.00	6.00	IS5	426.60	SCE-12P12J	11.00	11.00	9.08
SCE-1412ELJSS6	14.00	12.00	6.00	IS5	453.85	SCE-14P12J	13.00	11.00	10.13
SCE-14128ELJSS6	14.00	12.00	8.00	IS5	481.10	SCE-14P12J	13.00	11.00	10.13
SCE-1614ELJSS6	16.00	14.00	6.00	IS5	533.84	SCE-16P14J	15.00	13.00	19.96
SCE-16148ELJSS6	16.00	14.00	8.00	IS5	610.06	SCE-16P14J	15.00	13.00	19.96




Available within 10 working days if not in stock

Back to
SS Wall-Mount
Enclosures

Phone (989) 799-6871
Fax (989) 799-4524



STAINLESS STEEL ENVIROLINE® SERIES
JUNCTION ENCLOSURES
TECHNICAL DATA

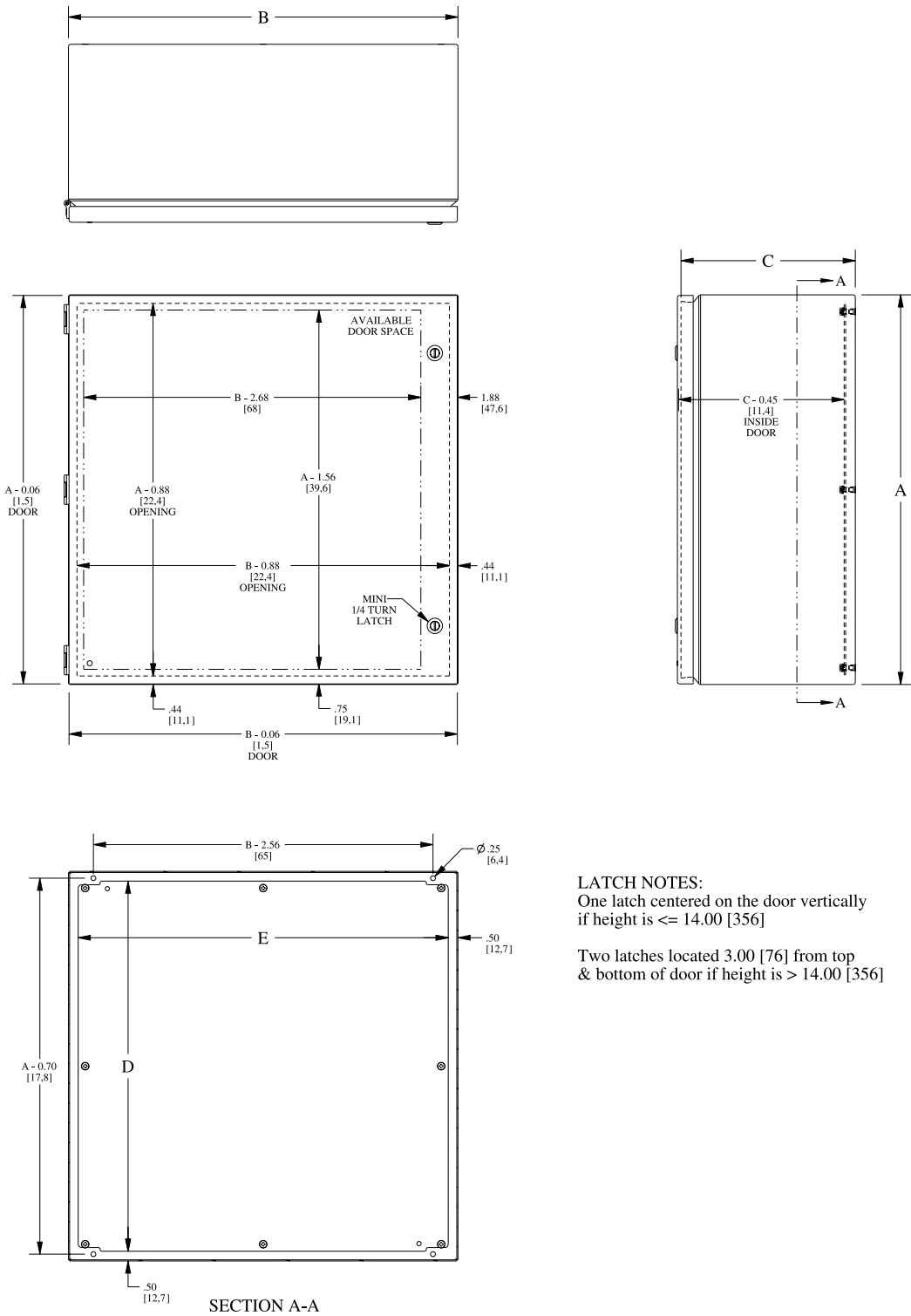

Phone (989) 799-6871
Fax (989) 799-4524

304 & 316 Stainless Steel
Enviroline® Series
Junction Enclosures

Application -

Designed to house electrical controls, instruments and components in areas, which may be regularly hosed down or are in very wet or oily conditions. Provides protection from dust, dirt, oil, and water. For outdoor application a drip shield is recommended. For installation information, consult our Installation Manual at www.saginawcontrol.com.

Construction -

- 0.063" stainless steel Type 304 & 316/316L.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Oil-resistant gasket.
- Standoffs provided for mounting optional panels.
- Removable hinge.
- Doors open 180 degrees.
- Black mini quarter turn latches.
- Latches are opened or closed with a screwdriver.
- Sealing washers and hole plugs included.
- Ground stud on door & body.
- Mounting feet included.
- Optional latches available.

Finish -

#4 brushed finish on all exterior surfaces. Optional sub-panels are powder coated white.

IS5 - Industry Standards -
NEMA Type 4, 4X, 12 & Type 13
UL Listed Type 4, 4X & 12
CSA Type 4, 4X & 12
IEC 60529 IP66

304 STAINLESS STEEL ENVIROLINE® SERIES
JUNCTION ENCLOSURES

ENCLOSURE PRODUCT CODE S6						SUB-PANEL (P3)			
Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard	List Price	Catalog No.	Panel Height (D)	Panel Width (E)	List Price
SCE-604ELJSS	6.00	4.00	4.00	IS5	135.53	SCE-6P4J	5.00	3.00	3.02
SCE-606ELJSS	6.00	6.00	4.00	IS5	169.40	SCE-6P6J	5.00	5.00	3.62
SCE-806ELJSS	8.00	6.00	4.00	IS5	176.82	SCE-8P6J	7.00	5.00	4.17
SCE-8066ELJSS	8.00	6.00	6.00	IS5	202.17	SCE-8P6J	7.00	5.00	4.17
SCE-1008ELJSS	10.00	8.00	4.00	IS5	260.94	SCE-10P8J	9.00	7.00	5.70
SCE-10086ELJSS	10.00	8.00	6.00	IS5	290.44	SCE-10P8J	9.00	7.00	5.70
SCE-1210ELJSS	12.00	10.00	6.00	IS5	328.93	SCE-12P10J	11.00	9.00	7.72
SCE-12108ELJSS	12.00	10.00	8.00	IS5	352.80	SCE-12P10J	11.00	9.00	7.72
SCE-1212ELJSS	12.00	12.00	6.00	IS5	355.50	SCE-12P12J	11.00	11.00	9.08
SCE-1412ELJSS	14.00	12.00	6.00	IS5	378.21	SCE-14P12J	13.00	11.00	10.13
SCE-14128ELJSS	14.00	12.00	8.00	IS5	400.92	SCE-14P12J	13.00	11.00	10.13
SCE-1614ELJSS	16.00	14.00	6.00	IS5	444.87	SCE-16P14J	15.00	13.00	19.96
SCE-16148ELJSS	16.00	14.00	8.00	IS5	508.38	SCE-16P14J	15.00	13.00	19.96

316 STAINLESS STEEL ENVIROLINE® SERIES
JUNCTION ENCLOSURES

ENCLOSURE PRODUCT CODE S7						SUB-PANEL (P3)			
Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard	List Price	Catalog No.	Panel Height (D)	Panel Width (E)	List Price
SCE-604ELJSS6	6.00	4.00	4.00	IS5	162.64	SCE-6P4J	5.00	3.00	3.02
SCE-606ELJSS6	6.00	6.00	4.00	IS5	203.28	SCE-6P6J	5.00	5.00	3.62
SCE-806ELJSS6	8.00	6.00	4.00	IS5	212.18	SCE-8P6J	7.00	5.00	4.17
SCE-8066ELJSS6	8.00	6.00	6.00	IS5	242.60	SCE-8P6J	7.00	5.00	4.17
SCE-1008ELJSS6	10.00	8.00	4.00	IS5	313.13	SCE-10P8J	9.00	7.00	5.70
SCE-10086ELJSS6	10.00	8.00	6.00	IS5	348.53	SCE-10P8J	9.00	7.00	5.70
SCE-1210ELJSS6	12.00	10.00	6.00	IS5	394.72	SCE-12P10J	11.00	9.00	7.72
SCE-12108ELJSS6	12.00	10.00	8.00	IS5	423.36	SCE-12P10J	11.00	9.00	7.72
SCE-1212ELJSS6	12.00	12.00	6.00	IS5	426.60	SCE-12P12J	11.00	11.00	9.08
SCE-1412ELJSS6	14.00	12.00	6.00	IS5	453.85	SCE-14P12J	13.00	11.00	10.13
SCE-14128ELJSS6	14.00	12.00	8.00	IS5	481.10	SCE-14P12J	13.00	11.00	10.13
SCE-1614ELJSS6	16.00	14.00	6.00	IS5	533.84	SCE-16P14J	15.00	13.00	19.96
SCE-16148ELJSS6	16.00	14.00	8.00	IS5	610.06	SCE-16P14J	15.00	13.00	19.96




Available within 10 working days if not in stock

Back to
SS Wall-Mount
Enclosures

Phone (989) 799-6871
Fax (989) 799-4524



STAINLESS STEEL ENVIROLINE® SERIES
JUNCTION ENCLOSURES
TECHNICAL DATA

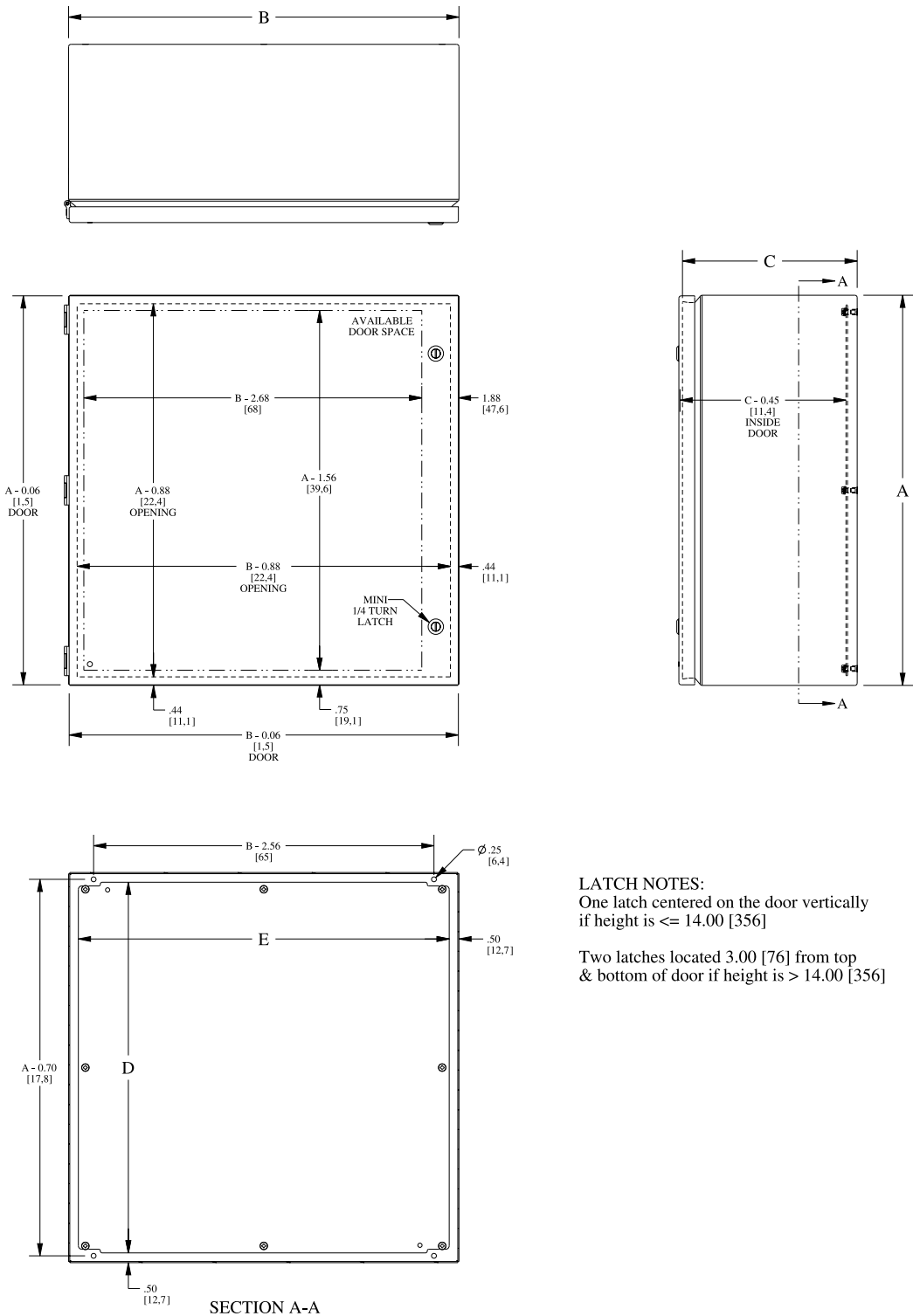

LATCH NOTES:
One latch centered on the door vertically if height is <= 14.00 [356]

Two latches located 3.00 [76] from top & bottom of door if height is > 14.00 [356]



Phone (989) 799-6871
Fax (989) 799-4524

304 & 316 Stainless Steel Enviroline® Series Junction Enclosures with Viewing Window

Application -

Designed to house electrical controls, instruments and components that require unrestricted viewing of the gages or controls, in areas, which may be regularly hosed down or are in very wet or oily conditions. Provides protection from dust, dirt, oil, and water. For outdoor application a drip shield is recommended. For installation information, consult our Installation Manual at www.saginawcontrol.com.

Construction -

- 0.063" stainless steel Type 304 & 316/316L.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Oil-resistant gasket.
- 0.25" polycarbonate viewing window.
- Standoffs provided for mounting optional panels.
- Removable hinge.
- Doors open 180 degrees.
- Black mini quarter turn latches.
- Latches are opened or closed with a screwdriver.
- Sealing washers and hole plugs included.
- Ground stud on door & body.
- Mounting feet included.
- Optional latches available.

Finish -

#4 brushed finish on all exterior surfaces. Optional panels are powder coated white.

IS5 - Industry Standards -

NEMA Type 4, 4X, 12 & Type 13
UL Listed Type 4, 4X & 12
CSA Type 4, 4X & 12
IEC 60529 IP66

304 Stainless Steel Enviroline® Series Junction Enclosures with Viewing Window

ENCLOSURE PRODUCT CODE S6							SUB-PANEL (P3)	
Catalog No.	Height (A)	Width (B)	Depth (C)	Window Viewing Size	Industry Standard	List Price	Catalog No.	List Price
SCE-1008ELJWSS	10.00	8.00	4.00	6.00 x 3.375	IS5	359.33	SCE-10P8J	5.70
SCE-10086ELJWSS	10.00	8.00	6.00	6.00 x 3.375	IS5	378.97	SCE-10P8J	5.70
SCE-1210ELJWSS	12.00	10.00	6.00	8.00 x 5.375	IS5	418.25	SCE-12P10J	7.72
SCE-12108ELJWSS	12.00	10.00	8.00	8.00 x 5.375	IS5	432.12	SCE-12P10J	7.72
SCE-1614ELJWSS	16.00	14.00	6.00	12.00 x 9.375	IS5	563.84	SCE-16P14J	19.96
SCE-16148ELJWSS	16.00	14.00	8.00	12.00 x 9.375	IS5	597.34	SCE-16P14J	19.96

316 Stainless Steel Enviroline® Series Junction Enclosures with Viewing Window

ENCLOSURE PRODUCT CODE S7							SUB-PANEL (P3)	
Catalog No.	Height (A)	Width (B)	Depth (C)	Window Viewing Size	Industry Standard	List Price	Catalog No.	List Price
SCE-1008ELJWSS6	10.00	8.00	4.00	6.00 x 3.375	IS5	431.20	SCE-10P8J	5.70
SCE-10086ELJWSS6	10.00	8.00	6.00	6.00 x 3.375	IS5	454.77	SCE-10P8J	5.70
SCE-1210ELJWSS6	12.00	10.00	6.00	8.00 x 5.375	IS5	501.91	SCE-12P10J	7.72
SCE-12108ELJWSS6	12.00	10.00	8.00	8.00 x 5.375	IS5	518.54	SCE-12P10J	7.72
SCE-1614ELJWSS6	16.00	14.00	6.00	12.00 x 9.375	IS5	676.60	SCE-16P14J	19.96
SCE-16148ELJWSS6	16.00	14.00	8.00	12.00 X 9.375	IS5	716.81	SCE-16P14J	19.96

Available within 10 working days if not in stock







Back to
SS Wall-Mount
Enclosures

Phone (989) 799-6871
Fax (989) 799-4524



STAINLESS STEEL ENVIROLINE® SERIES JUNCTION ENCLOSURES WITH VIEWING WINDOW
TECHNICAL DATA

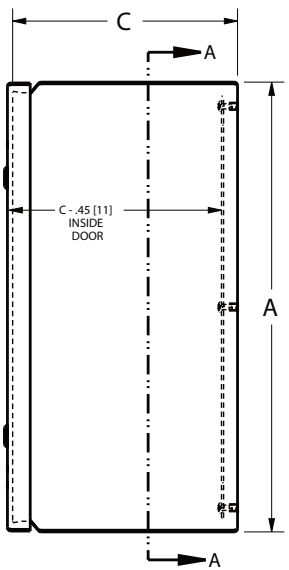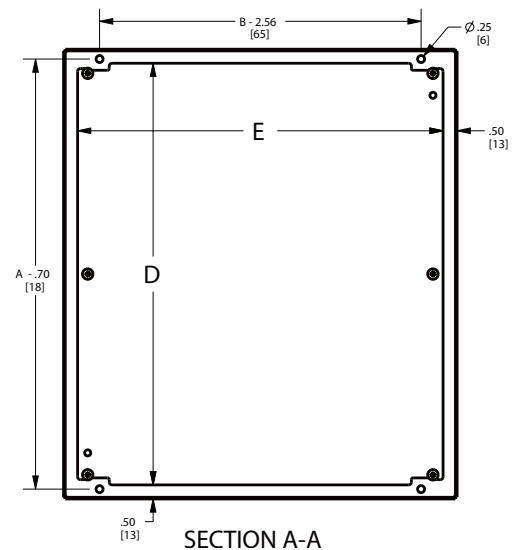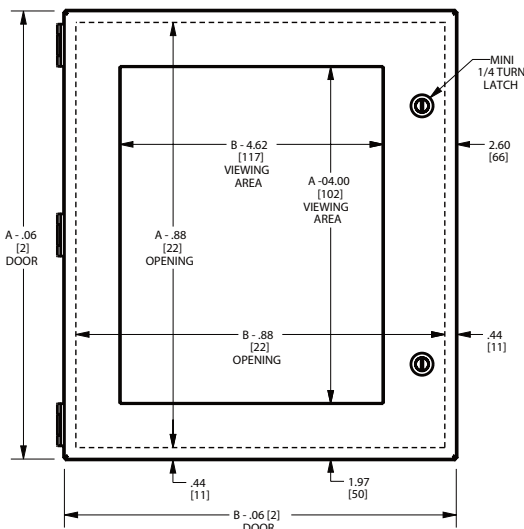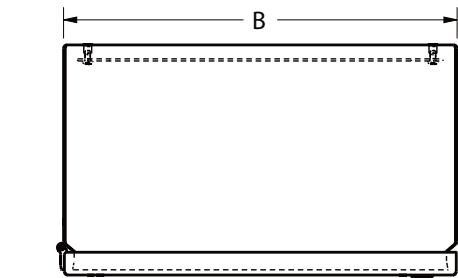

LATCH NOTES:
One latch centered on the door vertically if height is <= 14.00 [356]
Two latches located 3.00 [76] from top & bottom of door if height is > 14.00 [356]



Phone (989) 799-6871
Fax (989) 799-4524

316 Stainless Steel
Enviroline® Series
Enclosures

Application -

Designed to house electrical and electronic controls, instruments and components in areas which may be regularly hosed down or are in very wet conditions. Provides protection from dust, dirt, oil, and water. For outdoor application a drip shield is recommended. For installation information, consult our Installation Manual at www.saginawcontrol.com.

Construction -

- 0.075" stainless steel Type 316/316L.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Oil-resistant gasket.
- Collar studs provided for mounting optional sub-panels.
- Stainless steel concealed hinge.
- Removable and interchangeable doors.
- Black quarter turn latches.
- Latches are opened or closed with a screwdriver (optional tamper-resistant inserts are available).
- Mounting holes in back of enclosure.
- Mounting hardware, sealing washer and hole plug included.
- Removable print pocket.
- Ground studs on door and body.

Options -

- Optional mounting feet available.
- Door hardware available.

Finish -

#4 brushed finish on all exterior surfaces. Optional sub-panels are powder coated white.



IS5 - Industry Standards -
NEMA Type 4, 4X, 12 & Type 13
UL Listed Type 4, 4X & 12
CSA Type 4, 4X & 12
IEC 60529 IP66



316 STAINLESS STEEL ENVIROLINE® SERIES ENCLOSURES

ENCLOSURE PRODUCT CODE S7						SUB-PANEL (P3)			
Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard	List Price	Catalog No.	Panel Height (D)	Panel Width (E)	List Price
SCE-12EL1206SS6LP	12.00	12.00	6.00	IS5	643.39	SCE-12DLP12	9.00	9.00	13.67
SCE-12EL2406SS6LP	12.00	24.00	6.00	IS5	855.14	SCE-12P24	9.00	21.00	27.86
SCE-16EL1206SS6LP	16.00	12.00	6.00	IS5	708.54	SCE-16P12	13.00	9.00	14.81
SCE-16EL1208SS6LP	16.00	12.00	8.00	IS5	757.41	SCE-16P12	13.00	9.00	14.81
SCE-16EL1606SS6LP	16.00	16.00	6.00	IS5	785.11	SCE-16P16	13.00	13.00	24.57
SCE-16EL1608SS6LP	16.00	16.00	8.00	IS5	825.83	SCE-16P16	13.00	13.00	24.57
SCE-16EL2008SS6LP	16.00	20.00	8.00	IS5	925.17	SCE-20P16	17.00	13.00	30.37
SCE-20EL1606SS6LP	20.00	16.00	6.00	IS5	871.43	SCE-20P16	17.00	13.00	30.37
SCE-20EL1608SS6LP	20.00	16.00	8.00	IS5	925.17	SCE-20P16	17.00	13.00	30.37
SCE-20EL1610SS6LP	20.00	16.00	10.00	IS5	987.08	SCE-20P16	17.00	13.00	30.37
SCE-20EL2006SS6LP	20.00	20.00	6.00	IS5	952.88	SCE-20P20	17.00	17.00	35.44
SCE-20EL2008SS6LP	20.00	20.00	8.00	IS5	1,024.54	SCE-20P20	17.00	17.00	35.44
SCE-20EL2010SS6LP	20.00	20.00	10.00	IS5	1,091.33	SCE-20P20	17.00	17.00	35.44
SCE-20EL2408SS6LP	20.00	24.00	8.00	IS5	1,120.64	SCE-24P20	21.00	17.00	45.57
SCE-24EL1608SS6LP	24.00	16.00	8.00	IS5	1,008.25	SCE-24P16	21.00	13.00	32.92
SCE-24EL2006SS6LP	24.00	20.00	6.00	IS5	1,068.52	SCE-24P20	21.00	17.00	45.57
SCE-24EL2008SS6LP	24.00	20.00	8.00	IS5	1,120.64	SCE-24P20	21.00	17.00	45.57
SCE-24EL2010SS6LP	24.00	20.00	10.00	IS5	1,197.20	SCE-24P20	21.00	17.00	45.57
SCE-24EL2012SS6LP	24.00	20.00	12.00	IS5	1,270.49	SCE-24P20	21.00	17.00	45.57
SCE-24EL2408SS6LP	24.00	24.00	8.00	IS5	1,231.40	SCE-24P24	21.00	21.00	53.18
SCE-24EL2410SS6LP	24.00	24.00	10.00	IS5	1,316.08	SCE-24P24	21.00	21.00	53.18
SCE-24EL2412SS6LP	24.00	24.00	12.00	IS5	1,400.80	SCE-24P24	21.00	21.00	53.18
SCE-24EL2416SS6LP	24.00	24.00	16.00	IS5	1,588.12	SCE-24P24	21.00	21.00	53.18
SCE-24EL3008SS6LP	24.00	30.00	8.00	IS5	1,399.17	SCE-30P24	27.00	21.00	63.29
SCE-24EL3010SS6LP	24.00	30.00	10.00	IS5	1,505.04	SCE-30P24	27.00	21.00	63.29
SCE-30EL1606SS6LP	30.00	16.00	6.00	IS5	1,172.77	SCE-30P16	27.00	13.00	45.57
SCE-30EL2008SS6LP	30.00	20.00	8.00	IS5	1,270.49	SCE-30P20	27.00	17.00	55.70
SCE-30EL2010SS6LP	30.00	20.00	10.00	IS5	1,376.37	SCE-30P20	27.00	17.00	55.70
SCE-30EL2408SS6LP	30.00	24.00	8.00	IS5	1,400.80	SCE-30P24	27.00	21.00	63.29
SCE-30EL2410SS6LP	30.00	24.00	10.00	IS5	1,506.67	SCE-30P24	27.00	21.00	63.29
SCE-30EL2412SS6LP	30.00	24.00	12.00	IS5	1,596.26	SCE-30P24	27.00	21.00	63.29
SCE-30EL2416SS6LP	30.00	24.00	16.00	IS5	1,759.14	SCE-30P24	27.00	21.00	63.29
SCE-30EL3008SS6LP	30.00	30.00	8.00	IS5	1,604.41	SCE-30P30	27.00	27.00	83.55
SCE-30EL3010SS6LP	30.00	30.00	10.00	IS5	1,702.14	SCE-30P30	27.00	27.00	83.55
SCE-30EL3012SS6LP	30.00	30.00	12.00	IS5	1,808.01	SCE-30P30	27.00	27.00	83.55
SCE-30EL3608SS6LP	30.00	36.00	8.00	IS5	1,794.98	SCE-36P30	33.00	27.00	101.27
SCE-36EL2408SS6LP	36.00	24.00	8.00	IS5	1,579.97	SCE-36P24	33.00	21.00	75.96
SCE-36EL2410SS6LP	36.00	24.00	10.00	IS5	1,685.86	SCE-36P24	33.00	21.00	75.96
SCE-36EL3008SS6LP	36.00	30.00	8.00	IS5	1,794.98	SCE-36P30	33.00	27.00	101.27
SCE-36EL3010SS6LP	36.00	30.00	10.00	IS5	1,928.54	SCE-36P30	33.00	27.00	101.27
SCE-36EL3012SS6LP	36.00	30.00	12.00	IS5	2,044.18	SCE-36P30	33.00	27.00	101.27
SCE-36EL3608SS6LP	36.00	36.00	8.00	IS5	2,068.63	SCE-36P36	33.00	33.00	118.99
SCE-36EL3612SS6LP	36.00	36.00	12.00	IS5	2,296.66	SCE-36P36	33.00	33.00	118.99
SCE-42EL2410SS6LP	42.00	24.00	10.00	IS5	1,954.61	SCE-42P24	39.00	21.00	91.14
SCE-42EL3010SS6LP	42.00	30.00	10.00	IS5	2,140.28	SCE-42P30	39.00	27.00	116.47
SCE-42EL3612SS6LP	42.00	36.00	12.00	IS5	2,527.96	SCE-42P36	39.00	33.00	136.72
SCE-42EL3616SS6LP	42.00	36.00	16.00	IS5	2,684.32	SCE-42P36	39.00	33.00	136.72
SCE-48EL3612SS6LP	48.00	36.00	12.00	IS5	2,801.61	SCE-48P36	45.00	33.00	154.46
SCE-48EL3616SS6LP	48.00	36.00	16.00	IS5	3,054.06	SCE-48P36	45.00	33.00	154.46
SCE-60EL3612SS6LP	60.00	36.00	12.00	IS5	3,306.53	SCE-60P36	57.00	33.00	189.89
SCE-60EL3616SS6LP	60.00	36.00	16.00	IS5	3,567.15	SCE-60P36	57.00	33.00	189.89
SCE-72EL3016SS6LP	72.00	30.00	16.00	IS5	3,827.77	SCE-72P30	69.00	27.00	210.15
SCE-72EL3612SS6LP	72.00	36.00	12.00	IS5	3,933.64	SCE-72P36	69.00	33.00	225.33
SCE-72EL3616SS6LP	72.00	36.00	16.00	IS5	4,153.63	SCE-72P36	69.00	33.00	225.33

STAINLESS STEEL ENVIROLINE® SERIES ENCLOSURES
TECHNICAL DATA

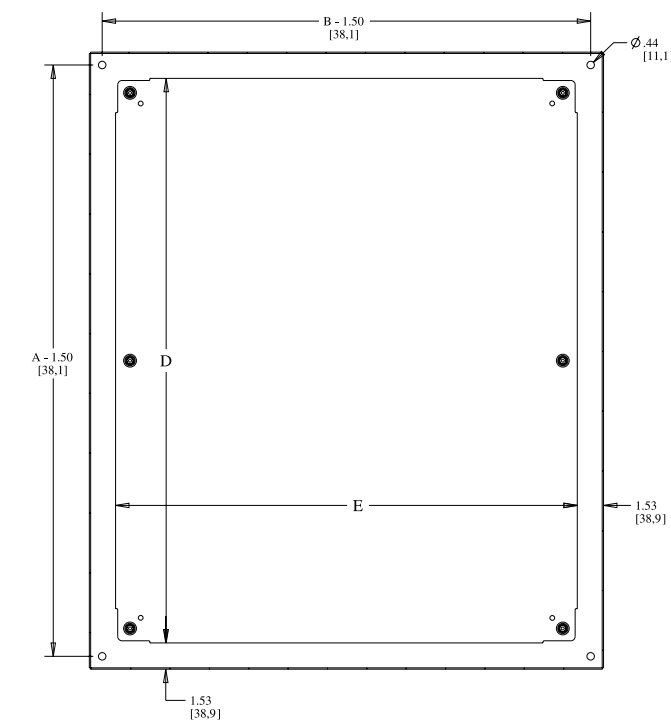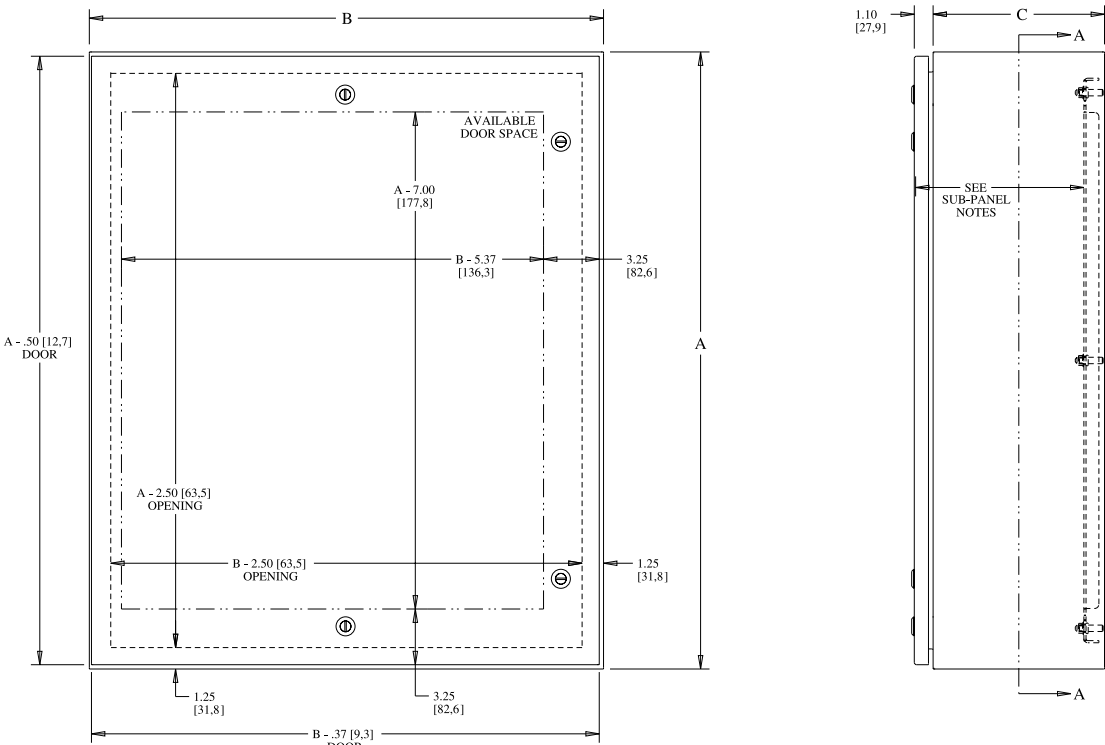

SECTION A-A

SUB-PANEL NOTES:
Dimensions are from the inside of the door
C + 0.32 [8.1] for flat sub-panels
C - 0.18 [4.5] for bent sub-panels

LATCH NOTES:
Enclosures < 24.00" [609.6] in height require only one latch centered on door.
Enclosures >= 24.00" [609.6] and < 40.00" [1016] in height require two latches on door.
Enclosures >= 40.00" [1016] require three latches on door.
Omit center latch top and bottom of door when door width is <= 30.00" [762]



Phone (989) 799-6871
Fax (989) 799-4524

[Back to
SS Wall-Mount
Enclosures](#)

Stainless Steel
Enviroline® Series
Wall-Mount
Sloping Top Enclosures

Application -

Designed to house electrical and electronic controls, instrumentation and components in indoor, outdoor and sanitary locations. For installation information, consult our Installation Manual at www.saginawcontrol.com.

Construction -

- 0.075" stainless steel Type 304.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- 15 Degree Sloping Top.
- Collar studs provided for mounting optional sub-panels.
- Mounting holes in back of the enclosure for wall mounting.
- Mounting hardware, sealing washers and hole plugs included.
- Stainless steel concealed hinges.
- Removable and interchangeable doors.
- Black quarter turn latches.
- Latches are opened or closed with a screwdriver (optional tamper resistant latches are available).
- Removable print pocket.
- Oil & water resistant gasket.
- Ground stud on door and body.

Finish -

4 Brushed finish on all exterior surfaces. Optional sub-panels are powder coated white.

IS5 - Industry Standards -

NEMA Type 4, 4X, 12 & Type 13
UL Listed Type 4, 4X & 12
CSA Type 4, 4X & 12
IEC 60529 IP66

STAINLESS STEEL ENVIROLINE® SERIES
WALL-MOUNT SLOPING TOP ENCLOSURES

ENCLOSURE PRODUCT CODE S8						SUB-PANEL (P3)			
Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard	List Price	Catalog No.	Panel Height (D)	Panel Width (E)	List Price
SCE-16EL1208SSST	16.00	12.00	8.00	IS5	883.65	SCE-16P12	13.00	9.00	14.81
SCE-16EL1608SSST	16.00	16.00	8.00	IS5	963.47	SCE-16P16	13.00	13.00	24.57
SCE-20EL1608SSST	20.00	16.00	8.00	IS5	1,079.37	SCE-20P16	17.00	13.00	30.37
SCE-20EL1612SSST	20.00	16.00	12.00	IS5	1,210.13	SCE-20P16	17.00	13.00	30.37
SCE-20EL2008SSST	20.00	20.00	8.00	IS5	1,195.31	SCE-20P20	17.00	17.00	35.44
SCE-20EL2012SSST	20.00	20.00	12.00	IS5	1,343.69	SCE-20P20	17.00	17.00	35.44
SCE-24EL2008SSST	24.00	20.00	8.00	IS5	1,307.56	SCE-24P20	21.00	17.00	45.57
SCE-24EL2012SSST	24.00	20.00	12.00	IS5	1,482.24	SCE-24P20	21.00	17.00	45.57
SCE-24EL2408SSST	24.00	24.00	8.00	IS5	1,436.64	SCE-24P24	21.00	21.00	53.18
SCE-24EL2412SSST	24.00	24.00	12.00	IS5	1,634.28	SCE-24P24	21.00	21.00	53.18
SCE-30EL2408SSST	30.00	24.00	8.00	IS5	1,634.28	SCE-30P24	27.00	21.00	63.29
SCE-30EL2412SSST	30.00	24.00	12.00	IS5	1,862.29	SCE-30P24	27.00	21.00	63.29
SCE-30EL3008SSST	30.00	30.00	8.00	IS5	1,871.80	SCE-30P30	27.00	27.00	83.55
SCE-36EL2408SSST	36.00	24.00	8.00	IS5	1,843.30	SCE-36P24	33.00	21.00	75.96
SCE-36EL2412SSST	36.00	24.00	12.00	IS5	2,072.73	SCE-36P24	33.00	21.00	75.96
SCE-36EL3008SSST	36.00	30.00	8.00	IS5	2,094.15	SCE-36P30	33.00	27.00	101.27
SCE-36EL3012SSST	36.00	30.00	12.00	IS5	2,384.87	SCE-36P30	33.00	27.00	101.27
SCE-36EL3016SSST	36.00	30.00	16.00	IS5	2,528.04	SCE-36P30	33.00	27.00	101.27
SCE-36EL3612SSST	36.00	36.00	12.00	IS5	2,435.89	SCE-36P36	33.00	33.00	118.99
SCE-48EL3616SSST	48.00	36.00	16.00	IS5	3,563.07	SCE-48P36	45.00	33.00	154.46
SCE-60EL3616SSST	60.00	36.00	16.00	IS5	4,162.10	SCE-60P36	57.00	33.00	189.89






Back to
SS Wall-Mount
Enclosures

Phone (989) 799-6871
Fax (989) 799-4524



STAINLESS STEEL ENVIROLINE® SERIES WALL-MOUNT
SLOPING TOP ENCLOSURES
TECHNICAL DATA

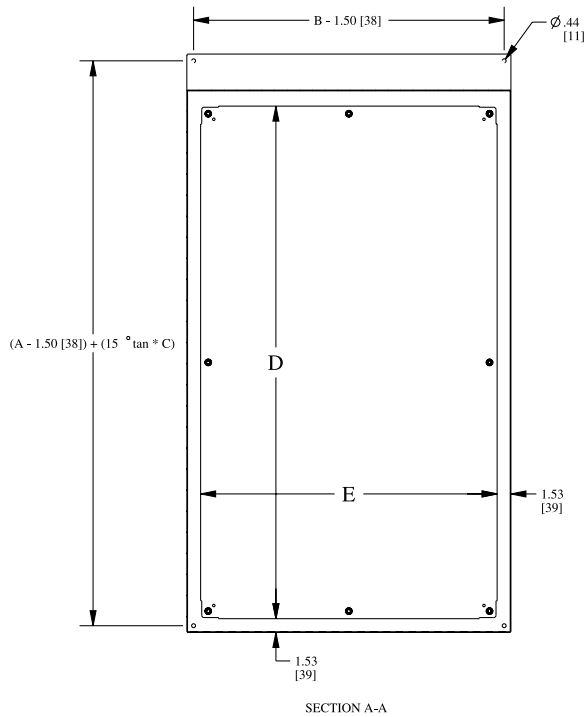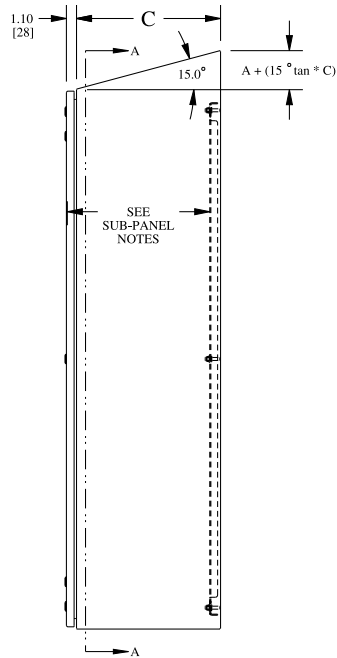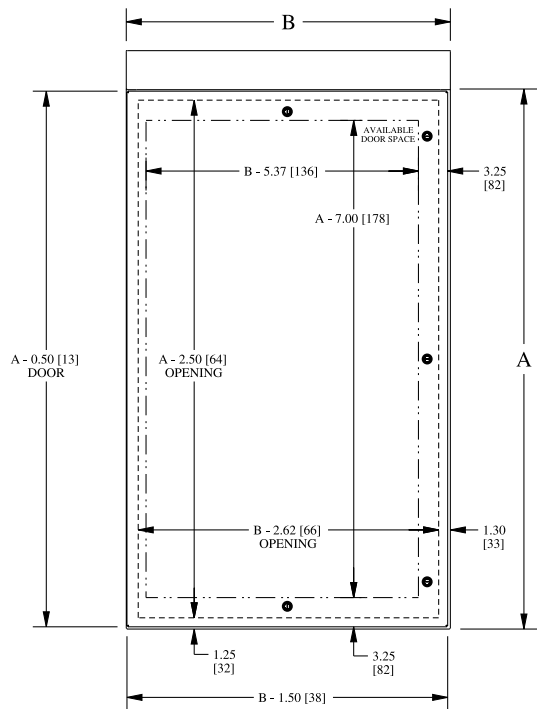

SUB-PANEL NOTES:
Dimensions are from the inside of the door
C = 0.32 [x,1] for flat sub-panels
C = 0.18 [4,5] for bent sub-panels

LATCH NOTES:
Enclosures < 24.00" [609,6] in height require only one latch centered on door.
Enclosures >= 24.00" [609,6] and < 40.00" [1016] in height require two latches on door.
Enclosures >= 40.00" [1016] require three latches on door.
Omit center latch top and bottom of door when door width is <= 30.00" [762]



Phone (989) 799-6871
Fax (989) 799-4524

Stainless Steel
Enviroline® Series
Wall-Mount Two-Door
Enclosures With
3-Point Hardware

Application -

Designed to house electrical and electronic controls, instrumentation and components. For outdoor applications a drip shield is recommended. For installation information, consult our Installation Manual at www.saginawcontrol.com.

Construction -

- 0.075" stainless steel Type 304.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Collar studs provided for mounting optional sub-panels.
- Removable center posts permit easy panel installation.
- Mounting holes in back of the enclosure for wall mounting.
- Mounting hardware, sealing washers and hole plugs included.
- Stainless steel concealed hinges.
- Removable and interchangeable doors.
- Black keylocking padlocking handles.
- 3-point latching mechanism.
- Removable print pocket.
- Oil & water resistant gasket.
- Ground stud on door and body.

Options -

Provisions for mechanical interlock.
See accessory section to order.

Finish -

#4 Brushed finish on all exterior surfaces.
Optional sub-panels are powder coated white.

IS5 - Industry Standards -

NEMA Type 4, 4X, 12 & Type 13
UL Listed Type 4, 4X & 12
CSA Type 4, 4X & 12
IEC 60529 IP66

STAINLESS STEEL ENVIROLINE® SERIES WALL-MOUNT
TWO-DOOR ENCLOSURES WITH 3-POINT HARDWARE

ENCLOSURE PRODUCT CODE S5						SUB-PANEL (P3)			
Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard	List Price	Catalog No.	Panel Height (D)	Panel Width (E)	List Price
SCE-24EL4210SSWFLP	24.00	42.00	10.00	IS5	2,990.12	SCE-42P24	39.00	21.00	91.14
SCE-24EL4810SSWFLP	24.00	48.00	10.00	IS5	3,108.66	SCE-48P24	45.00	21.00	98.74
SCE-30EL4210SSWFLP	30.00	42.00	10.00	IS5	3,168.28	SCE-42P30	39.00	27.00	116.47
SCE-30EL4810SSWFLP	30.00	48.00	10.00	IS5	3,347.42	SCE-48P30	45.00	27.00	129.13
SCE-30EL6010SSWFLP	30.00	60.00	10.00	IS5	3,758.21	SCE-60P30	57.00	27.00	159.52
SCE-36EL4212SSWFLP	36.00	42.00	12.00	IS5	3,772.54	SCE-42P36	39.00	33.00	136.72
SCE-36EL4812SSWFLP	36.00	48.00	12.00	IS5	3,866.89	SCE-48P36	45.00	33.00	154.46
SCE-36EL6012SSWFLP	36.00	60.00	12.00	IS5	4,269.15	SCE-60P36	57.00	33.00	189.89
SCE-42EL4212SSWFLP	42.00	42.00	12.00	IS5	3,824.34	SCE-42P42	39.00	39.00	156.97
SCE-42EL4812SSWFLP	42.00	48.00	12.00	IS5	4,248.08	SCE-48P42	45.00	39.00	177.24
SCE-42EL6012SSWFALP	42.00	60.00	12.00	IS5	4,460.85	SCE-60BFP42	56.00	38.00	230.41
SCE-48EL4812SSWFLP	48.00	48.00	12.00	IS5	4,359.04	SCE-48P48	44.00	44.00	212.67




Back to
SS Wall-Mount
Enclosures


Phone (989) 799-6871
Fax (989) 799-4524



STAINLESS STEEL ENVIROLINE® SERIES WALL-MOUNT
TWO-DOOR ENCLOSURES WITH 3-POINT HARDWARE
TECHNICAL DATA

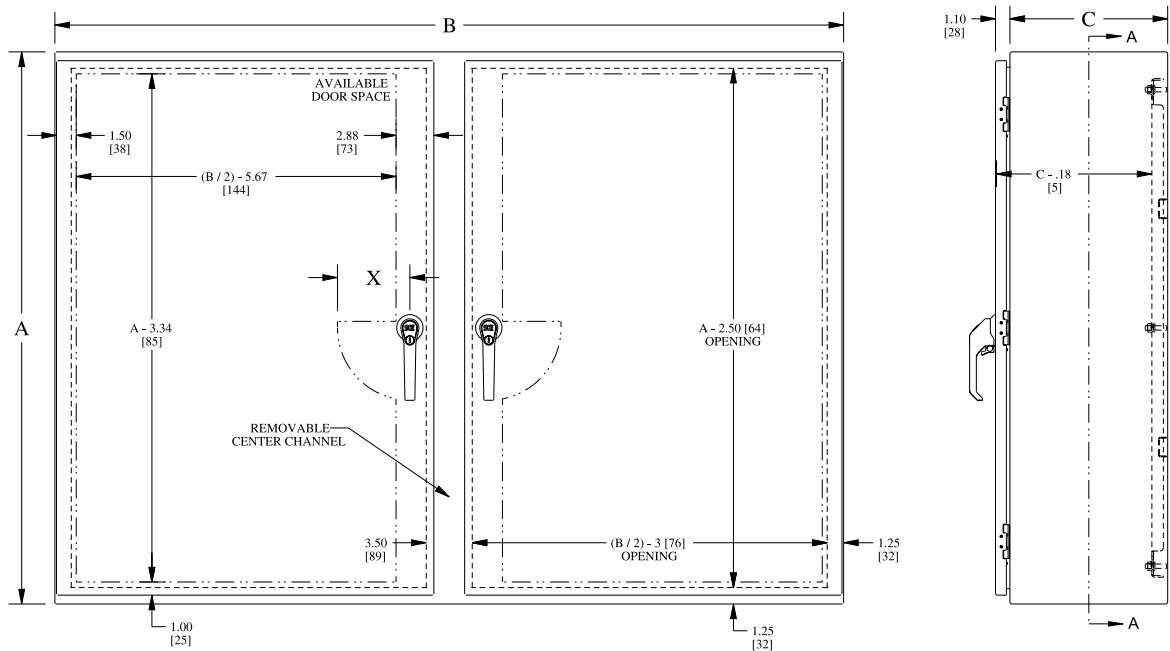

HANDLE NOTES:
Enclosures <= 42.00 [1067] in height
X = 5.50 [140] and uses 5.00 [127]
key-locking/padlocking handle.
Enclosures > 42.00 [1067] in height
X = 6.75 [171] and uses 7.00 [178]
key-locking/padlocking handle.

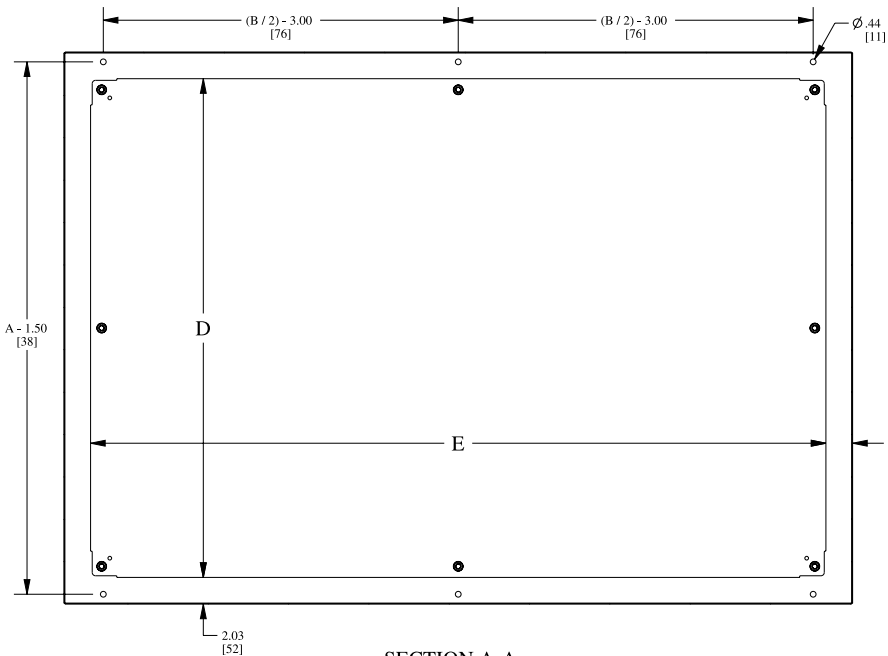

SECTION A-A



Phone (989) 799-6871
Fax (989) 799-4524

Fiberglass Screw Cover
Junction Enclosures

Application -

Designed for indoor or outdoor use to house electronic controls, instruments and components in areas that may be regularly hosed down, are in very wet conditions, or are exposed to corrosive agents. Provides protection from dust, dirt, oil and water.

Construction -

- Fiberglass reinforced compression molded polyester.
- Continuous memory retaining gasket.
- Mounting strips molded in.
- Captive screw fasteners.
- Integral panel mounting inserts.
- Stainless steel continuous hinge.

Finish -

Light gray fiberglass. Optional sub-panels are marine grade aluminum.

IS5 - Industry Standards -

NEMA Type 4, 4X, 12 & Type 13
UL Listed Type 4, 4X & 12
CSA Type 4, 4X & 12
IEC 60529 IP66



FIBERGLASS SCREW COVER JUNCTION ENCLOSURES

ENCLOSURE PRODUCT CODE F1									
Catalog No.	Height (A)	Width (B)	Depth (C)	Mounting (G)	Mounting (H)	Interior (J)	Interior (K)	Interior (L)	Industry Standard
SCE-604FG	7.39	5.43	4.75	6.75	2.00	5.84	3.85	4.00	IS5
SCE-606FG	7.52	7.50	4.75	6.75	4.00	5.72	5.72	4.00	IS5
SCE-806FG	9.50	7.50	4.75	8.88	4.00	7.73	5.74	4.00	IS5
SCE-808FG	9.50	9.41	4.25	8.75	6.00	7.73	7.73	4.06	IS5
SCE-1008FG	11.35	9.41	4.25	10.75	6.00	9.73	7.73	3.50	IS5
SCE-10086FG	11.38	9.38	5.06	10.75	6.00	9.73	7.73	4.37	IS5
SCE-1210FG	13.41	11.43	5.21	12.75	8.00	11.79	9.80	4.50	IS5
SCE-1212FG	13.41	13.50	6.25	12.75	10.00	11.70	11.70	5.53	IS5
SCE-1407FG	15.75	8.75	6.81	15.00	5.00	14.00	7.00	6.12	IS5
SCE-1412FG	15.47	13.50	6.25	14.62	10.00	13.53	11.55	5.37	IS5
SCE-1614FG	17.45	15.46	6.23	16.75	12.00	15.63	13.60	5.36	IS5
SCE-1816FG	19.61	17.61	8.82	18.88	12.00	17.69	15.69	7.99	IS5
SCE-2016FG	21.68	17.68	8.83	21.25	10.00	19.72	15.72	8.00	IS5




SUB-PANELS (F2)		
Catalog No.	Panel Height (D)	Panel Width (E)
SCE-6P4AL	4.88	2.88
SCE-6P6AL	4.88	4.88
SCE-8P6AL	6.88	4.88
SCE-8P8AL	6.88	6.88
SCE-10P8AL	8.88	6.88
SCE-12P10AL	10.88	8.88
SCE-12P12AL	10.88	10.88
SCE-14P8AL	12.88	5.88
SCE-14P12AL	12.88	10.88
SCE-16P14AL	14.88	12.88
SCE-18P16AL	16.88	14.88
SCE-20PJ16AL	18.88	14.88

Phone (989) 799-6871
Fax (989) 799-4524

Back to
Fiberglass
Enclosures



FIBERGLASS SCREW COVER JUNCTION ENCLOSURES
TECHNICAL DATA

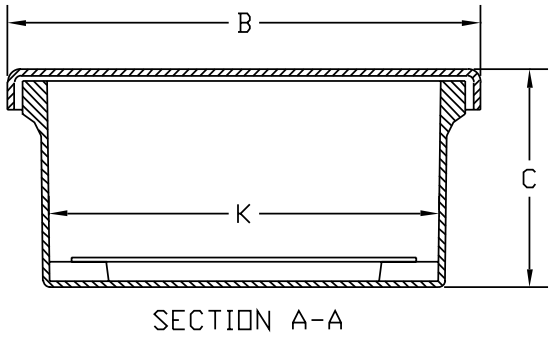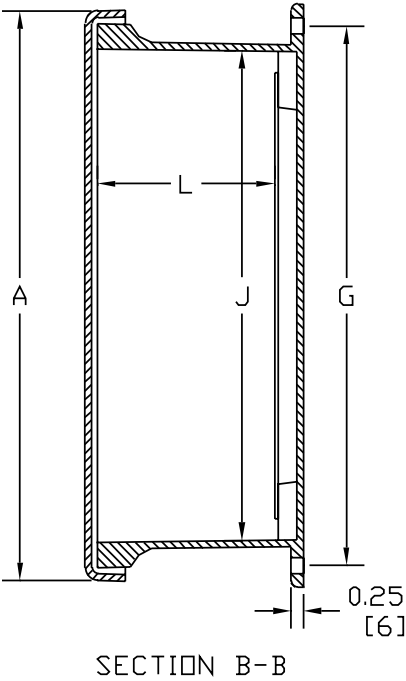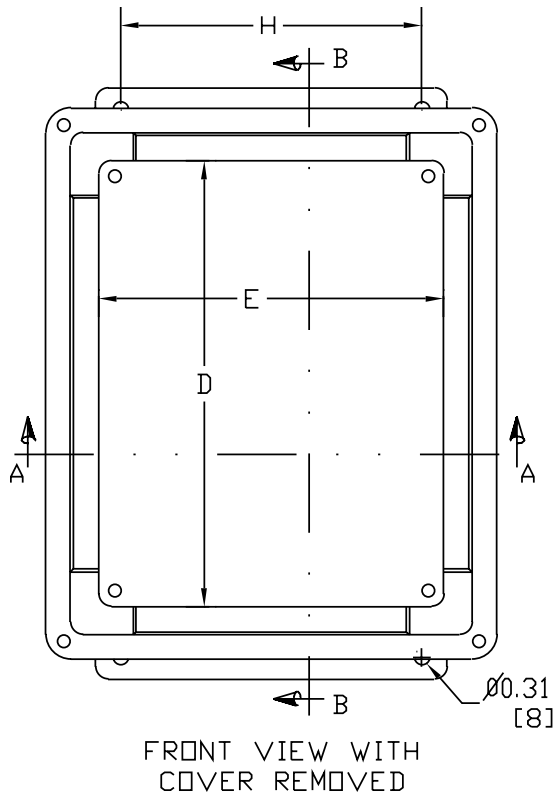

Phone (989) 799-6871
Fax (989) 799-4524

DOOR HARDWARE

1/4 Turn Door Latch Inserts

Designed to replace black quarter turn latches when additional security is required.

**Slotted 2 x 4 Door Latch
(28mm cam included)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-DLSB	1	Chrome	P2	17.38
SCE-DLSBB	1	Black	P2	17.38
SCE-DLSSB	1	Stainless	P2	42.22

**Wing Knob Door Latch
(28mm cam included)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-DLWKC	1	Chrome	P2	17.38
SCE-DLWKF	1	Black	P2	17.38
SCE-DLWKF-25	25	Black	V1	284.83

**Padlocking Wing Knob Latch
(28mm cam included)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-PLWKB	1	Black	P2	19.87
SCE-PLWKB-50	50	Black	V1	651.65

**7mm Triangular Latch with Key
(28mm cam included) (Key: SCE-107930)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-DL7TE	1	Chrome	P2	17.38

**Coinproof Door Latch
(28mm cam included)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-DLCA	1	Chrome	P2	14.90

**5mm Double Bit Door Latch with Key
(28mm cam included) (Key: SCE-110047)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-DL5MDB	1	Chrome	P2	12.91
SCE-DL5MDBB	1	Black	P2	12.91

**Small Three Point Cam, Plated Steel for use with
SCE 5" Handles.**

Catalog No.	Qty. Per Kit	Product Code	List Price
SCE-3PTSMC	1	P2	13.12

**6 mm External Stop Cam, Plated Steel for use
with Quarter Turn Latch.**

Catalog No.	Qty. Per Kit	Product Code	List Price
SCE-100814	10	P2	24.00

**Padlocking Housing Latch
(28mm cam included)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-PLHG	1	Black	P2	17.38

**Keylocking Wing Knob Latch
(28mm cam included) (Key: SCE-K333)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-KLWN	1	Chrome	P2	34.77
SCE-KLWNB	1	Black	P2	34.77

**Keylocking Door Latch
(28mm cam included) (Key: SCE-K333)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-DLKLD	1	Chrome	P2	27.32
SCE-DLKLDDB	1	Black	P2	27.99
SCE-DLKLDDB-25	25	Black	V1	543.12

**7mm Square Door Latch with Key
(28mm cam included) (Key: SCE-101695)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-DL7SC	1	Chrome	P2	17.38

**8mm Square Door Latch with Key
(28mm cam included) (Key: SCE-101697)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-DL8SB	1	Black	P2	12.91
SCE-DL8SC	1	Chrome	P2	12.91

**Non-Locking "T" Handle
(28mm cam included)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-NLTH	1	Chrome	P2	24.84

**Keylocking "T" Handle
(28mm cam included) (Key: SCE-K333)**

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-ELKLT	1	Chrome	P2	39.19

**28 mm External Stop Cam, Plated Steel for use
with Quarter Turn Latch.**

Catalog No.	Qty. Per Kit	Product Code	List Price
SCE-102804	10	P2	24.00



DOOR HARDWARE

Mini Quarter Turn Latches

Designed for use on ELJ enclosures and window kits.
(35° cam included)

Catalog No.	Qty. Per Kit	Finish	Product Code	List Price
SCE-MINQ	1	Chrome	P2	9.94
SCE-MINQB	1	Black	P2	9.94

**"SCE" Handle**

Designed for use on custom and stock SCE enclosures. Can be used as replacements for installed SCE hardware when a different locking mechanism is desired. 7" and 5" lengths for different size enclosures. Black zinc die cast. For 2 or 3-point latch, use SCE-ARK Door Rod Kit.

Catalog No.	Description	Length	Qty. Per Kit	Product Code	List Price
SCE-PCH5	Coinproof/Padlocking	5 in.	1	P2	86.93
SCE-PH5	Padlocking	5 in.	1	P2	86.93
SCE-PKH5	Keylocking/Padlocking	5 in.	1	P2	86.93
SCE-PCH5-7SC	7 mm Square Insert	5 in.	1	P2	86.93
SCE-PCH7	Coinproof/Padlocking	7 in.	1	P2	99.34
SCE-PH7	Padlocking	7 in.	1	P2	99.34
SCE-PKH7	Keylocking/Padlocking	7 in.	1	P2	99.34
SCE-PCH7-7SC	7 mm Square Insert	7 in.	1	P2	99.34



SCE-PCH5
SCE-PCH7



SCE-PKH5
SCE-PKH7
Key: SCE-KC101



SCE-PH5
SCE-PH7



SCE-PCH5-7SC
SCE-PCH7-7SC
Key: SCE-101695

Mini Quarter Turn Latch Options**304 Stainless Steel Padlock Bracket for Miniature Quarter Turn.
(ELJ & HWK)**

Catalog No.	Qty. Per Kit	Product Code	List Price
SCE-MINQPL	1	P2	8.52

**Black Keylocking Lever Knob for Miniature Quarter Turn.
(ELJ & HWK) (No cam included)**

Catalog No.	Qty. Per Kit	Product Code	List Price
SCE-MINQKLB	1	P2	49.52



Key: SCE-2233X

**Black Non-Locking Lever Knob for Miniature Quarter Turn.
(ELJ & HWK) (No cam included)**

Catalog No.	Qty. Per Kit	Product Code	List Price
SCE-MINQLB	1	P2	28.56

**Black 6 mm Square Miniature Quarter Turn with Key.
(ELJ & HWK) (No cam included)**

 
Catalog No.	Qty. Per Kit	Product Code	List Price
SCE-MINQ6MS	1	P2	34.19

**28 mm Cam, Plated Steel for use with Miniature Quarter**

Catalog No.	Qty. Per Kit	Product Code	List Price
SCE-105419	1	P2	2.04

**35° Cam, Plated Steel for use with Miniature Quarter Turns on ELJ
Enclosures. (ELJ, HWK & HA)**

Catalog No.	Qty. Per Kit	Product Code	List Price
SCE-112984	1	P2	1.73



DOOR HARDWARE

Enviroline® Series Handles


Designed for use in the Enviroline® Series enclosures, for a quick and easy conversion from the standard quarter turn latch with no added holes or cutouts necessary for installation. (Key: SCE-K333)

Catalog No.	Description	Qty. Per Kit	Product Code	List Price
SCE-ELKL	Keylocking Handle	1	P2	62.09
SCE-ELPL	Padlocking Handle	1	P2	62.09



Stainless Steel Handle (KEY: SCE-KC101)

Catalog No.	Description	Qty. Per Kit	Product Code	List Price
SCE-SSPCH5	Coinproof/Padlocking	1	P2	173.86
SCE-SSPH5	Padlocking	1	P2	173.86
SCE-SSPKH5	Keylocking	1	P2	191.88

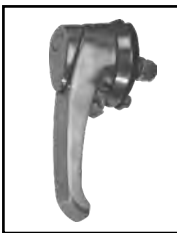

Flush Swing Handles

Designed for use on custom and stock SCE enclosures. Can be used as replacements on SCE work stations when a different locking mechanism is required. Zinc die cast metal powder coated black.

Catalog No.	Description	Qty. Per Kit	Product Code	List Price
SCE-FSH2	Keylocking	1	P2	63.34
SCE-FSH4	8mm Square Lock	1	P2	63.34
SCE-FSH6	Keylocking/Padlocking	1	P2	81.96
SCE-FSH8	Padlocking	1	P2	72.03



SCE-FSH2
Key: SCE-K333



SCE-FSH4
Key: SCE-101697



SCE-FSH6
Key: SCE-K333




SCE-FSH8

Enviroline® Three-Point Latch Kit

Designed for use with all Enviroline® Series enclosures. This latch kit will add a two or three point latching system to the enclosures with easy to cut and install rod guides and 5/16 inch round rods with rollers for a strong easy functioning latching system. No added holes or cutouts in enclosure necessary for installation.

Catalog No.	Qty. Per Kit	Product Code	List Price
SCE-3PTL	1	P2	62.09

 

Back to Accessories

Phone (989) 799-6871
Fax (989) 799-4524



DOOR HARDWARE

Quick Release Clamp Assembly

Designed for quick access to an enclosure with standard screw clamps. Clamps can be used on Type 4, 4X, and 12 enclosures.

Catalog No.	Enclosure Type	Thread Type	Finish	Qty. Per Kit	Product Code	List Price
SCE-QR1	"CHNF"	1/4-28	Chrome	1	P2	9.94
SCE-QR1SS	"CHNF"	1/4-28	Stainless	1	P2	19.87
SCE-QR2	"LP"	1/4-28	Stainless	2	P2	22.97
SCE-QRLP	"LP"	1/4-20	Stainless	2	P2	12.87



SCE-QR1



SCE-QR2



SCE-QRLP

Replacement Clamps

Designed as replacement clamps for SCE enclosures.


Catalog No.	Enclosure Type	Thread Type	Finish	Qty. Per Kit	Product Code	List Price
SCE-DRL-6	"CHNF"	1/4-28	Stainless	2	P2	7.46
SCE-DRL-4K	"LP"	1/4-28	Stainless	2	P2	12.42
SCE-LPCLAMP	"LP"	1/4-20	Chrome	2	P2	17.38
SCE-LPCLAMPSS	"LP"	1/4-20	Stainless	2	P2	21.87



SCE-DRL-6



SCE-DRL-4K

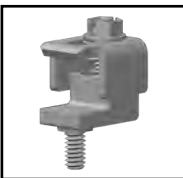

SCE-LPCLAMP/SS

Pull Handle

Designed for use as a handle on enclosures. Handle is a steel tube plastic coated black with black molded polyamide plastic end stays.

Catalog No.	Qty. Per Kit	Size	Product Code	List Price
SCE-UHK13	1	3.15 x 13.00	P2	39.74




Phone (989) 799-6871
Fax (989) 799-4524

Finger Pull

Designed for use as pull latch for the removable wireway.

Catalog No.	Description	Qty. Per Kit	Product Code	List Price
SCE-ELFP	Aluminum	1	P2	9.94

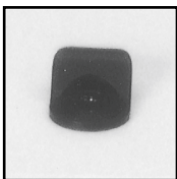

Padlock Kit For Junction Boxes

Designed for "CHNF" enclosures. Maintains water-tight and dust-tight seal. Made of plated steel.

Catalog No.	Qty. Per Kit	Product Code	List Price
SCE-PLKJIC	1	P2	9.94



Pull Handles - 4"

Designed for use on keyboard drawers, swing out panels, etc. Mounting hardware is included.

Catalog No.	Finish	Hole Center	Qty. Per Kit	Product Code	List Price
SCE-APH	Aluminum	4.00	1	P2	7.46



SCE-APH

GENERAL ACCESSORIES


Grounding Straps

Grounding straps can be used to provide electrical continuity between metal parts which must be electrically connected. Consists of braided copper with a ring terminal at both ends. Braid is insulated with green and yellow striped plastic.



Grounding Bars

Designed to provide a grounding area for controls and equipment. Has ten 10-32 tapped conductor holes and two mounting holes. Made of copper.

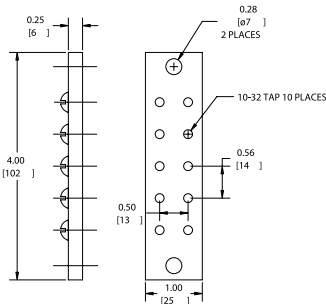

Door Stop Kit


For use on most SCE Type 4, 4X and 12 enclosures to lock door in the open position. Door opening must be at least 12 inches and must open horizontally. Designed to be installed at the bottom of the door opening. For installation information, consult our Installation Manual at www.saginawcontrol.com.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.



Removable Wire Cover

Designed to provide a “false” bottom in an enclosure with a bottom flange larger than 7 inches. Cover is bolted to a frame made of heavy gauge steel. Opens with a finger pull latch. A plate is provided to connect wire covers for a continuous bottom. Made of steel and powder coated white. For installation information, consult our Installation Manual at www.saginawcontrol.com.

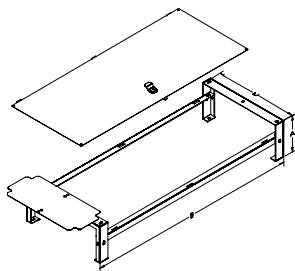

Phone (989) 799-6871
Fax (989) 799-4524



Catalog No.	Approx. Wire Size (AWG)	Length Between Ring Terminals (CTOC)	Ring Terminal Hole Size	Product Code	List Price
SCE-GS808	#8	8.00	0.330	P2	33.92

Catalog No.	Height (A)	Width (B)	Depth (C)	Product Code	List Price
SCE-GB10	1.00	4.00	0.25	P2	86.93

Catalog No.	Finish	Product Code	List Price
SCE-DSTOPK	Zinc Plated	P2	67.05

Catalog No.	Length (A)	Width (B)	Depth (C)	Enclosure Depth	Product Code	List Price
SCE-14RMW	6.00	35.00	14.00	18.00	P2	198.69
SCE-20RMW	6.00	35.00	20.00	24.00	P2	223.52

GENERAL ACCESSORIES

Keyboard Kit


Designed to house a keyboard input. Mounted on the outside of an enclosure. Enviroline® type construction with concealed hinge and quarter turn latches. Mouse drawer. Made of heavy gauge steel and powder coated ANSI-61 gray. For installation information, consult our Installation Manual at www.saginawcontrol.com.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.



Pull-Out Keyboard Drawer

Designed to hold a keyboard and mouse on a separate pull-out shelf. Mounts between mounting channels. Made of heavy gauge steel with a white powder coat finish. A mouse pad is included.

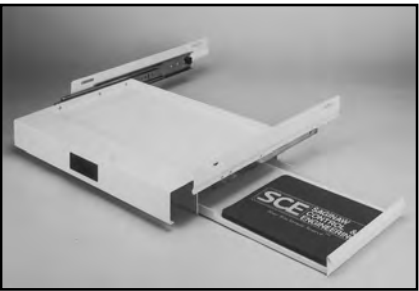

Catalog No.	Height (A)	Width (B)	Depth (C)	Product Code	List Price
SCE-24KB	12.25	24.00	5.62	P2	447.04

Catalog No.	Height (A)	Width (B)	Depth (C)	Enclosure Depth	Product Code	List Price
SCE-KBS	3.00	20.00	14.00	24.25	P2	372.54
SCE-KBS32	3.00	20.00	14.00	32.25	P2	372.54



Phone (989) 799-6871
Fax (989) 799-4524

Back to Accessories

GENERAL ACCESSORIES

Drip Shield Kit For Type 12 & 4 Enclosures

Protects door against dripping water and settling dust. Stainless steel screws and sealing washers are supplied with each kit. Made of steel and powder coated ANSI-61 gray.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.


Stainless Steel Drip Shield Kit For Type 4X Enclosures

Protects door against dripping water and settling dust. Furnished with stainless steel screws and sealing washers. Kit made of stainless steel Type 304.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.

Catalog No.	Fits Enclosure Width (B)	Product Code	List Price
SCE-DS12N4	12.00	P2	35.83
SCE-DS16N4	16.00	P2	40.80
SCE-DS20N4	20.00	P2	43.28
SCE-DS24N4	24.00	P2	50.74
SCE-DS30N4	30.00	P2	53.22
SCE-DS36N4	36.00	P2	56.40
SCE-DS42N4	42.00	P2	60.31
SCE-DS48N4	48.00	P2	68.82
SCE-DS60N4	60.00	P2	80.17
SCE-DS72N4	72.00	P2	90.43

Catalog No.	Fits Enclosure Width (B)	Product Code	List Price
SCE-DS12SS	12.00	P2	81.96
SCE-DS16SS	16.00	P2	89.41
SCE-DS20SS	20.00	P2	96.86
SCE-DS24SS	24.00	P2	104.31
SCE-DS30SS	30.00	P2	116.72
SCE-DS36SS	36.00	P2	129.14
SCE-DS42SS	42.00	P2	141.56
SCE-DS48SS	48.00	P2	158.95
SCE-DS60SS	60.00	P2	181.31
SCE-DS72SS	72.00	P2	216.07

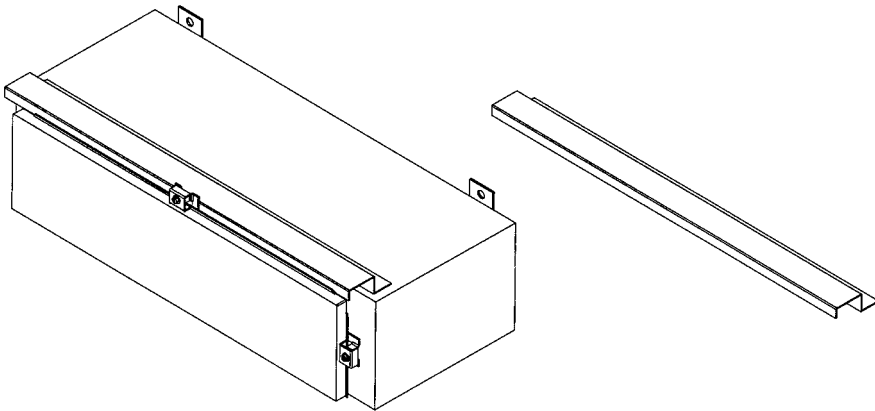

Back to Accessories

Phone (989) 799-6871
Fax (989) 799-4524



GENERAL ACCESSORIES

Folding Shelf

Folding shelves can be installed on the inside or outside of large enclosures. They are designed to support test equipment and programmers. Locks in the horizontal position. When not in use, shelf can be folded down. Made of heavy gauge steel and powder coated white. "SS" parts are stainless steel Type 304 with #4 brush finish. For installation information, consult our Installation Manual at www.saginawcontrol.com.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.




Accessory Columns and Bases

Designed to allow enclosures to be floor mounted. Columns can be mounted to either size base. Columns have flanges at each end and a gasketed access plate. Bases are to be bolted to the floor. Gasket and mounting hardware included. For technical information, consult the Installation Manual at www.saginawcontrol.com. Pedestals and bases are ANSI-61 gray powder coated. "SS" parts are stainless steel Type 304 with #4 brush finish.

Catalog No.	Height	Width	Product Code	List Price
SCE-FS1212	12.00	12.00	P2	146.53
SCE-FS1818	18.00	18.00	P2	183.79
SCE-FS2424	24.00	24.00	P2	221.04
Stainless Steel				
SCE-FS1212SS	12.00	12.00	P2	418.00
SCE-FS1818SS	18.00	18.00	P2	476.22
SCE-FS2424SS	24.00	24.00	P2	496.72

Catalog No.	Description	Depth	Width	Product Code	List Price
SCE-18SBASE	Pedestal Base	18.00	18.00	P2	111.76
SCE-24SBASE	Pedestal Base	24.00	24.00	P2	253.32
SCE-44CCOL	Straight Column	4.00	4.00	P2	183.79
SCE-44PBCOL	Angled Column	4.00	4.00	P2	218.56
SCE-66CCOL	Straight Column	6.00	6.00	P2	275.68
SCE-66PBCOL	Angled Column	6.00	6.00	P2	327.83
Stainless Steel					
SCE-18SBASESS	Pedestal Base, Stainless Steel	18.00	18.00	P2	424.63
SCE-24SBASESS	Pedestal Base, Stainless Steel	24.00	24.00	P2	451.45
SCE-44CCOLSS	Straight Column, Stainless Steel	4.00	4.00	P2	524.13
SCE-66CCOLSS	Straight Column, Stainless Steel	6.00	6.00	P2	554.52

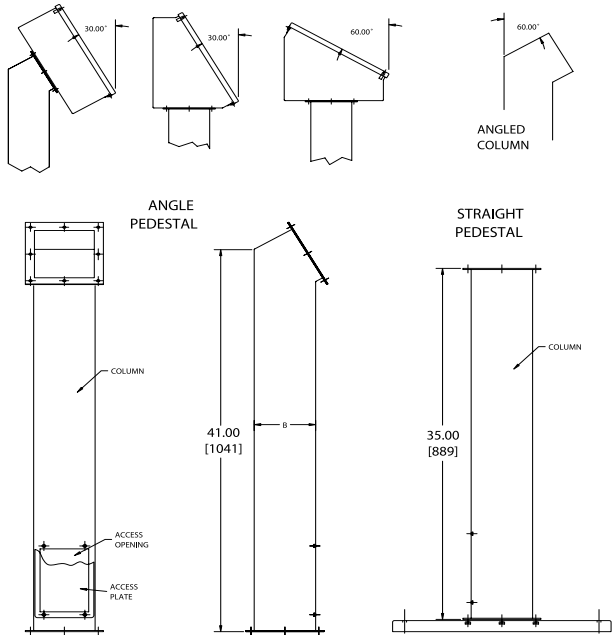

MOUNTING
OPTIONS

Eyebolts

Set of two eyebolts to use for lifting an enclosure. Includes sealing washers and flange nuts. Carbon steel plated zinc clear. For technical information, consult our Installation Manual at www.saginawcontrol.com.

Lifting Lugs

Lifting lugs are designed to be mounted to the left and right side of a standard wall-mount type enclosure for easy handling of fully wired enclosures. Mounting hardware is included. UL Recognized sealing washers supplied to maintain UL ratings of Type 3R, 4, 4X and 12.

Casters

Set of 4 casters. Swivel casters have ball bearing pivots and brakes. Load rating 250 lbs for each caster. For technical information, consult our Installation Manual at www.saginawcontrol.com.

Leveling Pads

Designed to attach to the bottom of the enclosure to allow for adjustments for uneven floors. Pads are zinc plated with a plastic base.

Angle Iron Mounting Feet

Designed for use with free-standing type enclosures when the enclosure must be secured to a concrete floor or base. Two angle iron-mounting feet per kit. Made of heavy gauge carbon steel powder coated ANSI-61 gray. Hardware is included to fasten mounting foot kit to the enclosure.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.

Heavy Duty Mounting Kit for
Free-Standing / Wall-Mount
Enclosures

Designed for use on SCE Multi-Door Free-Standing/Wall-Mount enclosures. Four mounting feet per kit, made of heavy gauge carbon steel with a black textured finish. Hardware is included to fasten mounting foot kit to the enclosure.


Catalog No.	Description	Quantity Per Kit	Product Code	List Price
SCE-EYE50	1/2"	2	P2	24.84
SCE-EYE63	5/8"	2	P2	28.56
SCE-EYE75	3/4"	2	P2	32.29



Catalog No.	Description	Quantity Per Kit	Product Code	List Price
SCE-LLB5	Steel, Zinc Plated	2	P2	26.55
SCE-LLB5SS	316 Stainless Steel, #4 Brush Finish	2	P2	39.86
SCE-LLB7	For use with Vented 3R Enclosures Steel, Powder Coated White	2	P2	30.32




Catalog No.	Description	Size of Wheel	Product Code	List Price
SCE-CAKR	Set of 4 - 2 Rigid, 2 Swivel	3"	P2	109.28
SCE-CAKS	Set of 4 Swivel Casters	3"	P2	136.60
SCE-CAKR4	Set of 4 - 2 Rigid, 2 Swivel	4"	P2	163.91
SCE-CAKS4	Set of 4 Swivel Casters	4"	P2	191.23

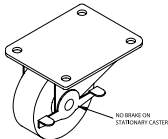



Catalog No.	Quantity Per Kit	Thread Size	Height	Product Code	List Price
SCE-LPD2	4	3/8 - 16	2.00	P2	37.25



Catalog No.	Used on Enclosure Depth	Product Code	List Price
SCE-XMAIMF18	18"	P2	38.34
SCE-XMAIMF20	20"	P2	42.60
SCE-XMAIMF24	24"	P2	51.12

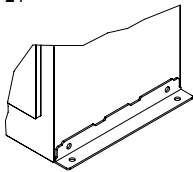

Catalog No.	Description	Quantity Per Kit	Product Code	List Price
SCE-HDWMK	Mounting Kit for use with Multi-Door Free-Standing / Wall-Mount Enclosures	4	P2	78.54

 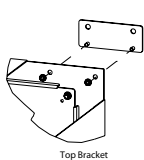

Phone (989) 799-6871
Fax (989) 799-4524



MOUNTING
OPTIONS

Mounting Foot Kit

Made for use with all SCE Envirolite® Series enclosures and two-door wall-mount enclosures. Chemical and Corrosion resistant Polyamide material rated for type 3, 3R, 4, 4X and 12. Available in kits of four or six, with plated steel or stainless steel fasteners.

Type 3R Mounting Foot Kit

Designed for use on large wall-mount type 3R enclosures. Four mounting feet per kit, made of heavy gauge carbon steel and powder coated ANSI-61 gray. Hardware is included to fasten mounting foot kit to the enclosure.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.

Envirolite® Junction Enclosure
(ELJ) Mounting Foot Kit

Made for use with all SCE Envirolite® Series junction enclosures. Chemical and Corrosion resistant Polyamide material rated for type 3, 3R, 4, 4X and 12 with stainless steel fasteners. Four mounting feet per kit. Hardware is included to fasten mounting foot kit to the enclosure.

S.S. Envirolite® Junction
Enclosure (ELJ) Mounting
Foot Kit

Made for use with all SCE Envirolite® Series junction enclosures. Four mounting feet per kit, made from type 304 stainless steel. Hardware is included to fasten the mounting foot kit to the enclosure.

S.S. Mounting Foot Kit

Made for use with all SCE Envirolite® Series enclosures and two-door wall-mount enclosures. Made of heavy gauge stainless steel type 316/316L with stainless steel stud. Available in kits of four.


Catalog No.	Fasteners	Quantity Per Kit	NEMA Rating	Product Code	List Price
SCE-ELMFK4	Zinc Plated	4	4 & 12	P2	17.69
SCE-ELMFK4SS	Stainless Steel	4	4, 4X & 12	P2	26.05
SCE-ELMFK6	Zinc Plated	6	4 & 12	P2	23.86
SCE-ELMFK6SS	Stainless Steel	6	4, 4X & 12	P2	31.02

Bulk Parts - 25 Kits per Package

SCE-ELMFK4-25	Zinc Plated	25	4 & 12	V1	307.85
SCE-ELMFK4SS-25	Stainless Steel	25	4, 4X & 12	V1	448.36




Catalog No.	Height (A)	Width (B)	Depth (C)	Product Code	List Price
SCE-N3RMFK4	3.25	2.00	0.51	P2	26.00

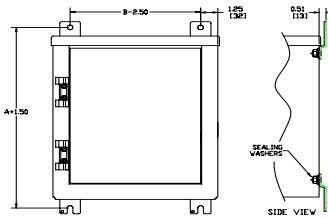

Catalog No.	Height (A)	Width (B)	Product Code	List Price
SCE-ELJMFKSS	2.13	1.25	P2	46.86



Catalog No.	Height (A)	Width (B)	Product Code	List Price
SCE-ELJMFKSS-OS	6.00	6.00	P2	48.86

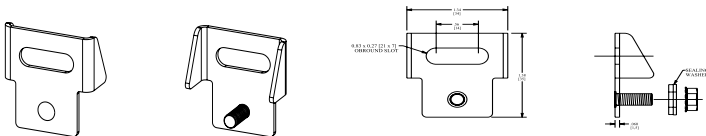

Catalog No.	Description	Quantity Per Kit	NEMA Rating	Product Code	List Price
SCE-ELMFK4SS6-OS	Stainless Steel Type 316	4	4, 4X & 12	P2	53.50



Phone (989) 799-6871
Fax (989) 799-4524

Back to
Accessories


MOUNTING
OPTIONS

Floor Stand Kit

Can be installed on most wall-mounted enclosures with a width of 20 inches or more. Can also be installed on SCE free-standing enclosures. Kits include two stands. This configuration can be ordered in special sizes. Consult a factory representative for price and delivery. For specifications, consult our Installation Manual at www.saginawcontrol.com. Made of carbon steel and finished with ANSI-61 recoatable gray finish. "SS" parts are made of stainless steel Type 304 with #4 brushed finish. "SS6" parts are made of stainless steel Type 316/316L with #4 brushed finish.

Catalog No.	Height (A)	Width (B)	Product Code	List Price
SCE-FK0608	6.00	8.00	P2	111.76
SCE-FK0610	6.00	10.00	P2	116.72
SCE-FK0612	6.00	12.00	P2	131.63
SCE-FK0618	6.00	18.00	P2	153.98
SCE-FK0624	6.00	24.00	P2	178.81
SCE-FK1208	12.00	8.00	P2	139.08
SCE-FK1210	12.00	10.00	P2	146.53
SCE-FK1212	12.00	12.00	P2	153.98
SCE-FK1216	12.00	16.00	P2	178.81
SCE-FK1218	12.00	18.00	P2	186.27
SCE-FK1220	12.00	20.00	P2	196.20
SCE-FK1224	12.00	24.00	P2	201.17
SCE-FK1512	15.00	12.00	P2	178.81
SCE-FK1516	15.00	16.00	P2	186.27
SCE-FK1518	15.00	18.00	P2	202.77
SCE-FK1524	15.00	24.00	P2	221.04
SCE-FK1808	18.00	8.00	P2	168.89
SCE-FK1810	18.00	10.00	P2	178.81
SCE-FK1812	18.00	12.00	P2	186.27
SCE-FK1816	18.00	16.00	P2	206.14
SCE-FK1824	18.00	24.00	P2	260.78
SCE-FK2412	24.00	12.00	P2	196.93
Stainless Steel				
SCE-FK1208SS	12.00	8.00	P2	379.99
SCE-FK1210SS	12.00	10.00	P2	409.79
SCE-FK1212SS	12.00	12.00	P2	437.11
SCE-FK1216SS	12.00	16.00	P2	496.72
SCE-FK1218SS	12.00	18.00	P2	524.03
SCE-FK1224SS	12.00	24.00	P2	552.60
SCE-FK1512SS	15.00	12.00	P2	536.45
SCE-FK1518SS	15.00	18.00	P2	584.89
SCE-FK1524SS	15.00	24.00	P2	618.41
SCE-FK2410SS	24.00	10.00	P2	581.16
SCE-FK2412SS	24.00	12.00	P2	608.48
SCE-FK1212SS6	12.00	12.00	P2	524.53
SCE-FK1218SS6	12.00	18.00	P2	628.84
SCE-FK1224SS6	12.00	24.00	P2	663.12
SCE-FK1512SS6	15.00	12.00	P2	643.74
SCE-FK1518SS6	15.00	18.00	P2	701.87
SCE-FK1524SS6	15.00	24.00	P2	742.09
SCE-FK2412SS6	24.00	12.00	P2	730.18

Available within 10 working days if not in stock

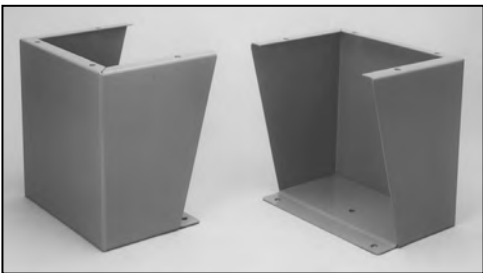

Phone (989) 799-6871
Fax (989) 799-4524



MOUNTING
OPTIONS


EL Flush Mount Frame

Flush Mount Frames are designed for use with the Enviroline® Series Wall-Mount Enclosures, quickly converting the wall-mount enclosure to a flush mount enclosure.

Two part numbers are required to complete the assembly: one part number for the height of the enclosure and one part number for the width of the enclosure.

All kits are provided with hardware to assemble the frame to the enclosure and maintain the environmental rating of the enclosure. For technical information, consult our Installation Manual at www.saginawcontrol.com. Frame is made of heavy gauge steel and finished with ANSI-61 gray powder coat. "SS" parts are made of heavy gauge Type 316/316L stainless steel with #4 brushed finish.

Catalog No.	Enclosure Height	Enclosure Width	Product Code	List Price
SCE-ELFM12H	12.00		P2	51.20
SCE-ELFM16H	16.00		P2	54.47
SCE-ELFM20H	20.00		P2	56.85
SCE-ELFM24H	24.00		P2	60.89
SCE-ELFM30H	30.00		P2	64.95
SCE-ELFM36H	36.00		P2	70.16
SCE-ELFM12HSS	12.00		P2	122.88
SCE-ELFM16HSS	16.00		P2	130.73
SCE-ELFM20HSS	20.00		P2	136.44
SCE-ELFM24HSS	24.00		P2	146.14
SCE-ELFM30HSS	30.00		P2	155.88
SCE-ELFM36HSS	36.00		P2	168.38
SCE-ELFM12W		12.00	P2	47.10
SCE-ELFM16W		16.00	P2	50.33
SCE-ELFM20W		20.00	P2	52.75
SCE-ELFM24W		24.00	P2	56.79
SCE-ELFM30W		30.00	P2	60.85
SCE-ELFM36W		36.00	P2	66.10
SCE-ELFM12WSS		12.00	P2	113.04
SCE-ELFM16WSS		16.00	P2	120.79
SCE-ELFM20WSS		20.00	P2	126.60
SCE-ELFM24WSS		24.00	P2	136.60
SCE-ELFM30WSS		30.00	P2	146.04
SCE-ELFM36WSS		36.00	P2	158.64

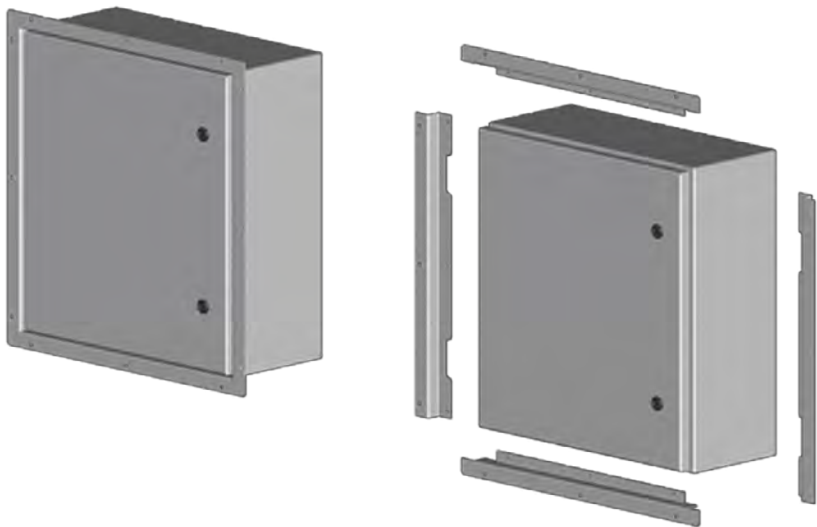

Phone (989) 799-6871
Fax (989) 799-4524

[Back to
Accessories](#)

MOUNTING
PANELS

SUB-PANELS

Construction -

Sub-panels are constructed from carbon steel. Size determines steel thickness.

Finish -

Powder coated white.

Options -

Configuration A - Add (SS) to the end of the sub-panel part number. (Example: SCE-12P10SS). Sub-panels are made of 316/316L stainless steel.

Configuration B & C - Add (SS) to the end of the sub-panel part number for 304 stainless steel (Example: SCE-30P30SS). Add (SS6) to the end of the sub-panel part number for 316/316L stainless steel (Example: SCE-30P30SS6).

Available within 10 working days if not in stock

Catalog No.	Height (A)	Width (B)	Configuration	Edge Flanges	Product Code	List Price
SCE-6P4	4.88	2.88	A	Flat	P3	3.01
SCE-6P6	4.88	4.88	A	Flat	P3	3.61
SCE-8P6	6.75	4.88	A	Flat	P3	4.17
SCE-8P8	6.75	6.88	A	Flat	P3	4.89
SCE-10P8	8.75	6.88	A	Flat	P3	5.70
SCE-10P10	8.75	8.88	A	Flat	P3	6.73
SCE-12DLP12	9.00	9.00	B	Flat	P3	13.67
SCE-12P10	10.75	8.88	C	Four	P3	7.72
SCE-12P12	10.75	10.88	A	Flat	P3	9.08
SCE-12P24	9.00	21.00	A	Flat	P3	27.86
SCE-12P6	10.75	4.88	A	Flat	P3	5.35
SCE-14P8	12.75	6.88	A	Flat	P3	7.39
SCE-14P12	12.75	10.88	A	Flat	P3	10.13
SCE-16P12	13.00	9.00	B	Flat	P3	14.81
SCE-16DLP14	13.00	11.00	B	Flat	P3	17.72
SCE-16P16	13.00	13.00	B	Flat	P3	24.57
SCE-16P10	14.75	8.88	A	Flat	P3	9.90
SCE-16P14	14.75	12.88	A	Flat	P3	19.95
SCE-20P12	17.00	9.00	B	Flat	P3	23.14
SCE-20P16	17.00	13.00	B	Flat	P3	30.37
SCE-20P20	17.00	17.00	B	Flat	P3	35.44
SCE-24P16	21.00	13.00	C	Two	P3	32.92
SCE-24P20	21.00	17.00	C	Two	P3	45.57
SCE-24P24	21.00	21.00	C	Four	P3	53.18
SCE-30P16	27.00	13.00	C	Two	P3	45.57
SCE-30P20	27.00	17.00	C	Two	P3	55.70
SCE-30P24	27.00	21.00	C	Four	P3	63.29
SCE-30P30	27.00	27.00	C	Four	P3	83.55
SCE-36P16	33.00	13.00	C	Two	P3	53.18
SCE-36P24	33.00	21.00	C	Four	P3	75.96
SCE-36P30	33.00	27.00	C	Four	P3	101.27
SCE-36P36	33.00	33.00	C	Four	P3	118.99
SCE-40P24	37.00	21.00	C	Four	P3	86.08
SCE-42P24	39.00	21.00	C	Four	P3	91.14
SCE-42P30	39.00	27.00	C	Four	P3	116.47
SCE-42P36	39.00	33.00	C	Four	P3	136.72
SCE-42P42	39.00	39.00	C	Four	P3	156.97
SCE-48P48	44.00	44.00	C	Four	P3	212.67
SCE-48P24	45.00	21.00	C	Four	P3	98.74
SCE-48P30	45.00	27.00	C	Four	P3	129.13
SCE-48P36	45.00	33.00	C	Four	P3	154.46
SCE-48P42	45.00	39.00	C	Four	P3	177.24
SCE-60BFP42	56.00	38.00	C	Four	P3	230.41
SCE-60PC36	55.63	33.00	C	Four	P3	181.41
SCE-60P24	57.00	21.00	C	Four	P3	129.13
SCE-60P30	57.00	27.00	C	Four	P3	159.52
SCE-60P36	57.00	33.00	C	Four	P3	189.89
SCE-60P48	56.00	44.00	C	Four	P3	268.38
SCE-60P60	56.00	56.00	C	Four	P3	331.68
SCE-64P25	60.00	21.75	C	Four	P3	159.52
SCE-64P31	60.00	27.75	C	Four	P3	167.11
SCE-64P37	60.00	33.75	C	Four	P3	182.30

MOUNTING
PANELS

SUB-PANELS

Construction -

Sub-panels are constructed from carbon steel. Size determines steel thickness.

Finish -


Powder coated white.

Options -

Configuration A - Add (SS) to the end of the sub-panel part number. (Example: SCE-12P10SS). Sub-panels are made of 316/316L stainless steel.

Configuration B & C - Add (SS) to the end of the sub-panel part number for 304 stainless steel (Example: SCE-30P30SS). Add (SS6) to the end of the sub-panel part number for 316/316L stainless steel (Example: SCE-30P30SS6).

Available within 10 working days if not in stock

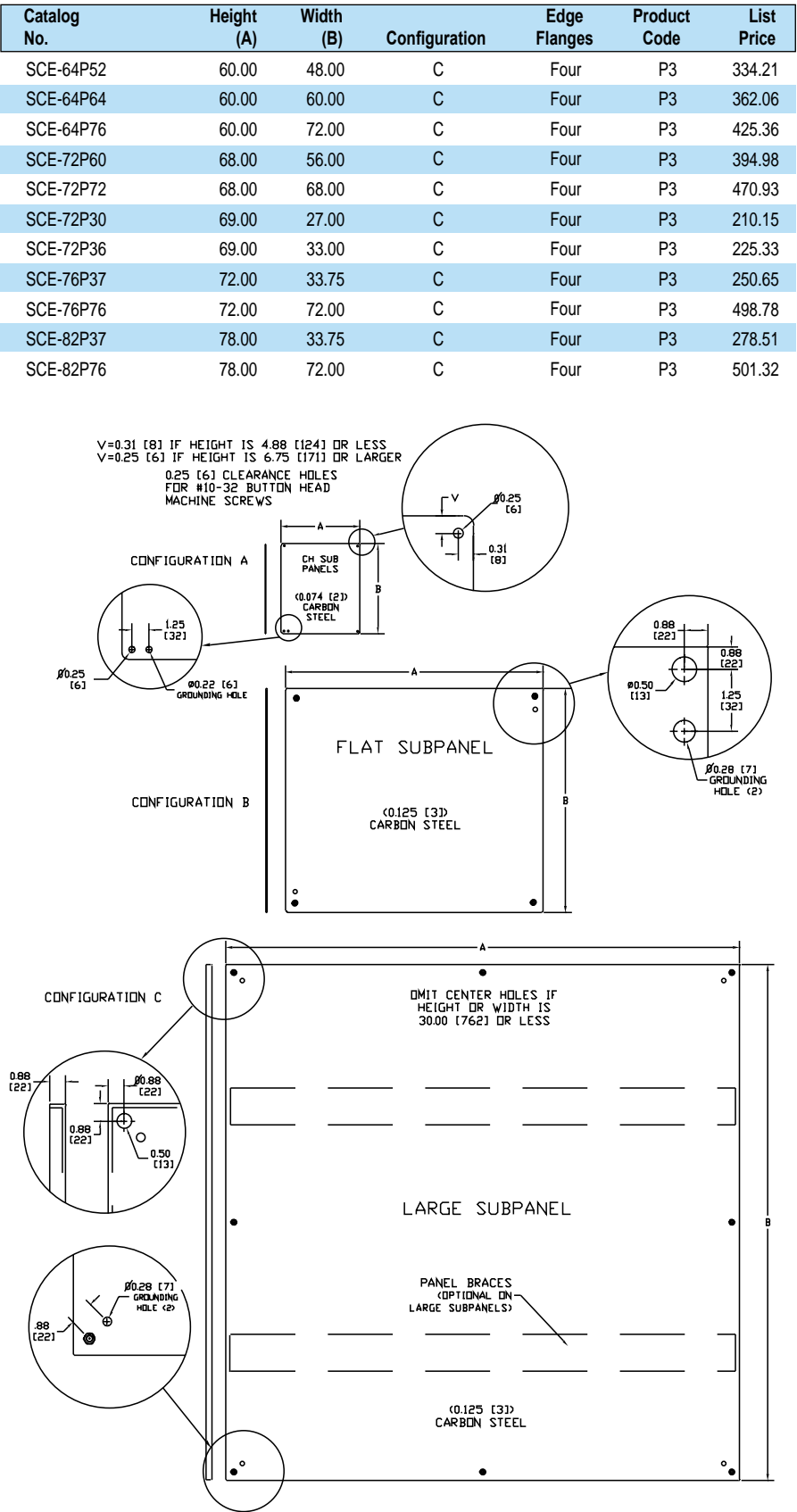

Phone (989) 799-6871
Fax (989) 799-4524

[Back to Accessories](#)


Sub-panels are constructed from galvanized steel for direct bonding of electrical components. Size determines steel thickness.

Catalog No.	Height (A)	Width (B)	Configuration	Edge Flanges	Product Code	List Price
SCE-6P4GALV	4.88	2.88	A	Flat	P3	3.01
SCE-6P6GALV	4.88	4.88	A	Flat	P3	3.61
SCE-8P6GALV	6.75	4.88	A	Flat	P3	4.17
SCE-8P8GALV	6.75	6.88	A	Flat	P3	4.89
SCE-10P8GALV	8.75	6.88	A	Flat	P3	5.70
SCE-10P10GALV	8.75	8.88	A	Flat	P3	6.73
SCE-12DLP12GALV	9.00	9.00	B	Flat	P3	13.67
SCE-12P24GALV	9.00	21.00	C	Four	P3	27.86
SCE-12P6GALV	10.75	4.88	A	Flat	P3	5.35
SCE-12P10GALV	10.75	8.88	A	Flat	P3	7.72
SCE-12P12GALV	10.75	10.88	A	Flat	P3	9.08
SCE-14P8GALV	12.75	6.88	A	Flat	P3	7.39
SCE-14P12GALV	12.75	10.88	A	Flat	P3	10.13
SCE-16P12GALV	13.00	9.00	B	Flat	P3	14.81
SCE-16DLP14GALV	13.00	11.00	B	Flat	P3	17.72
SCE-16P16GALV	13.00	13.00	B	Flat	P3	24.57
SCE-16P10GALV	14.75	8.88	A	Flat	P3	9.90
SCE-16P14GALV	14.75	12.88	A	Flat	P3	19.95
SCE-20P12GALV	17.00	9.00	B	Flat	P3	23.14
SCE-20P16GALV	17.00	13.00	B	Flat	P3	30.37
SCE-20P20GALV	17.00	17.00	B	Flat	P3	35.44
SCE-24P16GALV	21.00	13.00	C	Two	P3	32.92
SCE-24P20GALV	21.00	17.00	C	Two	P3	47.85
SCE-24P24GALV	21.00	21.00	C	Four	P3	55.84
SCE-30P16GALV	27.00	13.00	C	Two	P3	47.85
SCE-30P20GALV	27.00	17.00	C	Two	P3	58.49
SCE-30P24GALV	27.00	21.00	C	Four	P3	66.45
SCE-30P30GALV	27.00	27.00	C	Four	P3	87.73
SCE-36P16GALV	33.00	13.00	C	Two	P3	55.84
SCE-36P24GALV	33.00	21.00	C	Four	P3	79.76
SCE-36P30GALV	33.00	27.00	C	Four	P3	111.40
SCE-36P36GALV	33.00	33.00	C	Four	P3	130.89
SCE-40P24GALV	37.00	21.00	C	Four	P3	94.69
SCE-42P24GALV	39.00	21.00	C	Four	P3	100.25
SCE-42P42GALV	39.00	39.00	C	Four	P3	180.52
SCE-42P30GALV	39.00	27.00	C	Four	P3	128.12
SCE-42P36GALV	39.00	33.00	C	Four	P3	157.23
SCE-48P48GALV	44.00	44.00	C	Four	P3	244.57
SCE-48P24GALV	45.00	21.00	C	Four	P3	108.61
SCE-48P30GALV	45.00	27.00	C	Four	P3	142.04
SCE-48P36GALV	45.00	33.00	C	Four	P3	177.63
SCE-48P42GALV	45.00	39.00	C	Four	P3	203.83
SCE-60BFP42GALV	56.00	38.00	C	Four	P3	264.97
SCE-60P48GALV	56.00	44.00	C	Four	P3	308.64
SCE-60P60GALV	56.00	56.00	D	Four	P3	381.43
SCE-60P24GALV	57.00	21.00	C	Four	P3	142.04
SCE-60P30GALV	57.00	27.00	C	Four	P3	183.45
SCE-60P36GALV	57.00	33.00	C	Four	P3	218.37
SCE-64P25GALV	60.00	21.75	C	Four	P3	183.45
SCE-64P31GALV	60.00	27.75	C	Four	P3	192.18
SCE-64P37GALV	60.00	33.75	C	Four	P3	209.65



Sub-panels are constructed from galvanized steel for direct bonding of electrical components. Size determines steel thickness.

Catalog No.	Height (A)	Width (B)	Configuration	Edge Flanges	Product Code	List Price
SCE-64P52GALV	60.00	48.00	D	Four	P3	384.34
SCE-64P64GALV	60.00	60.00	D	Four	P3	452.58
SCE-64P76GALV	60.00	72.00	D	Four	P3	531.70
SCE-72P60GALV	68.00	56.00	D	Four	P3	454.23
SCE-72P72GALV	68.00	68.00	D	Four	P3	588.66
SCE-72P30GALV	69.00	27.00	C	Four	P3	241.67
SCE-72P36GALV	69.00	33.00	C	Four	P3	259.13
SCE-76P37GALV	72.00	33.75	C	Four	P3	288.25
SCE-76P76GALV	72.00	72.00	D	Four	P3	623.48
SCE-82P37GALV	78.00	33.75	C	Four	P3	320.29
SCE-82P76GALV	78.00	72.00	D	Four	P3	626.65

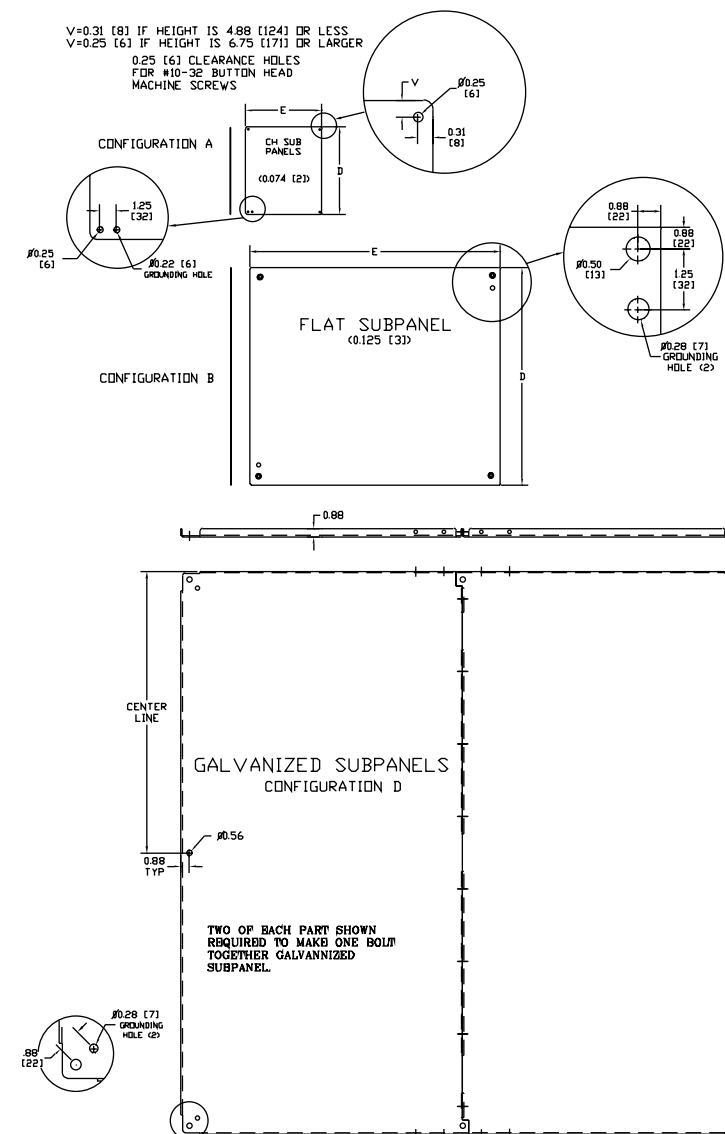

MOUNTING PANELS

Aluminum Sub-Panels For Fiberglass Enclosures

Designed to mount in the back of an enclosure. Made of marine grade aluminum.


Catalog No.	Height (A)	Width (B)	Edge Flanges	Product Code
SCE-6P4AL	4.88	2.88	Flat	F2
SCE-6P6AL	4.88	4.88	Flat	F2
SCE-8P6AL	6.88	4.88	Flat	F2
SCE-8P8AL	6.88	6.88	Flat	F2
SCE-10P8AL	8.88	6.88	Flat	F2
SCE-12P10AL	10.88	8.88	Flat	F2
SCE-12P12AL	10.88	10.88	Flat	F2
SCE-14P8AL	12.88	5.88	Flat	F2
SCE-14P12AL	12.88	10.88	Flat	F2
SCE-16P10AL	13.00	8.50	Flat	F2
SCE-16P14AL	14.88	12.88	Flat	F2
SCE-18P16AL	16.88	14.88	Flat	F2
SCE-20P16AL	17.00	13.00	Flat	F2
SCE-20PJ16AL	18.88	14.88	Flat	F2
SCE-24P12AL	21.00	9.00	Flat	F2
SCE-24P20AL	21.00	17.00	Formed	F2
SCE-30P20AL	27.00	17.00	Formed	F2
SCE-30P24AL	27.00	21.00	Formed	F2
SCE-36P30AL	33.00	27.00	Formed	F2
SCE-36P36AL	31.00	33.00	Formed	F2
SCE-48P36AL	45.00	33.00	Formed	F2
SCE-60P36AL	57.00	33.00	Formed	F2

Filler Plates

Designed to provide additional mounting surface between sub-panels in a large enclosure or between sub-panels or sections of a modular enclosure. Slotted mounting holes allow flexible installation. Panels are powder coated white.

Catalog No.	Height (D)	Width	Enclosure Height	Product Code	List Price
SCE-72FP	60.00	9.75	72.00	P3	78.49
SCE-84FP	72.00	9.75	84.00	P3	88.62
SCE-90FP	78.00	9.75	90.00	P3	96.21

Available within 10 working days if not in stock

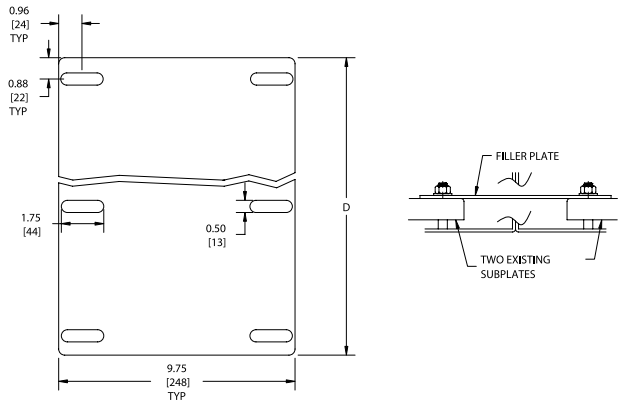


MOUNTING PANELS

Type 1 Sub-Panels

Designed to be used with Nema 1 enclosures. Made of heavy gauge steel and powder coated white.

Catalog No.	Height (A)	Width (B)	Product Code	List Price
SCE-6N6MP	4.00	4.00	N1	2.82
SCE-8N6MP	6.00	4.00	N1	3.26
SCE-8N8MP	6.00	6.00	N1	3.82
SCE-10N8MP	8.00	6.00	N1	4.46
SCE-10N10MP	8.00	8.00	N1	5.27
SCE-12N10MP	10.00	8.00	N1	6.03
SCE-12N12MP	10.00	10.00	N1	7.10
SCE-14N12MP	12.00	10.00	N1	7.92
SCE-16N12MP	14.00	10.00	N1	11.58
SCE-16N16MP	14.00	14.00	N1	19.21
SCE-20N16MP	18.00	14.00	N1	21.62
SCE-20N20MP	18.00	18.00	N1	27.84
SCE-24N16MP	22.00	14.00	N1	22.89
SCE-24N20MP	22.00	18.00	N1	31.67
SCE-24N24MP	22.00	22.00	N1	36.97
SCE-30N24MP	28.00	22.00	N1	43.99
SCE-30N30MP	28.00	28.00	N1	58.07
SCE-36N24MP	34.00	22.00	N1	52.80
SCE-36N30MP	34.00	28.00	N1	70.39

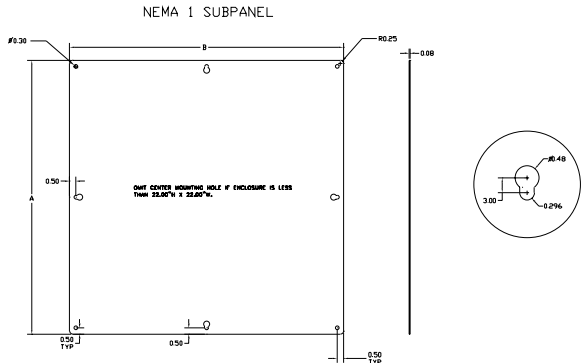

Catalog No.	Notes	Product Code	List Price
SCE-FSPS4	Set of 4	P2	55.88
SCE-FSPS6	Set of 6	P2	84.44
SCE-FSPS8	Set of 8	P2	126.66



[Back to Accessories](#)

Individual Panel Supports

Individual Panel Supports are available for mounting sub-panels. Packaged in sets with all mounting hardware included. Made of heavy gauge steel and plated. For technical information, consult our Installation Manual at www.saginawcontrol.com.


MOUNTING
PANELS

Perforated Sub-Panels

Perforated Sub-panels have 0.13 mounting holes with 0.25 staggered patterns for the installation of lightweight control components with #8 self threading screws, for use in small and medium size Type 1 enclosures.

Catalog No.	Height (A)	Width (B)	Product Code	List Price
SCE-6N6MPP	4.00	4.00	N1	7.36
SCE-8N6MPP	6.00	4.00	N1	8.71
SCE-8N8MPP	6.00	6.00	N1	9.83
SCE-10N8MPP	8.00	6.00	N1	11.58
SCE-10N10MPP	8.00	8.00	N1	13.47
SCE-12N10MPP	10.00	8.00	N1	15.11
SCE-12N12MPP	10.00	10.00	N1	15.94
SCE-14N12MPP	12.00	10.00	N1	17.14
SCE-16N12MPP	14.00	10.00	N1	19.25
SCE-16N16MPP	14.00	14.00	N1	22.58
SCE-20N16MPP	18.00	14.00	N1	26.46
SCE-20N20MPP	18.00	18.00	N1	30.55
SCE-24N16MPP	22.00	14.00	N1	30.55
SCE-24N20MPP	22.00	18.00	N1	36.52
SCE-24N24MPP	22.00	22.00	N1	53.44
SCE-30N24MPP	28.00	22.00	N1	68.13
SCE-30N30MPP	28.00	28.00	N1	85.12
SCE-36N24MPP	34.00	22.00	N1	85.12
SCE-36N30MPP	34.00	28.00	N1	100.48

NEMA 1 PERFORATED SUBPANEL

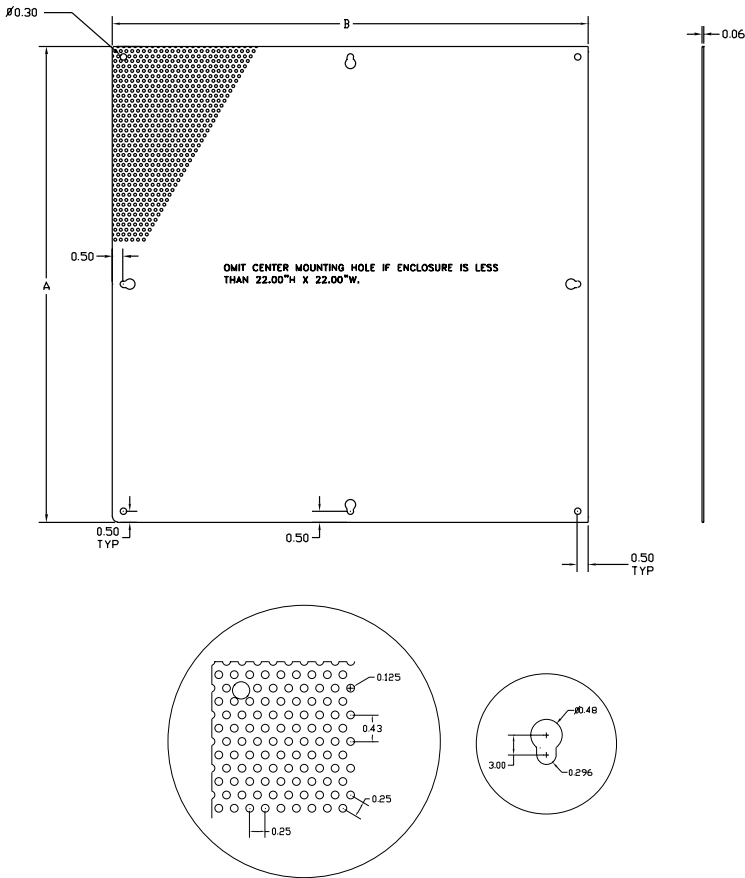

MOUNTING
PANELS


Enviroline® Junction
Enclosure (ELJ) Sub-Panels

Designed to be used with Enviroline® Series Junction Enclosures. Made of heavy gauge steel and powder coated white.

Catalog No.	Height (A)	Width (B)	Product Code	List Price
SCE-6P4J	5.00	3.00	P3	3.02
SCE-6P6J	5.00	5.00	P3	3.62
SCE-8P6J	7.00	5.00	P3	4.17
SCE-8P8J	7.00	7.00	P3	4.89
SCE-10P8J	9.00	7.00	P3	5.70
SCE-10P10J	9.00	9.00	P3	6.73
SCE-12P10J	11.00	9.00	P3	7.72
SCE-12P12J	11.00	11.00	P3	9.08
SCE-14P12J	13.00	11.00	P3	10.13
SCE-16P14J	15.00	13.00	P3	19.96
SCE-20P16J	19.00	15.00	P3	30.40
SCE-20P20J	19.00	19.00	P3	35.44

Catalog No.	Height (A)	Width (B)	Product Code	List Price
SCE-9P12L	8.00	11.00	P3	18.86
SCE-9P18L	8.00	17.00	P3	26.63
SCE-9P24L	8.00	23.00	P3	29.14
SCE-9P30L	8.00	29.00	P3	31.92
SCE-9P36L	8.00	35.00	P3	34.97

Enclosure Size - 0.75 = Sub-Panel Size

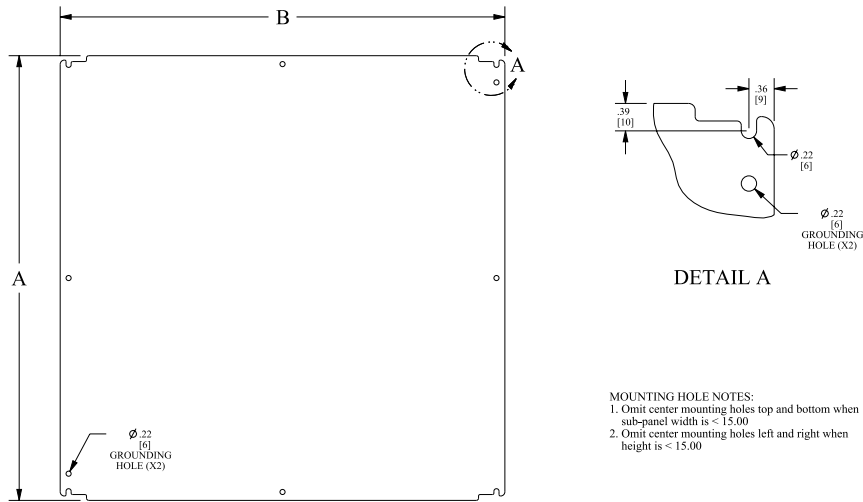

MOUNTING HOLE NOTES:
1. Omit center mounting holes top and bottom when sub-panel width is < 15.00
2. Omit center mounting holes left and right when height is < 15.00

MOUNTING PANELS

Dead Front Panel For Wall-Mount Enclosures

Designed for installation into Enviroline® Series wall-mount enclosures, to be installed in the front of an enclosure and to swing out of the enclosure. Kit consists of heavy gauge brackets, hinges, and mounting hardware. Installed by detaching door hinge from enclosure and installing swing out panel kit to the existing holes. Hinge supplied with the enclosure. Made of steel and powder coated white.


Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.

Dead Front Panel For CHNF & ELJ Enclosures

Designed for installation into Enviroline® Series junction enclosures and continuous hinged junction enclosures, to be installed in the front of an enclosure and to swing out of the enclosure. Kit consists of heavy gauge brackets, hinges, and mounting hardware. Installed by drilling hole in the side of the enclosure. Made of steel and powder coated white.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.


Catalog No.	Height	Width	Product Code	List Price
SCE-DF20EL16LP	16.00	12.63	P2	72.59
SCE-DF20EL20LP	16.00	16.63	P2	77.44
SCE-DF24EL20LP	20.00	16.63	P2	80.84
SCE-DF24EL24LP	20.00	20.63	P2	87.32
SCE-DF30EL20LP	26.00	16.63	P2	92.78
SCE-DF30EL24LP	26.00	20.63	P2	98.27
SCE-DF30EL30LP	26.00	26.63	P2	116.19
SCE-DF36EL20LP	32.00	17.63	P2	105.54
SCE-DF36EL24LP	32.00	20.63	P2	113.74
SCE-DF36EL30LP	32.00	26.63	P2	134.11
SCE-DF36EL36LP	32.00	32.63	P2	152.14
SCE-DF42EL24LP	38.00	20.63	P2	131.34
SCE-DF42EL30LP	38.00	26.63	P2	154.88
SCE-DF42EL36LP	38.00	32.63	P2	170.17
SCE-DF48EL24LP	44.00	20.63	P2	158.72
SCE-DF48EL36LP	44.00	32.63	P2	189.95
SCE-DF60EL36LP	56.00	32.63	P2	224.79
SCE-DF72EL36LP	68.00	32.63	P2	236.75

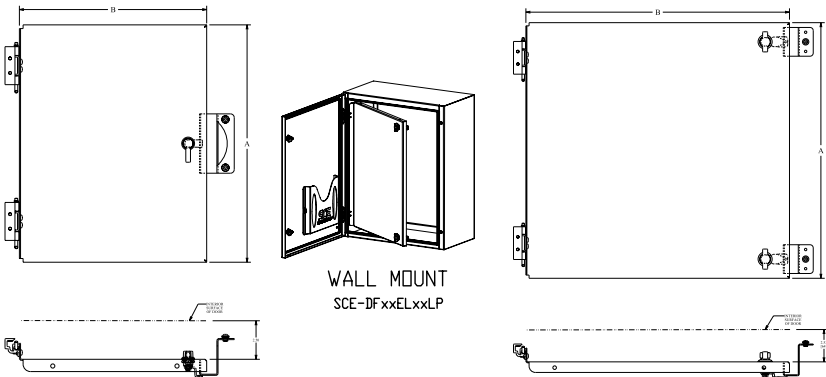

Enclosures 20 Inches High and Less

Enclosures Greater than 20 Inches

Catalog No.	Height	Width	Product Code	List Price
SCE-DFJ1008	8.50	6.50	P2	49.54
SCE-DFJ1210	10.50	8.50	P2	53.75
SCE-DFJ1212	10.50	10.50	P2	55.79
SCE-DFJ1412	12.50	10.50	P2	57.83
SCE-DFJ1614	14.50	12.50	P2	62.22
SCE-DFJ2016	18.50	14.50	P2	67.54

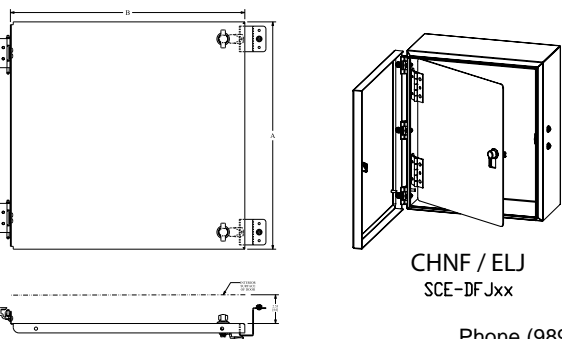

Phone (989) 799-6871
Fax (989) 799-4524



MOUNTING PANELS

Dead Front Panel For Two Door Enclosures with Center Channel

Designed for installation into Enviroline® Series two-door enclosures with center channel, to be installed in the front of an enclosure and to swing out of the enclosure. Kit consists of heavy gauge brackets, hinges, and mounting hardware. Installed by detaching door hinge from enclosure and installing swing out panel kit to the existing holes. Hinge is supplied with the enclosure. Made of steel and powder coated white. Kit contains one panel and all hardware for one dead front behind one door.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.

Dead Front Panel For Two Door Enclosures with Overlapping Doors


Designed for installation into two-door enclosures with overlapping doors, to be installed in the front of an enclosure and to swing out of the enclosure. Kit consists of heavy gauge brackets, hinges, and mounting hardware. Installed by detaching door hinge from enclosure and installing swing out panel kit to the existing holes. Hinge is supplied with the enclosure. Made of steel and powder coated white. Kit contains one panel and all hardware for one dead front behind one door.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.


Dead Front Extension Brackets for Wall Mount Enclosures

Designed to increase the distance from the door to the dead front. Brackets can be used when additional space is required when mounting parts to the dead front. Five brackets provided per kit.


Catalog No.	Height	Width	Qty. Per Kit	Product Code	List Price
SCE-DF60EL48	56.00	19.88	1	P2	345.67
SCE-DF60EL60	56.00	25.88	1	P2	385.11
SCE-DF72EL60	68.00	25.88	1	P2	425.77
SCE-DF72EL72	68.00	31.88	1	P2	475.40

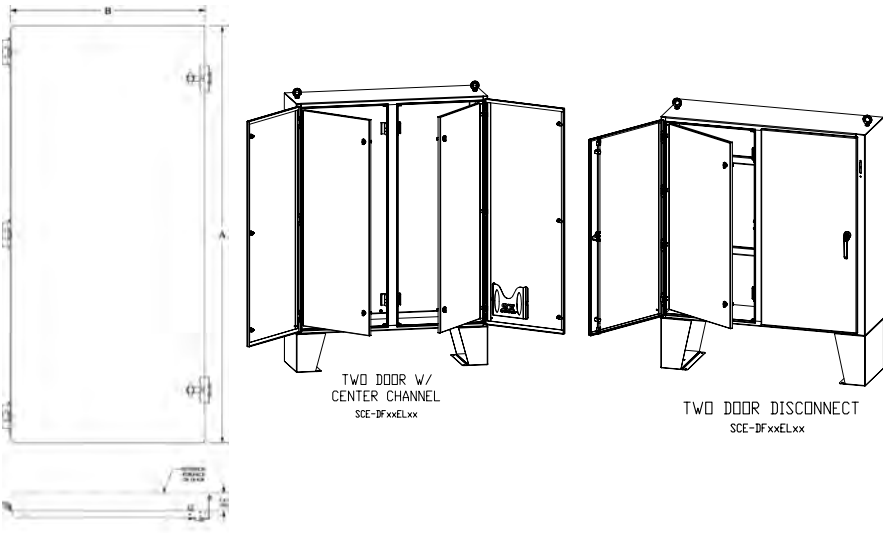

Catalog No.	Height	Width	Qty. Per Kit	Product Code	List Price
SCE-DF6048	56.00	22.13	1	P2	356.31
SCE-DF6060	56.00	28.13	1	P2	396.74
SCE-DF7260	68.00	28.13	1	P2	438.41
SCE-DF7272	68.00	34.13	1	P2	489.29

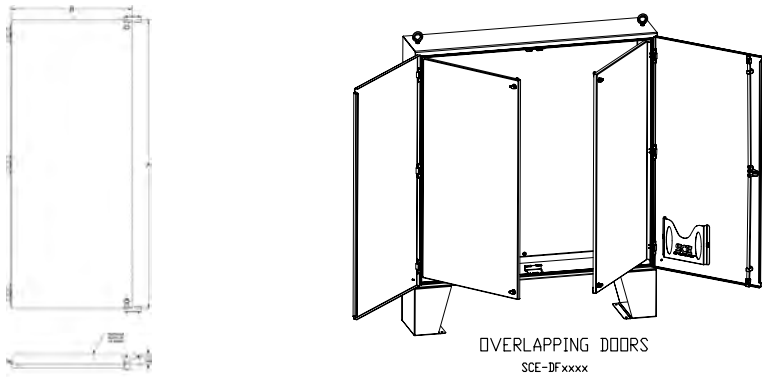

Catalog No.	Description	Product Code	List Price
SCE-115259	For use with Enviroline® Wall-Mount Enclosures	P2	34.43

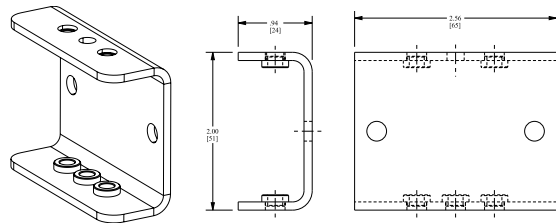

Phone (989) 799-6871
Fax (989) 799-4524

[Back to Accessories](#)

MOUNTING
PANELS

Swing Out Panel Kits For
Type 4 & 12 Enclosures


Designed to allow a standard sub-panel to be installed in the front of an enclosure and to swing out of the enclosure. Kits consist of heavy gauge brackets and hinges. Installed by drilling small hole in the side of the enclosure and bolting the bracket in place. Sealing washers are provided to insure that the enclosure will meet original standards after installation. For use in any Type 4 & 12 LP style wall mount enclosure where A x B dimensions are 12" x 12" or larger.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.

Swing Out Panel Kits For
EnviroLine®, Wall-mount,
3R Hinged Enclosures



Designed to allow a standard sub-panel to be installed in the front of an enclosure and to swing out of the enclosure. Kit consists of heavy gauge brackets, hinges, and mounting hardware. Installed by detaching door hinge from enclosure and installing swing out panel kit to the existing holes and hinge supplied with the enclosure. Made of steel and zinc plated.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.

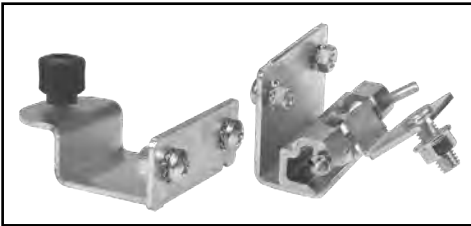

Catalog No.	Description	Product Code	List Price
SCE-NADFK	Swing Panel Kit (used with panels 30 inches and under)	P2	44.71
SCE-NADFK-3	Swing Panel Kit (used with panels over 30 inches)	P2	55.89
SCE-NADFKSS	Swing Panel Kit - Stainless Steel	P2	159.02

Catalog No.	Enclosure Height	Product Code	List Price
SCE-ELSP	12 to 16	P2	45.00
SCE-ELSP3	20 to 60	P2	56.00

 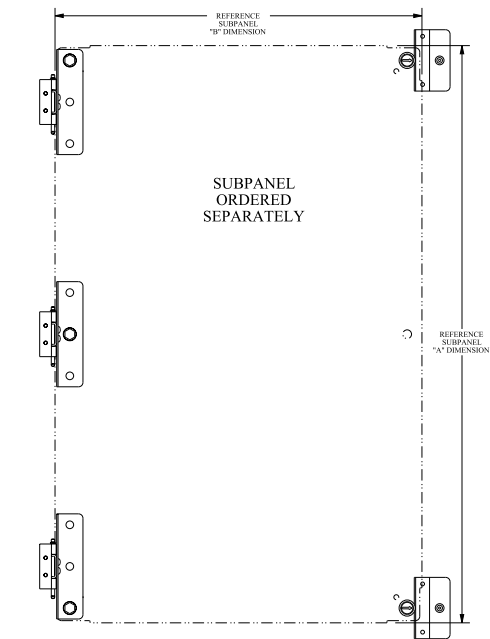


Phone (989) 799-6871
Fax (989) 799-4524



MOUNTING
PANELS

XM Barrier Plates

Designed to be installed on the back panel of XM Enclosures to provide protection against Arc Flash the height of the sub-plate, and allowing you to separate the high voltage and low voltage within the enclosure. Made of heavy gauge carbon steel and powder coated white. Mounting hardware included.

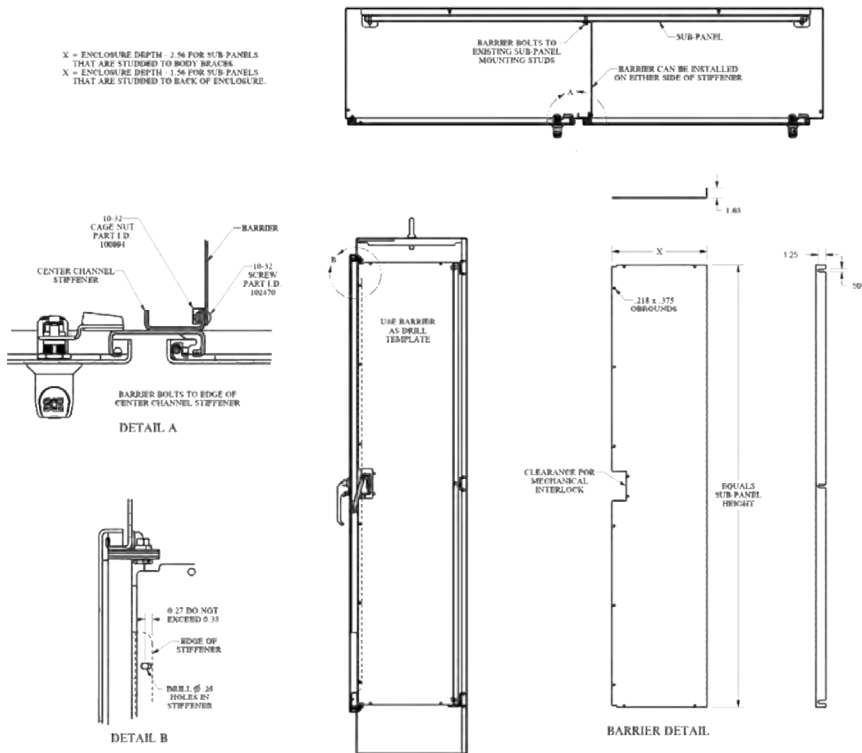

Catalog No.	For Use With	Length	Product Code	List Price
SCE-BPEX18	18 Inch Wide XM Barrier Plates	13.50	P2	91.48
SCE-BPEX24	24 Inch Wide XM Barrier Plates	19.50	P2	101.52

Barrier Extension for
XM Barrier Plates

Designed to be used with the XM Barrier Plates to extend the barrier, closing up the space between barrier plate and top or bottom of enclosure. Made of heavy gauge carbon steel and powder coated white.



Phone (989) 799-6871
Fax (989) 799-4524

Back to
Accessories


MEDIA POCKETS
& WINDOWS

Exterior Print Pocket

Designed for use on the exterior of an enclosure or door to keep prints clean and easy to access. Exterior print pockets have a hinged cover with cable stops to hold the door at 90 degrees open position and black quarter turn latches. Made of steel and powder coated RAL 7035 gray.

Provided with UL Recognized sealing washer to maintain Environmental Rating of the enclosure.

Catalog No.	Height	Width	Depth	Product Code	List Price
SCE-13ELJEXPP	13.00	19.00	2.45	P2	152.23
SCE-19ELJEXPP	19.00	13.00	2.45	P2	152.23

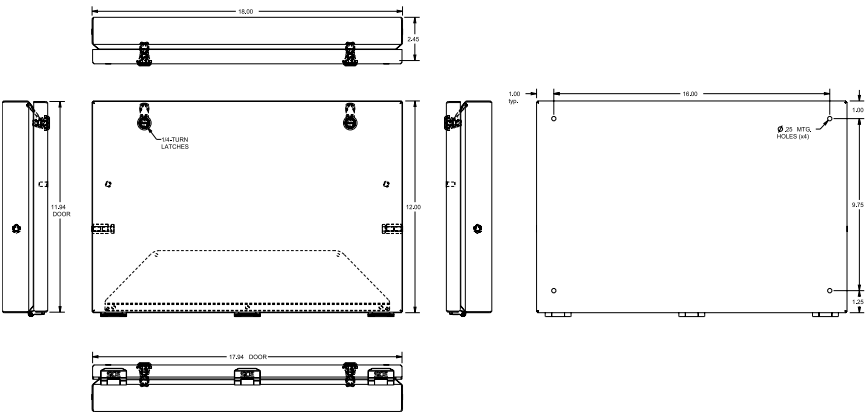

Media Storage Pockets

Designed to provide storage for electronic media. Padlockable. This pocket is not fire proof. Made of steel and powder coated white. For technical information, consult our Installation Manual at www.saginawcontrol.com.

Catalog No.	Description	Height	Width	Depth	Product Code	List Price
SCE-CDPK	CD Pocket	6.00	6.00	2.00	P2	124.18
SCE-DISPK	Disk Pocket	4.31	5.50	1.50	P2	124.18



Print Pockets

Designed to provide storage for prints on the interior of an enclosure. Intended for use as a replacement or as an additional pocket.

Catalog No.	Description	Height	Width	Depth	Product Code	List Price
SCE-PP7701	Small Standard Print Pocket White Polypropylene material	7.00	7.00	1.00	P2	22.35
SCE-PP101201	Large Standard Print Pocket White Polypropylene material	10.00	11.50	1.00	P2	24.84
SCE-PP101203	Extra Deep Print Pocket Heavy gauge steel powder coated white	10.00	11.50	3.00	P2	27.32



Phone (989) 799-6871
Fax (989) 799-4524



MEDIA POCKETS
& WINDOWS

Window Kits


Designed for use on most SCE Type 4, 4X and 12 enclosures. Consists of frame, window, oil-resistant gasket, and mounting hardware. Installed by making a cutout in the enclosure and fastening the window and frame in place. For technical information, consult our Installation Manual at www.saginawcontrol.com. The window is 0.25" polycarbonate material. Made of heavy gauge steel and powder coated ANSI-61 gray. "SS" kits are made of Type 304 stainless with #4 brushed finish.

UL Recognized Type 1, 3R & 12

Catalog No.	Viewing Area (L)	Viewing Area (W)	Cut-Out Size (G)	Cut-Out Size (H)	Height (A)	Width (B)	Product Code	List Price
SCE-PWK53NF	5.25	3.25	6.69	4.69	7.50	5.50	P2	99.34
SCE-PWK63NF	6.55	2.85	7.99	4.29	8.80	5.10	P2	109.28
SCE-PWK95NF	9.25	5.75	10.69	7.19	11.50	8.00	P2	119.22
SCE-PWK138NF	13.25	8.25	14.69	9.69	15.50	10.50	P2	151.50
SCE-PWK1711NF	17.25	11.25	18.69	12.69	19.50	13.50	P2	208.62
SCE-PWK2315NF	23.25	15.25	24.69	16.69	25.50	17.50	P2	257.05
SCE-PWK2919NF	29.25	19.25	30.69	20.69	31.50	21.50	P2	382.47

Stainless Steel

SCE-PWK53NFSS	5.25	3.25	6.69	4.69	7.50	5.50	P2	149.01
SCE-PWK95NFSS	9.25	5.75	10.69	7.19	11.50	8.00	P2	180.06
SCE-PWK138NFSS	13.25	8.25	14.69	9.69	15.50	10.50	P2	228.49
SCE-PWK1711NFSS	17.25	11.25	18.69	12.69	19.50	13.50	P2	300.51
SCE-PWK2315NFSS	23.25	15.25	24.69	16.69	25.50	17.50	P2	388.68
SCE-PWK2919NFSS	29.25	19.25	30.69	20.69	31.50	21.50	P2	576.19

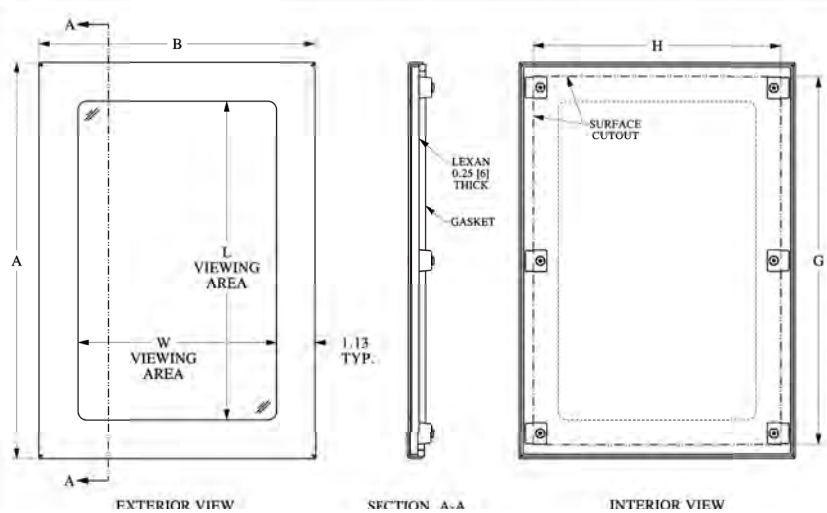

Phone (989) 799-6871
Fax (989) 799-4524

Back to
Accessories

Service Parts

Gasket Rolls

Oil-resistant gasket made of a urethane closed cell sponge material. Self adhesive backing. For installation information, consult our Installation Manual at www.saginawcontrol.com. UL, CSA recognized.

IS9 - Industry Standards -
UL Component Recognized
CSA Component Recognized

EMI/RFI Shielded Gasket

Specifically designed to combine outstanding attenuation characteristics and environmental protection against dust, dirt, moisture, and severe temperature variations. For Technical Information, consult our Installation Manual at www.saginawcontrol.com. Made of urethane foam wrapped in nickel plated copper fabric with adhesive backing.

Conductive Tape

Copper foil tape with conductive adhesive backing. Makes it unnecessary to plate an enclosure in preparation for shielding protection. Apply the tape over unprotected steel in a small free area around the perimeter of the door. Provides protection to the steel against corrosion and rusting as well as grounding protection necessary in shielding protection.

Mechanical Defeater for V-Style Disconnects


Designed to prevent the disconnect from being turned to the on position, until the master door is shut and the handle or latch is in the closed/latched position. Works with most standard enclosures with SCE three-point door hardware or quarter turn latches. For Technical Information, consult our Installation Manual at www.saginawcontrol.com.

Catalog No.	Length	Size	Product Code	List Price
SCE-GA14X1	40 Feet	0.25 x 1.00	P2	29.80
SCE-GA14X75	40 Feet	0.25 x 0.75	P2	28.56
SCE-GA18X50	50 Feet	0.13 x 0.75	P2	21.11

Catalog No.	Length	Size	Product Code	List Price
SCE-EMIG	7 Feet	0.25 x 1.00	P2	119.22

Catalog No.	Length	Size	Product Code	List Price
SCE-SLT	50 Feet	3 MILS x 1.00	P2	144.05

Catalog No.	Description	Product Code	List Price
SCE-MDV	Mechanical Defeater	P2	181.05

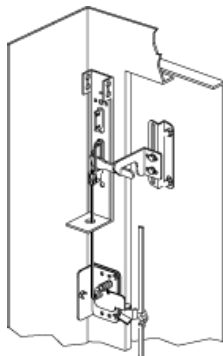

Phone (989) 799-6871
Fax (989) 799-4524



Service Parts

Sealing Washers

Designed for use on the flat surface of environmentally rated enclosures to maintain the rating of type 2, 3, 3R, 3S, 4, 4X & 12 when holes for fastener must be provided for the installation of mounting brackets, drip shields and other accessories on the inside or outside of the enclosure body or doors.

IS10 - Industry Standards -
UL Component Recognized

Channel Nuts

Designed for use in free-standing enclosures to allow mounting of additional equipment.

Channel Nuts

Designed for use with the SCE light channels on the inside top of larger enclosures. For quick easy installation of lights.

Clamping Nuts

Clamping nuts with a #10-32 retained nut to fit all rack mounting angles and rack mounting frames to provide tapped holes. Nuts are zinc plated.

Catalog No.	Suitable For Use With	Qty. Per Kit	Product Code	List Price
SCE-BSW19SS	10-32	50	P2	20.43
SCE-BSW25SS	1/4-20	50	P2	21.69
SCE-BSW31SS	5/16	50	P2	22.38
SCE-BSW38SS	3/8	50	P2	29.95



Catalog No.	Description	Qty. Per Kit	Product Code	List Price
SCE-PS3816CN	3/8 - 16 Strut Nut	20	P2	42.22
SCE-PS1420CN	1/4-20 Strut Nut	20	P2	42.22



SCE-PS1420CN




SCE-PS3816CN

Catalog No.	Description	Qty. Per Kit	Product Code	List Price
SCE-PS1032CN	10-32 for Small Channel	20	P2	36.02



Catalog No.	Description	Qty. Per Kit	Product Code	List Price
SCE-CN1032	10-32 for Rack Angles	20	P2	32.31

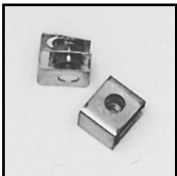

Phone (989) 799-6871
Fax (989) 799-4524

[Back to Accessories](#)