

Straight Blade Devices

30 Ampere, 125, 250 Volts, 277 Volts AC and 125/250 Volts

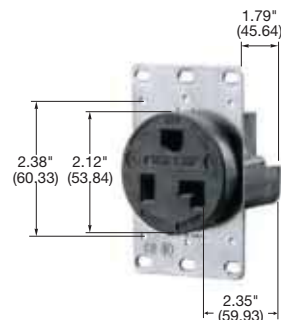
2 Pole, 3 Wire Grounding and 3 Pole, 3 Wire Non-Grounding

Single Receptacles and Plugs

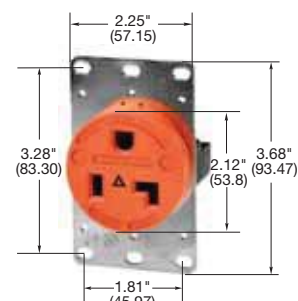
Fed.Spec.

**30A, 125V****2 Pole, 3 Wire Grounding
Receptacles and Plugs****IP20**
SUITABILITY**30A 125V**
NEMA 5-30R
UL CSA
2 HP**30A 125V**
NEMA 5-30P
UL CSA
2 HP

Description	Cord Diameter	Catalog Numbers
Receptacle, black RTP.	—	HBL9308 —
Receptacle, orange, isolated ground. ⁽¹⁾	—	IG9308 —
Plug, nylon, angle, 4-position.	.625"-1.187" (15.9-30.1)	— HBL9309*

**HBL9308****30A, 250V****2 Pole, 3 Wire Grounding
Receptacles and Plugs****IP20**
SUITABILITY**30A 250V**
NEMA 6-30R
UL CSA
2 HP**30A 250V**
NEMA 6-30P
UL CSA
2 HP

Description	Cord Diameter	Catalog Numbers
Receptacle, black RTP.	—	HBL9330 —
Receptacle, orange, isolated ground. ⁽¹⁾	—	IG9330 —
Plug, nylon, angle, 4-position	.625"-1.187" (15.9-30.1)	— HBL9331*

**IG9308****30A, 277V****2 Pole, 3 Wire Grounding
Receptacles and Plugs****IP20**
SUITABILITY**30A 277V AC**
NEMA 7-30R
UL CSA
3 HP**30A 277V AC**
NEMA 7-30P
UL CSA
3 HP

Description	Cord Diameter	Catalog Numbers
Receptacle, black RTP.	—	HBL9315 —
Plug, nylon, angle, 4-position.	.625"-1.187" (15.9-30.1)	— HBL9319*

**30A, 125/250V****3 Pole, 3 Wire Non-Grounding
Receptacles and Plugs****IP20**
SUITABILITY**30A 125/250V**
NEMA 10-30R
UL Listed
2(2) HP**30A 125/250V**
NEMA 10-30P
UL Listed
2(2) HP

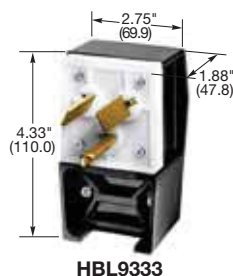
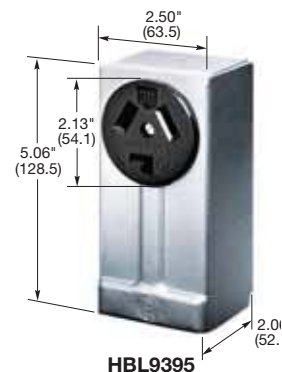
Description	Cord Diameter	Catalog Numbers
Receptacle, black phenolic.	—	HBL9350 —
Receptacle, surface mount aluminum housing.	—	HBL9395 —
Plug, Insulgrip®, nylon.	.625"-1.00" (15.9-25.4)	— HBL9337C
Plug, nylon, angle, 4-position.	.625"-1.187" (15.9-30.1)	— HBL9333

**HBL9331**

Notes: (1) See Section J for complete line of isolated ground devices.

*Not Fed. Spec. Listed.

See page A-46 for accessories.

**HBL9333****HBL9350****HBL9395**