

Outdoor Lampholders

Technical Specifications

Applications :

- Security and general outdoor lighting fixture for residential and commercial applications
- Accent lighting fixture for highlighting outdoor signs and architectural details
- Compact outdoor lighting fixture which can be mounted easily in most places and can be aimed in any direction
- Suitable for use in wet locations.

Features/Benefits :

- Clean lines and precision manufacturing result in a fixture which will enhance any application
- High-quality replaceable porcelain socket with high-temperature leads allow for easy field maintenance
- Positive locking mounting arm keeps fixture in aimed position to reduce costly callbacks
- Ground screw boss in arm


Standard Materials :

- Fixture: Certified die cast zinc alloy ZAMAK 3 (less than 0.004 copper content), or nonmetallic
- Gasket: Heat resistant composition or high-temperature silicone
- Socket: Center contact, porcelain, medium base

Compliances :

Compliances as noted on each page of the catalogue include:

- CSA Certified
- UL Listed
- cUL Listed

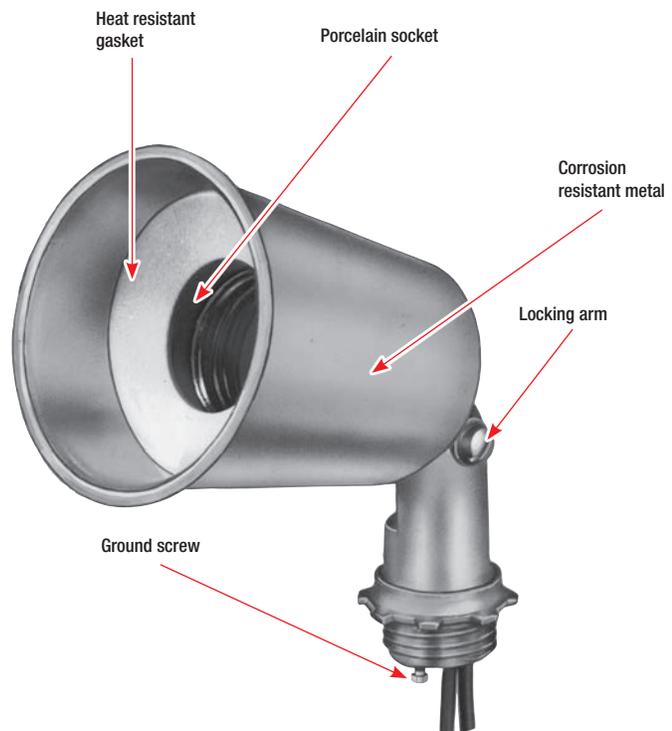

Outdoor Lampholders




S500EG-CN



S513BREG-CN

B228E-R

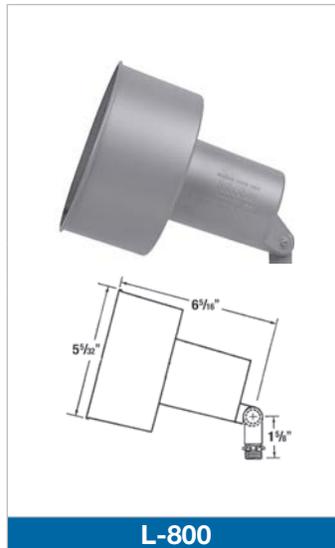

L-800

Cat. No.	Finish	Description
Economy Style – Internal Gasket (zinc)		
S500BREG-CN	Bronze	For 75 to 150 Watt Par 38 and R40 lamps
S500EG-CN	Silver	For 75 to 150 Watt Par 38 and R40 lamps
S500WHEG-CN	White	For 75 to 150 Watt Par 38 and R40 lamps
Deep-Shielded Style – Internal Gasket (zinc)		
L-800	Silver	For 75 to 150 Watt Par 38 and R40 Lamps
Double Economy Style Lampholders with Round Cover (zinc)		
S513EG-CN	Silver	For up to 150 Watt Par 38 and R40 lamps
S513BREG-CN	Bronze	For up to 150 Watt Par 38 and R40 lamps
S513WHEG-CN	White	For up to 150 Watt Par 38 and R40 lamps
Contemporary Lampholders Kit		
B228E-R	Silver	Contemporary lampholder kit
B228BRE-R	Bronze	Contemporary lampholder kit
B228WHE-R	White	Contemporary lampholder kit




SPK6-P-GR

SPK6-P-BK

SPK6-P-BR



Cat. No.	Finish	Description
Spike Light (zinc)		
SPK6-P-GR	Green	Portable lamp, 6-foot cord - Metal
SPK6-P-BK	Black	Portable lamp, 6-foot cord - Metal
SPK6-P-BR	Bronze	Portable lamp, 6-foot cord - Metal

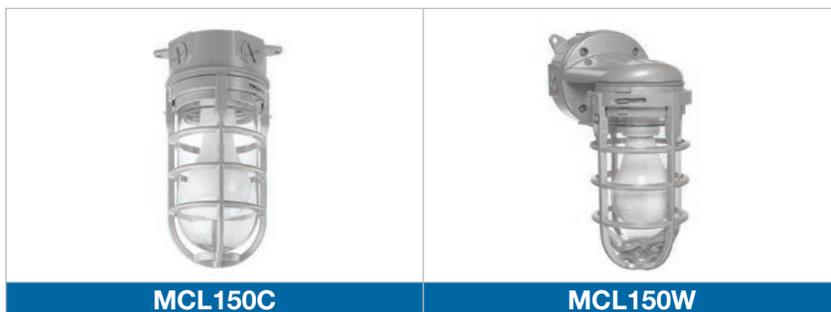

MCL150C

MCL150W



Cat. No.	Hub Size (in.)	Max. Watt	Description
Ceiling Mount (5 holes)			
MCL150C	1	150	Can be surface mounted or mounted to a junction box. Kit includes: Aluminum housing, junction box, globe and guard assembly.
Wallmount (5 holes)			
MCL150W	1	150	Can be surface mounted in a vertical position (globe pointed down only). Kit includes: Aluminum housing, junction box, globe and guard assembly.