


# Light Pipe LED Combo **NEW**

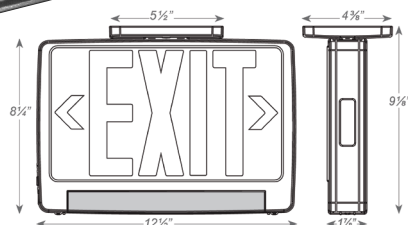

- LED Combo Exit/Emergency Light - Light Bar Design
- Remote Capable - up to 3 Watts - 4.8V remote lamp heads (see Pg 100 for compatible LED Remote Lamp Heads)
- Dual 120/277 voltage
- 4.5W light output - (36 LEDs X .125W per LED) - 184 Lumens
- Chrome Reflector & Acrylic UV Stabilized Lens
- Charge Rate/Power "ON" LED Indicator Light and sealed push-to-test switch for mandated code compliance testing
- 4.8V 900 mAH maintenance-free, rechargeable Ni-Cad battery
- Internal Solid-State Transfer Switch automatically connects the internal battery to LED board for minimum 90-minute emergency illumination
- Fully Automatic Solid-State, Dual-rate Charger initiates battery charging to recharge a discharged battery in 24 hours
- Flame Retardant, UV-stabilized High Impact Housing
- Top and side KD's provided for conduit feed applications
- Operating Temperature 32°F to +122°F
- Meets UL924 for Wet Locations, NFPA 101 Life Safety Code, NEC, OSHA
- Certified to CEC under Title 24 Regulations
- 3 Year Warranty

CAT. NO.	LED COLOR	HOUSING	LUMENS	WIDTH	DEPTH	HEIGHT	CASE QTY	EACH
73372	RED	WHITE	184	12.50"	1.87"	8.25"	6	
73373	GREEN	WHITE	184	12.50"	1.87"	8.25"	6	
<b>SELF DIAGNOSTIC</b>								
73374	RED	WHITE	184	12.50"	1.87"	8.25"	6	

## LED Combo Exit/Emergency Light Indoor Wet Location



- Flame Retardant, UV-stabilized Corrosion & Impact Resistant Polycarbonate Housing with Clear Polycarbonate Cover
- Enclosure Resistant to Corrosive Atmospheres, Non-Hazardous Dust Environment, Hose-Down Water Spray or Splashing Water
- Universal Canopy Mount & 2 Face Plates for Side or Top Installation
- Universal KD Pattern on Back Plate for Wall Mount
- Engineering Grade Rubber Gasketing
- Top and Side KD's provided for conduit feed applications
- EZ Snap-Out Chevron Directional Indicators
- NiCad or Ni-MH battery Backup
- Operating Temperature: 0°F to +104°F
- Input Voltage: 120/277
- Meets UL924 for Wet Locations, NFPA 101 Life Safety Code, NEC & OSHA Codes
- 3 Year Warranty
- See Pg 100 for remote lamp heads

Models 73454/73055 & 73458/73459 - Remote Capability for up to 2 Additional LED Remote Lamp Heads. See Cat Pg 100

- 2 heads - 3 hours operation (Base Unit)
- 3 heads - 2 hours operation (Base Unit + 1 Head)
- 4 heads - 1.5 hours operation (Base Unit + 2 Heads)

CAT. NO.	LED COLOR	BATTERY	LENGTH	DEPTH	HEIGHT	CASE QTY	EACH
<b>STANDARD EXIT SIGN</b>							
73452	RED	2.4V 500MAH NI-CD	12-5/8"	2-1/2"	8-1/8"	4	
73453	GREEN	2.4V 500MAH NI-CD	12-5/8"	2-1/2"	8-1/8"	4	
<b>REMOTE CAPABLE EXIT SIGN</b>							
73454	RED	3.6V 1800MAH NI-MH	12-5/8"	2-1/2"	8-1/8"	4	
73455	GREEN	3.6V 1800MAH NI-MH	12-5/8"	2-1/2"	8-1/8"	4	
<b>STANDARD COMBO HIGH OUTPUT</b>							
73456	RED	3.6V 1000MAH NI-CD	12-9/16"	2-1/2"	13-5/16"	4	
73457	GREEN	3.6V 1000MAH NI-CD	12-9/16"	2-1/2"	13-5/16"	4	
<b>REMOTE CAPABLE COMBO HIGH OUTPUT</b>							
73458	RED	3.6V 1800MAH NI-MH	12-9/16"	2-1/2"	13-5/16"	4	
73459	GREEN	3.6V 1800MAH NI-MH	12-9/16"	2-1/2"	13-5/16"	4	