



Features

- Line voltage - no drivers needed
- Interconnectable kits (3000K Warm White and 6400K Cool White) or custom cut lengths (2100K Ultra Warm White, 3000K Warm White, and 6400K Cool White)
- LED Flexbrite consumes only 1 watt per foot
- Dimmable 5-100%*
- UL Listed† for indoor and outdoor use
- 60,000 hours rated life

Available Colors



2100K 3000K 6400K

Dimming Options

- ELV (5-100%*)
- LED (5-100%*)
- CL (5-100%*)

Listing / Ratings†



LED Flexbrite Kits / Custom Cut

Easy to use flexible, dimmable, and economical LED rope light has UV inhibitor built into the PVC housing for use outdoors. Save 73% in running costs compared to incandescent rope light. LED Flexbrite last up to three times as long as incandescent rope. Choose from interconnectable UL Listed kits or 150ft reels (UL listing is void if reel is cut).


Technical Information

Series	LR-LED (Kits) / ULR-LED (custom cut)
Input Voltage	120V AC, 60Hz
CCT	2100K (UWW) / 3000K (WW) / 6400K (WH)
CRI	67+ (UWW) / 72+ (WW) / 75+ (WH)
Wattage	1W per ft
Lumens	See individual product
Max Run	192 feet (kits) / 150 feet (custom cut)
Cuttable	N/A†
IP Rating	IP65** (uncut), void if cut
Dimmable	5-100%*
Rating	UL Listed† for indoor/outdoor use
Rated Life	60,000 hrs

*Minimum loads may apply. Per the NEC, switched wall outlets cannot be used with wall dimmers.

**IP65 rated only when used with pre-attached molded power cord and end cap is either pre-attached or properly sealed with dielectric grease, silicone and shrink tube

†UL Listing is void if product is cut

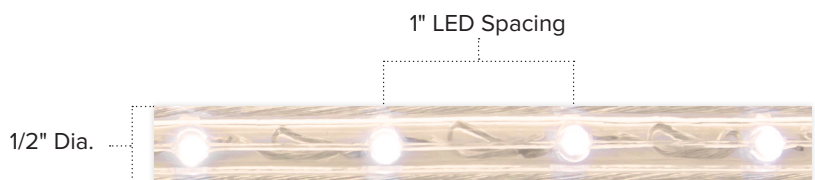

LED Flexbrite Kits



Warm White Kits

120V / 3000K / 72CRI / 32Lm/ft / 1/2" Diameter

LR-LED-WW-3 (3ft / 3W)

LR-LED-WW-9 (9ft / 9W)

LR-LED-WW-15 (15ft / 15W)

LR-LED-WW-30 (30ft / 30W)

LR-LED-WW-75 (75ft / 75W)



Cool White Kits

120V / 6400K / 75CRI / 34Lm/ft / 1/2" Diameter

LR-LED-CW-3 (3ft / 3W)

LR-LED-CW-9 (9ft / 9W)

LR-LED-CW-15 (15ft / 15W)

LR-LED-CW-30 (30ft / 30W)

LR-LED-CW-75 (75ft / 75W)

120V Kits Include: (1) Removable 5ft power cord with 1.6A inverter, (1) removable end cap, and (1) mounting clip per foot of rope

LED Flexbrite Custom Cut

Ultra Warm White Custom Cut

120V / 2100K / 67+ CRI / 30Lm/ft / 1/2" Dia.

ULRL-LED-UWW (36" increments)

ULRL-CONKIT-LED SHELL

(Required for custom cut lengths)

120V UL2388 compliant power connection: (1) 5ft cord with 1.6A inverter with fused plug and end cap

Warm White Custom Cut

120V / 3000K / 72+ CRI / 32Lm/ft / 1/2" Dia.

ULRL-LED-WW (36" increments)

ULRL-CONKIT-LED SHELL

(Required for custom cut lengths)

120V UL2388 compliant power connection: (1) 5ft cord with 1.6A inverter with fused plug and end cap

Cool White Custom Cut

120V / 6400K / 75+ CRI / 34Lm/ft / 1/2" Dia.

ULRL-LED-CW (36" increments)

ULRL-CONKIT-LED SHELL

(Required for custom cut lengths)

120V UL2388 compliant power connection: (1) 5ft cord with 1.6A inverter with fused plug and end cap

Custom Cut: Please allow up to 1 week for custom cut order processing and delivery

LED Flexbrite Accessories



Linking Cable
Jumper for LED Flexbrite Kits
Interconnectable

LR-LED-EXT3 (3ft)



Mounting Track
Clear plastic

RL-TRK-3 (3ft / Case of 40)

RL-TRACK-4 (4ft)



Mounting Clips
Clear plastic

RL-CLIP/SCREW

(10) Clips with (20) Screws

LR-CLIP-20

(20) Clips with (40) Screws