 



30SBAT Super Trim™ AIR-TITE™ Reflector



HOUSING / LAMP:
H7RT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, 150W A21
H7T: 50W PAR30, 75W PAR30, 100W R30, 85W BR30, 150W R40, 120W BR40, 100W A19, 150W PAR38, 150W A21
H7TNB: 50W PAR30, 75W PAR30, 100W R30, 85W BR30, 150W R40, 120W BR40, 100W A19, 150W PAR38, 150W A21
H7TCP: 50W PAR30, 75W PAR30, 100W R30, 85W BR30, 150W R40, 120W BR40, 100W A19, 150W PAR38, 150W A21

DIMENSIONS: Height: 5" [127mm]; OD: 7-1/4" [184mm]

 
30 Super Trim™ AIR-TITE™ Reflector



HOUSING / LAMP:
H7RT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, 150W A21
H7T: 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 100W A19
H7TNB: 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 100W A19
H7TCP: 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 100W A19

DIMENSIONS: Height: 5" [127mm]; OD: 7-1/4" [184mm]

 405 Specular Reflector



HOUSING / LAMP:
H7RT: 150W A21
H7T: 150W A21
H7TNB: 150W A21
H7TCP: 150W A21

DIMENSIONS: Height: 6" [152mm]; OD: 7-1/4" [184mm]


4051 Self Flanged White Reflector



HOUSING / LAMP:
H7RT: 150W A21
H7T: 150W A21
H7TNB: 150W A21
H7TCP: 150W A21

DIMENSIONS: Height: 6" [152mm]; OD: 7-1/4" [184mm]


429 Dayform White Cone

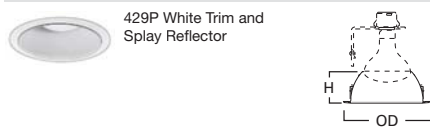

HOUSING / LAMP:
H7RT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L
H7T: 65W BR30, 75W R30
H7TCP: 65W BR30, 75W R30

DIMENSIONS: Height: 3" [76mm]; OD: 7-1/4" [184mm]

4261 Self Flange White Reflector Cone

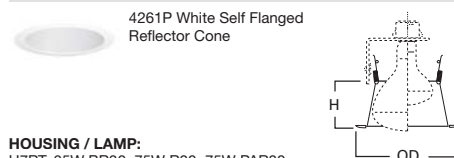

HOUSING / LAMP:
H7RT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 120W BR40, 150W R40
H7T: 65W BR30, 75W R30, 75W PAR30, 120W BR40, 150W R40, 150W PAR38
H7TCP: 65W BR30, 75W R30, 75W PAR30, 120W BR40, 150W R40, 150W PAR38

DIMENSIONS: Height: 2-5/8" [67mm]; OD: 7-1/4" [184mm]

426 Reflector Cone



HOUSING / LAMP:
H7RT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 120W BR40, 150W R40
H7T: 65W BR30, 75W R30, 75W PAR30, 120W BR40, 150W R40, 150W PAR38
H7TCP: 65W BR30, 75W R30, 75W PAR30, 120W BR40, 150W R40, 150W PAR38

DIMENSIONS: Height: 2-11/16" [68mm]; OD: 7-1/4" [184mm]


30 Super Trim™ AIR-TITE™ Baffle



HOUSING / LAMP:
H7RT: 50W PAR30, 50W PAR30L, 100W R30, 85W BR30, 100W A19, 150W PAR38
H7T: 100W R30, 150W PAR38, 75W PAR30, 75W PAR30L, 85W BR30, 100W A19
H7TNB: 100W R30, 150W PAR38, 75W PAR30, 75W PAR30L, 85W BR30, 100W A19
H7TCP: 100W R30, 150W PAR38, 75W PAR30, 75W PAR30L, 85W BR30, 100W A19

DIMENSIONS: Height: 5" [127mm]; OD: 7-1/4" [184mm]

310 Coilex® Baffle

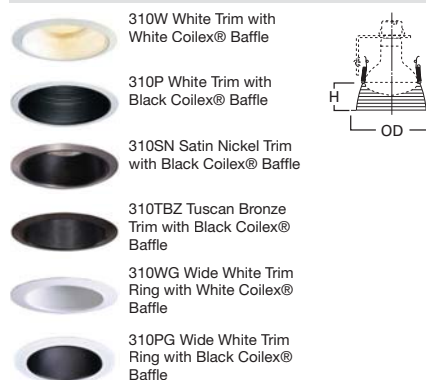

HOUSING / LAMP:
H7RT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L
H7T: 65W BR30, 75W R30, 75W PAR30
H7TCP: 65W BR30, 75W R30, 75W PAR30

DIMENSIONS: 310W, P, SN, TBZ
H: 3-1/16" [78mm]
OD: 7-1/4" [184mm]
310WG, PG
H: 3-1/16" [78mm]
OD: 8" [203mm]

405 Specular Reflector



405SC White Trim with Clear Specular Reflector



 
405H White Trim with Haze Reflector



405RG White Trim with Residential Gold Reflector



405CG White Trim with Champagne Gold Reflector



HOUSING / LAMP:

 
H274E: 13W TTT or 13W DTT
H276E: 13W TTT or 13W DTT

DIMENSIONS: Height: 6" [152mm]; OD: 7-1/4" [184mm]

4051 Self Flanged White Reflector



4051P White Self Flanged Reflector



HOUSING / LAMP:

H274E: 13W TTT or 13W DTT
H276E: 13W TTT or 13W DTT

DIMENSIONS: Height: 6" [152mm]; OD: 7-1/4" [184mm]

406 Baffle




406WWB White Baffle with White Reflector and Torsion Springs



406WB White Baffle with Clear Specular Reflector and Torsion Springs



406BA Black Baffle with Clear Specular Reflector and Torsion Springs

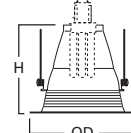

HOUSING / LAMP:

H274E: 13W TTT or 13W DTT
H276E: 13W TTT or 13W DTT

DIMENSIONS: Height: 6" [152mm]; OD: 7-3/4" [184mm]

 
70 Albalite Glass Lens



70P White Trim with Frosted Albalite Glass Lens



70PS White Trim with Frosted Albalite Glass Lens, Wet Location Listed



HOUSING / LAMP:

H274E: 13W TTT or 13W DTT
H276E: 13W TTT or 13W DTT

DIMENSIONS: OD: 8" [203mm]

 
71 Drop Opal Lens



71P White Trim with Drop Opal Glass Lens



71PS White Trim with Drop Opal Glass Lens, Wet Location Listed



HOUSING / LAMP:

H274E: 13W TTT or 13W DTT
H276E: 13W TTT or 13W DTT

DIMENSIONS: OD: 8" [203mm]

 
73 Fresnel Glass Lens



73P White Trim with Fresnel Glass Lens



73PS White Trim with Fresnel Glass Lens, Wet Location Listed



HOUSING / LAMP:


H274E: 13W TTT or 13W DTT
H276E: 13W TTT or 13W DTT

DIMENSIONS: OD: 8" [203mm]

270 Albalite Glass Lens with Reflector



270PS White Trim with Frosted Albalite Glass Lens, Wet Location Listed

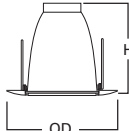

HOUSING / LAMP:


H274E: 13W TTT or 13W DTT
H276E: 13W TTT or 13W DTT

DIMENSIONS: Height: 6-5/8" [168mm]; OD: 8" [203mm]

271 Drop Opal Lens



271PS White Trim with Drop Opal Glass Lens, Wet Location Listed

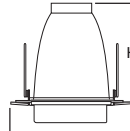

HOUSING / LAMP:


H274E: 13W TTT or 13W DTT
H276E: 13W TTT or 13W DTT

DIMENSIONS: Height: 6-1/2" [165mm]; OD: 8" [203mm]

272 Dome Lens with Reflectors



272PS White Trim with Frosted Glass Dome, Wet Location Listed

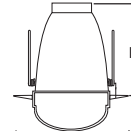

HOUSING / LAMP:

H274E: 13W TTT or 13W DTT
H276E: 13W TTT or 13W DTT

DIMENSIONS: Height: 5-1/2" [140mm]; OD: 7-3/4" [197mm]